


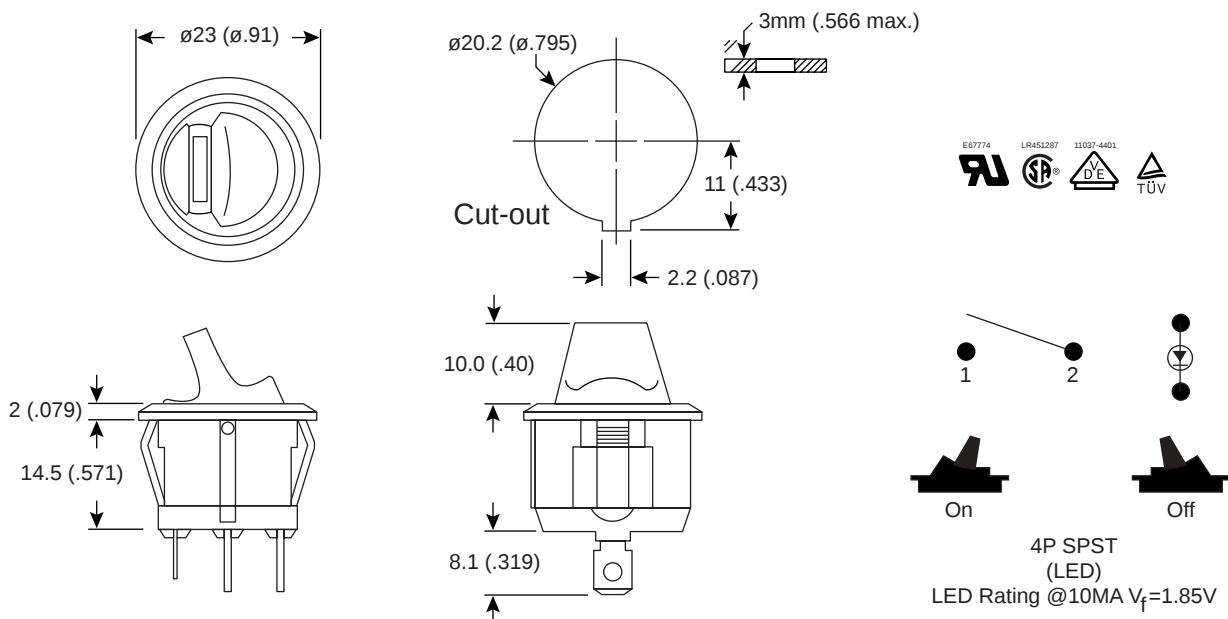

Dimensions mm (In.)

MOUSER STOCK NO.	Color
103-R13-112LP-02R	Red
103-R13-112LP-02Y	Yellow
103-R13-112LP-02G	Green

Specifications:

- Rating: 10A 125 VAC, 6A 250 VAC
- Contact resistance: 50mΩ max.
- Insulation resistance: DC 500V 100MΩ min.
- Dielectric strength: AC 1500V 1minute

Features:

- Material: Frames are nylon (UL flame: 94V-2). Terminals are silver plated brass.
- Illuminated actuators are molded in PC, available with red, yellow, and green color.
- Snap-in mounting, easy to install switch into panel