


CENTRAL Diodes

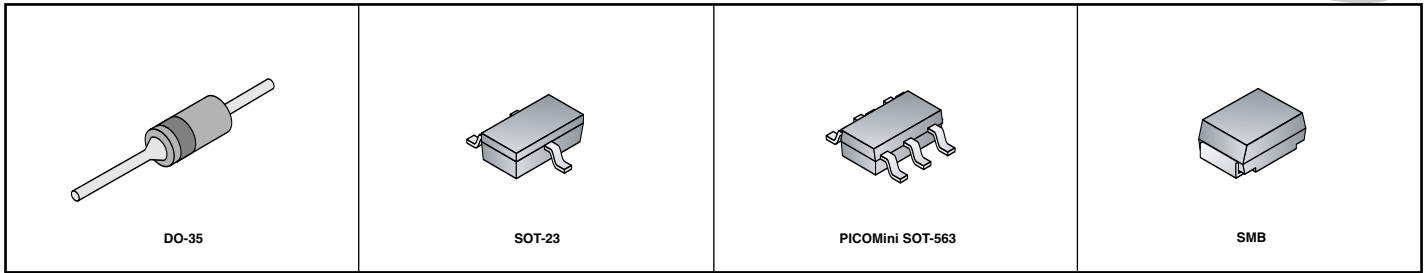

◆ Surface Mount Device

DIODES

For quantities of 2000 and up, call for quote.

MOUSER STOCK NO.	Central Part No.	Package	Description	Price Each			
				1	100	500	1000
Switching Diodes							
610-1N3600	1N3600	DO-35	Signal Diode	.12	.05	.05	.05
610-1N4152	1N4152	DO-35	Sili Sig Diode	.14	.12	.11	.10
610-1N914	1N914	DO-35	Sili Sig Diode	.06	.05	.04	.03
◆610-CMOD2004	CMOD2004	SOD-523	High Voltage	.25	.20	.17	.13
◆610-CMPD2004	CMPD2004	SOT-23	High Voltage Diode	.55	.45	.43	.39
◆610-CMPD4448	CMPD4448	SOT-23	SW Diode	.25	.19	.14	.09
◆610-CMPD914	CMPD914	SOT-23	Single Switch	.18	.14	.12	.09
◆610-CMKD7000	CMKD7000	SOT-363	100V, 200mA	.33	.27	.22	.17
◆610-CMSD7000	CMSD7000	SOT-323	100V, 200mA	.27	.20	.17	.14
◆610-CMPD6001A	CMPD6001A	SOT-23	100V, 250mA	.38	.28	.24	.19
◆610-CMPD6001C	CMPD6001C	SOT-23	100V, 250mA	.38	.28	.24	.19
◆610-CMLD6001	CMLD6001	SOT-563	100V, 250mA	.42	.35	.29	.26
◆610-CMLD6001DO	CMLD6001DO	SOT-563	100V, 250mA	.48	.40	.33	.30
◆610-CMPD6001S	CMPD6001S	SOT-23	100V, 250mA	.38	.28	.24	.19
◆610-CMOD4448	CMOD4448	SOD-523	100V, 250mA	.17	.14	.11	.09
◆610-CMOD6001	CMOD6001	SOD-523	100V, 250mA	.22	.18	.14	.12
◆610-CMPD6001	CMPD6001	SOT-23	100V, 250mA	.38	.28	.24	.19
◆610-CMXD4448	CMXD4448	SOT-26	100V, 250mA	.33	.24	.20	.17
◆610-CMKD6001	CMKD6001	SOT-363	100V, 250mA	.33	.27	.22	.17
◆610-CMXD6001	CMXD6001	SOT-26	100V, 250mA	.40	.29	.25	.20
◆610-CLL914	CLL914-TR	SOD-80	100V 1A	.20	.15	.12	.08
◆610-CMPD2836E	CMPD2836E	SOT-23	120V, 200mA	.13	.11	.09	.07
◆610-CMPD2838E	CMPD2838E	SOT-23	120V, 200mA	.13	.11	.09	.07
◆610-CMPD7000E	CMPD7000E	SOT-23	120V, 200mA	.13	.11	.09	.07
◆610-CMLD4448DO	CMLD4448DO	SOT-563	120V, 250mA	.39	.32	.25	.21
◆610-CMLD4448	CMLD4448	SOT-563	120V, 250mA	.39	.32	.25	.21
◆610-CMPD914E	CMPD914E	SOT-23	120V, 250mA	.10	.08	.07	.06
◆610-CMHD3595	CMHD3595	SOD-123	150V, 225mA	.44	.32	.27	.22
◆610-CMPD3003A	CMPD3003A	SOT-23	180V, 200mA	.30	.25	.21	.19
◆610-CMPD3003C	CMPD3003C	SOT-23	180V, 200mA	.30	.25	.21	.19
◆610-CMPD3003S	CMPD3003S	SOT-23	180V, 200mA	.30	.25	.21	.19
◆610-CMPD3003	CMPD3003	SOT-23	180V, 200mA	.35	.25	.21	.18
◆610-CMSD2004S	CMSD2004S	SOT-323	300V, 200mA	.53	.38	.32	.27
◆610-CMXD2004	CMXD2004	SOT-26	300V, 200mA	.44	.32	.27	.22
◆610-CMXD2004TO	CMXD2004TO	SOT-26	300V, 200mA	.48	.40	.33	.30
◆610-CMLD2004A	CMLD2004A	SOT-563	300V, 225mA	.52	.43	.35	.28
◆610-CMLD2004C	CMLD2004C	SOT-563	300V, 225mA	.52	.43	.35	.28
◆610-CMLD2004DO	CMLD2004DO	SOT-563	300V, 225mA	.52	.43	.35	.28
◆610-CMLD2004S	CMLD2004S	SOT-563	300V, 225mA	.52	.43	.35	.28
◆610-CMPD2004S	CMPD2004S	SOT-23	300V, 225mA	.63	.63	.25	.23
◆610-CMOD2004	CMOD2004	SOT-563	300V, 225mA	.25	.20	.17	.13
◆610-CMLD2004	CMLD2004	SOT-563	300V, 225mA	.46	.38	.31	.24
◆610-CMPD2005S	CMPD2005S	SOT-23	350V, 225mA	.41	.34	.27	.22
◆610-CMKD2836	CMKD2836	SOT-363	75V, 200mA	.33	.27	.22	.17
◆610-CMSD2836	CMSD2836	SOT-323	75V, 200mA	.27	.20	.17	.14
◆610-CMKD2838	CMKD2838	SOT-363	75V, 200mA	.33	.27	.22	.17
◆610-CMSD2838	CMSD2838	SOT-323	75V, 200mA	.27	.20	.17	.14
◆610-CMEDA-6I	CMEDA-6I	SOT-28	Array 60V, 250mA	1.14	.93	.76	.60
Current Limiting Diode							
610-1N5283	1N5283	DO-35	.22mA Curr Reg	4.61	4.32	4.09	4.03
610-1N5284	1N5284	DO-35	.24mA Curr Reg	4.29	3.86	3.48	3.13
610-1N5285	1N5285	DO-35	.27mA Curr Reg	2.35	2.16	1.97	1.60
610-1N5286	1N5286	DO-35	.30mA Curr Reg	2.35	2.16	1.97	1.60
610-1N5287	1N5287	DO-35	.33mA Curr Reg	2.35	2.16	1.97	1.60
610-1N5288	1N5288	DO-35	.39mA Curr Reg	2.35	2.16	1.97	1.60
610-1N5289	1N5289	DO-35	.43mA Curr Reg	2.35	2.16	1.97	1.60
610-1N5290	1N5290	DO-35	.47mA Curr Reg	4.29	3.86	3.48	3.13
610-1N5291	1N5291	DO-35	.56mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5292	1N5292	DO-35	.62mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5293	1N5293	DO-35	.68mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5294	1N5294	DO-35	.75mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5295	1N5295	DO-35	.82mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5296	1N5296	DO-35	.91mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5297	1N5297	DO-35	1.0mA Curr Reg	4.29	3.86	3.48	3.13
610-1N5298	1N5298	DO-35	1.1mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5299	1N5299	DO-35	1.2mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5301	1N5301	DO-35	1.4mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5302	1N5302	DO-35	1.5mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5303	1N5303	DO-35	1.6mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5304	1N5304	DO-35	1.8mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5305	1N5305	DO-35	2.0mA Curr Reg	4.29	3.86	3.48	3.13
610-1N5306	1N5306	DO-35	2.2mA Curr Reg	1.78	1.63	1.49	1.21

DIODES (CONT.)

For quantities of 2000 and up, call for quote.

MOUSER STOCK NO.	Central Part No.	Package	Description	Price Each			
				1	100	500	1000
Current Limiting Diode (Cont.)							
610-1N5307	1N5307	DO-35	2.4mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5308	1N5308	DO-35	2.7mA Curr Reg	1.78	1.63	1.49	1.21
610-1N5309	1N5309	DO-35	3.0mA Curr Reg	4.29	3.86	3.48	3.13
610-1N5310	1N5310	DO-35	3.3mA Curr Reg	2.35	2.16	1.97	1.60
610-1N5311	1N5311	DO-35	3.6mA Curr Reg	2.35	2.16	1.97	1.60
610-1N5312	1N5312	DO-35	3.9mA Curr Reg	2.35	2.16	1.97	1.60
610-1N5313	1N5313	DO-35	4.3mA Curr Reg	2.35	2.16	1.97	1.60
610-1N5314	1N5314	DO-35	4.7mA Curr Reg	4.29	3.86	3.48	3.13
Schottky Diode							
◆610-CMSH120	CMSH1-20	SMB	1A 20V	.67	.47	.33	.29
610-CDSH270	CDSH270A	DO-35	100V 100mA Rec	.35	.28	.25	.23
◆610-CMOSH-3	CMOSH3	SOD-523	30V 100mA	.30	.24	.20	.16
◆610-CMPSH-3C	CMPSH-3C	SOT-23	Dual Cl Cathode	.42	.36	.32	.29
◆610-CMLD6263A	CMLD6263A	SOT-563	Pair Common Anode	.99	.89	.79	.69
◆610-CMLD6263C	CMLD6263C	SOT-563	Pair Common Cathode	.99	.89	.79	.69
◆610-CMLD6263S	CMLD6263S	SOT-563	Dual Pair In Series	.99	.89	.79	.69
◆610-CMLD6263DO	CMLD6263DO	SOT-563	Dual Opposing	.99	.89	.79	.69
◆610-CMLD6263	CMLD6263	SOT-563	Single	.89	.80	.71	.62
◆610-CMHS5-2L	CMHS5-2L	SOD-123	20V, 500mA	.24	.20	.16	.13
◆610-CMPSH-3AE	CMPSH-3AE	SOT-23	30V, 100mA	.52	.44	.36	.28
◆610-CMSSH-3A	CMSSH-3A	SOT-323	30V, 100mA	.40	.29	.25	.20
◆610-CMPSH-3CE	CMPSH-3CE	SOT-23	30V, 100mA	.26	.22	.18	.14
◆610-CMSSH-3C	CMSSH-3C	SOT-323	30V, 100mA	.40	.29	.25	.20
◆610-CMKSH-3DO	CMKSH-3DO	SOT-363	30V, 100mA	.33	.27	.22	.17
◆610-CMPSH-3SE	CMPSH-3SE	SOT-23	30V, 100mA	.26	.22	.18	.14
◆610-CMSSH-3S	CMSSH-3S	SOT-323	30V, 100mA	.40	.29	.25	.20
◆610-CMOSH-3	CMOSH-3	SOD-523	30V, 100mA	.30	.24	.20	.16
◆610-CMPSH-3E	CMPSH-3E	SOT-23	30V, 100mA	.20	.16	.13	.11
◆610-CMSSH-3	CMSSH-3	SOT-323	30V, 100mA	.36	.26	.22	.18
◆610-CMKSH-3T	CMKSH-3T	SOT-363	30V, 100mA	.33	.27	.22	.17
◆610-CMXSH-3	CMXSH-3	SOT-26	30V, 100mA	.40	.29	.25	.20
◆610-CMOSH-4E	CMOSH-4E	SOD-523	40V, 200mA	.20	.16	.13	.11
◆610-CMHS5-4	CMHS5-4	SOD-123	40V, 500mA	.24	.20	.16	.13
◆610-CZSH5-40	CZSH5-40	SOT-223	40V, 500mA	.65	.53	.43	.34
◆610-CMPD6263A	CMPD6263A	SOT-23	70V, 15mA	.33	.27	.22	.17
◆610-CMSD6263A	CMSD6263A	SOT-323	70V, 15mA	.39	.32	.26	.21
◆610-CMPD6263C	CMPD6263C	SOT-23	70V, 15mA	.33	.27	.22	.17
◆610-CMSD6263C	CMSD6263C	SOT-323	70V, 15mA	.39	.32	.26	.21
◆610-CMKD6263DO	CMKD6263DO	SOT-363	70V, 15mA	.33	.27	.22	.17
◆610-CMPD6263S	CMPD6263S	SOT-23	70V, 15mA	.33	.27	.22	.17
◆610-CMSD6263S	CMSD6263S	SOT-323	70V, 15mA	.39	.32	.26	.21
◆610-CMOD6263	CMOD6263	SOD-523	70V, 15mA	.26	.22	.18	.14
◆610-CMOD6263	CMOD6263	SOD-523	70V, 15mA	.30	.24	.20	.16
◆610-CMPD6263	CMPD6263	SOT-23	70V, 15mA	.66	.59	.55	.53
◆610-CMSD6263	CMSD6263	SOT-323	70V, 15mA	.33	.27	.22	.17
◆610-CMKD6263	CMKD6263	SOT-363	70V, 15mA	.36	.30	.24	.19
Zener Diode							
610-1N746A	1N746A	DO-35	3.3V .5W	.18	.14	.10	.08
610-1N747A	1N747A	DO-35	3.6V .5W	.18	.14	.10	.08
610-1N748A	1N748A	DO-35	3.9V .5W	.18	.14	.10	.08
610-1N749A	1N749A	DO-35	4.3V .5W	.18	.14	.10	.08
610-1N750A	1N750A						