



SIMPSON Analog Panel Meters

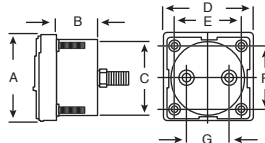

Simpson ANALOG PANEL METERS

- Features:**
- Clear, acrylic window for wide angle visibility
 - Rugged black phenolic case
 - Black spade pointer for easy distant viewing
 - Additional ranges available

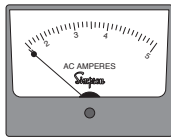

Meter Size	Dimensions In Inches						
	A	B	C	D	E	F	G
1-1/2"	1.76	0.86	1.50	1.75	1.31	1.31	1.00
2-1/2"	2.47	1.15	2.17	2.47	1.88	1.88	1.00
3-1/2"	3.25	1.22	2.73	3.25	2.25	2.25	1.50
4-1/2"	4.00	1.20	2.75	4.68	4.00	3.56	1.50

Wide-View Series



For quantities of 50 or more, call for quote.

Size	1-1/2"				2-1/2"				3-1/2"				4-1/2"				
	Range	MOUSER STOCK NO.	Simpson Part No.	Price Each		MOUSER STOCK NO.	Simpson Part No.	Price Each		MOUSER STOCK NO.	Simpson Part No.	Price Each		MOUSER STOCK NO.	Simpson Part No.	Price Each	
				1	10			1	10			1	10			1	10
AC Voltmeter With Iron Vane Movement																	
0-10	-----	-----	-	-	529-09670	09670	72.35	68.73	529-10170	10170	74.85	71.11	529-10270	10270	82.30	78.19	
0-25	-----	-----	-	-	529-09680	09680	72.35	68.73	529-10190	10190	74.85	71.11	529-10290	10290	82.30	78.19	
0-150	-----	-----	-	-	529-09700	09700	72.35	68.73	529-10220	10220	77.40	73.53	529-10320	10320	82.30	78.19	
0-300	-----	-----	-	-	529-09710	09710	72.35	68.73	529-10240	10240	77.40	73.53	529-10340	10340	82.30	78.19	
0-500	-----	-----	-	-	529-09715	09715	94.10	89.40	529-10250	10250	97.85	92.96	529-10350	10350	104.60	99.37	
AC Ammeters With Iron Vane Movement																	
0-1	-----	-----	-	-	529-02560	02560	66.65	63.32	529-03130	03130	70.65	67.12	529-03260	03260	74.55	70.82	
0-3	-----	-----	-	-	529-02575	02575	66.65	63.32	529-03160	03160	70.65	67.12	529-03290	03290	74.55	70.82	
0-5	-----	-----	-	-	529-02580	02580	66.65	63.32	529-03170	03170	70.65	67.12	529-03300	03300	74.55	70.82	
0-10	-----	-----	-	-	529-02590	02590	66.65	63.32	529-03180	03180	70.65	67.12	529-03310	03310	74.55	70.82	
0-10	-----	-----	-	-	-----	-----	-	-	529-35073	35073	70.65	67.12	529-35077	35077	74.55	70.82	
0-15	-----	-----	-	-	529-02599	02599	66.65	63.32	529-03190	03190	70.65	67.12	529-03320	03320	74.55	70.82	
0-25	-----	-----	-	-	529-02609	02609	69.00	65.55	529-03200	03200	72.85	69.21	529-03330	03330	76.75	72.91	
0-30	-----	-----	-	-	529-02615	02615	69.00	65.55	529-03205	03205	72.85	69.21	529-03335	03335	76.75	72.91	
0-50	-----	-----	-	-	529-02619	02619	69.00	65.55	529-35075	35075	70.65	67.12	529-35079	35079	74.55	70.82	
0-100	-----	-----	-	-	529-02622	02622	66.65	63.32	529-03220	03220	70.65	67.12	529-03350	03350	74.55	70.82	
0-200	-----	-----	-	-	529-02626	02626	66.65	63.32	529-03240	03240	70.65	67.12	529-03370	03370	74.55	70.82	
0-300	-----	-----	-	-	529-02627	02627	66.65	63.32	529-03250	03250	70.65	67.12	529-03380	03380	74.55	70.82	
DC Voltmeters																	
0-10	529-09541	09541	76.25	72.44	529-09560	09560	76.25	72.44	529-09740	09740	77.10	73.25	529-09890	09890	83.35	79.18	
0-15	529-09542	09542	76.25	72.44	529-09570	09570	76.25	72.44	529-09750	09750	77.10	73.25	529-09900	09900	83.35	79.18	
0-25	529-09543	09543	76.25	72.44	529-09580	09580	76.25	72.44	529-09760	09760	77.10	73.25	529-09910	09910	83.35	79.18	
0-30	529-09544	09544	76.25	72.44	529-09590	09590	76.25	72.44	529-09770	09770	77.10	73.25	529-09920	09920	83.35	79.18	
0-50	529-09545	09545	76.25	72.44	529-09600	09600	76.25	72.44	529-09780	09780	77.10	73.25	529-09930	09930	83.35	79.18	
0-100	529-09546	09546	76.25	72.44	529-09610	09610	76.25	72.44	529-09790	09790	77.10	73.25	529-09940	09940	83.35	79.18	
0-150	529-09547	09547	76.25	72.44	529-09620	09620	76.25	72.44	529-09800	09800	77.10	73.25	529-09950	09950	83.35	79.18	
0-500	529-09549	09549	87.89	83.49	529-09640	09640	78.45	74.53	529-09840	09840	81.25	77.19	529-09990	09990	87.05	82.69	
Taut Band DC Microammeters																	
0-10	-----	-----	-	-	529-04303	04303	144.15	136.94	529-04359	04359	150.75	143.21	529-04459	04459	161.40	153.33	
0-25	529-04602	04602	122.43	116.31	529-04306	04306	125.48	119.20	529-04371	04371	131.55	124.97	529-04471	04471	142.50	135.38	
0-100	529-04604	04604	87.05	82.69	529-04321	04321	90.20	85.69	529-04391	04391	93.25	88.59	529-04491	04491	102.70	97.57	
DC Microammeters																	
0-50	529-04294	04294	91.85	87.26	529-04310	04310	91.25	86.68	529-04380	04380	92.90	88.26	529-04480	04480	100.15	95.14	
0-100	529-04295	04295	81.48	77.41	529-04320	04320	82.64	78.50	529-04390	04390	85.15	80.89	529-04490	04490	94.60	89.87	
0-200	529-04296	04296	75.18	71.42	529-04330	04330	74.85	71.11	529-04400	04400	78.45	74.53	529-04500	04500	85.15	80.89	
25-0-25	529-04298	04298	91.85	87.26	-----	-----	-	-	529-04420	04420	94.10	89.40	529-04520	04520	101.00	95.95	
50-0-50	529-04302	04302	81.48	77.41	529-04350	04350	83.48	79.30	529-04430	04430	85.65	81.37	529-04530	04530	95.45	90.67	
100-0-100	529-04300	04300	75.18	71.42	529-04351	04351	76.25	72.44	529-04440	04440	79.07	75.11	529-04540	04540	85.65	81.37	
DC Milliameters																	
0-1	529-06163	06163	70.05	66.55	529-06175	06175	71.80	68.21	529-06310	06310	72.85	69.21	529-06470	06470	78.45	74.53	
0-5	529-06164	06164	70.05	66.55	529-06190	06190	71.80	68.21	529-06330	06330	72.85	69.21	529-06490	06490	78.45	74.53	
0-15	529-06166	06166	70.05	66.55	529-06210	06210	71.80	68.21	529-06350	06350	72.85	69.21	529-06502	06502	78.45	74.53	
0-25	529-06167	06167	73.40	69.73	529-06220	06220	72.35	68.73	529-06370	06370	76.25	72.44	529-06530	06530	81.80	77.71	
0-50	529-06168	06168	73.40	69.73	529-06230	06230	72.35	68.73	529-06380	06380	76.25	72.44	529-06540	06540	81.80	77.71	
0-100	529-06169	06169	73.40	69.73	529-06240	06240	72.35	68.73	529-06390	06390	76.25	72.44	529-06550	06550	81.80	77.71	
0-200	529-06171	06171	73.40	69.73	529-06260	06260	72.35	68.73	529-06410	06410	76.25	72.44	529-06570	06570	81.80	77.71	
0-300	529-06173	06173	73.40	69.73	529-06280	06280	72.35	68.73	529-06430	06430	76.25	72.44	529-06590	06590	81.80	77.71	
0-500	529-06174	06174	73.40	69.73	529-06290	06290	72.35	68.73	529-06440	06440	76.25	72.44	529-06600	06600	81.80	77.71	
DC Ammeters																	
0-1	529-02431	02431	73.40	69.73	529-02440	02440	72.35	68.73	529-02640	02640	76.25	72.44	529-02820	02820	82.30	78.19	
0-2	529-02432	02432	73.40	69.73	529-02460	02460	72.35	68.73	529-02660	02660	76.25	72.44	529-02840	02840	82.30	78.19	
0-3	529-02433	02433	73.40	69.73	529-02470	02470	72.35	68.73	529-02670	02670	76.25	72.44	529-02850	02850	82.30	78.19	
0-5	529-02434	02434	73.40	69.73	529-02480	02480	72.35	68.73	529-02680	02680	76.25	72.44	529-02860	02860	82.30	78.19	
0-10	529-02435	02435	73.40	69.73	529-02490	02490	72.35	68.73	529-02690	02690	76.25	72.44	529-02870	02870	82.30	78.19	
0-15	529-02436†	02436†	73.40	69.73	529-02500	02500	72.35	68.73	529-02700	02700	76.25	72.44	529-02880	02880	82.30	78.19	
0-25	529-02437†	02437†	73.40	69.73	529-02510	02510	72.35	68.73	529-02710	02710	76.25	72.44	529-02890	02890	82.30	78.19	
0-50	529-02438†	02438†	73.40	69.73	529-02530	02530	72.35	68.73	529-02730	02730	76.25	72.44	529-02910	02910	82.30	78.19	
0-100	-----	-----	-	-	529-02540 †	02540†	72.35	68.73	529-02740 †	02740†	76.25	72.44	529-02920 †	02920†	82.30	78.19	
0-200	-----	-----	-	-	529-02552 †	02552†	72.35	68.73	529-02760 †	02760†	76.25	72.44	529-02940 †	02940†	82.30	78.19	
0-300	-----	-----	-	-	529-02554 †	02554†	72.35	68.73	529-02770 †	02770†	76.25	72.44	529-02950 †	02950†	82.30	78.19	
0-500</																	