


ELECTROSWITCH Rotary Switches

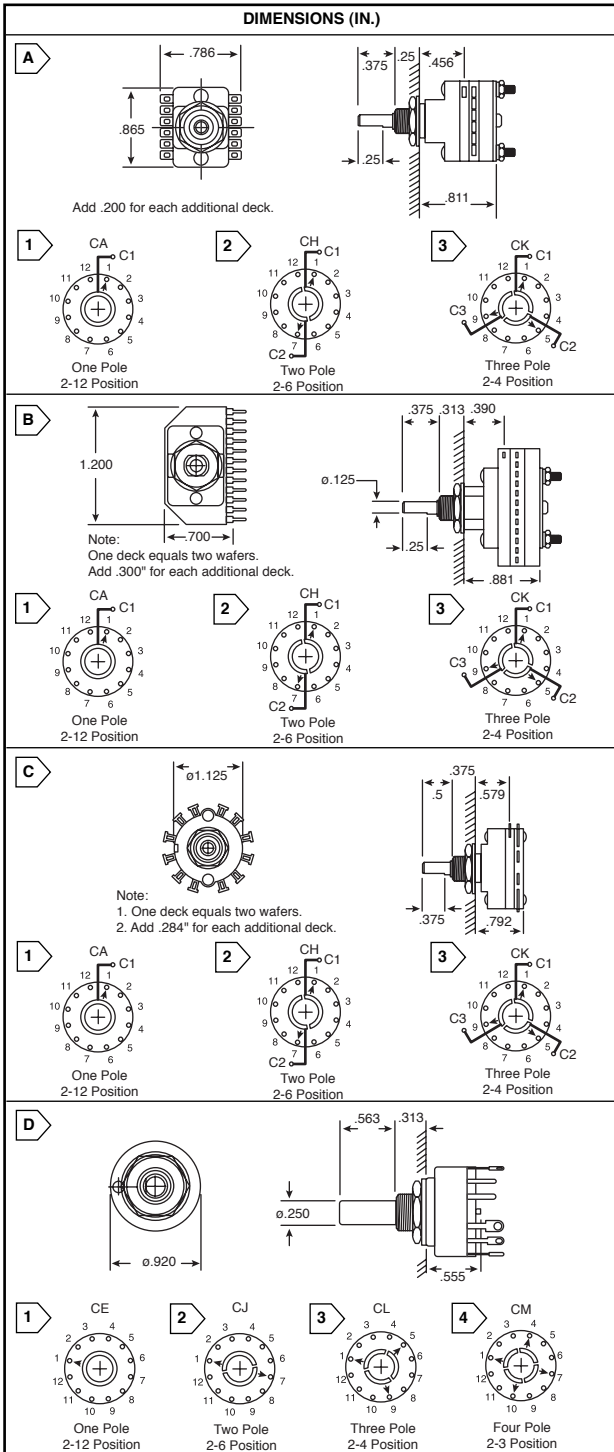

ELECTROSWITCH C1 SERIES: .865" WIDE ADJUSTABLE STOP ENCLOSED ROTARY SWITCHES

- Specifications:**
- Shaft diameter: .125"
 - Current and Voltage Rating: .25A @28VDC; 0.1A @125VAC
 - Current carrying capacity: 6A
 - Dielectric Strength: 600VAC
 - Insulation Material: Diallyl phthalate
 - Terminals and contacts: Brass with silver plate
 - Index: Dual-ball, hill and valley
 - Termination: Solder lug
 - Non-shorting
 - Stops set at 2 pos.

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Electroswitch Part No.	Fig.	Poles	Active Positions	Poles/Deck	No. of Decks	Index Angle	Price Each			
								1	10	25	50
690-C1D0112N-A	C1D0112N-A	A1	01	02-12	1	1	30°	18.09	17.76	16.65	15.54
690-C1D0206N-A	C1D0206N-A	A2	02	02-06	2	1	30°	18.09	17.76	16.65	15.54
690-C1D0304N-A	C1D0304N-A	A3	03	02-04	3	1	30°	18.09	17.76	16.65	15.54
690-C1D0212N-A	C1D0212N-A	A1	02	02-12	1	2	30°	21.52	21.12	19.80	18.48
690-C1D0406N-A	C1D0406N-A	A2	04	02-06	2	2	30°	21.52	21.12	19.80	18.48
690-C1D0604N-A	C1D0604N-A	A3	06	02-04	3	2	30°	21.52	21.12	19.80	18.48

ELECTROSWITCH C3 SERIES: 1.2" WIDE ADJUSTABLE STOP ENCLOSED ROTARY SWITCHES

- Specifications:**
- Shaft diameter: .125"
 - Current and Voltage Rating: .25A @28VDC; 0.1A @125VAC
 - Current carrying capacity: 6A
 - Insulation Material: Polyester
 - Terminals and contacts: Brass with silver plate
 - Termination: PC terminals
 - Index: Dual-ball, hill and valley
 - Non-shorting
 - 12 pin construction
 - Stops set at 2 pos.

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Electroswitch Part No.	Fig.	Poles	Active Positions	Poles/Deck	No. of Decks	Index Angle	Price Each			
								1	10	25	50
690-C3P0112N-A	C3P0112N-A	B1	01	02-12	1	1	30°	18.09	17.76	16.65	15.54
690-C3P0206N-A	C3P0206N-A	B2	02	02-06	2	1	30°	18.09	17.76	16.65	15.54
690-C3P0304N-A	C3P0304N-A	B3	03	02-04	3	1	30°	18.09	17.76	16.65	15.54
690-C3P0212N-A	C3P0212N-A	B1	02	02-12	1	2	30°	21.52	21.12	19.80	18.48
690-C3P0406N-A	C3P0406N-A	B2	04	02-06	2	2	30°	21.52	21.12	19.80	18.48
690-C3P0604N-A	C3P0604N-A	B3	06	02-04	3	2	30°	21.52	21.12	19.80	18.48

ELECTROSWITCH C4 SERIES: 1.5" DIAMETER ADJUSTABLE STOP ENCLOSED ROTARY SWITCHES

- Specifications:**
- Shaft diameter: .250"
 - Current and Voltage Rating: .5A @28VDC; 0.3A @125VAC
 - Current carrying capacity: 15A
 - Dielectric Strength: 1000VAC
 - Insulation Material: Diallyl phthalate
 - IP67 versions available. Please contact Mouser sales.
 - Terminals and contacts: Brass with silver plate
 - Termination: Solder lug
 - Index: Dual-ball, hill and valley
 - Non-shorting
 - Stops set at 2 pos.

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Electroswitch Part No.	Fig.	Poles	Active Positions	Poles/Deck	No. of Decks	Index Angle	Price Each			
								1	10	25	50
690-C4D0112N-A	C4D0112N-A	C1	01	02-12	1	1	30°	15.32	15.04	14.10	13.16
690-C4D0206N-A	C4D0206N-A	C2	02	02-06	2	1	30°	15.32	15.04	14.10	13.16
690-C4D0304N-A	C4D0304N-A	C3	03	02-04	3	1	30°	16.14	15.84	14.85	13.86
690-C4D0212N-A	C4D0212N-A	C1	02	02-12	1	2	30°	19.72	19.36	18.15	16.94
690-C4D0406N-A	C4D0406N-A	C2	04	02-06	2	2	30°	19.72	19.36	18.15	16.94
690-C4D0604N-A	C4D0604N-A	C3	06	02-04	3	2	30°	19.72	19.36	18.15	16.94
690-C4D0312N-A	C4D0312N-A	C1	03	02-12	1	3	30°	23.31	22.88	21.45	20.02
690-C4D0606N-A	C4D0606N-A	C2	06	02-06	2	3	30°	23.31	22.88	21.45	20.02
690-C4D0904N-A	C4D0904N-A	C3	09	02-04	3	3	30°	23.31	22.88	21.45	20.02
690-C4D0412N-A	C4D0412N-A	C1	04	02-12	1	4	30°	26.73	26.24	24.60	22.96
690-C4D0806N-A	C4D0806N-A	C2	08	02-06	2	4	30°	26.73	26.24	24.60	22.96
690-C4D1204N-A	C4D1204N-A	C3	12	02-04	3	4	30°	26.73	26.24	24.60	22.96

ELECTROSWITCH C5 SERIES: .92" SEALED ADJUSTABLE STOP ENCLOSED ROTARY SWITCHES

- Specifications:**
- Internal and external seals for washability
 - Shaft diameter: .250"
 - Current and Voltage Rating: 1A @28VDC; 1A @125VAC
 - Current carrying capacity: 5A
 - Insulation Material: Polyester
 - Terminals and contacts: Brass with silver plate
 - Termination: Solder lug
 - Index: Molded live spring detent
 - Non-shorting
 - Stops set at 2 pos.

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Electroswitch Part No.	Fig.	Poles	Active Positions	Poles/Sections	No. of Sections	Index Angle	Price Each			
								1	10	25	50
690-C5P0112N-A	C5P0112N-A	D1	01	02-12	1	1	30°	5.38	5.28	4.95	4.62
690-C5P0206N-A	C5P0206N-A	D2	02	02-06	2	1	30°	5.87	5.76	5.40	5.04
690-C5P0304N-A	C5P0304N-A	D3	03	02-04	3	1	30°	6.19	6.08	5.70	5.32
690-C5P0403N-A	C5P0403N-A	D4	04	02-03	4	1	30°	6.52	6.40	6.00	5.60

ELECTROSWITCH KNOBS

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Electroswitch Part No.	Fig.	Description	Price Each			
				1	10	25	50
690-1400R	1400R	E	Pointer knob w/set screw	2.12	2.08	1.95	1.82
690-1910DG	1910DG	F	Inner knob w/ skirt and spun silver color cap	3.26	3.20	3.00	2.80
690-1202BJ	1202BJ	G	Round knob w/ spun silver cap, set screw	5.05	4.96	4.65	4.34
690-1930BP	1930BP	H	Large round knob w/ skirt, set screw	4.08	4.00	3.75	3.50
690-1914N	1914N	I	Round knob w/ brass insert, set screw	6.03	5.92	5.55	5.18
690-2300	2300	J	Pointer knob w/ set screw	1.79	1.76	1.65	1.54