


MUELLER Leads and Test Clips



DIMENSIONS (IN.)

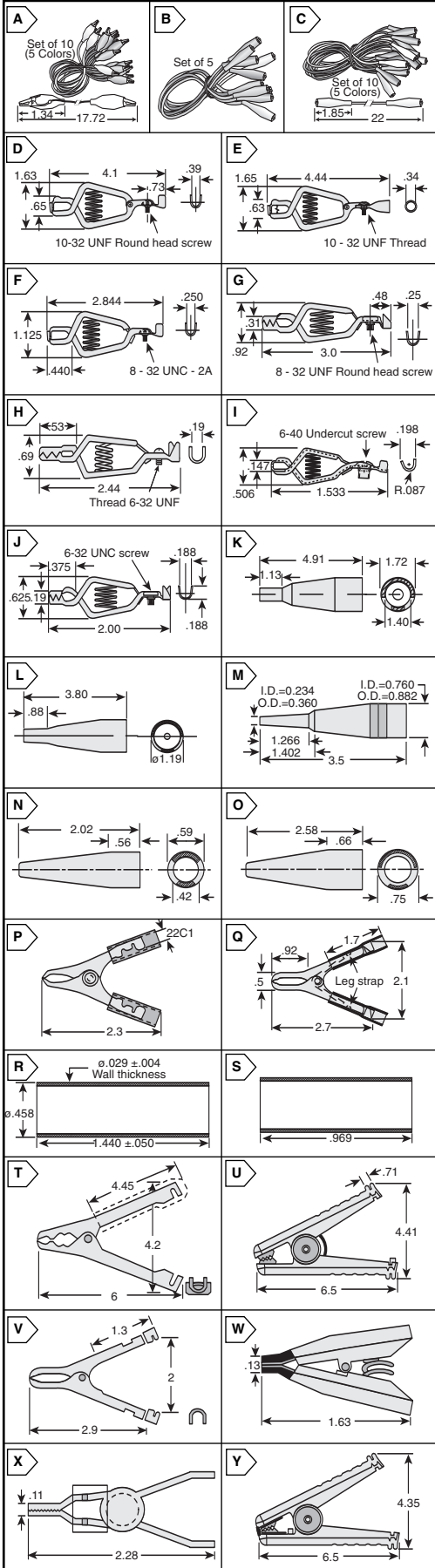

MUELLER ALLIGATOR LEAD SETS

• 22 AWG wire • Black-Green-Yellow-Red-White

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Mueller Part No.	Fig.	Length (In.)	Description	Price Each		
					1	100	500
548-285	BU-00285	A	18	Mini test clips, 10 clips, 5 colors	5.97	5.38	5.10
548-286	BU-00286	B	12	Heavy duty test clips, 5 clips, 5 colors	3.97	3.57	3.40
548-287	BU-00287	C	18	Standard test clips, 10 clips, 5 colors	5.97	5.38	5.10

MUELLER CLIPS

Center-Squeeze Clips

See insulators below for pricing.

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Mueller Part No.	Fig.	Amps	Use with Insulator	Jaw Opening	Wire AWG	Plating	Price Each		
								1	100	500
548-21APN	BU-21APN	D	50	548-23	1-1/16	1-1/0	Steel	2.15	1.93	1.84
548-BU21CPN	BU-21CPN	E	100	548-23	1-1/16	1-1/0	Copper	3.89	3.50	3.33
548-24APN	BU-24APN	F	25	548-26	3/4	8	Steel	1.01	.95	.89
548-24APS	BU-24APS	F	25	548-26	3/4	8	Steel	1.01	.95	.89
548-BU-25	BU-25	G	40	548-26	3/4	1	Steel	.97	.88	.84
548-25C	BU-25C	G	75	548-26	3/4	1	Copper	1.62	1.46	1.39
548-27	BU-27	H	20	548-29	5/8	12	Zinc	.70	.63	.59
548-27C	BU-27C	H	40	548-29	5/8	12	Solid Copper	.83	.75	.71
548-45	BU-45	I	5	548-47	5/16	7	Steel	.48	.43	.41
548-45C	BU-45C	I	10	548-47	5/16	7	Copper	.73	.69	.64
548-48-B	BU-48B	J	10	548-49	1/2	5	Steel	.64	.58	.55
548-48-C	BU-48C	J	20	548-49	1/2	5	Copper	.68	.61	.58

Center-Squeeze Clip Insulators

Replace Blank with:

Black-0	Yellow-4	Blue-6
Red-2	Green-5	White-9

Available in 6 colors

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Mueller Part No.	Fig.	Length (In.)	Description	Price Each		
					1	100	500
548-23-__	BU-23-__	K	5.00	Vinyl/insulator for #21 series alligator clips	1.18	1.06	1.01
548-26-__	BU-26-__	L	3.78	Vinyl/insulator for #22 & 25 series alligator clips	.86	.77	.74
548-29-__	BU-29-__	M	3.50	Vinyl/insulator for #20 series alligator clips	.58	.53	.50
548-47-__	BU-47-__	N	2.02	Vinyl insulator for # 45 & 45C	.20	.19	.18
548-49-__	BU-49-__	O	2.56	Vinyl insulator for #48B & 48C	.51	.47	.43

Small Plier-Style Clips

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Mueller Part No.	Fig.	Amps	Use with Insulator Below	Jaw Opening	Wire AWG	Plating	Price Each		
								1	100	500
548-40A-0	BU-40A-0	P	15	548-42PR-__	3/4	12	Steel	.72	.65	.62
548-40A-2	BU-40A-2	P	15	548-42PR-__	3/4	12	Steel	.72	.65	.62
548-40C-0	BU-40C-0	P	20	548-42PR-__	3/4	12	Copper	.90	.81	.77
548-40C-2	BU-40C-2	P	20	548-42PR-__	3/4	12	Copper	.90	.81	.77
548-46A-B	BU-46A-0	Q	50	548-BU-46PR-__	1-1/8	2	Steel	.93	.84	.79
548-46A-R	BU-46A-2	Q	50	548-BU-46PR-__	1-1/8	2	Steel	.93	.84	.79
548-46C-0	BU-46C-0	Q	75	548-BU-46PR-__	1-1/8	2	Copper	1.23	1.11	1.05
548-46C-2	BU-46C-2	Q	75	548-BU-46PR-__	1-1/8	2	Copper	1.23	1.11	1.05

Small Plier-Style Clip Insulators

Additional colors are available. Contact a Mouser Representative for assistance.

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Mueller Part No.	Fig.	Length (In.)	Description	Price Each		
					1	100	500
548-BU-46PR-0	BU-46PR-0	R	1-3/4	Black vinyl insulator plier type for # 46A & 46C	.18	.16	.16
548-BU-46PR-2	BU-46PR-2	R	1-3/4	Red vinyl insulator plier type for # 46A & 46C	.18	.16	.16
548-42PR-0	BU-42PR-0	S	0.969	Pair of Black Insulators for #40 Clip	.49	.46	.43
548-42PR-2	BU-42PR-2	S	0.969	Pair of Red Insulators for #40 Clip	.49	.46	.43

Large Plier-Style Clips

Available in 6 colors

Replace Blank with:

Black-0	Yellow-4	Blue-6
Red-2	Green-5	White-9

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Mueller Part No.	Fig.	Amps	Use with Insulator	Jaw Opening	Wire AWG	Plating	Price Each		
								1	100	500
548-41A-__	BU-41A-__	T	200	548-43PR-__	1-9/16	1	Steel	2.34	2.11	2.00
548-41C-__	BU-41C-__	T	400	548-43PR-__	1-9/16	1	Copper	5.24	4.72	4.48
548-102B-__	BU-102B-__	U	500	Included	1.6	1	Copper	6.48	5.83	5.54

* Available in red and black only

Large Plier-Style Clip Insulators

Additional colors are available. Contact a Mouser Representative for assistance.

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Mueller Part No.	Fig.	Length (In.)	Description	Price Each		
					1	100	500
548-43PR-0	BU-43PR-0	S	4.44	Pair of Black Insulators for BU-41 Clip	.49	.44	.42
548-43PR-2	BU-43PR-2	S	4.44	Pair of Red Insulators for BU-41 Clip	.49	.44	.42

Kelvinized Test Clips

Jaws are electrically isolated when opened for battery testing

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Mueller Part No.	Fig.	Length (In.)	Description	Plating	Price Each		
						1	100	500
548-BU-46K-0	BU-46K-0	V	2.9	Black Kelvin Clip - 50 Amp	Dichromate	2.76	2.48	2.36
548-BU-46K-2	BU-46K-2	V	2.9	Red Kelvin Clip - 50 Amp	Dichromate	2.76	2.48	2.36
548-BU-75K	BU-75K	W	1-5/8	Silver/Black Kelvin Steel Clip - 10 Amp	Silver	10.41	9.37	8.91
548-BU-78K	BU-78K	X	2.28	Gold Kelvin Copper Clip - 10 Amp	Gold	36.00	34.00	32.00
548-BU-102BK-0	BU-102BK-0	Y	6.5	Black Kelvin Clip - 500 Amp, Fully Insulated	Solid Copper	23.00	21.00	19.00
548-BU-102BK-2	BU-102BK-2	Y	6.5	Red Kelvin Clip - 500 Amp, Fully Insulated	Solid Copper	23.00	21.00	19.00

Mueller Test Connectors