


HEYCO Liquid Tight Cordgrrips



RoHS Compliant This product is RoHS compliant.

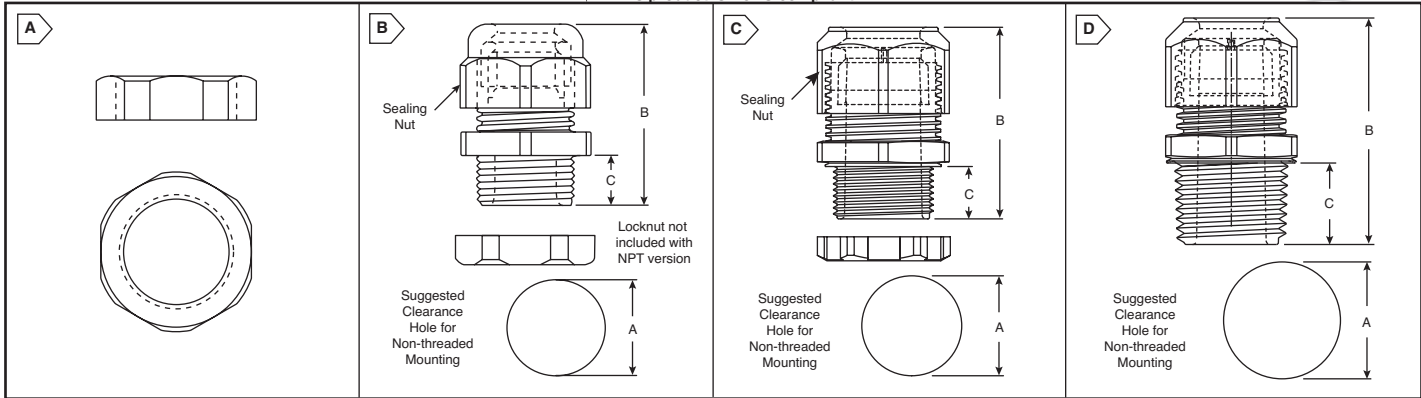

HEYCO LIQUID TIGHT STRAIGHT-THRU CORDGRIPS

Nylon Locknuts, NPT Thread

Cordgrrips are for flexible cords. Install in either clearance or threaded holes.

For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	MOUSER STOCK NO.	Fig.	Description	Price Each			
				1	10	50	100
836-8461	836-8462	A	NLN 3/8 NPT	.29	.23	.21	.19
836-8463	836-8464	A	NLN 1/2 NPT	.29	.23	.21	.19
836-8465	836-8466	A	NLN 3/4 NPT	.34	.28	.24	.22
836-8467	836-8468	A	NLN 1 NPT	.75	.61	.51	.45



Cordgrrips for PG Hubs

* Locknuts are included. For quantities of 250 and up, call for quote.

Cable Diameter Range (In.)	MOUSER STOCK NO.	Heyco Part No.	MOUSER STOCK NO.	Heyco Part No.	Fig.	Description	Dimensions (In.)			Price Each			
							A	B	C	1	10	50	100
0.064	836-3444	3444	836-3445	3445	B	RLTF 7	0.492	1.170	0.330	.85	.67	.56	.48
0.114	836-3207	3207	836-3208	3208	B	LTF 7	0.492	1.170	0.330	.85	.67	.56	.48
0.069	836-3446	3446	836-3447	3447	B	RLTF 9	0.599	1.300	0.340	.89	.70	.58	.50
0.181	836-3210	3210	836-3211	3211	B	LTF 9	0.599	1.300	0.340	.89	.70	.58	.50
0.069	836-3448	3448	836-3449	3449	B	RLTF 11	0.733	1.460	0.390	1.07	.85	.70	.61
0.230	836-3213	3213	836-3214	3214	B	LTF 11	0.733	1.460	0.390	1.07	.85	.70	.61
0.170	836-3216	3216	836-3217	3217	B	LTF 13.5	0.804	1.530	0.410	1.61	1.27	1.04	.89
0.230	836-3219	3219	836-3220	3220	B	LTF 16	0.886	1.660	0.450	1.35	1.07	.88	.77
0.250	836-3454	3454	836-3455	3455	B	RLTF 21	1.115	1.870	0.520	1.89	1.49	1.24	1.07
0.450	836-3222	3222	836-3223	3223	B	LTF 21	1.115	1.870	0.520	1.89	1.49	1.24	1.07
0.590	836-3225	3225	836-3226	3226	B	LTF 29	1.470	2.230	0.590	3.36	2.65	2.19	1.90

Heyco

Cordgrrips for NPT Hubs

* Locknuts are not included. For quantities of 250 and up, call for quote.

Cable Diameter Range (In.)	MOUSER STOCK NO.	Heyco Part No.	MOUSER STOCK NO.	Heyco Part No.	Fig.	Description	Dimensions (In.)			Price Each			
							A	B	C	1	10	50	100
0.069	836-3458	3458	836-3459	3459	B	RLTF 3/8	0.670	1.490	0.530	.80	.63	.53	.45
0.181	836-3228	3228	836-3229	3229	B	LTF 3/8	0.670	1.490	0.530	.80	.63	.53	.45
0.170	836-3231	3231	836-3232	3232	B	LTF 1/2	0.875	1.720	0.620	1.07	.85	.70	.61
0.230	836-3200	3200	836-3201	3201	B	LLTF 1/2	0.875	1.830	0.620	1.22	.97	.80	.69
0.450	836-3234	3234	836-3235	3235	B	LTF 3/4	1.068	1.970	0.630	1.70	1.34	1.11	.97
0.250	836-3460	3460	836-3461	3461	B	RLTF 3/4	1.068	1.970	0.630	1.70	1.34	1.11	.97
0.590	836-8437	8437	836-8438	8438	B	LTF 1	1.375	2.420	0.750	3.02	2.38	1.97	1.71

Hardware

"HEYCO TITE" LIQUID TIGHT STRAIGHT-THRU CORDGRIPS

"Ratchet design" of sealing nut assembly provides superior anti-vibration protection and ensures a firm grip on the cable. Integral "Sealing Ring" ensures a superior seal at mounting location every time.

Cordgrrips for PG Hubs

* Locknuts are included. For quantities of 250 and up, call for quote.

Cable Diameter Range (In.)	MOUSER STOCK NO.	Heyco Part No.	MOUSER STOCK NO.	Heyco Part No.	Fig.	Description	Dimensions (In.)			Price Each			
							A	B	C	1	10	50	100
0.065	836-M3444	M3444	836-M3445	M3445	C	RLTCG 7	0.492	1.160	0.320	.96	.87	.80	.72
0.115	836-M3207	M3207	836-M3208	M3208	C	LTCG 7	0.492	1.160	0.320	.96	.87	.80	.72
0.065	836-M3446	M3446	836-M3447	M3447	C	RLTCG 9	0.599	1.250	0.320	1.02	.92	.83	.76
0.105	836-M3210	M3210	836-M3211	M3211	C	LTCG 9	0.599	1.250	0.320	1.02	.92	.83	.76
0.069	836-M3448	M3448	836-M3449	M3449	C	RLTCG 11	0.733	1.480	0.380	1.22	1.11	1.02	.92
0.230	836-M3213	M3213	836-M3214	M3214	C	LTCG 11	0.733	1.480	0.380	1.22	1.11	1.02	.92
0.095	836-M4500	M4500	836-M4501	M4501	C	RLTCG 13.5	0.804	1.500	0.410	1.34	1.22	1.11	1.02
0.170	836-M3216	M3216	836-M3217	M3217	C	LTCG 13.5	0.804	1.500	0.410	1.34	1.22	1.11	1.02
0.180	836-M4502	M4502	836-M4503	M4503	C	RLTCG 16	0.886	1.680	0.440	1.54	1.40	1.27	1.16
0.260	836-M3219	M3219	836-M3220	M3220	C	LTCG 16	0.886	1.680	0.440	1.54	1.40	1.27	1.16
0.250	836-M3454	M3454	836-M3455	M3455	C	RLTCG 21	1.115	1.890	0.520	2.14	1.94	1.77	1.61
0.485	836-M3222	M3222	836-M3223	M3223	C	LTCG 21	1.115	1.890	0.520	2.14	1.94	1.77	1.61
0.490	836-M4504	M4504	836-M4505	M4505	C	RLTCG 29	1.470	2.230	0.580	3.81	3.47	3.15	2.86
0.590	836-M3225	M3225	836-M3226	M3226	C	LTCG 29	1.470	2.230	0.580	3.81	3.47	3.15	2.86

Cordgrrips for NPT Hubs

* Locknuts are not included. For quantities of 250 and up, call for quote.

Cable Diameter Range (In.)	MOUSER STOCK NO.	Heyco Part No.	MOUSER STOCK NO.	Heyco Part No.	Fig.	Description	Dimensions (In.)			Price Each			
							A	B	C	1	10	50	100
0.065	836-M3458	M3458	836-M3459	M3459	D	RLTCG 3/8	0.680	1.410	0.490	.91	.82	.75	.68
0.105	836-M3228	M3228	836-M3229	M3229	D	LTCG 3/8	0.680	1.410	0.490	.91	.82	.75	.68
0.095	836-M4518	M4518	836-M4519	M4519	D	RLTCG 1/2	0.875	1.700	0.610	1.22	1.11	1.02	.92
0.170	836-M3231	M3231	836-M3232	M3232	D	LTCG 1/2	0.875	1.700	0.610	1.22	1.11	1.02	.92
0.256	836-M3460	M3460	836-M3461	M3461	D	RLTCG 3/4	1.040	2.000	0.620	1.92	1.75	1.59	1.45
0.485	836-M3234	M3234	836-M3235	M3235	D	LTCG 3/4	1.040	2.000	0.620	1.92	1.75	1.59	1.45
0.490	836-M8439	M8439	836-M8440	M8440	D	RLTCG 1	1.326	2.410	0.760	3.42	3.11	2.83	2.57
0.590	836-M8437	M8437	836-M8438	M8438	D	LTCG 1	1.326	2.410	0.760	3.42	3.11	2.83	2.57

