


PANDUIT Cable Ties and Tools



RoHS Compliant This product is RoHS compliant.

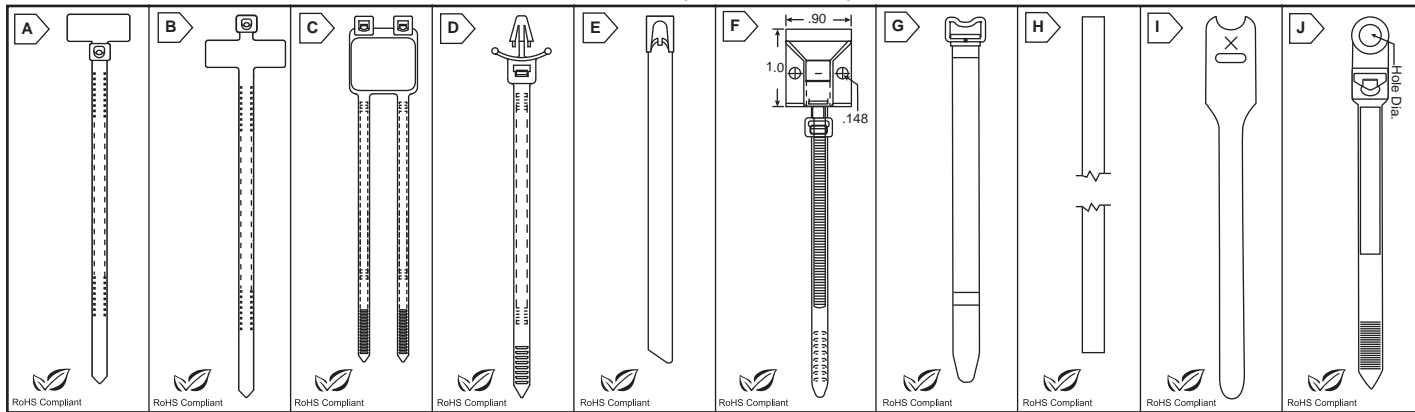

NYLON 6.6 MARKER TIES

• Natural Nylon • UL94V-2 rating

MOUSER STOCK NO.	Fig.	Tensile Strength (Lbs.)	Length (In.)	Max. Bundle Dia. (In.)	Width (In.)	Price Each			
						1	100	500	1000
Nylon 6.6 (Natural)									
644-PLF1M-M	A	18	4.3	0.87	0.098				
644-PLM1M-M	B	18	3.9	0.75	0.098				
644-PLM2M-M	B	18	8	2	0.098				
644-PLM2S-D	B	18	7.4	1.75	0.098				
644-PL2M2S-L	C	50	7.4	1.75	0.185				
Weather (UV) Resistant Nylon 6.6 (Black)									
644-PLF1M-M0	A	18	4.3	0.87	0.098				
644-PLM2M-M0	B	18	8	2	0.098				
644-PLM2S-D0	B	18	7.4	1.75	0.098				
Nylon 6.6 Winged Push Mount Ties									
644-PLWP1M-D	D	18	4.3	.87	.098				
644-PLWP1.5I-C	D	40	6.0	1.25	.135				
644-PLWP1S-C	D	50	5.2	1.00	.190				
644-PLWP2S-C	D	50	7.8	1.75	.190				
644-PLWP3H-TL	D	120	12.0	3.00	.300				

TAK-TY® HOOK AND LOOP CABLE TIES

• Black • Material: Nylon loop, polyethylene hook

MOUSER STOCK NO.	Fig.	Tensile Strength (Lbs.)	Length (In.)	Max. Bundle Dia. (In.)	Width (In.)	Price Each			
						1	10	100	500
644-HLS1.5S-X0	H	50	6.0	1.5	.75				
644-HLSP1.5S-X0	H	50	6.0	1.5	.75				
644-HLT2I-X0	I	40	8.0	1.9	.50				
644-HLTP2I-X0	I	40	8.0	1.9	.50				
644-HLC3S-X0	G	50	12.0	3.0	.75				
644-HLTP3I-X0	I	50	12.0	3.0	.75				
644-HLS3S-X0	H	50	12.0	3.2	.75				
644-HLSP3S-X0	H	50	12.0	3.2	.75				
644-HLT3I-X0	I	40	12.0	3.2	.50				
644-HLC5S-X0	G	50	18.0	5.0	.75				
644-HLS5S-X0	H	50	18.0	5.0	.75				
644-HLSP5S-X0	H	50	18.0	5.0	.75				
644-HLM-15R0	H	18	180.0	Various	.33				
644-HLS-15R0	H	50	180.0	Various	.75				

PAN-STEEL™ STAINLESS STEEL TIE SYSTEM

MOUSER STOCK NO.	Fig.	Tensile Strength (Lbs.)	Hole Dia.	Length (In.)	Max. Bundle Dia. (In.)	Screw Size	Price Each			
							1	100	500	1000
644-MLT1S-CP	E	100	5.00	1.00	0.18					
644-MLT2S-CP	E	100	7.90	2.00	0.18					
644-MLT4H-LP	E	100	14.30	4.00	0.18					
644-MLT4S-CP	E	100	14.20	4.00	0.18					
644-MLT6H-LP	E	100	20.50	6.00	0.18					
644-MLT6S-CP	E	100	20.40	6.00	0.18					
644-MLT2H-LP	E	250	7.90	2.00	0.31					

STAINLESS STEEL MARKER PLATE

• Color: Natural For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Size (W x L)	Description	Price Each			
			1	100	500	1000
644-MMP350-C	.75" x 3.50"	304 stainless steel				

ADHESIVE MOUNT/CABLE TIE

Adhesive mount and cable tie molded as one piece helps reduce inventory costs.


MOUSER STOCK NO.	Fig.	Tensile Strength (Lbs.)	Length (In.)	Max. Bundle Dia. (In.)	Width (In.)	Price Each			
						1	100	500	1000
644-PLA2S-A-Q	F	50	7.30	1.85	.19				

CABLE TIE INSTALLATION TOOLS

- The preferred tool design in the industry.
- Lightweight and balanced.
- Requires no special maintenance.
- Rugged all-steel construction
- Easy to operate.

GS4H

- Installs standard, light heavy and heavy cross section cable ties.
- Installs superflex cable ties.
- Q.P.L. per Mil. std. MS90387-2 and Mil. spec. Mil-T-81306A.

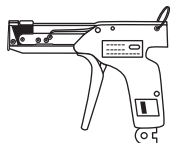

644-GS4H

STS2


- Installer controlled tension and cut-off.
- Perfect size for pocket or tool box.
- Especially suited to maintenance and construction applications.
- Installs miniature, intermediate and standard ties.



644-STS2

ST2MT


- Used with all Pan-Steel™ type MLT.
- Single handle trigger for fast installation.
- Cut off capability with the twist of the wrist.

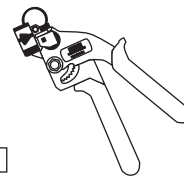

644-ST2MT

HTMT


- Specially adapted screwdriver type tool is used to tension standard and heavy cross section ties safely.
- Used with all Pan-Steel™ type MLT ties, type MLTC coated ties and type MLPT plenum ties.
- Manual tension, no cut-off.

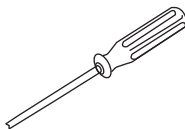

644-HTMT

GTS

- Installs miniature, intermediate and standard cross section cable ties.
- Manual tool/lightweight 8.8 oz.
- Meets Mil. std. MS90387-1

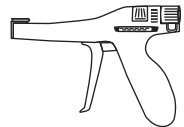

644-GTS


GTH

- Installs Standard, Heavy-Standard, Light-Heavy and Heavy cross section cable ties.
- Manual tool/ lightweight 11.2 oz.

644-GTH

GS2B

- Tool controlled tension and cut-off.
- Automatic tension and cut-off by squeezing trigger.
- Reduces fatigue and increases productivity.
- Especially suited to medium production applications.
- Q.P.L. per Mil. Std. MS90387-1
- Installs miniature, intermediate and standard ties.

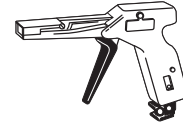

644-GS2B