

VISHAY Diodes

Products may be RoHS compliant.
Check mouser.com for RoHS status.

 


RoHS Compliant


For quantities of 2000 and up, call for quote.

VISHAY SCHOTTKY DIODES

MOUSER STOCK NO.	Vishay Part No.	Case Type	VRMM Max. (V)	IF Max. (A)	VF @ IF Max. (V)	IF (mA)	IFSM Max. (A)	trr Typ/Max (ns)	Tj Max. (°C)	Price Each			
										1	100	500	1000
Surface Mount													
625-LL103C	LL103C-GS08	SOD-80C	20	0.35	0.37	20	15	----/10	125	.10	.072	.056	.048
625-SD103CW-V	SD103CW-V-GS08	SOD-123	20	0.35	0.37	20	2	10/----	125	.10	.072	.056	.048
625-BAT54-V	BAT54-V-GS08	SOT-23-3	30	0.2	0.4	10	0.6	----/5	125	.06	.047	.037	.032
625-BAT54A-V	BAT54A-V-GS08	SOT-23-3	30	0.2	0.4	10	0.6	----/5	125	.07	.054	.042	.036
625-BAT54C-V	BAT54C-V-GS08	SOT-23-3	30	0.2	0.4	10	0.6	----/5	125	.07	.054	.042	.036
625-BAT54S-V	BAT54S-V-GS08	SOT-23-3	30	0.2	1	100	0.6	----/5	125	.07	.054	.042	.036
625-LL103B	LL103B-GS08	SOD-80C	30	0.35	0.37	20	15	----/10	125	.10	.073	.057	.049
625-SD103BW-V	SD103BW-V-GS08	SOD-123	30	0.35	0.37	20	2	10/----	125	.10	.072	.056	.048
625-LL101C	LL101C-GS08	SOD-80C	40	0.2	0.39	1	2	----/1	125	.09	.064	.05	.043
625-SD101CW-V	SD101CW-V-GS08	SOD-123	40	0.2	0.39	1	2	----/1	125	.09	.068	.053	.045
625-SD103AW-V	SD103AW-V-GS08	SOD-123	40	0.35	0.37	20	2	10/----	125	.10	.072	.056	.048
625-LL103A	LL103A-GS08	SOD-80C	40	0.35	0.37	20	15	----/10	125	.10	.074	.058	.05
625-LL101B	LL101B-GS08	SOD-80C	50	0.2	0.4	1	2	----/1	125	.09	.065	.051	.044
625-SD101BW-V	SD101BW-V-GS08	SOD-123	50	0.2	0.4	1	2	----/1	125	.09	.068	.053	.045
625-LL101A	LL101A-GS08	SOD-80C	60	0.2	0.41	1	2	----/1	125	.09	.068	.053	.045
625-SD101AW-V	SD101AW-V-GS08	SOD-123	60	0.2	0.41	1	2	----/1	125	.09	.068	.053	.045
625-BAS70-00-V	BAS70-00-V-GS08	SOT-23-3	70	0.2	0.41	1	0.6	----/5	150	.10	.072	.056	.048
625-BAS70-04-V	BAS70-04-V-GS08	SOT-23-3	70	0.2	0.41	1	0.6	----/5	150	.11	.081	.063	.054
625-BAS70-05-V	BAS70-05-V-GS08	SOT-23-3	70	0.2	0.41	1	0.6	----/5	150	.11	.081	.063	.054
625-BAS70-06-V	BAS70-06-V-GS08	SOT-23-3	70	0.2	0.41	1	0.6	----/5	150	.11	.081	.063	.054
Thru-Hole													
625-SD103C	SD103C-TR	DO-35	20	0.35	0.37	20	15	10/----	125	.10	.072	.056	.048
625-BAT42	BAT42-TR	DO-35	30	0.2	0.4	10	4	----/5	125	.11	.079	.061	.053
625-SD103B	SD103B-TR	DO-35	30	0.35	0.37	20	15	10/----	125	.09	.07	.054	.047
625-SD101C	SD101C-TR	DO-35	40	0.2	0.39	1	2	----/1	125	.08	.06	.046	.04
625-SD103A	SD103A-TR	DO-35	40	0.35	0.37	20	15	10/----	125	.09	.071	.055	.047
625-SD101B	SD101B-TR	DO-35	50	0.2	0.4	1	2	----/1	125	.08	.061	.047	.041
625-SD101A	SD101A-TR	DO-35	60	0.2	0.41	1	2	----/1	125	.08	.062	.048	.041



SOD-123

 

SOT-23-3




RoHS Compliant


For quantities of 2000 and up, call for quote.

VISHAY SMALL SIGNAL DIODES

MOUSER STOCK NO.	Vishay Part No.	Case Type	VRMM Max. (V)	IF(AV) Max. (mA)	IR @ VR Max. (nA)	VR (V)	VF @ IF Max. (V)	IF (mA)	trr Typ/Max (ns)	Price Each			
										1	100	500	1000
Surface Mount													
78-LL4150	LL4150-GS08	SOD-80C	50	600	0.1	50	1	200	----/4	.06	.044	.021	.017
625-BAV99-V	BAV99-V-GS08	SOT-23-3	70	250	25000	70	1	50	----/6	.08	.056	.027	.021
625-BAV70-V	BAV70-V-GS08	SOT-23-3	70	250	25000	70	1	50	----/6	.08	.056	.027	.021
625-BAW56-V	BAW56-V-GS08	SOT-23-3	70	250	25000	70	1	50	----/6	.08	.056	.027	.021
78-LL4151	LL4151-GS08	SOD-80C	75	200	50	50	1	50	----/4	.06	.042	.02	.016
625-1N4148W-V	1N4148W-V-GS08	SOD-123	100	150	5000	75	1	10	----/4	.09	.064	.03	.024
625-1MBD4148-V	1MBD4148-V-GS08	SOT-23-3	100	150	25000	70	1	10	----/4	.08	.056	.027	.021
78-LL4448	LL4448-GS08	SOD-80C	100	150	.005	75	1	100	----/8	.05	.038	.018	.014
625-1MMBD7000-V	1MMBD7000-V-GS08	SOT-23-3	100	200	3000	100	0.82	10	----/4	.09	.06	.029	.023
625-BAS16-V	BAS16-V-GS08	SOT-23-3	100	150	1000	75	1	50	----/6	.08	.056	.027	.021
78-LL4148	LL4148-GS08	SOD-80C	100	450	5	75	1	10	----/8	.05	.038	.018	.014
78-LS4148	LS4148-GS08	Quadro MELF	100	500	5	75	1	50	----/8	.05	.038	.018	.014
625-BAS21-V	BAS21-V-GS08	SOT-23-3	250	200	100	200	1	100	----/50	.10	.068	.032	.026
Thru-Hole													
78-1N4154	1N4154-TR	DO-35	35	450	0.1	25	1	30	----/4	.04	.026	.012	.01
78-1N4150	1N4150-TR	DO-35	50	600	0.1	50	1	200	----/4	.06	.044	.021	.017
78-1N4151	1N4151-TR	DO-35	75	450	0.05	50	1	50	----/4	.04	.026	.012	.01
78-1N914	1N914-TR	DO-35	100	300	5	75	1	10	----/4	.03	.024	.011	.009
78-1N4148	1N4148-TR	DO-35	100	500	5	75	1	10	----/4	.03	.021	.01	.008
78-1N4448	1N4448-TR	DO-35	100	500	5	75	1	100	----/4	.04	.026	.012	.01
78-BAV20	BAV20-TR	DO-35	200	200	100	100	1	100	----/50	.05	.035	.017	.013
78-BAV21	BAV21-TR	DO-35	250	250	100	200	1	100	----/50	.05	.038	.018	.014

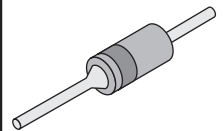

DO-35

 

MELF/SOD-80C




RoHS Compliant

For quantities of 2000 and up, call for quote.

VISHAY ZENER DIODES

MOUSER STOCK NO.	Vishay Part No.	Case Type	Nominal Voltage (V)	Power Rating (W)	Test Current (mA)	Price Each			
						1	100	500	1000
Surface Mount									
625-BZX84C2V7-V	BZX84C2V7-V-GS08	SOT-23-3	2.7	0.35	100	.04	.034	.029	.024
625-BZX84C3V0-V	BZX84C3V0-V-GS08	SOT-23-3	3.0	0.35	100	.04	.034	.029	.024
625-BZX84C3V3-V	BZX84C3V3-V-GS08	SOT-23-3	3.3	0.35	95	.04	.034	.029	.024
625-BZX84C3V6-V	BZX84C3V6-V-GS08	SOT-23-3	3.6	0.35	95	.04	.034	.029	.024
625-BZX84C3V9-V	BZX84C3V9-V-GS08	SOT-23-3	3.9	0.35	90	.04	.034	.029	.024
625-BZX84C4V3-V	BZX84C4V3-V-GS08	SOT-23-3	4.3	0.35	90	.04	.034	.029	.024
625-BZX84C4V7-V	BZX84C4V7-V-GS08	SOT-23-3	4.7	0.35	80	.04	.034	.029	.024
625-BZX84C5V1-V	BZX84C5V1-V-GS08	SOT-23-3	5.1	0.35	60	.04	.034	.029	.024
625-BZX84C5V6-V	BZX84C5V6-V-GS08	SOT-23-3	5.6	0.35	40	.04	.034	.029	.024

 

QUADRO MELF

