


PSP Solderless Breadboards




A

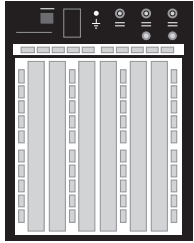

- Built-in power supply (short-proof)
- DC power: +5V/1A
- Adjustable: 0 to +15V or -15V @ 500mA
- Input line voltage: AC 120V 60Hz


B

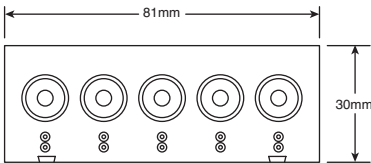

81mm

30mm

C

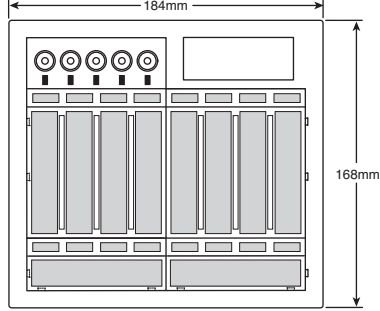


184mm

168mm


383-A1906 Shown

D



- Programmable 25-pin detachable I/O D-sub connectors included (1 male, 1 female)
- Fits up to 36 14 pin dual in-line ICs

E

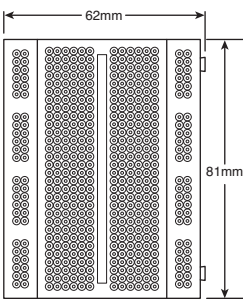


62mm

81mm

383-A456 Shown

F

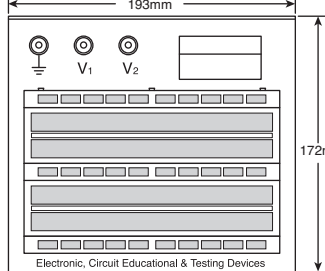


193mm

172mm

383-R32KSW Shown

G

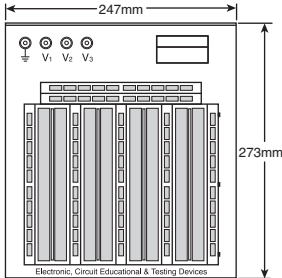


247mm

273mm

383-R74KSW Shown

 H




12mm

81mm

383-A48 Shown

I

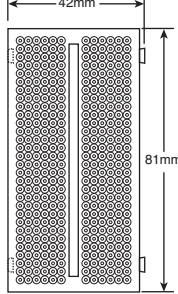


42mm

81mm

383-A360 Shown

J

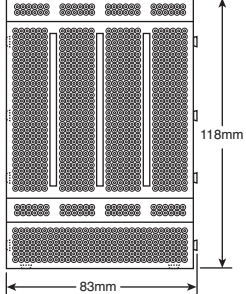

118mm

83mm

383-A948 Shown

SOLDERLESS BREADBOARDS

Specifications:

- Snap lock breadboards join easily for expansion
- Round holes accept solid wires from 22 AWG to 30 AWG
- Power blocks accept 4.5mm Y-terminal, stripped wire, and 4mm banana plug

MOUSER STOCK NO.	Fig.	Description	Power Block	Tie Points	Binding Posts	Interconnected Clips				25 Intercon. Bus	Holds 14-Pin ICs	Dimen. (mm)		Price Each
						5	6	12	24			L	W	
383-K2400	A	Power Project Board with illuminated power switch, Fixed + 5 VDC at 1 A, Variable 0 VDC to +/- 15 VDC at 500 mA	Yes	2420	4	-	-	-	-	-	-	250	200	179.22
383-A10	B	Power Block	Yes	10	5	-	-	-	-	-	-	81	30	9.29
383-A958	C	Power Block and Breadboard	Yes	958	5	-	142	4	2	-	-	83	147	19.30
383-A1906	C	Power Block and Breadboard	Yes	1906	5	-	284	8	4	-	-	184	168	45.38
383-A2854	C	Power Block and Breadboard	Yes	2854	5	-	426	12	6	-	-	266	168	62.13
383-A3802	C	Power Block and Breadboard	Yes	3802	5	-	568	16	8	-	-	346	168	79.88
383-K2300-1	D	Universal Interface Breadboard	Yes	2320	4	384	-	-	-	16	27	230	250	66.90
383-R21KSW	E	Solderless Breadboard with 383-SWS350 Jump Wire Kit	-	840	-	128	-	-	-	8	9	172	65	15.95
383-R21BKSW	F	Solderless Breadboard with 383-SWS350 Jump Wire Kit	-	840	3	128	-	-	-	8	9	195	122	23.04
383-R32KSW	F	Solderless Breadboard with 383-SWS2100 Jump Wire Kit	-	1580	3	256	-	-	-	12	18	193	172	28.86
383-R53KSW	G	Solderless Breadboard with 383-SWS2100 Jump Wire Kit	-	2420	4	384	-	-	-	20	27	192	254	37.53
383-R74KSW	G	Solderless Breadboard with 383-SWS2100 Jump Wire Kit	-	3260	4	512	-	-	-	28	36	247	273	40.57
383-K158	G	Solderless Breadboard	-	1580	3	-	-	-	-	-	18	193	172	18.80
383-K242	G	Solderless Breadboard	-	2420	4	-	-	-	-	-	27	192	254	23.99
383-K326	G	Solderless Breadboard	-	3260	4	-	-	-	-	-	36	247	273	33.58
383-R840B	F	Solderless Breadboard	-	840	3	128	-	-	-	8	9	195	122	18.50
383-A48	H	Solderless Breadboard	-	48	-	-	-	2	1	-	-	81	12	2.67
383-A360	I	Solderless Breadboard	-	360	-	-	-	60	-	-	-	81	42	4.90
383-K39	E	Solderless Breadboard	-	390	-	58	-	-	-	4	4	80	60	6.03
383-A408	E	Solderless Breadboard	-	408	-	-	-	60	2	1	-	81	52	5.76
383-A456	E	Solderless Breadboard	-	456	-	-	-	60	4	2	-	81	62	6.82
383-R740	E	Solderless Breadboard	-	740	-	128	-	-	-	4	9	172	52	10.41
383-R840	E	Solderless Breadboard	-	840	-	128	-	-	-	8	9	172	65	11.79
383-A948	J	Solderless Breadboard	-	948	-	-	-	142	4	2	-	83	118	15.52