

AVERY DENNISON Cable Mounting Hardware



RoHS Compliant This product is RoHS compliant.

SCREW MOUNT TIES

Screw Mount Ties are preferred when position is critical or the operation requires the product to be pre-mounted to a surface before final assembly. For an added dimension of security, Avery Dennison Screw Mount Cable Ties are easily applied to keep your application secure and positioned exactly where it needs to be.

For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Avery Dennison Part No.	Fig.	Color	Length (in.)	Width (in.)	Thickness (in.)	Bundle Dia min-max.	Min Loop Tensile Strength	Price Each		
									1	100	1000
514-08415	08415	A	Natural	7.5	0.177	0.055	1/16"-1-3/4"	50lbs.	.41	.25	.17
514-08443	08443	A	Black	7.5	0.177	0.055	1/16"-1-3/4"	50lbs.	.45	.27	.18
514-10351	10351	A	Black	11	0.177	0.50	1/16"-3"	50lbs.	.59	.36	.24
514-10035	10035	A	Natural	14.5	0.25	0.075	3/16"-3.5"	120lbs.	1.38	.83	.55
514-08441	08441	A	Black	14.5	0.25	0.075	3/16"-3.5"	120lbs.	1.39	.83	.55
514-20085	20085	A	Natural	7.5	0.18	0.05	1/16"-1-3/4"	50lbs.	1.10	.66	.44

HOLE TIES

Hole Ties are an easy way to secure wire, hose, or tubing bundles. Fir Tree Ties are designed with either punched or threaded holes of any shape and are ideal for securing bundles in a fixed position on a specific surface. Push Mount Arrow Head Ties require significantly less extraction force than Fir Tree Ties.

For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Avery Dennison Part No.	Fig.	Color	Length (in.)	Width (in.)	Thickness (in.)	Bundle Dia min-max.	Min Loop Tensile Strength	Price Each		
									1	100	1000
Fir Tree											
514-20049	20049	B	Black	7.5	0.25	0.053	1/16"-1-3/4"	50lbs.	1.47	.88	.59
Arrow Head Push Mount											
514-20060	20060	C	Black	7.5	0.18	0.053	1/16"-5/8"	50lbs.	2.94	1.76	1.18

STUD TIES

A fool-proof bundling tie that really holds tight. Ideal for bundling wires, hoses, and tubing and for attaching the bundle to the bolt, Weld Stud Ties are designed to fit all over threaded bolts that protrude from a surface. They take very little force to insert and much greater force to remove.

For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Avery Dennison Part No.	Fig.	Color	Length (in.)	Width (in.)	Thickness (in.)	Bundle Dia min-max.	Min Loop Tensile Strength	Price Each		
									1	100	1000
Weld Stud											
514-20014	20014	D	Brown	7.5	0.25	0.053	1/4"-1-3/4"	50lbs.	2.94	1.76	1.18
514-20015	20015	D	Natural	7.5	0.25	0.053	1/16"-1-3/4"	50lbs.	1.03	.62	.41
514-20046	20046	D	Natural	7.5	0.25	0.053	1/16"-1-3/4"	50lbs.	1.03	.62	.41
Mount											
514-20062	20062	E	Natural	7.5	0.175	0.047	1/16"-1-3/4"	50lbs.	1.03	.62	.41

SPECIALTY TIES

Avery Dennison offers many innovative products including: Super Bar-Lok, Ladder Tie, Secure-a-Seal, all of which take advantage of Avery Dennison's highly advanced stretching technology. Using this technology, they continue to produce strong, flexible, light-weight and economical products.


For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Avery Dennison Part No.	Fig.	Color	Length (in.)	Width (in.)	Thickness (in.)	Bundle Dia min-max.	Min Loop Tensile Strength	Price Each		
									1	100	1000
Flip-Clip Fasteners											
514-08316	08316	F	--	1.18	0.75	--	1/2"	--	.16	.10	.07
Stopper Ties											
514-10319	10319	G	Black	8	0.13	0.054	1.6"	40lbs.	.17	.10	.07
514-10660	10660	G	Black	11	0.13	0.054	2"	50lbs.	.45	.27	.18
514-20097	20097	G	Gray	5.5	0.12	0.05	17mm	40lbs.	.24	.14	.09
514-20086	20086	G	Brown	8	0.25	0.05	7/8"-1-3/4"	50lbs.	2.94	1.76	1.18
Releasable											
514-10361	10361	H	Natural	7.5	0.177	0.05	1/16"-1-3/4"	50lbs.	.61	.37	.25
514-10362	10362	H	Black	7.5	0.177	0.05	1/16"-1-3/4"	50lbs.	.67	.40	.27
514-10367	10367	H	Natural	11	0.177	0.05	1/16"-3"	50lbs.	.71	.43	.29
514-10368	10368	H	Black	11	0.177	0.05	1/16"-3"	50lbs.	.78	.47	.31
Double Headed											
514-10424	10424	I	Natural	7.5	0.177	0.055	1/16"-1-3/4"	50lbs.	.40	.24	.16
514-10425	10425	I	Black	7.5	0.177	0.055	1/16"-1-3/4"	50lbs.	.44	.26	.18
514-10430	10430	I	Natural	11	0.177	0.055	1/16"-3"	50lbs.	.44	.27	.18
514-10431	10431	I	Black	11	0.177	0.055	1/16"-3"	50lbs.	.49	.29	.19
Convuluted Tubing Tie											
514-20093	20093	J	Black	7.5	0.25	0.04	1/16"-1-3/4"	50lbs.	1.47	.88	.59
Double Strap											
514-20040	20040	K	Black	6	0.13	0.048	1/4"-1-5/8"	20lbs.	1.03	.62	.41
Super Bar-Lok®											
514-10001	10001	L	Natural	7.5	0.195	0.038	1/16"-1-3/4"	50 lbs.	.34	.20	.14
514-10003	10003	L	Black	7.5	0.195	0.038	1/16"-1-3/4"	50 lbs.	.34	.21	.14
Inline Arrow											
514-20087	20087	M	Black	7.5	0.25	0.05	1/4"-1-3/4"	50 lbs.	1.47	.88	.59

CONNECTOR CABLE TIES

For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Avery Dennison Part No.	Fig.	Description	Price Each		
				1	100	1000
514-20101	20101	--	Amp/Tyco Connector Cable Tie	1.47	.88	.59
514-20111	20111	--	FCI Apex Connector Cable Tie	1.84	1.10	.74
514-20113	20113	--	Delphi GT Connector Cable Tie	1.84	1.10	.74

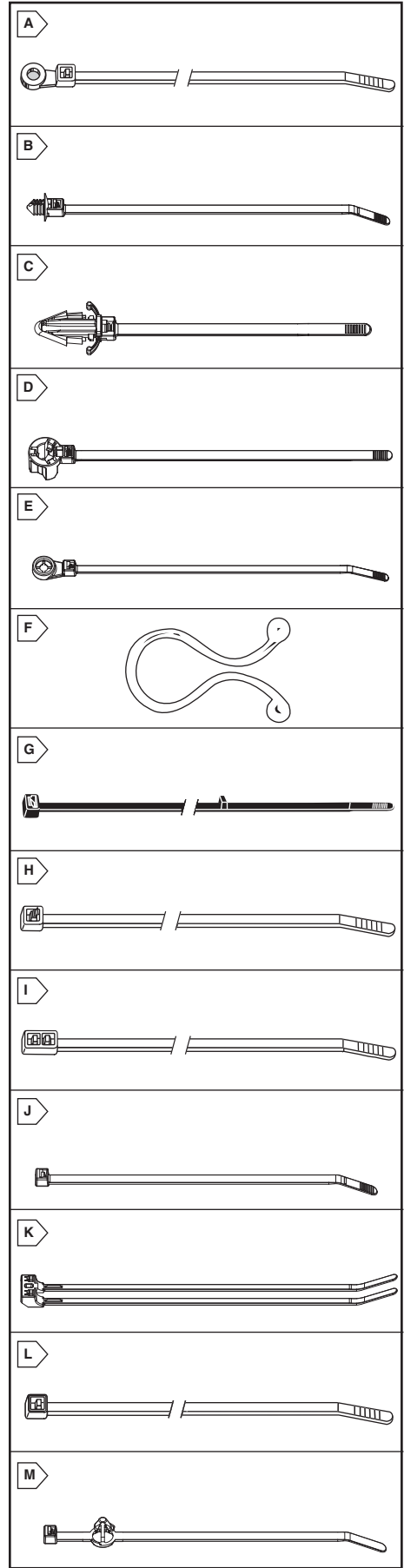

Avery Dennison Wire & Cable Mgmt.