


AVERY DENNISON Cable Mounting Hardware

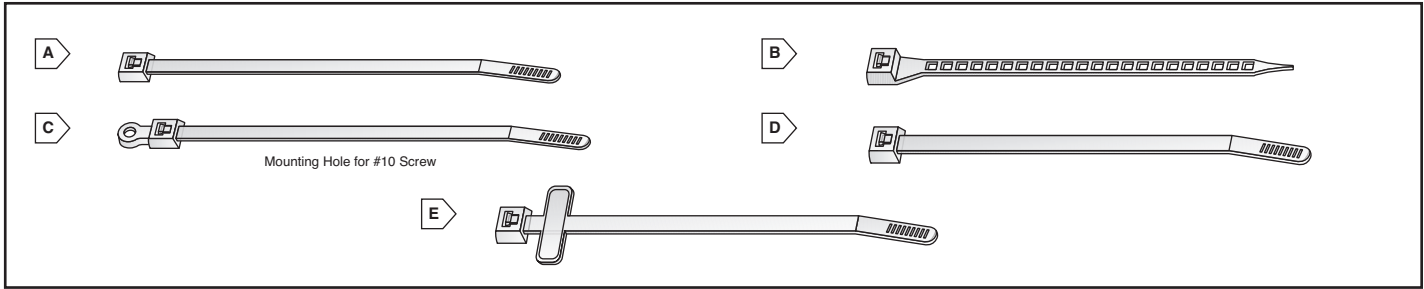

AVERY DENNISON BAR-LOK® CABLE TIES

- Features:**
- Manufactured of 100% Nylon
 - Bent-tip design for ease of handling and installation
 - Maximum holding ability

Miniature Ties For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Style	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each		
							1	100	1000
514-08432	A	Natural	18	4	.875	.095	.06	.03	.02
514-08433	A	Black Weather Resist	18	4	.875	.095	.06	.03	.02

Intermediate Ties For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Style	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each		
							1	100	1000
514-08376	A	Natural	40	5.5	1 1/4	.130	.07	.06	.05
514-08377	A	Natural	40	8	2 1/8	.130	.11	.09	.06
514-08380	A	Black Weather Resist	40	8	2 1/8	.130	.13	.11	.07

Standard Ties For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Style	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each		
							1	100	1000
514-08387	A	Natural	50	7.5	1 3/4	.177	.09	.07	.05
514-08600	A	Natural	50	11	3	.177	.15	.12	.10
514-10036	A	Natural	50	15	4	.177	.23	.19	.15
514-10037	A	Black Weather Resist	50	15	4	.177	.28	.23	.18

Ladder Ties For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Style	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each		
							1	100	1000
514-08472	B	Black Heat Stabilized	40	7	1 3/4	.140	.07	.06	.04
514-08476-1	B	Natural	40	7	1 3/4	.140	.11	.06	.04
514-08471	B	Natural	40	11	3	.140	.16	.09	.07

Specifications:

- Type 6/6 Nylon
- Self-extinguishing - UL94 flam., class: V-2
- Meet MIL-S-23190, MS3367, ASTM D 4066-82
- Operating Temperature: -40°C to 85°C
- Heat Stabilized: -40°C to 105°C

Screw Mount-Standard Ties

For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Style	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each		
							1	100	1000
514-08484-1	C	Natural	50	7.5	1 3/4	.177	.16	.13	.10
514-10327	C	Natural	50	11	3	.177	.14	.14	.12

Slim Line Ties

For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Style	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each		
							1	100	1000
514-10325	D	Natural	18	8	2 1/8	.095	.06	.05	.03
514-10327	D	Black Weather Resist.	18	8	2 1/8	.095	.09	.06	.04
514-10335	D	Natural	40	15	4	.140	.29	.21	.13

Miniature Identification Ties

Features:

- Made for bundling and identification purposes
- Can be heat stamped

Specifications:


- Type 6/6 Nylon
- Self-extinguishing - UL94 flam., class: V-2
- Designed in accordance with MIL-S-23190 and MS 3368

For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Style	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each		
							1	100	1000
514-08412	E	Natural ID	18	4	.875	.095	.20	.16	.07

AVERY DENNISON CABLE TIE ID PLATE (NYLON)

- Features:**
- For convenient tagging of wire bundles and cables

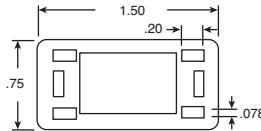

DIMENSIONS: in.

For quantities of 25,000 and up, call for quote.

MOUSER STOCK NO.	Price Each			
	1	100	1000	10,000
514-08457-1	.36	.19	.14	.12

AVERY DENNISON BAR-LOK® CABLE TIE MOUNTS


- Features:**
- Natural Nylon (Type 6/6)
 - Accommodates minimal space limitations
 - Slips through slot easily and is securely contained for easy assembly and tensioning



MOUSER STOCK NO.	Fig.	Description	Price Each			
			1	100	500	1000
514-08461	A	3/4" adhesive 4-way mount for mini & intermediate ties	.54	.19	.12	.11
514-08462-1	A	1" adhesive 4-way mount for mini and standard ties	.55	.28	.21	.16
514-10045-1	B	#8 screw size, cradle mount, for standard ties	.29	.16	.12	.10
514-10046-1	B	#10 screw size, cradle mount, for heavy duty ties	.36	.19	.15	.11
514-10027-1	C	#8 screw size, ANC base mount, for standard ties	.21	.11	.09	.06
514-10028-1	C	#10 screw size, ANC base mount, for standard ties	.27	.14	.11	.08
514-10056-1	D	Push-in mount for standard ties, .25" mounting hole	.35	.18	.14	.10

AVERY DENNISON CABLE TIE INSTALLATION TOOL

- Features:**
- This tool can accommodate all miniature, intermediate and standard ties and is ideally built to withstand the rigors of daily use on the assembly line of high production operations
 - Rugged, lightweight cast Aluminum body built to last in production environments
 - Nose of the tool allows easy access for miniature, intermediate and standard ties
 - Distance between the trigger and handle designed to lower the trigger force necessary or operation, avoiding fatigue and increasing comfort for smaller hands

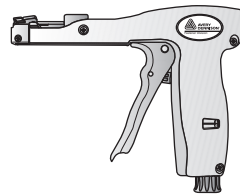



For quantities of 5 and up, call for quote.

MOUSER STOCK NO.	Price Each
514-12001-0	145.42

AVERY DENNISON CABLE CLIP

- Features:**
- Allows use of any width cable
 - Made of Type 6 Nylon
 - Accommodates stacked cable

MOUSER STOCK NO.	Description	Price Each			
		1	100	500	1000
514-08406	High quality, durable, non-conductive cable clip	.85	.45	.32	.24

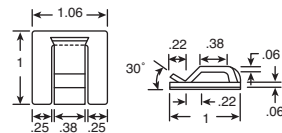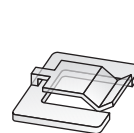

DIMENSIONS: in.