 


# EAGLE PLASTIC DEVICES Nylon Cable Ties and Installation Tool

## /// eagle STANDARD TIES




- Color: Natural
- Material: Type 6/6 Nylon (UL94V2)

For quantities of 25,000 and up, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each			
					1	100	1000	10000
<b>Miniature Range</b>								
561-N3502	17	3.15	.55	.098	.07	.05	.04	.03
481-0102	18	4.0	.98	.098	.05	.04	.03	.02
561-N3506	17	6.3	1.40	.098	.08	.06	.04	.03
561-N3508	17	7.9	2.0	.098	.12	.09	.06	.04
<b>Intermediate Range</b>								
481-0108	40	6.0	1.50	.146	.07	.05	.04	.03
561-N3512	40	7.9	2.0	.142	.13	.10	.08	.06
561-N3514	40	11.6	2.95	.142	.16	.13	.09	.08
<b>Standard Range</b>								
561-N3522	50	6.3	1.42	.189	.09	.06	.05	.04
561-N3515	50	7.1	1.58	.189	.10	.08	.06	.05
481-0115	50	8.0	2.17	.181	.08	.05	.04	.03
561-N3524	50	9.8	2.76	.189	.10	.08	.07	.06
<b>Light Heavy Range</b>								
561-N3540	120	5.9	1.42	.299	.20	.15	.13	.11
561-N3542	120	7.9	2.0	.299	.25	.20	.18	.15
561-N3544	120	11.4	3.15	.299	.25	.20	.18	.15

## /// eagle LABEL BEADED TIES

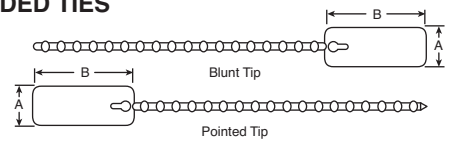

Nylon beaded tie with integral label area for writing. Permanent ink pens, felt tip pens, pressure-sensitive adhesive labels, or even Post-it® notes can be used on the polished label area.

For quantities of 5,000 and up, call for quote.

MOUSER STOCK NO.	Description	Dimensions (in.)		Price Each		
		A-Width	B-Length	1	100	1000
561-0400N	4" Blunt Tip	0.50	1.31	.57	.38	.29
561-0600N	6" Blunt Tip	0.50	1.31	.57	.38	.29
561-0400P	4" Pointed Tip	0.50	1.31	.57	.38	.29
561-0600P	6" Pointed Tip	0.50	1.31	.57	.38	.29

## /// eagle BEADED TIES

 


- Color: Natural
- Material: Type 6/6 Nylon (UL94V2)

For quantities of 25,000 and up, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Price Each			
				1	100	1000	10000
561-N3525	30	4 1/4	1.00	.05	.04	.03	.03
561-N3530	30	6	1.25	.09	.07	.06	.05
561-N3535	30	8	2.00	.12	.09	.08	.07
561-N35100	30	10	2.25	.15	.11	.09	.08


## /// eagle AC CORD TIES



For quantities of 25,000 and up, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Color	Price Each			
					1	100	1000	10000
481-0600	18	6.2	1.77	Natural	.14	.115	.099	.055
481-0601	18	6.2	1.77	Black	.14	.115	.099	.055

## /// eagle NYLON WIRE & CABLE TIE MOUNTS

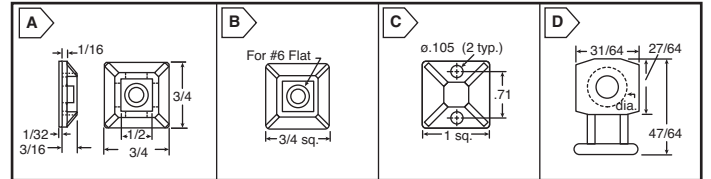

### Cradle Mounts

Used in applications where low profile is necessary. Each mount offers a four way entry and is secured with either a screw or adhesive backing. Note: the adhesive mounts have an acrylic foam backing and should be used on a smooth, clean, dry surface.

For quantities of 2000 and up, call for quote.

MOUSER STOCK NO.	Mfr.	Mfr. Part No.	Fig.	Description	Price Each			
					1	100	500	1000
561-N3588			A	3/4" Cradle Mount (adhesive)	.21	.17	.15	.09
561-N3608			B	3/4" Cradle Mount (screw)	.37	.29	.24	.18
561-N3590			C	1" Cradle Mount (adhesive)	.34	.24	.18	.15
561-N3590B			C	1" Cradle Mount (adhesive) black	.34	.24	.19	.16


### Screw Tabs

Designed for use where space is limited. Tabs are fastened with a screw to provide a low profile assembly.

MOUSER STOCK NO.	Fig.	Description	1	100	500	1000
561-N3595	D	#8 Screw Tab	.14	.11	.07	.06

## /// eagle CABLE TIE GUN

Standard adjustable metal tensioning tool for cable tie widths from .087 inch to .189 inch.

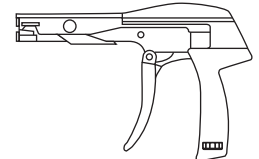


MOUSER STOCK NO.	Price Each	
	1	5
561-N3000	73.32	68.18

## /// eagle CABLE TIE KITS

- 105 cable ties per kit
- 15 pieces of each size
- 7 different ties in each
- Resealable storage bag

For quantities of 5 and up, call for quote.

MOUSER STOCK NO.	Size Range (in.)	Price Each
370-CT-1	4-6	12.95
370-CT-2	6-8	12.95

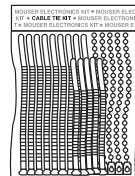

## /// eagle STANDARD WEATHER RESISTANT TIES



- UV Resistant
- Material: Type 6/6 Nylon (UL94V2)
- Color: Black

For quantities of 25,000 and up, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each			
					1	100	1000	10000
<b>Miniature Range</b>								
561-N3503	17	3.15	.55	.098	.10	.08	.07	.05
481-0102UV	18	4.0	.98	.098	.08	.06	.04	.02
561-N3507	17	6.3	1.4	.098	.11	.09	.07	.06
561-N3509	17	7.9	2.0	.098	.12	.09	.07	.06
<b>Intermediate Range</b>								
481-0108UV	40	6.0	1.5	.146	.10	.08	.06	.04
561-N3513	40	7.9	2.0	.142	.12	.10	.08	.06
561-N3516	40	11.6	2.95	.142	.16	.14	.11	.08
<b>Standard Range</b>								
561-N3523	50	6.3	1.42	.189	.21	.16	.14	.12
561-N3534	50	7.1	1.58	.189	.21	.16	.14	.12
481-0115UV	50	8.0	2.17	.181	.16	.11	.09	.07
561-N3537	50	9.8	2.76	.189	.23	.18	.15	.13
<b>Light Heavy Range</b>								
561-N3541	120	5.9	1.42	.299	.25	.20	.18	.15
561-N3543	120	7.9	2.0	.299	.25	.20	.18	.15
561-N3545	120	11.4	3.15	.299	.36	.29	.25	.21

 
## /// eagle SCREWMOUNT TIES



- Color: Natural
- Screw Mount: ø0.181"

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each			
					1	100	1000	10000
<b>Intermediate Range</b>								
481-0200	40	6.7	1.57	.146	.09	.064	.056	.05

## /// eagle IDENTIFICATION TIES



- Material: Type 6/6 Nylon (UL94V2)

For quantities of 25,000 and up, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each			
					1	100	1000	10000
<b>Miniature Range</b>								
481-0500	18	4.1	.98	.098	.12	.10	.09	.08
481-0501	18	4.4	.98	.098	.12	.10	.09	.08

## /// eagle RELEASABLE TIES



- Color: Natural

For quantities of 25,000 and up, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Price Each				
				1	100	1000	10000	
<b>Standard Release</b>								
481-0300	26	4.9	1.18	.20	.12	.088	.077	
481-0301	50	5.9	1.38	.21	.145	.12	.096	
481-0302	50	7.8	1.97	.25	.20	.17	.10	
481-0303	50	11.7	3.15	.36	.25	.18	.15	