


EAGLE PLASTIC DEVICES Nylon Wire Handling Hardware



RoHS Compliant This page of product is compliant.

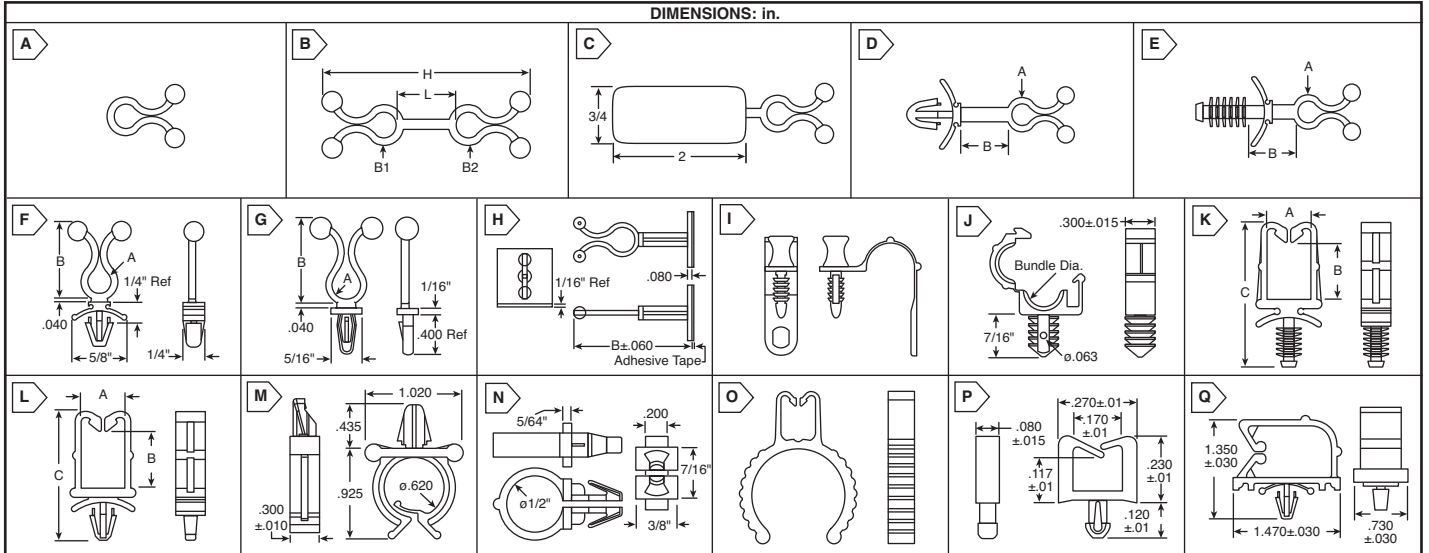

NYLON "EZ" TWIST LOCKS

Securely positions and holds wire, cable or tubing. Simply twist to wrap; untwist to unwrap. Reusable and molded of tough, resilient nylon 6/6 (UL 94V2), color: natural.

"EZ" Twist Locks

For quantities of 10,000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Description	Bundle Dia.: in.	Price Each			
				1	100	1000	5000
561-EZ125	A	1/8" lock	.11 - .14	.15	.11	.07	.05
561-EZ250	A	1/4" lock	.20 - .27	.16	.11	.07	.06
561-EZ375	A	3/8" lock	.30 - .40	.18	.11	.06	.04
561-EZ500	A	1/2" lock	.40 - .50	.17	.10	.05	.03
561-EZ625	A	5/8" lock	.55 - .65	.21	.12	.07	.06
561-EZ750	A	3/4" lock	.70 - .80	.22	.12	.09	.07

Double Ended "EZ" Twist Locks

• Color: Natural

For quantities of 2000 and up, call for quote.

MOUSER STOCK NO.	Fig.	B1 / B2	H	L	Price Each			
					1	100	500	1000
561-23DBEZ001	B	.30/.40	2 3/4	11/16	.57	.34	.20	.19
561-23DBEZ002	B	.40/.50	2 31/32	11/16	.57	.34	.20	.19

"EZ" Twist Lock Labels

For quantities of 2000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Bundle Dia.: in.	Price Each			
			1	100	500	1000
561-EZLB0250	C	1/4"	.60	.36	.21	.20
561-EZLB0375	C	3/8"	.60	.36	.21	.20

"EZ" Twist Lock Supports

• Color: Natural

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions: in.		Price Each		
		A	B	1	100	500
561-EZS250	D	.250	.954	.17	.11	.10
561-EZS200	D	.200	.011	.15	.10	.09
561-EZS450	D	.450	.625	.18	.12	.10
561-EZS625	D	.625	.028	.22	.15	.13
561-EZS375N30	D	.050	1.066	.18	.15	.09
561-EZS450N30	D	.028	1.180	.20	.18	.15
561-EZFB025	E	.375	.200	.29	.20	.17
561-EZFB050	E	.375	.437	.30	.20	.18
561-EZFB375	E	.375	.315	.15	.13	.10
561-EZ37B62	E	.375	.555	.16	.13	.11
561-EZ50C37	E	.500	.318	.18	.16	.14
561-EZ50C50	E	.500	.447	.16	.13	.11
561-EZ50C62	E	.500	.596	.16	.14	.11
561-EZ50C100	E	.500	.942	.26	.21	.18
561-EZ62C37	E	.625	.319	.27	.24	.22
561-EZ62C50	E	.625	.442	.24	.20	.18
561-EZ62C62	E	.625	.595	.24	.20	.18
561-EZ62C100	E	.625	.935	.24	.20	.18
561-EZS250B40	F	.250	1.078	.20	.17	.10
561-EZS375B40	F	.375	1.203	.21	.18	.12
561-EZS250C40	G	.250	.719	.20	.17	.10
561-EZS345C40	G	.375	.750	.20	.17	.10

"EZ" Twist Lock Support Adhesive Base

• Color: Natural

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions: in.		Price Each		
		A	B	1	100	500
561-EZAB450T	H	.190	1.230	.22	.20	.17
561-EZAB580T	H	.190	1.400	.39	.29	.23
561-EZAB5450T	H	1.070	2.149	.33	.28	.23

QUICK CABLE CLAMPS

Quick cable clamps are designed for one-handed installation. The design features an integrated ratchet fastener which eliminates the need for a screw or other fastener. The part is self-aligning, and the built-in handle allows for quick and easy installation without tools. The parts are molded from nylon 6/6 and are suitable for many different wire, cable, or tubing routing applications. Parts are designed to fit a 3/16" diameter hole.

• Color: Natural

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions: in.			Price Each		
		Bundle Dia.	Hole Size	Width	1	100	1000
561-C187250	I	.250	.187	.375	.45	.35	.23
561-C187312	I	.313	.187	.375	.45	.35	.23
561-C187375	I	.375	.187	.375	.45	.35	.23
561-C187437	I	.437	.187	.375	.45	.35	.23

RELEASEABLE CLAMPS

• On Fin clip base

• Color: Natural

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions: in.			Price Each		
		Bundle Dia.	Hole Size	Width	1	100	1000
561-CB037	J	.375	.187	.187	.55	.41	.28
561-CB050	J	.500	.187	.187	.57	.43	.29
561-CB025	J	.500	.250	.187	.55	.41	.28
561-CB100	J	1.000	.250	.375	.62	.48	.44

WIRE / CABLE HOLDERS

Wire/Cable Holders are designed to mount into 3/16 or 5mm hole diameters. Wire/Cable Holders can be used in a variety of panel thicknesses and materials. Sizes are available to handle wire bundle diameters from .375" to .500".

• Color: Natural

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions: in. ±.031			Price Each		
		A	B	C	1	100	1000
561-HA3750	K	.375	.500	.922	.40	.26	.18
561-HA3775	K	.375	.750	1.172	.40	.26	.18
561-HA5075	K	.500	.750	1.219	.40	.26	.18
561-HA5000	K	.500	1.000	1.469	.40	.26	.18
561-HB3750	L	.375	.500	.922	.40	.26	.18
561-HB3775	L	.375	.750	1.172	.40	.26	.18
561-HB5075	L	.500	.750	1.219	.40	.26	.18
561-HB5000	L	.500	1.000	1.500	.42	.28	.20

WIRE / CABLE CLIPS

Features:

- Wire Clips are molded in Nylon 6/6 material. Holds up to ten 26 gauge wires (1/32 outside dia.)
- They can be used on densely packed PC boards or any other limited space applications
- Wires install easily by pressing down on retaining arms which flex to accept wire then spring back into place
- Split wire routing clips allow for the loading of wires by separating the cup at the split and then inserting the prongs of the clip into a hole in the panel
- Various wiring, such as telephone wire, is often routed with electrical conduit
- Conduit Clips are designed to snap onto electrical conduit
- The integrated wire holder on the clip allows wiring to be secured to the conduit
- Installation is faster and easier than with a wire tie, which is often used for this purpose
- The clip can be easily removed if necessary, up to 5/16" diameter. Parts are molded in light weight, chemical and corrosion resistant Nylon 6/6

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each		
			1	100	1000
561-PM62250	M	Cord clip, bundle dia. .620	.51	.40	.37
561-RC2550	N	Split wire routing clip. Bundle dia. .500	.45	.35	.23
561-C05025	O	Conduit clip for 1/2" conduit	.51	.40	.37
561-C07531	P	Conduit clip for 3/4" conduit	.51	.40	.37
561-C170120	O	Micro wire clip	.21	.14	.11
561-WC7510	Q	Wire clip with push-in mount	.63	.48	.33