


Flat Cable, Discrete Wire and Data Cable

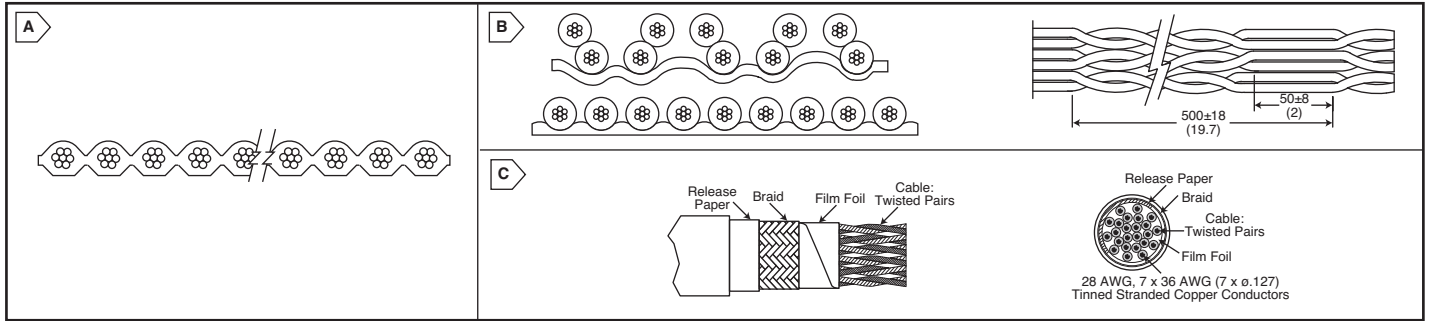

3M ROUND CONDUCTOR FLAT CABLE

3302 Series .050" Color Coded Flat Cable

By the 100ft. Spool

By the Foot

RoHS Compliant

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Conductors	Wire Gauge	Insulation Material	Conductors	Color	Price Per 100' Spool	MOUSER STOCK NO.	Price Per Foot		
										1	10	25
517-3302/9	3302/09-100	A	9	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	32.14	517-3302/9FT	1.00	.93	.88
517-3302/10	3302/10-100	A	10	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	35.70	517-3302/10FT	1.10	1.04	.99
517-3302/14	3302/14-100	A	14	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	49.98	517-3302/14FT	1.55	1.45	1.38
517-3302/16	3302/16-100	A	16	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	57.12	517-3302/16FT	1.77	1.66	1.58
517-3302/20	3302/20-100	A	20	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	71.40	517-3302/20FT	2.22	2.07	1.96
517-3302/25	3302/25-100	A	25	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	89.26	517-3302/25FT	2.77	2.59	2.46
517-3302/26	3302/26-100	A	26	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	92.82	517-3302/26FT	2.88	2.69	2.55
517-3302/34	3302/34-100	A	34	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	121.38	517-3302/34FT	3.76	3.52	3.34
517-3302/37	3302/37-100	A	37	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	132.10	517-3302/37FT	4.10	3.83	3.63
517-3302/40	3302/40-100	A	40	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	142.80	517-3302/40FT	4.43	4.14	3.93
517-3302/50	3302/50-100	A	50	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	178.50	517-3302/50FT	5.53	5.18	4.91

Twisted Pair Flat Cable 1700 Series .050"

By the 100ft. Spool

By the Foot



MOUSER STOCK NO.	3M Part No.	Fig.	No. of Conductors	Wire Gauge	Insulation Material	Conductors	Color	Price Per 100' Spool	MOUSER STOCK NO.	Price Per Foot		
										1	10	25
517-1700/10	1700/10-100	B	10	28AWG	PVC	Tinned Stranded Copper	10 color repeat	27.41	517-1700/10FT	.91	.61	.53
517-1700/14	1700/14-100	B	14	28AWG	PVC	Tinned Stranded Copper	10 color repeat	38.37	517-1700/14FT	1.27	.85	.74
517-1700/16	1700/16-100	B	16	28AWG	PVC	Tinned Stranded Copper	10 color repeat	43.85	517-1700/16FT	1.82	1.69	1.61
517-1700/26	1700/26-100	B	26	28AWG	PVC	Tinned Stranded Copper	10 color repeat	71.25	517-1700/26FT	2.94	2.75	2.61
517-1700/34	1700/34-100	B	34	28AWG	PVC	Tinned Stranded Copper	10 color repeat	93.18	517-1700/34FT	3.85	3.60	3.41
517-1700/40	1700/40-100	B	40	28AWG	PVC	Tinned Stranded Copper	10 color repeat	109.62	517-1700/40FT	4.54	4.24	4.02
517-1700/50	1700/50-100	B	50	28AWG	PVC	Tinned Stranded Copper	10 color repeat	182.70	517-1700/50FT	5.66	5.30	5.03

Round, Shielded/Jacketed, Discrete Wire Cable 3600X Series

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Conductors	Wire Gauge	Insulation Material	Conductors	Color	Price Per 300' Spool
517-3600B/14	3600B/14-300	C	14	28AWG	PVC	Tinned Stranded Copper	Beige	171.33
517-3600B/20-300	3600B/20-300	C	20	28AWG	PVC	Tinned Stranded Copper	Beige	244.76
517-3600B/26-300	3600B/26-300	C	26	28AWG	PVC	Tinned Stranded Copper	Beige	318.95
517-3600B/36	3600B/36-300	C	36	28AWG	PVC	Tinned Stranded Copper	Beige	440.57
517-3600B/68-300	3600B/68-300	C	68	28AWG	PVC	Tinned Stranded Copper	Beige	832.17


KOBICONN .050" FLAT IDC RIBBON CABLE

- By the 100ft. Spool
- RoHS Compliant per Kobiconn documentation



RoHS Compliant

MOUSER STOCK NO.	No. of Cond.	Wire Gauge	Conductors	Insulation Material	Color	Price Per 100' Spool		
						1	5	10
172-0902-E	9	28AWG	Tinned Stranded Copper	PVC	Gray	25.50	23.18	21.07
172-1010-E	10	28AWG	Tinned Stranded Copper	PVC	Gray	28.29	25.72	23.38
172-1402-E	14	28AWG	Tinned Stranded Copper	PVC	Gray	38.14	34.67	31.52
172-1502-E	15	28AWG	Tinned Stranded Copper	PVC	Gray	40.14	36.49	33.17
172-1602-E	16	28AWG	Tinned Stranded Copper	PVC	Gray	43.56	39.60	36.00
172-2002-E	20	28AWG	Tinned Stranded Copper	PVC	Gray	53.55	48.68	44.25
172-2502-E	25	28AWG	Tinned Stranded Copper	PVC	Gray	66.92	60.84	55.31
172-2602-E	26	28AWG	Tinned Stranded Copper	PVC	Gray	67.29	61.17	55.61
172-3402-E	34	28AWG	Tinned Stranded Copper	PVC	Gray	83.79	76.18	68.25
172-4002-E	40	28AWG	Tinned Stranded Copper	PVC	Gray	103.49	94.08	85.53
172-5002-E	50	28AWG	Tinned Stranded Copper	PVC	Gray	145.51	111.93	101.75
172-6002-E	60	28AWG	Tinned Stranded Copper	PVC	Gray	147.87	134.43	122.21
172-6402-E	64	28AWG	Tinned Stranded Copper	PVC	Gray	157.73	143.39	118.50

 

KOBICONN FLAT MODULAR TELEPHONE AND DATA CABLE

This modular telephone cable is available in 4, 6, and 8 conductor in three colors: silver satin, black and white. It is sold in 1000' spools.


- Features:**
- Available in black, white, or silver satin
 - Tinned copper conductors prevent corrosion
 - Compatible with all USOC modular plugs
 - RoHS Compliant per Kobiconn documentation

- Specifications:**
- 26AWG, 7 x 34 stranding
 - Conductors are USOC color coded
 - PVC jacket



RoHS Compliant

MOUSER STOCK NO.	Cond.	Color	Price Per 1000' Spool	
			1	5
172-UL4010-E	4	Silver	119.96	109.05
172-UL6010-E	6	Silver	171.14	155.58
172-UL8010-E	8	Silver	231.18	215.55
172-UL4110-E	4	Black	116.21	108.05
172-UL6110-E	6	Black	166.38	151.25
172-UL8110-E	8	Black	231.18	215.55
172-UL4210-E	4	White	116.21	108.05
172-UL6210-E	6	White	166.38	151.25
172-UL8210-E	8	White	231.18	215.55

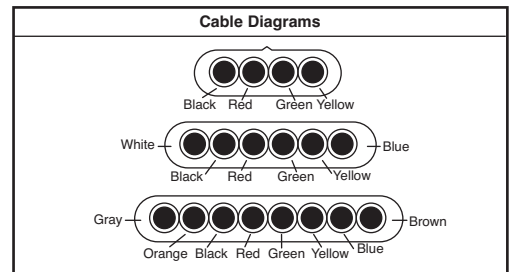

© Copyright 2009 Mouser Electronics