

AMPHENOL Spectra-Strip Cable

Amphenol®

RoHS Compliant This product is RoHS compliant.

SKewCLEAR PLUS 1X & 4X INFINIBAND CABLE

- Targets copper Infiniband links running 500MB through 6GB bandwidths




For quantities greater than 1000', call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Pairs	AWG	Application	Price Per 1000' Spool
523-160-2499-997	160-2499-997	2	24	1X	1585.63
523-160-2699-997	160-2699-997	2	26	1X	1471.50
523-160-2899-993	160-2899-993	2	28	1X	1385.80
523-166-2499-998	166-2499-998	8	24	4X	2357.00
523-166-2699-997	166-2699-997	8	26	4X	2214.30
523-166-2899-997	166-2899-997	8	28	4X	2085.80

.025" TWIST'N'FLAT 125 SERIES

- 68 count and 32 pairs
- Programmable twist-length sections
- Ideal for single-ended, LVD SCSI, Ultra320 higher
- 1.707 (in.) width (A)
- 1.675 ± 0.010 (in.) width (B)

 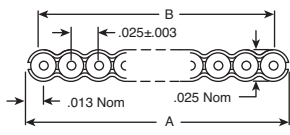


For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	Price Per Foot			
		1	50	100	500
523-125-3017-068	125-3017-068	3.81	2.87	2.80	2.80
523-125-3011-068	125-3011-068	3.81	2.80	2.80	2.80
523-125-3007-068	125-3007-068	3.81	2.80	2.80	2.80
523-125-3096-900	125-3096-900	3.81	3.33	3.08	2.87
523-425-3006-068	425-3006-068	4.27	3.07	3.07	3.07
523-125-3096-996	125-3096-996	5.24	4.19	3.81	3.49

TWIST'N'FLAT .050" CENTERS COLOR CODED FLAT CABLE

- Rapid mass termination of twisted pair cable
- 28AWG, 7/36 strand tinned copper
- Temperature rating: 176°F (80°C)
- Terminates to standard IDC connectors

 


For quantities greater than 100', call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Pairs	Total Width A (in.)	Total Width B (in.)	Price Per 100' Spool
523-132-2801-010	132-2801-010	5	0.526	0.450±0.015	37.03
523-132-2801-016	132-2801-016	8	0.826	0.750±0.015	50.82
523-132-2801-020	132-2801-020	10	1.026	0.950±0.015	73.92
523-132-2801-026	132-2801-026	13	1.326	1.250±0.015	89.24
523-132-2801-034	132-2801-034	17	1.726	1.650±0.015	115.45
523-132-2801-050	132-2801-050	25	2.526	2.450±0.020	164.04
523-132-2801-060	132-2801-060	30	3.026	2.950±0.025	178.89
523-132-2801-064	132-2801-064	32	3.226	3.150±0.025	203.43

ROUND TWIST'N'FLAT LOOSE PAIR .050" FLAT CABLE

- 28AWG, 7/36 strand tinned copper
- Voltage Rating: 300V
- Temperature rating: 221°F (105°C)

 


For quantities greater than 100', call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Pairs	Total Width A (in.)	Total Width B (in.)	Price Per 100' Spool
523-169-2832-010	169-2832-010	5	0.526	0.450±0.015	154.16
523-169-2832-020	169-2832-020	10	1.026	0.950±0.015	223.42
523-169-2832-026	169-2832-026	13	1.326	1.25±0.015	213.43
523-169-2832-034	169-2832-034	17	1.726	1.65±0.020	222.42
523-169-2832-050	169-2832-050	25	2.526	2.45±0.020	309.00

ROUND'N'FLAT .050" CENTERS ZIP CABLE

- 28AWG, 7/36 strand tinned copper
- Voltage Rating: 300V
- Internal cable is gray with a red edge
- Temperature rating: 221°F (105°C)
- Black PVC jacket with indicators for cable flats




For quantities greater than 100', call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Pairs	Total Width A (in.)	Total Width B (in.)	Price Per 100' Spool
523-159-2801-010	159-2801-010	10	0.500	0.450±0.015	119.35
523-159-2801-016	159-2801-016	16	0.800	0.750±0.015	133.09
523-159-2801-020	159-2801-020	20	1.000	0.950±0.015	131.86
523-159-2801-025	159-2801-025	25	1.250	1.200±0.011	136.84
523-159-2801-026	159-2801-026	26	1.300	1.250±0.011	139.88
523-159-2801-034	159-2801-034	34	1.700	1.650±0.011	158.07
523-159-2801-040	159-2801-040	40	2.000	1.950±0.015	168.96
523-159-2801-050	159-2801-050	50	2.500	1.450±0.015	193.21

HIGH FLEX ZIP 191-2811 SERIES

- Designed for applications that require repeated flexing without circuit interruption

 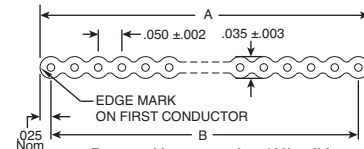


For quantities greater than 100', call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Conditions	Total Width A (in.)	Total Width B (in.)	Price Per 100' Spool
523-191-2811-010	191-2811-010	10	0.500	0.450±0.007	125.39
523-191-2811-016	191-2811-016	16	0.800	0.750±0.011	192.52
523-191-2811-020	191-2811-020	20	1.000	0.950±0.011	242.53
523-191-2811-034	191-2811-034	34	1.700	1.650±0.011	371.42

SPECTRA-ZIP .050" CENTERS GRAY FLAT CABLE

- 28AWG, 7/36 strand tinned copper
- Current Rating: 1A
- Voltage rating: 300V
- Temperature rating: 221°F (105°C)




For quantities greater than 100', call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Conditions	Total Width A (in.)	Total Width B (in.)	Price Per 100' Spool
523-191-2801-110	191-2801-110	10	0.500	0.450±0.007	21.07
523-191-2801-114	191-2801-114	14	0.700	0.650±0.007	25.68
523-191-2801-116	191-2801-116	16	0.800	0.750±0.011	28.38
523-191-2801-120	191-2801-120	20	1.000	0.950±0.011	35.48
523-191-2801-124	191-2801-124	24	1.200	1.150±0.011	35.75
523-191-2801-125	191-2801-125	25	1.250	1.200±0.011	37.24
523-191-2801-126	191-2801-126	26	1.300	1.250±0.011	38.72
523-191-2801-134	191-2801-134	34	1.700	1.650±0.011	48.62
523-191-2801-136	191-2801-136	36	1.800	1.750±0.015	67.03
523-191-2801-137	191-2801-137	37	1.850	1.800±0.015	47.42
523-191-2801-140	191-2801-140	40	2.000	1.950±0.015	57.20
523-191-2801-150	191-2801-150	50	2.500	2.450±0.015	67.24
523-191-2801-160	191-2801-160	60	3.000	2.950±0.015	70.13
523-191-2801-164	191-2801-164	64	3.200	3.150±0.015	85.80

JACKETED AND SHIELDED ZIP .050" FLAT CABLE

- Rugged flexible black PVC jacket
- EMI/RFI internal shielding
- Terminates to standard IDC connectors
- 28 AWG, 7/36 strand tinned copper
- Temperature rating: 221°F (105°C)
- Voltage rating: 300V

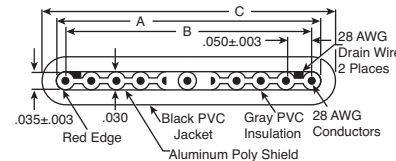


For quantities greater than 100', call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Cond.	A (in.)	B (in.)	C (in.)	Price Per 100' Spool
523-151-2831-010	151-2831-010	10	0.500	0.450	0.560	105.99
523-151-2831-015	151-2831-015	15	0.750	0.700	0.810	117.43
523-151-2831-016	151-2831-016	16	0.800	0.750	0.860	144.93
523-151-2831-020	151-2831-020	20	1.000	0.950	1.060	181.20
523-151-2831-034	151-2831-034	34	1.700	1.650	1.760	274.08
523-151-2831-037	151-2831-037	37	1.850	1.800	1.910	289.75
523-151-2831-040	151-2831-040	40	2.000	1.950	2.060	317.74
523-151-2831-050	151-2831-050	50	2.500	2.450	2.560	403.05

3C COLOR CODED .050" CENTERS FLAT CABLE

- 28AWG, 7/36 strand tinned copper
- Temperature rating: 221°F (105°C)
- Terminates to standard IDC connector
- Current Rating: 1A
- Voltage rating: 300V
- Precise spacing for controlled electrical current

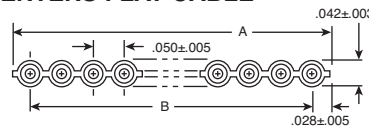

For quantities greater than 100', call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Conditions	Total Width A (in.)	Total Width B (in.)	Price Per 100' Spool
523-135-2801-010	135-2801-010	10	0.505	0.450±0.015	41.25
523-135-2801-014	135-2801-014	14	0.705	0.650±0.015	48.62
523-135-2801-016	135-2801-016	16	0.805	0.750±0.015	54.34
523-135-2801-020	135-2801-020	20	1.005	0.950±0.015	68.62
523-135-2801-025	135-2801-025	25	1.255	1.200±0.015	76.74
523-135-2801-026	135-2801-026	26	1.305	1.250±0.015	74.90
523-135-2801-037	135-2801-037	37	1.855	1.800±0.015	107.40
523-135-2801-040	135-2801-040	40	2.005	1.950±0.020	116.98
523-135-2801-050	135-2801-050	50	2.505	2.450±0.020	134.76
523-135-2801-064	135-2801-064	64	3.205	3.150±0.020	178.37