


# BELDEN 75 Ohm Coaxial and Camera Cables

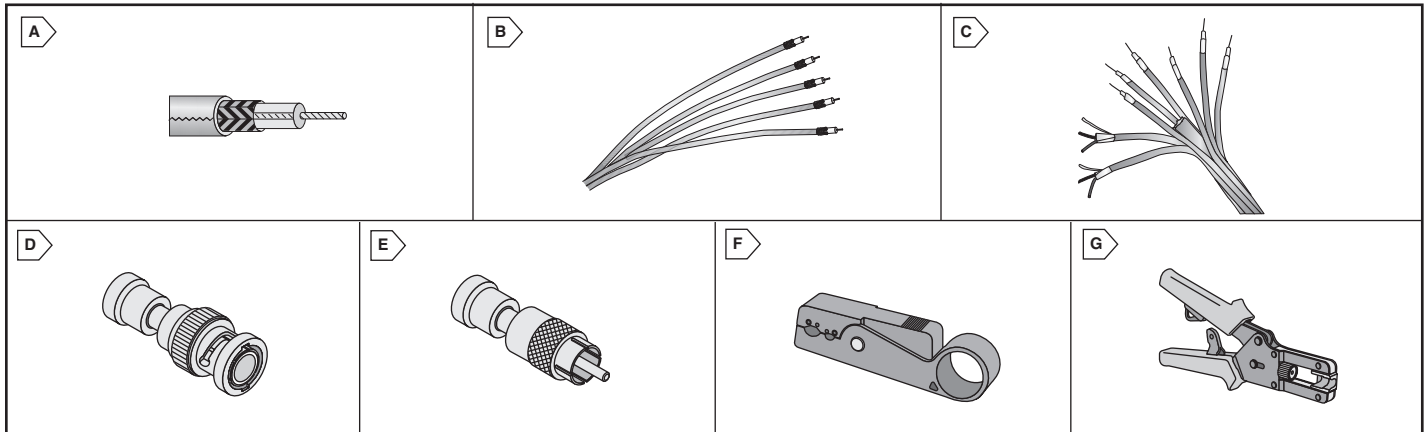

## BELDEN COAXIAL CABLES

### MIL-C-17G QPL Cable

- 94% Silver Coated Copper Braid
- Tinted Brown FEP Jacket



RoHS Compliant



Recommend Heat Shrink **FT221**

Belden Part No.	Fig.	AWG (Stranded)	Nominal O.D. (in.)	100' Spools		500' Spools		1000' Spools	
				MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
83264	A	30 (7 x 38)	.100	<a href="#">566-83264-100</a>	151.50	<a href="#">566-83264-500</a>	591.16	<a href="#">566-83264-1000</a>	1154.95

### Mini Hi-Res Component Video Cable

- Available Colors: 00 is Clear, 10 is Black



RoHS Compliant



Recommend Heat Shrink **FT400**

Belden Part No.	Fig.	Component Descriptions	AWG (Stand)	Shielding	500' Spools		1000' Spools	
					MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
1281S3	B	75Ω Coax 3C	25 (Solid)	100% Duobond® Foil	<a href="#">566-1281S3-500-00</a>	483.49	<a href="#">566-1281S3-1000-00</a>	914.13
1281S5	B	75Ω Coax 5C	25 (Solid)	100% Duobond® Foil	<a href="#">566-1281S5-500-00</a>	727.98	<a href="#">566-1281S5-1000-00</a>	1376.39
1281S6	B	75Ω Coax 6C	25 (Solid)	100% Duobond® Foil	<a href="#">566-1281S6-500-00</a>	903.64	<a href="#">566-1281S6-1000-00</a>	1731.06
1282S3	B	75Ω Coax 3C Plenum	25 (Solid)	100% Duobond® Foil	<a href="#">566-1282S3-500-00</a>	554.30	<a href="#">566-1282S3-1000-00</a>	1048.03
1282S4	B	75Ω Coax 4C Plenum	25 (Solid)	100% Duobond® Foil	<a href="#">566-1282S4-500-00</a>	734.94	<a href="#">566-1282S4-1000-00</a>	1408.32
1282S5	B	75Ω Coax 5C Plenum	25 (Solid)	100% Duobond® Foil	<a href="#">566-1282S5-500-00</a>	888.21	<a href="#">566-1282S5-1000-00</a>	1679.31
1282S6	B	7Ω Coax 6C Plenum	25 (Solid)	100% Duobond® Foil	<a href="#">566-1282S6-500-00</a>	1051.06	<a href="#">566-1282S6-1000-00</a>	2014.19
1283S3	B	75Ω Coax 3C	20 (Solid)	95% Duofoil® + TC Foil	<a href="#">566-1283S3-500-00</a>	2535.19	<a href="#">566-1283S3-1000-00</a>	4858.20
1283S5	B	75Ω Coax 5C	20 (Solid)	95% Duofoil® + TC Foil	<a href="#">566-1283S5-500-00</a>	3996.08	-----	-----
1283S6	B	75Ω Coax 6C	20 (Solid)	95% Duofoil® + TC Foil	<a href="#">566-1283S6-500-00</a>	4685.81	<a href="#">566-1283S6-1000-00</a>	8979.43

## BELDEN BANANA PEEL® PROJECTOR CABLES

- Inter-room Audio/Video Composites: 6 Mini Hi-res Coaxes
- + 2 Shielded Twisted Pairs Riser- and Plenum-rated
- Insulation for 5788AV: Gas-injected foam Polyethylene (coax) and PVC (pairs)
- 6788AV: Low smoke foam Fluoropolymer (coax) and LS-PVC (pairs)



Recommend Heat Shrink **FT400**

Belden Part No.	Fig.	NEC Type	No. of Pairs	AWG Stranded	Nominal O.D. (in.)	Nom Imp.	% Type Shield	500' Box		1000' Spools	
								MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
5788AV	C	CMR	6-Coax 2-Pair	25 (solid) 22 (7x30)	.442	75	95	<a href="#">566-5788AV-250-09</a>	445.68	<a href="#">566-5788AV-1000-09</a>	1695.04
6788AV	C	CMR	6-Coax 2-Pair	20 (solid) 22 (7x30)	.433	75	95	-----	-----	<a href="#">566-6788AV-1000-09</a>	2402.69

## BELDEN 75 OHM BNC CONNECTOR (MADE FOR MINI HI-RES COAXIAL CABLE)



RoHS Compliant

- Current Rating: 5 amps
- Max. Working Voltage: 300V
- Body Material: Brass
- Body Plating: Nickel
- Cable Attachment Method: Compression Style

MOUSER STOCK NO.	Belden Part No.	Fig.	Price Each	
			1	5
<a href="#">566-1B25A</a>	1B25A	D	4.24	3.75

## BELDEN COAX CABLE STRIPPER TOOL



RoHS Compliant

This Prep tool is suitable for RG-6, RG-59 and Mini RG-59 cable.

MOUSER STOCK NO.	Belden Part No.	Fig.	Price Each	
			1	2
<a href="#">566-HCST</a>	HCST	F	49.11	47.87

## BELDEN RCA CONNECTOR (MADE FOR MINI HI-RES COAXIAL CABLE)



RoHS Compliant

- Current Rating: 2 amps
- Max. Working Voltage: 300V
- Body Material: Brass
- Body Plating: Nickel
- Cable Attachment Method: Compression Style

MOUSER STOCK NO.	Belden Part No.	Fig.	Price Each	
			1	5
<a href="#">566-1R25A</a>	1R25A	E	3.81	3.55

## BELDEN COMPRESSION TOOL (WORKS WITH BNC AND RCA PRODUCTS)



RoHS Compliant

This Compression tool is suitable for connectors 1B25A and 1R25A

MOUSER STOCK NO.	Belden Part No.	Fig.	Price Each	
			1	2
<a href="#">566-HCCT</a>	HCCT	G	84.54	81.98