


BELDEN 75 Ohm Coaxial Cables

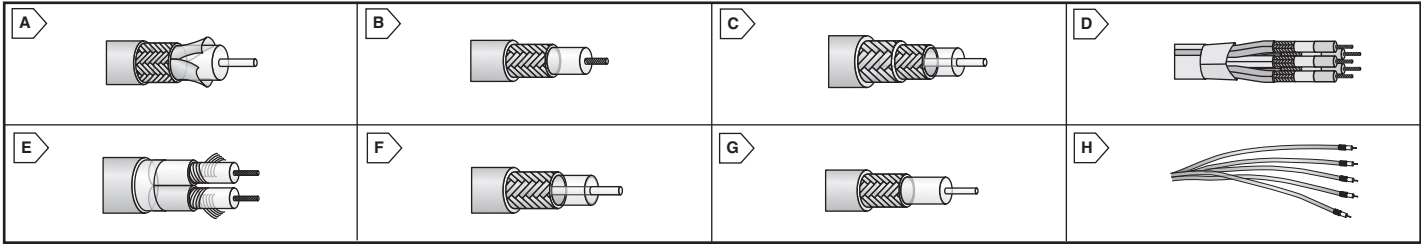

RoHS Compliant **This product is RoHS compliant.**



BELDEN PRECISION VIDEO INTERCONNECTS

COLOR CODE CHART

Colors=Ordering Suffix

01=Brown	02=Red	03=Orange	04=Yellow	05=Green
06=Blue	07=Violet	08=Gray	09=White	10=Black

† Cables are tested to 4.5 GHz and have guaranteed return loss -23dB 5MHz-1.6GHz, 21db 1.6GHz-4.5GHz



To order replace ___ with applicable code for color desired.

500' Spools

1000' Spools

Belden Part No.	Fig.	NEC Type	AWG (Stranded)	Nominal O.D. (in.)	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
Duofoil® 95% Tinned Copper Braid Shield								
† 179DT	A	CMR	28.5 (Solid)	.100	566-179DT-500-10	267.44	566-179DT-1000-___	507.52
† 1855A	A	CMR	23 (Solid)	.102	566-1855A-500-10	217.80	566-1855A-1000-___	413.33
† 1506A	A	CMP	20 (Solid)	.196	566-1506A-500-10	775.72	566-1506A-1000-___	1472.11
† 1505A	A	CMR	20 (Solid)	.223	566-1505A-500	227.48	566-1505A-1000-BLK	420.57
† 1695A	A	CMP	18 (Solid)	.234	566-1695A-500-10	890.56	566-1695A-1000-___	1690.04
† 1694A	A	CMR	18 (Solid)	.274	566-1694A-500	264.94	566-1694A-1000	502.40
† 7731A	A	CMR	14 (Solid)	.400	566-7731A-500-___	762.95	566-7731A-1000-___	1307.28
Double Tinned Copper Braid Shield								
1505F	C	CM	22 (7 x 29)	.242	-----	-----	566-1505F-1000-___	611.82
1694F	C	CMR	19 (4 x 27)	.274	-----	-----	566-1694F-1000-BK	748.60
8281F	C	---	22 (7 x 29)	.305	566-8281F-500	671.71	566-8281F-1000	1274.72

Wire & Cable Belden

BELDEN MINIATURE BRILLIANCE® SNAKE CABLE



• Duofoil® Tape and 95% Tinned Copper Braid (100% Shield Coverage)

500' Spools

1000' Spools

Belden Part No.	Fig.	No. of Cond.	NEC Type	AWG (Stranded)	Nominal O.D. (in.)	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
7787A	D	3	CMR	23 (solid)	.432	566-7787A-500	1120.54	566-7787A-1000	2237.74
7789A	D	5	CMR	23 (Solid)	.539	566-7789A-500-10	1641.84	566-7789A-1000-10	3370.06
7790A	D	6	CMR	23 (solid)	.597	566-7790A-500	2300.98	566-7790A-1000	4375.64

BELDEN HIGH FLEX, S-VHS PRECISION VIDEO CABLE



• Matte Black PVC Jacket • Dual Coaxial Cables
• 90% Tinned Copper Shield

500' Spools

1000' Spools

Belden Part No.	Fig.	Description	AWG (Stranded)	Nominal O.D. (in.)	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
1808A	E	Dual conductor, high flex VHS	30 (7 x 38)	.255	566-1808A-500	566.55	566-1808A-1000	1075.15

BELDEN STANDARD ANALOG VIDEO CABLE



* Available in Box only

100' Spools

500' Spools

1000' Spools

Belden Part No.	Fig.	NEC Type	AWG (Stranded)	MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
RG-59/U95% Bare Copper Braid Shield									
8241	F	CM	23 (Solid)	566-8241-100	62.11	566-8241-500	161.76	566-8241-1000	307.35
8241F	F	---	22 (7 x 30)	-----	-----	-----	-----	566-8241F-1000	520.86
82241	G	CMP	23 (Solid)	-----	-----	*566-82241-U500	859.69	-----	-----
8263	B	CMX	23 (Solid)	-----	-----	-----	-----	566-8263-1000	642.43
9259	B	CM	22 (7 x 30)	566-9259-100	75.07	566-9259-500	229.32	566-9259-1000	436.09
9274	G	CM	20 (Solid)	-----	-----	566-9274-500	225.56	-----	-----
1426A	G	CM	20 (Solid)	-----	-----	-----	-----	*566-1426A-1000	371.03
RG-6/U Duofoil®/60% Tinned Copper Braid Shield									
9248	A	CM	18 (Solid)	-----	-----	566-9248-500	245.25	566-9248-1000	466.37
RG-6/U 96% Bare Copper Braid Shield									
8215	C	---	21 (Solid)	-----	-----	-----	-----	566-8215-1000-10	1762.66

BELDEN BRILLIANCE® BANANA PEEL PRECISION VIDEO SNAKE CABLES



Duofoil® + 95% Tinned Copper Braid Shield (100% coverage)

500' Spools

1000' Spools

Belden Part No.	Fig.	No. of Cond.	NEC Type	AWG (Stranded)	Nominal O.D. (in.)	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
1855S3	H	3	CMR	23 (solid)	.159	566-1855S3-500	740.74	566-1855S3-1000	1408.61
1855S5	H	5	CMR	23 (solid)	.159	566-1855S5-500	1132.56	566-1855S5-1000	2219.26
1855S6	H	6	CMR	23 (solid)	.159	566-1855S6-500	1267.36	566-1855S6-1000	2410.05
1505S3	H	3	CMR	20 (solid)	.235	566-1505S3-500	750.20	566-1505S3-1000	1423.68
1505S5	H	5	CMR	20 (solid)	.235	566-1505S5-500	1183.25	566-1505S5-1000	2245.49
1505S6	H	6	CMR	20 (solid)	.235	566-1505S6-500	1389.00	566-1505S6-1000	2721.90
1694S3	H	3	CMR	18 (solid)	.274	566-1694S3-500	1108.47	566-1694S3-1000	2107.89
1694S5	H	5	CMR	18 (solid)	.274	566-1694S5-500	1750.01	566-1694S5-1000	3327.88
1694S6	H	6	CMR	18 (solid)	.274	566-1694S6-500	2047.66	566-1694S6-1000	3893.90

