


# BELDEN Audio, Security, Alarm and Camera Cables



RoHS Compliant This product is RoHS compliant.

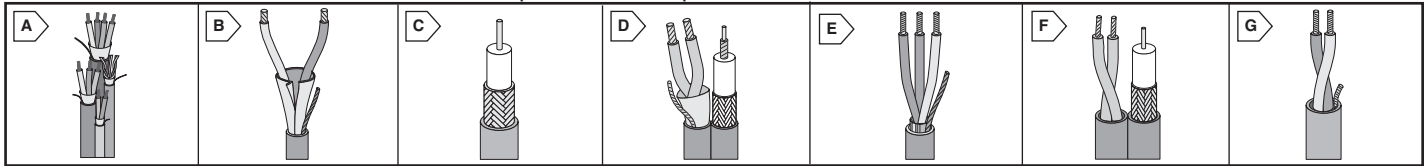

## BELDEN® NEW GENERATION® WATERDOG CABLES

- Water and Moisture Resistant
- UL Listed for a Range of Indoor/Outdoor and Direct Burial Installations

Belden Part No.	Fig.	No. of Conductors	AWG (Stranded)	Nominal O.D. (in.)	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
<b>Stranded Tinned Copper, PVC Jacketed, Unshielded</b>								
5300U1	A	2	18 (7 x 26)	.207	566-5300U1-500-08	114.01	566-5300U1-1000-08	229.60
<b>Stranded Tinned Copper, PVC Jacketed, Shielded</b>								
5500F1	B	2	22 (7 x 30)	.192	-----	-----	566-5500F1-1000-08	186.84
5400F1	B	2	20 (7 x 28)	.206	-----	-----	566-5400F1-1000-08	247.61
5300F1	B	2	18 (7 x 26)	.222	-----	-----	566-5300F1-1000-08	306.19
<b>Stranded Tinned Copper, PVC Jacketed, Unshielded</b>								
5302U1	A	4	18 (7 x 26)	.254	-----	-----	566-5302U1-1000-10	370.94
5202U1	A	4	16 (7 x 24)	.291	-----	-----	566-5202U1-1000-10	566.71
5102U1	A	4	14 (19 x 27)	.341	-----	-----	566-5102U1-1000-10	895.00
<b>Stranded Tinned Copper, PVC Jacketed, Shielded</b>								
5302F1	B	4	18 (7 x 26)	.255	-----	-----	566-5302F1-1000-10	441.86
5202F1	B	4	16 (7 x 24)	.295	-----	-----	566-5202F1-1000-10	630.08
<b>Bare Copper Coax, PVC Jacket, Aluminum Braid Plus 100% Foil Shield (CATV)</b>								
5339W5	C	-----	18 (solid)	.270	566-5339W5-500-10	110.60	566-5339W5-1000-10	194.91
<b>Bare Copper Coax, PVC Jacket, Bare Copper Braid Shield (CCTV)</b>								
5439X5	C	-----	20 (solid)	.244	-----	-----	566-5439X5-1000-10	297.95
5339X5	C	-----	18 (solid)	.277	-----	-----	566-5339X5-1000-10	376.26
<b>Bare Copper Coax, PVC Jacket, Tinned Copper Braid Shield Plus 100% Foil Shield (CCTV/MATV)</b>								
5439W5	C	-----	20 (solid)	.236	566-5439W5-500-10	133.77	566-5439W5-1000-10	269.79
<b>COAX: Solid Bare Copper, PAIR: Stranded Bare Copper, PVC Jacket (CCTV + Power)</b>								
5399X5	D	-----	18(cx)Solid 16(pr) 7/w	.279 x .549	-----	-----	566-5399X5-1000-10	662.39
5499X5	D	-----	20(cx)Solid 18(pr) 7/w	.249 x .497	-----	-----	566-5499X5-1000-10	546.28

## BELDFOIL® SHIELD AUDIO, SECURITY, AND ALARM CABLE

- Bare Copper Conductors
- PVC Insulation
- Cabled Beldfoil® Shield Tape (Aluminum side out) with drain wire
- Sequential footage marking every two feet
- Gray PVC Jacket

\* Available in box only

5000FE	B	2	12 (19 x 25)	0.272	566-5000FE-500-08	253.44	566-5000FE-1000-08	568.92
5200FE	B	2	16 (19 x 29)	0.188	566-5200FE-500-08	98.74	566-5200FE-1000-08	187.38
5300FE	B	2	18 (7 x 26)	0.165	566-5300FE-500-08	68.91	566-5300FE-1000-08	130.77
5301FE	B	3	18 (7 x 26)	0.175	566-5301FE-500-08	101.20	566-5301FE-1000-08	208.09
5302FE	B	4	18 (7 x 26)	0.192	566-5302FE-500-08	126.99	566-5302FE-1000-08	240.99
5304FE	B	6	18 (7 x 26)	0.23	-----	-----	566-5304FE-1000-08	413.53
5400FE	B	2	20 (7 x 28)	0.145	-----	-----	566-5400FE-1000-08	146.52
5500FE	B	2	22 (7 x 30)	0.150	566-5500FE-500-08	45.59	566-5500FE-1000-08	90.90
5502FE	B	4	22 (7 x 30)	0.152	566-5502FE-500-08	72.60	566-5502FE-1000-08	154.35
5504FE	B	6	22 (7 x 30)	0.179	* 566-5504FE-U500-08	113.88	* 566-5504FE-U1000-08	240.91

## UNSHIELDED AUDIO, SECURITY, AND ALARM CABLE

- Bare Copper Conductors
- PVC Insulation with rip cord
- Sequential footage marking every two feet
- Gray PVC Jacket

\* Available in box only

5100UE	E	2	14 (19 x 26)	.234	566-5100UE-500-08	140.45	566-5100UE-1000-08	266.54
5200UE	E	2	16 (19 x 29)	.184	566-5200UE-500-08	86.68	566-5200UE-1000-08	164.50
5202UE	E	4	16 (19 x 29)	.216	566-5202UE-500-08	153.83	566-5202UE-1000-08	291.92
5300UE	E	2	18 (7 x 26)	.161	566-5300UE-500-08	59.84	566-5300UE-1000-08	120.24
5302UE	E	4	18 (7 x 26)	.188	-----	-----	566-5302UE-1000-08	208.09
5500UE	E	2	22 (7 x 30)	.128	-----	-----	566-5500UE-1000-08	89.37
5502UE	E	4	22 (7 x 30)	.148	* 566-5502UE-U500-08	63.74	* 566-5502UE-U1000-08	123.30
5504UE	E	6	22 (7 x 30)	.177	566-5504UE-500-08	102.04	566-5504UE-1000-08	161.66
5582UE	E	4	22 (Solid)	.141	* 566-5582UE-U500-08	74.79	* 566-5582UE-U1000-08	138.58

- Bare Copper Conductors
- Flamarrest® Insulation
- Conductors Cabled
- Natural Flamarrest® Jacket with rip cord
- Sequential footage marking every two feet
- Plenum-Rated

\* Available in box only

6200UE	E	2	16 (19 x 29)	.180	566-6200UE-500	122.18	-----	-----
6300UE	E	2	18 (7 x 26)	.157	566-6300UE-500	80.95	566-6300UE-1000	123.92
6301UE	E	3	18 (7 x 26)	.168	566-6301UE-500	134.06	566-6301UE-1000	253.98
6302UE	E	4	18 (7 x 26)	.186	566-6302UE-500	158.67	566-6302UE-1000	289.33
6502UE	E	4	22 (7 x 30)	.143	566-6502UE-500	81.34	566-6502UE-1000	146.48

## CAMERA CABLES (FOR CCTV APPLICATIONS)

- Banana Peel Jacketless Cables**
- No Overall Jacket
- PVC Insulation
- PVC Jacket

Belden Part No.	Fig.	Component Description	AWG (Stranded)	Shielding	500' Spools		1000' Spools	
					MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 500' Spool
558AFS	F	4-Conductors	18 (7 x 26)	Bare Copper Shielded	566-558AFS-500	459.16	566-558AFS-1000	875.97
		3-Pair	22 (7 x 30)					
		2-Conductors	22 (7 x 30)					
658AFS	F	4-Conductors	18 (7 x 26)	Bare Copper Shielded	566-658AFS-500	501.84	566-658AFS-1000	1414.08
		3-Pair	22 (7 x 30)					
		2-Conductors	22 (7 x 30)					
		4-Conductors	22 (7 x 30)					

### Composite Camera Cable

9265	D	75 Ohm Coax RG-59/U Foil Shielded Twisted Pair	22 (7 x 30) 22 (7 x 30)	95% Bare Copper Braid Beldfoil®	566-9265-500	519.03	566-9265-1000	982.13
549945	F	75 Ohm Coax RG-59/U 1 Twisted Pair	20 (Solid) 18 (7 x 26)	95% Bare Copper Braid Unshielded	566-549945-500	134.73	566-549945-1000	284.40
539945	F	75 Ohm Coax RG-6/U 1 Twisted Pair	18 (Solid) 18 (7)	95% Bare Copper Braid Unshielded	566-539945-500-10	222.78	566-539945-1000-10	373.75

### 75 Ohm Coaxial Camera Cable

543945	G	RG-59/U	20 (Solid)	95% Bare Copper Braid	566-543945-500-10	79.38	566-543945-1000-10	150.64
533945	G	RG-6/U	18 (Solid)	95% Bare Copper Braid	566-533945-500	142.80	566-533945-1000	222.78
513945	G	RG-11/U	14 (Solid)	95% Bare Copper Braid	566-513945-500-10	237.07	566-513945-1000-10	474.15

