


BELDEN Multi-Conductor Cables



RoHS Compliant This product is RoHS compliant.

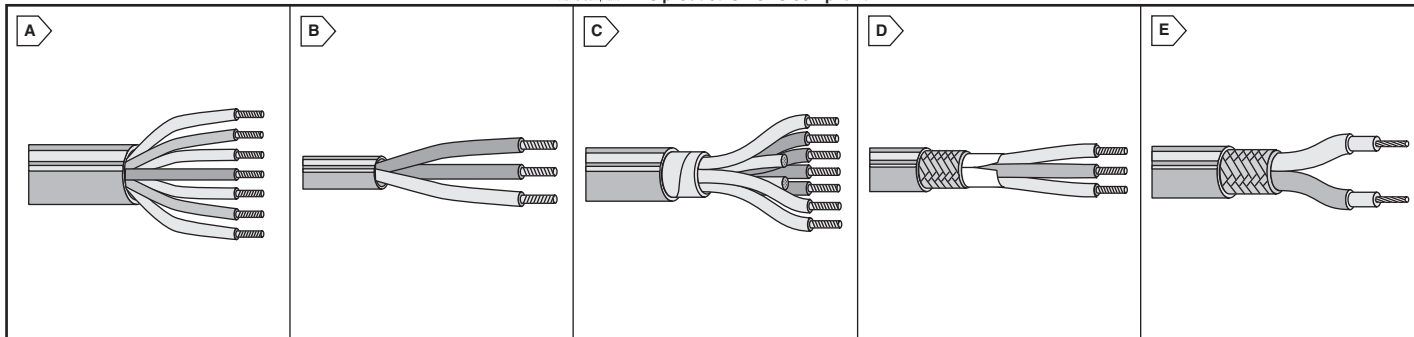

UNSHIELDED AUDIO, CONTROL, AND INSTRUMENTATION CABLE

- Tinned copper stranded, PVC insulated, conductor cabled. Chrome PVC jacket
- Non-Plenum

Recommend Heat Shrink **FTI221**



Belden Part No.	Fig.	No. of Cond.	AWG Stranding	Nominal O.D. (in.)	MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	500' Spool		MOUSER STOCK NO.	1000' Spool	
								1	2		1	2
UL AWM Style 2464, (300V 80°C)												
9439	A	7	20 (7 x 28)	.260	566-9439-100	100.77	566-9439-500	398.93	377.91	-----	-----	-----
9444	A	4	20 (7 x 28)	.217	566-9444-100	57.67	566-9444-500	207.06	206.07	566-9444-1000	432.54	399.03
9445	A	5	20 (7 x 28)	.239	566-9445-100	67.45	566-9445-500	288.18	272.97	566-9445-1000	545.94	503.76
9455	A	9	20 (7 x 28)	.317	566-9455-100	139.59	-----	-----	-----	-----	-----	-----
UL AWM Style 2598, (300V 60°C)												
8489	A	4	18 (19 x 30)	.257	566-8489-100	66.47	566-8489-500	265.12	252.08	-----	-----	-----
8465	A	5	18 (19 x 30)	.282	566-8465-100	82.42	566-8465-500	352.20	333.63	-----	-----	-----
8467	A	7	18 (19 x 30)	.314	566-8467-100	125.08	-----	-----	-----	-----	-----	-----
8466	A	12	18 (19 x 30)	.412	566-8466-100	201.78	-----	-----	-----	-----	-----	-----
8468	A	15	18 (19 x 30)	.500	566-8468-100	281.85	-----	-----	-----	-----	-----	-----
8619	A	19	18 (19 x 30)	.490	566-8619-100	435.05	-----	-----	-----	-----	-----	-----
9626	A	25	18 (19 x 30)	.612	566-9626-100	683.39	-----	-----	-----	-----	-----	-----
600V RMS 80°C												
8620	A	4	16 (19 x 29)	.376	566-8620-100	158.64	-----	-----	-----	-----	-----	-----
8621	A	7	16 (19 x 29)	.458	566-8621-100	267.57	-----	-----	-----	-----	-----	-----
9721	A	8	16 (19 x 29)	.496	566-9721-100	319.57	-----	-----	-----	-----	-----	-----
UL AWM Style 2576, (150V 80°C)												
8443	B	3	22 (7 x 30)	.172	-----	-----	566-8443-500	132.55	125.55	566-8443-1000	277.92	268.39
8444	B	4	22 (7 x 30)	.185	-----	-----	566-8444-500	162.77	154.76	566-8444-1000	309.51	295.01
8445	B	5	22 (7 x 30)	.194	566-8445-100	54.90	-----	-----	-----	566-8445-1000	444.42	429.21
9430	B	7	22 (7 x 30)	.214	-----	-----	566-9430-500	265.56	251.55	566-9430-1000	503.10	485.95
9421	B	8	22 (7 x 30)	.229	566-9421-100	71.96	566-9421-500	268.35	260.22	566-9421-1000	582.66	561.59
9423	B	9	22 (7 x 30)	.244	566-9423-100	79.86	566-9423-500	309.76	300.17	-----	-----	-----
8456	B	10	22 (7 x 30)	.264	566-8456-100	96.37	-----	-----	-----	-----	-----	-----
8457	B	12	22 (7 x 30)	.272	566-8457-100	106.14	-----	-----	-----	-----	-----	-----
9431	B	20	22 (7 x 30)	.345	566-9431-100	232.55	-----	-----	-----	-----	-----	-----
8459	B	25	22 (7 x 30)	.387	566-8459-100	276.64	-----	-----	-----	-----	-----	-----
9432	B	30	22 (7 x 30)	.400	566-9432-100	361.10	-----	-----	-----	-----	-----	-----
9433	B	40	22 (7 x 30)	.455	566-9433-100	526.10	-----	-----	-----	-----	-----	-----

Wire & Cable
Belden

UNSHIELDED POWER AND CONTROL CABLE

- Rubber and Oil Resistant Rubber SO Cables
- 600V RMS 60°C
- Rubber Insulation
- Conductors Cabled with Fillers
- Stranded Conductors
- Black Oil-resistant Rubber Jacket
- Bare Copper

RoHS Compliant

Recommend Heat Shrink **FTI600**

Recommend Heat Shrink **FTI700**

Recommend Heat Shrink **FTI750**

Belden Part No.	Fig.	No. of Conductors	AWG Stranding	Nominal O.D. (in.)	MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	500' Spool	
								1	2
9422	C	7	16 (65 x 34)	.581	566-9422-100	492.65	-----	-----	-----
9424	C	9	16 (65 x 34)	.720	566-9424-100	624.11	-----	-----	-----

OVERALL BRAID AUDIO, CONTROL, AND INSTRUMENTATION CABLE

- 200V RMS 105°C
- Chrome PVC Jacket
- Polypropylene Insulation
- 95% Tinned Copper Braid Shield

Recommend Heat Shrink **FTI221**



Belden Part No.	Fig.	No. of Conductors	AWG Stranding	Nominal O.D. (in.)	MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	250' Spool	
								1	2
8643	D	3	30 (7 x 38)	.096	-----	-----	566-8643-250	297.03	287.84

OVERALL BRAID COMMUNICATION AND INSTRUMENTATION SHIELD CABLE

- 600V RMS 105°C
- 90% Tinned Copper Braid Shield
- MIL-W-16878 (Type) Conductors, Shielded, and Jacketed
- PVC Insulation and White PVC Jacket

Recommend Heat Shrink **FTI221**



Belden Part No.	Fig.	No. of Conductors	AWG Stranding	Nominal O.D. (in.)	MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	500' Spool	
								1	2
9962	E	2	20 (19 x 32)	.192	566-9962-100	138.55	-----	-----	-----

