


# BELDEN Portable Cordage & Datatuff® Industrial Ethernet Cable



ROHS Compliant This page of product is compliant.

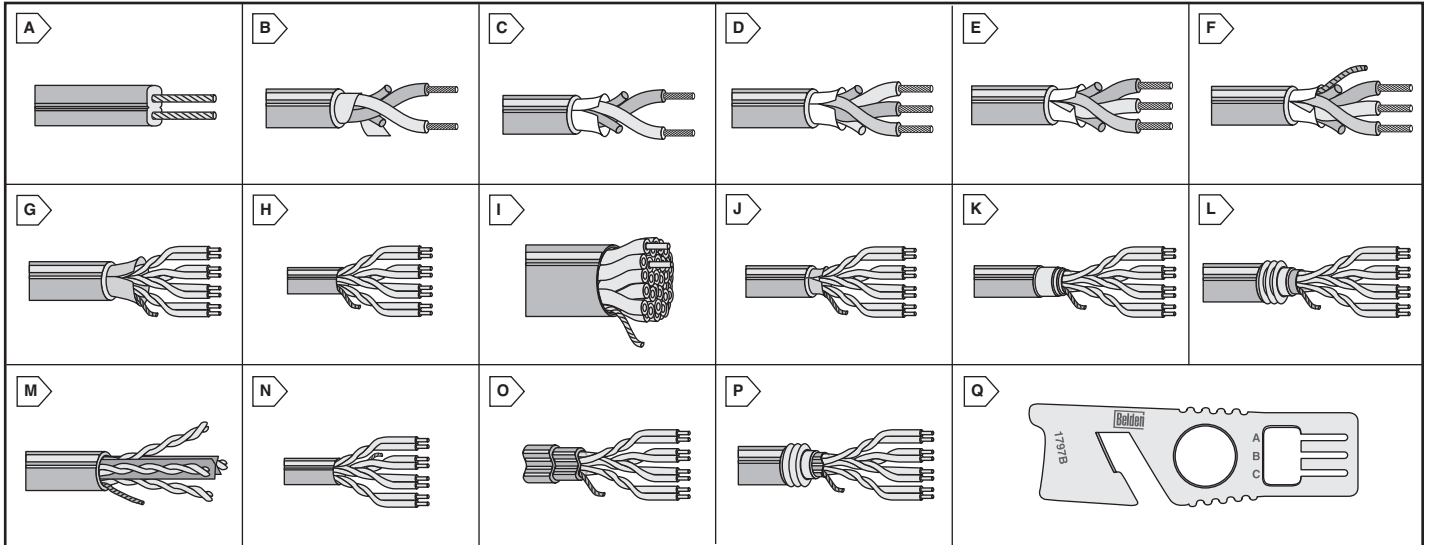

Belden® portable cordage products are available in a wide assortment of styles, lengths, and thickness. Products offered include 2-, 3-, 4- and 5-conductor as well as multi-conductor constructions.

## PORTABLE CORDAGE 2-CONDUCTOR

### SPT-1 PVC Parallel Lamp Cord

• 300V, 60°C • UL/CSA Listed

AlphaWire Recommend Heat Shrink **FTI221**

MOUSER STOCK NO.	Belden Part No.	Fig.	AWG (Stranded)	Nominal O.D. (in.)	250' Spool	
					1	2
* 566-19122-250-10	19122	A	18 (42 x 34)	.110 x .207	128.38	119.18
566-8888-250	8888	A	18 (42 x 34)	.110 x .207	132.56	126.09

### SJO Oil-Resistant Rubber Jacket

• 300V, 90°C • UL/CSA Listed

MOUSER STOCK NO.	Belden Part No.	Fig.	AWG (Stranded)	Nominal O.D. (in.)	250' Spool	
					1	2
566-19227-250-10	19227	B	18 (16 x 30)	.290	259.09	252.87
566-19228-250-10	19228	B	16 (26 x 30)	.315	336.56	319.60

### SVT PVC Jacket

• 300V, 60°C • UL/CSA Listed

MOUSER STOCK NO.	Belden Part No.	Fig.	AWG (Stranded)	Nominal O.D. (in.)	250' Spool	
					1	2
566-19140-250-10	19140	C	18 (42 x 34)	.243	156.44	148.75

## PORTABLE CORDAGE 3-CONDUCTOR

### SJT PVC Jacket (Smooth)

• 300V, 60°C • UL/CSA Listed

AlphaWire Recommend Heat Shrink **FTI221**

MOUSER STOCK NO.	Belden Part No.	Fig.	AWG (Stranded)	Nominal O.D. (in.)	250' Spool	
					1	2
566-19348-250-10	19348	D	18 (42 x 34)	.328	261.27	235.41
566-19349-250-10	19349	D	16 (65 x 34)	.340	304.77	289.78

### SJT PVC Jacket (Serrated)

• 300V, 60°C • UL/CSA Listed

MOUSER STOCK NO.	Belden Part No.	Fig.	AWG (Stranded)	Nominal O.D. (in.)	250' Spool	
					1	2
566-19353-250-10	19353	E	16 (65 x 34)	.353	315.72	287.05

### SJTOW Belflex® Matte Black Premium PVC

• 300V, 105°C • UL/CSA Listed

MOUSER STOCK NO.	Belden Part No.	Fig.	AWG (Stranded)	Nominal O.D. (in.)	250' Spool	
					1	2
566-19509-250-10	19509	E	18 (42 x 34)	.315	243.09	231.13
566-19510-250-10	19510	E	16 (65 x 34)	.340	358.85	340.77

### SJT PVC Jacket (Smooth), Beldfoil® Shielded

• 300V, 60°C • UL/CSA Listed

MOUSER STOCK NO.	Belden Part No.	Fig.	AWG (Stranded)	Nominal O.D. (in.)	250' Spool	
					1	2
566-19364-250-10	19364	F	14 (41 x 30)	.402	489.56	464.89

## DATATWIST® 5 SCTP CABLE (NETWORKING CABLE)

- TIA/EIA-B.2, Category 5 Unbonded-Pair Cable
- Non-Plenum
- Polyolefin Insulation / PVC Jacket
- Solid Bare Copper

AlphaWire Recommend Heat Shrink **FTI221**

MOUSER STOCK NO.	Belden Part No.	Fig.	AWG	Nominal O.D. (in.)	1000' Spool	
					1	2
* 566-1624R-1000-02	1624R	G	24	.260	336.06	325.48
* 566-1583A-1000-10	1583A	H	24	.195	148.66	141.69
566-1633A-1000-06	1633A	G	24	.260	357.18	340.43
566-1864A-1000-06	1864A	I	24	.526	1853.28	1795.27

\*Other Colors Available

## DATATUFF® CAT 5E INDUSTRIAL ETHERNET CABLE

- Cat 5e Bonded-Pairs
- Non-Plenum
- Solid Bare Copper
- Polyolefin Insulation / PVC Jacket

AlphaWire Recommend Heat Shrink **FTI221**

MOUSER STOCK NO.	Belden Part No.	Fig.	No. Pairs	AWG	Nominal O.D. (in.)	1000' Spool	
						1	2
566-7918A-1000	7918A	H	4	24	.230	223.14	204.75
566-7919A-1000	7919A	J	4	24	.265	431.91	412.57
566-7921A-1000	7921A	J	4	24	.330	811.86	775.51
566-7929A-1000	7929A	J	4	24	.265	533.77	510.34
<b>Enhanced Cat 5e</b>							
566-7932A-1000	7923A	H	2	24	.230	242.09	231.26
566-7933A-1000	7933A	J	2	24	.235	366.48	357.30
566-7922A-1000	7922A	H	4	22	.301	492.47	480.13
566-7923A-1000-10	7923A	H	4	24	.230	303.94	290.33
* 566-7924A-1000	7924A	H	4	24	.242	432.07	412.72
566-7928A-1000	7928A	H	4	24	.187	980.65	959.71
566-7934A-1000	7934A	H	4	24	.230	349.35	333.71
566-11700A-1000-10	11700A	K	4	24	.285	408.75	386.56
566-11700A2-1000	11700A2	K	4	24	.285	480.95	462.69
566-121700A-1000-10	121700A	L	4	24	.530	2003.25	1915.05

\*\* Stranded Tinned Copper

## DATATUFF® CAT 6 INDUSTRIAL ETHERNET CABLE

- Cat 6 Bonded-Pairs
- Non-Plenum
- Solid Bare Copper
- Polyolefin Insulation / PVC Jacket

AlphaWire Recommend Heat Shrink **FTI221**

MOUSER STOCK NO.	Belden Part No.	Fig.	AWG	Nominal O.D. (in.)	1000' Spool	
					1	2
566-7927A-1000	7927A	M	23	.251x.339	690.38	657.31
566-7931A-1000	7931A	N	23	.214	1432.26	1411.92
566-11872A-1000-10	11872A	O	23	.475x.265	592.94	565.16
566-121872A-1000-10	121872A	P	23	.684	2347.69	2237.63

## WI-FI SHIELDED TWISTED PAIR (SCTP) CABLE

- Cat 5e Twisted Pairs
- Non-Plenum
- Solid Bare Copper
- Polyolefin Insulation / PVC Jacket

AlphaWire Recommend Heat Shrink **FTI221**

MOUSER STOCK NO.	Belden Part No.	Fig.	AWG	Nominal O.D. (in.)	1000' Spool	
					1	2
566-1300A-1000-10	1300A	J	24	.265	401.46	381.56

## CABLE PREPARATION TOOL (FOR DATATWIST® CABLE)

This tool makes it faster and easier to prepare cables for connector termination. It can be used to prepare any unbonded-pair cable for installation.

MOUSER STOCK NO.	Belden Part No.	Fig.	Price Each	
			1	5
566-1797B	1797B	Q	9.65	8.42



Wire & Cable Belden