


BELDEN LAN and Computer Cables



RoHS Compliant This page of product is compliant.

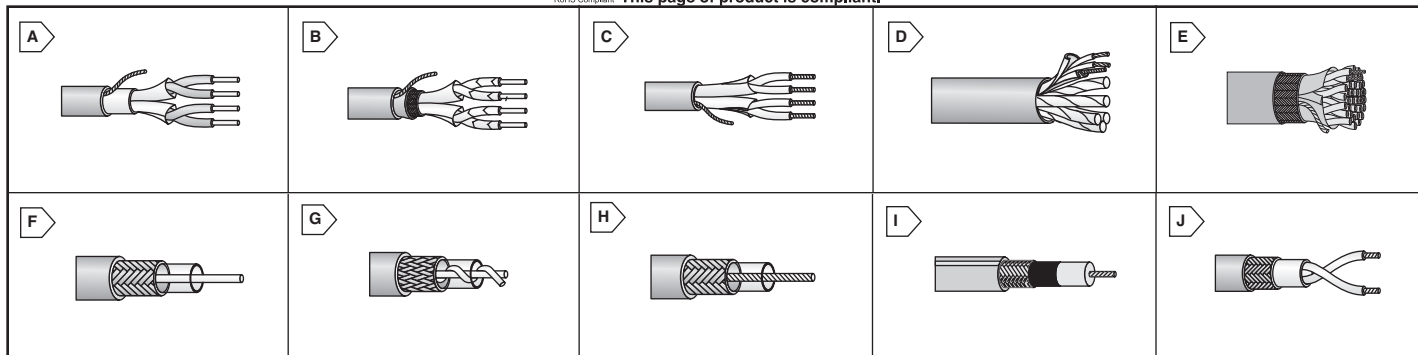

BELDEN IBM TYPE CABLES

IBM Type 1A, IEEE 802.5

• Strand: Solid



Belden Part No.	Fig.	Cable Type	IBM Part No.	NEC Type	AWG	No. of Pairs	Nom. O.D. (in.)	Nom. Imp. Ω	% Type Shield	100' Spools		500' Spools		1000' Spools	
										MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
9688	A	Non-Plenum	4716748	MPG/CMG	22	2	.296 x .431	150	100 / Foil, 65 Braid	566-9688-500	214.49	566-9688-1000	428.98		
82688	B	Plenum	4716749	CMP	22	2	.248 x .348	150	100 / Foil, 65 Braid	-----	-----	566-82688-1000	1319.93		

BELDEN COMPUTER CABLES, PAIRED, AND INDIVIDUALLY SHIELDED



Belden Part No.	Fig.	NEC Type	No. of Pairs	AWG	Stranded	Nom. O.D. (in.)	Nom. Imp. Ω	% Type Shield	100' Spools		500' Spools		1000' Spools	
									MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
8723	C	CM	2	22	7 x 30	.160	45	100 Foil	566-8723-100	39.97	566-8723-500	174.81	566-8723-1000	327.72
8777	D	CM	3	22	7 x 30	.273	50	100 Foil	566-8777-100	84.77	566-8777-500	358.06	566-8777-1000	736.73
8778	D	CM	6	22	7 x 30	.362	50	100 Foil	566-8778-100	171.03	566-8778-500	818.32	566-8778-1000	1436.54
9773	D	CM	3	18	19 x 30	.404	50	100 Foil	566-9773-100	156.09	-----	-----	566-9773-1000	1186.71

BELDEN LAN TRUNK CABLE

BELDEN NEW GENERATION® STP PLENUM-RATED CABLES

Low capacitance, plenum-rated 2- and 3-pair STP cables have individually foil-shielded pairs, a particularly small OD and they are made with Low Smoke Flammarest® PVC insulations and jackets.



Belden Part No.	Fig.	NEC Type	No. of Pairs	AWG	Stranded	Nom. O.D. (in.)	Nom. Imp. Ω	% Type Shield	100' Spools		500' Spools	
									MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool
1325A	C	CMP	2	22	7 x 30	.158	15	100	566-1325A-500-09	245.52	566-1325A-1000-09	465.93
1326A	C	CMP	3	22	7 x 30	.190	8.6	100	566-1326A-500-09	537.51	566-1326A-1000-09	1075.02

BELDEN LOW-CAPACITANCE COMPUTER CABLES

For EIA RS-232 and EIA RS-485 Applications



Belden Part No.	Fig.	NEC Type	No. of Pairs	AWG	Stranded	Nom. O.D. (in.)	Nom. Imp. Ω	% Type Shield	100' Spools		500' Spools	
									MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool
8132FO	E	CL2	2	28	7 x 36	.215	23.1	100	566-8132FO-500	330.19	566-8132FO-1000	620.12
8134FO	E	CL2	4	28	7 x 36	.270	20	100	566-8134FO-500	461.95	566-8134FO-1000	867.59
8135FO	E	CL2	5	28	7 x 36	.280	20	100	566-8135FO-500	483.77	566-8135FO-1000	967.54
8138FO	E	CL2	8	28	7 x 36	.310	17.7	100	-----	---	566-8138FO-1000	1268.24

BELDEN COMPUTER CABLES

* Available in box only



Belden Part No.	Fig.	Description	AWG	Stranding	Nom. O.D. (in.)	Nom. Imp.	% Type Shield	100' Spools		500' Spools		1000' Spools	
								MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
8240	F	51.5Ω Transmission Cable, RG58 /U	20	Solid	.193	51.5	95	566-8240-100	51.37	566-8240-500	178.51	566-8240-1000	349.39
9201	F	51.5Ω Transmission Cable, RG58 /U	20	Solid	.193	51.5	78	-----	---	566-9201-500-10	178.29	566-9201-1000-10	344.34
82240	F	RG 58/U Type, Plenum	20	Solid	.159	53.5	95	-----	---	*566-82240-U500	631.05	566-82240-1000	1269.96
9269	G	RG 62A/U Type	22	Solid	.239	93	95	-----	---	566-9269-500	224.28	566-9269-1000	436.76
82269	G	RG 62/U Type, Plenum	22	Solid	.200	93	94	-----	---	-----	---	566-82269-1000	1078.82
8216	H	RG 174/U Type	26	7 x 34	.110	50	90	566-8216-100	46.44	566-8216-500	161.05	566-8216-1000	322.09
8219	H	RG 58A/U	20	19 x 32	.194	53.5	93	-----	---	566-8219-500	245.88	566-8219-1000	460.28
9311	I	RG 58A/U	20	19 x 32	.193	50	55	-----	---	566-9311-500-10	395.89	566-9311-1000-10	722.45
9207	J	Twinaxial, Foil / Braid Shield	20	7 x 28	.330	100	86	566-9207-100	103.43	566-9207-500	459.88	566-9207-1000	873.41

Wire & Cable Belden