


AIM/CAMBRIDGE BNC and Network Cable Assemblies



BNC THIN ETHERNET COAXIAL CABLES

Features:

- Body Plating: Nickel
- Center Contact Plating: Gold
- Impedance: 50ohm
- Cable Color: Black PVC
- AWG: 20 stranded

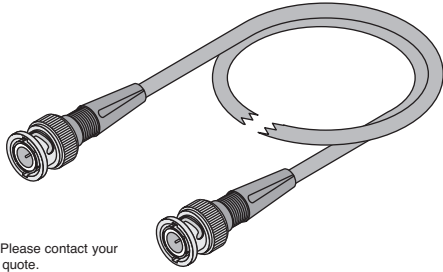

Custom assemblies are available. Please contact your Mouser Sales Representative for a quote.

MOUSER STOCK NO.	AIM/Cambridge Part No.	Boot Color	Length: ft (m)	Price Each			
				1	10	25	100
BNC plug to BNC plug, RG-58AU							
601-736300-3	73-6300-3	Black	3 (.914)	8.48	6.78	6.24	5.61
601-736351-3	73-6351-3	Blue	3 (.914)	8.48	6.78	6.24	5.61
601-736353-3	73-6353-3	Red	3 (.914)	8.48	6.78	6.24	5.61
601-736354-3	73-6354-3	Yellow	3 (.914)	8.48	6.78	6.24	5.61
601-736300-6	73-6300-6	Black	6 (1.829)	9.68	8.03	7.38	6.64
601-736351-6	73-6351-6	Blue	6 (1.829)	9.68	8.03	7.38	6.64
601-736352-6	73-6352-6	Green	6 (1.829)	9.68	8.03	7.38	6.64
601-736353-6	73-6353-6	Red	6 (1.829)	9.68	8.03	7.38	6.64
601-736354-6	73-6354-6	Yellow	6 (1.829)	9.68	8.03	7.38	6.64
601-736300-10	73-6300-10	Black	10 (3.05)	11.69	9.71	8.93	8.03
601-736351-10	73-6351-10	Blue	10 (3.05)	11.69	9.71	8.93	8.03
601-736352-10	73-6352-10	Green	10 (3.05)	11.69	9.70	8.93	8.03
601-736353-10	73-6353-10	Red	10 (3.05)	11.69	9.70	8.93	8.03
601-736354-10	73-6354-10	Yellow	10 (3.05)	11.69	9.70	8.93	8.03
601-736300-25	73-6300-25	Black	25 (7.62)	19.95	15.96	14.69	13.20
601-736351-25	73-6351-25	Blue	25 (7.62)	19.95	15.96	14.69	13.20
601-736352-25	73-6352-25	Green	25 (7.62)	19.95	15.96	14.69	13.20
601-736353-25	73-6353-25	Red	25 (7.62)	19.95	15.96	14.69	13.20
601-736354-25	73-6354-25	Yellow	25 (7.62)	19.95	15.96	14.69	13.20

BNC plug to BNC plug, RG-58 Thin

MOUSER STOCK NO.	AIM/Cambridge Part No.	Boot Color	Length: ft (m)	Price Each			
				1	10	25	100
601-736340-3	73-6340-3	Black	3 (.914)	7.54	6.93	6.38	5.73
601-736361-3	73-6361-3	Blue	3 (.914)	7.54	6.93	6.38	5.73
601-736362-3	73-6362-3	Green	3 (.914)	7.54	6.93	6.38	5.73
601-736363-3	73-6363-3	Red	3 (.914)	7.54	6.93	6.38	5.73
601-736364-3	73-6364-3	Yellow	3 (.914)	7.54	6.93	6.38	5.73
601-736340-6	73-6340-6	Black	6 (1.829)	10.13	8.37	7.70	6.93
601-736361-6	73-6361-6	Blue	6 (1.829)	10.13	8.37	7.70	6.93
601-736362-6	73-6362-6	Green	6 (1.829)	10.13	8.37	7.70	6.93
601-736363-6	73-6363-6	Red	6 (1.829)	10.13	8.37	7.70	6.93
601-736364-6	73-6364-6	Yellow	6 (1.829)	10.13	8.37	7.70	6.93
601-736340-10	73-6340-10	Black	10 (3.05)	12.71	10.26	9.43	8.48
601-736361-10	73-6361-10	Blue	10 (3.05)	12.71	10.26	9.43	8.48
601-736362-10	73-6362-10	Green	10 (3.05)	12.71	10.26	9.43	8.48
601-736363-10	73-6363-10	Red	10 (3.05)	12.71	10.26	9.43	8.48
601-736364-10	73-6364-10	Yellow	10 (3.05)	12.71	10.26	9.43	8.48
601-736340-25	73-6340-25	Black	25 (7.62)	21.13	17.44	16.05	14.41
601-736361-25	73-6361-25	Blue	25 (7.62)	21.13	17.44	16.05	14.41
601-736362-25	73-6362-25	Green	25 (7.62)	21.13	17.44	16.05	14.41
601-736363-25	73-6363-25	Red	25 (7.62)	21.13	17.44	16.05	14.41
601-736364-25	73-6364-25	Yellow	25 (7.62)	21.13	17.44	16.05	14.41

BNC AUDIO/VIDEO COAXIAL CABLES

Features:

- Body Plating: Nickel
- Center Contact Plating: Gold
- AWG: 22 stranded
- Matching color boot and cable
- Impedance: 75ohm

Custom assemblies are available. Please contact your Mouser Sales Representative for a quote.

BNC Plug to BNC Plug, RG-59


MOUSER STOCK NO.	AIM/Cambridge Part No.	Boot Color	Length: ft (m)	Price Each			
				1	10	25	100
601-736310-3	73-6310-3	Black	3 (.914)	7.87	6.68	6.10	5.62
601-736311-3	73-6311-3	Blue	3 (.914)	6.98	5.92	5.41	4.98
601-736312-3	73-6312-3	Green	3 (.914)	7.00	5.94	5.43	5.00
601-736313-3	73-6313-3	Red	3 (.914)	8.56	7.26	6.64	6.11
601-736314-3	73-6314-3	Yellow	3 (.914)	7.49	6.36	5.81	5.35
601-736310-6	73-6310-6	Black	6 (1.829)	8.96	7.60	6.95	6.40
601-736311-6	73-6311-6	Blue	6 (1.829)	7.93	6.74	6.16	5.67
601-736312-6	73-6312-6	Green	6 (1.829)	7.93	6.74	6.16	5.67
601-736313-6	73-6313-6	Red	6 (1.829)	11.11	9.43	8.62	7.94
601-736314-6	73-6314-6	Yellow	6 (1.829)	8.96	7.60	6.95	6.40
601-736310-10	73-6310-10	Black	10 (3.05)	11.42	9.70	8.86	8.16
601-736311-10	73-6311-10	Blue	10 (3.05)	9.82	8.34	7.62	7.02
601-736312-10	73-6312-10	Green	10 (3.05)	9.22	7.83	7.16	6.59
601-736314-10	73-6314-10	Yellow	10 (3.05)	10.91	9.26	8.47	7.79
601-736310-25	73-6310-25	Black	25 (7.62)	18.27	15.51	14.17	13.05
601-736311-25	73-6311-25	Blue	25 (7.62)	14.02	11.91	10.88	10.02
601-736312-25	73-6312-25	Green	25 (7.62)	14.02	11.91	10.88	10.02



USB CABLE ASSEMBLIES

Features:

- USB version 2.0
- Color: Beige
- Contacts: Gold plated
- AWG: 20-28 for power; 28 for signal

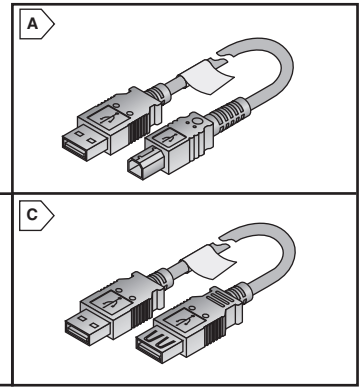


MOUSER STOCK NO.	AIM/Cambridge Part No.	Fig.	Length: ft (m)	Price Each			
				1	10	25	100
USB Type A Male to USB Type B Male							
601-30-3007-3	30-3007-3	A	3 (.914)	2.67	2.49	2.27	2.05
601-30-3007-6	30-3007-6	A	6 (1.829)	3.30	3.03	2.60	2.36
601-30-3007-10	30-3007-10	A	10 (3.05)	4.13	3.80	3.53	3.20
601-30-3007-15	30-3007-15	A	15 (4.572)	6.24	5.40	4.93	4.84
USB Type A Male to USB Type A Male							
601-30-3006-6	30-3006-6	B	6 (1.829)	3.86	3.56	3.38	3.18
601-30-3006-10	30-3006-10	B	10 (3.05)	4.66	4.30	4.08	3.82
USB Type A Male to USB Type A Female Extension							
601-30-3008-6	30-3008-6	C	6 (1.829)	4.21	3.74	3.18	2.96

MOLDED AND BOOTED LAN PATCH CABLES - CAT 5E AND CAT 6

Features:

- 24AWG Round UTP stranded
- Unshielded twisted pair cable
- Cat 5E-350MHz; Cat6-500MHz
- Tested to meet and exceed ANSI/TIA-568-B.2-1
- Cat 6 industry standards
- Flexible low-profile snagless strain relief

Custom assemblies are available. Please contact your Mouser Sales Representative for a quote.

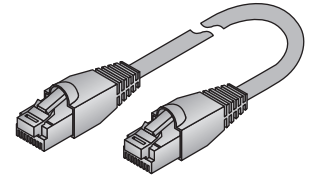

MOUSER STOCK NO.	AIM/Cambridge Part No.	Color	Length: ft (m)	Price Each			
				1	10	25	100
Cat 5E							
601-737790-3	73-7790-3	Gray	3 (.914)	1.59	1.42	1.31	1.26
601-737791-3	73-7791-3	Black	3 (.914)	1.59	1.42	1.31	1.26
601-737792-3	73-7792-3	Blue	3 (.914)	1.59	1.42	1.31	1.26
601-737793-3	73-7793-3	Green	3 (.914)	1.59	1.42	1.31	1.26
601-737794-3	73-7794-3	Red	3 (.914)	1.59	1.42	1.31	1.26
601-737795-3	73-7795-3	Yellow	3 (.914)	1.59	1.42	1.31	1.26
601-737796-3	73-7796-3	White	3 (.914)	1.59	1.42	1.31	1.26
601-737790-7	73-7790-7	Gray	7 (2.13)	2.55	2.30	2.03	1.92
601-737791-7	73-7791-7	Black	7 (2.13)	2.55	2.30	2.03	1.92
601-737792-7	73-7792-7	blue	7 (2.13)	2.55	2.30	2.03	1.92
601-737793-7	73-7793-7	Green	7 (2.13)	2.55	2.30	2.03	1.92
601-737794-7	73-7794-7	Red	7 (2.13)	2.55	2.30	2.03	1.92
601-737795-7	73-7795-7	Yellow	7 (2.13)	2.55	2.30	2.03	1.92
601-737796-7	73-7796-7	White	7 (2.13)	2.55	2.30	2.03	1.92
601-737790-14	73-7790-14	Gray	14 (4.27)	4.46	4.39	4.06	3.70
601-737791-14	73-7791-14	Black	14 (4.27)	4.46	4.39	4.06	3.70
601-737792-14	73-7792-14	Blue	14 (4.27)	4.46	4.39	4.06	3.70
601-737793-14	73-7793-14	Green	14 (4.27)	4.46	4.40	4.06	3.70
601-737794-14	73-7794-14	Red	14 (4.27)	4.46	4.39	4.06	3.70
601-737795-14	73-7795-14	Yellow	14 (4.27)	4.46	4.39	4.06	3.70
601-737796-14	73-7796-14	White	14 (4.27)	4.46	4.39	4.06	3.70
601-737790-25	73-7790-25	Gray	25 (7.62)	7.35	6.99	6.60	6.05
601-737791-25	73-7791-25	Black	25 (7.62)	7.35	6.99	6.60	6.05
601-737792-25	73-7792-25	Blue	25 (7.62)	7.35	6.99	6.60	6.05
601-737793-25	73-7793-25	Green	25 (7.62)	7.35	6.99	6.60	6.05
601-737794-25	73-7794-25	Red	25 (7.62)	7.35	6.99	6.60	6.05
601-737795-25	73-7795-25	Yellow	25 (7.62)	7.35	6.99	6.60	6.05
601-737796-25	73-7796-25	White	25 (7.62)	7.35	6.99	6.60	6.05
601-737790-50	73-7790-50	Gray	50 (15.24)	13.11	11.63	10.36	9.75
601-737791-50	73-7791-50	Black	50 (15.24)	13.11	11.63	10.36	9.75
601-737792-50	73-7792-50	Blue	50 (15.24)	13.11	11.63	10.36	9.75
601-737793-50	73-7793-50	Green	50 (15.24)	13.11	11.63	10.36	9.75
601-737794-50	73-7794-50	Red	50 (15.24)	13.11	11.63	10.36	9.75