


# QUALTEK Cable Assemblies

**Qualtek** ELECTRONICS CORPORATION  
(WCT) Wire, Cable and Tube Division

RoHS Compliant This product is RoHS compliant.

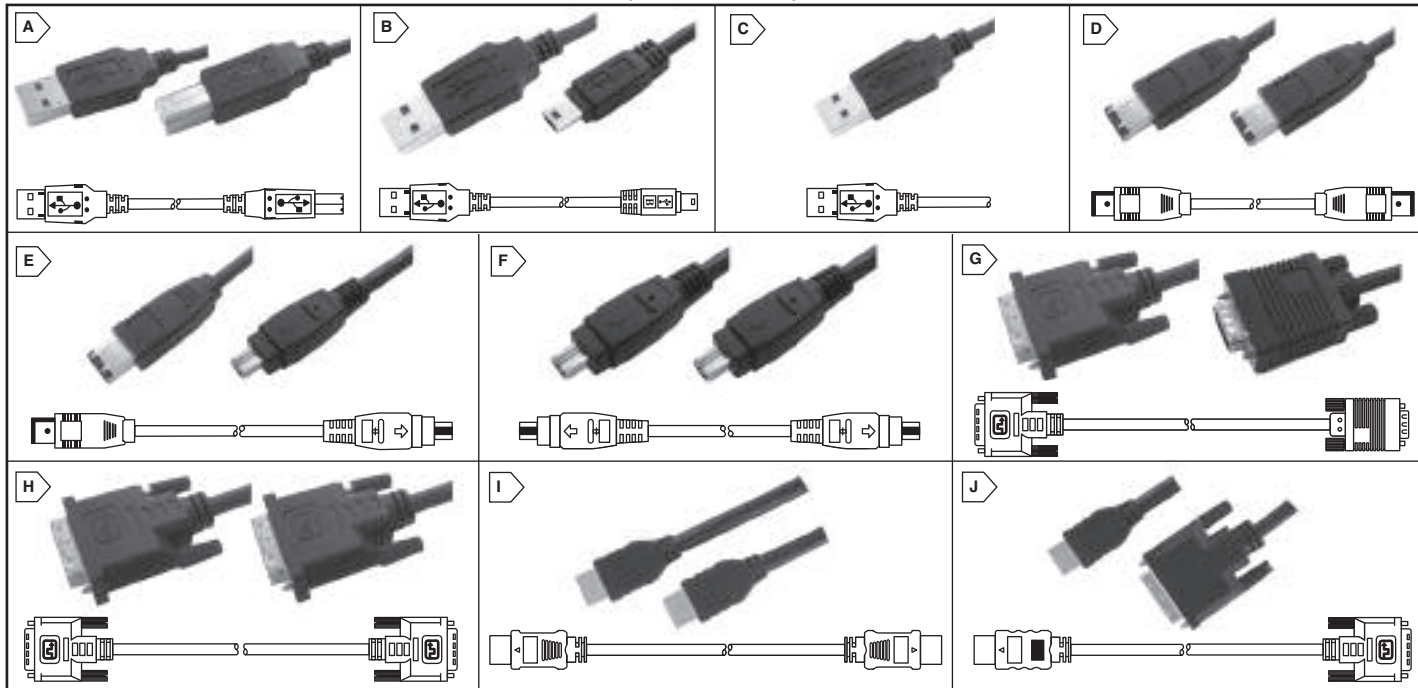

## USB CABLE ASSEMBLIES

### Universal Serial Bus

#### Features:

- Transfer rates up to 480Mbps depending on USB version
- Connect an USB peripheral to an USB Hub or USB port on PC/MAC
- Compatible with USB specifications 1.0, 1.1, and 2.0
- Make plug and play connections for such devices as keyboards, mice, modems, printers, and other USB peripherals.
- Black



## DVI CABLE ASSEMBLIES

### Digital Visual Interface

#### Features:

- Tri-shielded with dual Mylar® foil and braid shield which reduces interference
- Supports hot plugging of DVI display devices
- Black



- PC and MAC compatible
- Meets DVI DDWG standard
- Compatible with flat panel displays, digital CRT displays

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Conn. Plating	Wire (AWG)	Length (m)	Price Each		
							1	10	25
562-3021001-03	3021001-03	A	A-B	Nickel	28/28	.914	2.54	2.47	2.43
562-3021003-03	3021003-03	B	A-mini B	Nickel	28/28	.914	2.27	2.20	2.17
562-3021005-03	3021005-03	C	A-Blunt	Nickel	28/28	.914	1.85	1.79	1.71
562-3021015-06	3021015-06	A	A-B	Nickel	26/28	1.83	2.82	2.74	2.70
562-3021009-06	3021009-06	B	A-mini B	Nickel	26/28	1.83	2.87	2.79	2.74
562-3021011-06	3021011-06	C	A-Blunt	Nickel	26/28	1.83	2.74	2.54	2.32
562-3021015-10	3021015-10	B	A-mini B	Nickel	26/28	3.05	4.59	4.36	4.14
562-3021017-10	3021017-10	C	A-Blunt	Nickel	26/28	3.05	4.51	4.35	4.19
562-3021019-16	3021019-16	A	A-B	Gold	24/26	4.88	6.13	5.82	5.52
562-3021021-16	3021021-16	B	A-mini B	Gold	24/26	4.88	9.40	9.05	8.70
562-3021023-16	3021023-16	C	A-Blunt	Gold	24/26	4.88	8.22	7.91	7.60
562-3021027-16	3021027-16	B	A-mini B	Gold	20/26	4.88	9.40	9.05	8.70
562-3021029-16	3021029-16	C	A-Blunt	Gold	20/26	4.88	8.21	7.91	7.61

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Conn. Plating	Wire (AWG)	Length (m)	Price Each		
							1	10	25
562-1321001-03	1321001-03	G	12+5-HD15P	Nickel	28	.914	11.64	10.68	10.15
562-1321003-03	1321003-03	H	18+1 - 18+1	Nickel	28	.914	13.85	13.15	12.50
562-1321007-03	1321007-03	H	24+1 - 24+1	Nickel	28	.914	14.10	13.40	12.73
562-1321009-03	1321009-03	H	24+5 - 24+5	Nickel	28	.914	17.00	16.15	15.34
562-1321013-06	1321013-06	H	18+1 - 18+1	Nickel	28	1.83	18.00	17.10	16.25
562-1321019-06	1321019-06	H	24+5 - 24+5	Nickel	28	1.83	22.54	21.57	20.64
562-1321023-10	1321023-10	H	18+1 - 18+1	Nickel	28	3.05	22.30	21.33	20.36
562-1321029-10	1321029-10	H	24+5 - 24+5	Nickel	28	3.05	30.88	29.59	28.30
562-1321033-16	1321033-16	H	18+1 - 18+1	Gold	26	4.88	32.95	31.58	30.21

## HDMI CABLE ASSEMBLIES

### High Definition Multimedia Interface

Broadcast quality digital video/audio, and inter component control signals all in one compact. High-performance connection!

#### Features:

- Three layers of shielding
- Nitrogen-injected dielectric, meticulous construction
- Black

- DTV Link to DVD player, D-VHS recorder, set-top box and camcorder

RoHS Compliant

## IEEE 1394 CABLE ASSEMBLIES

### Fire Wire

#### Features:

- Supports Plug-n-Play operation
- Hot Pluggable
- Black

#### Applications:

- Video presentation and editing
- Desktop and commercial publishing
- Document imaging
- Home multimedia
- Personal computing

#### Designed For:

- Digital camcorders
- Scanners and printers
- Storage devices
- Other Firewire devices



For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Conn. Plating	Wire (AWG)	Length (m)	Price Each		
							1	10	25
562-1821001-03	1821001-03	D	6 pin-6 pin	Nickel	24/30	.914	6.36	6.15	5.86
562-1821003-03	1821003-03	E	6 pin-4 pin	Nickel	24/30	.914	6.29	5.97	5.69
562-1821009-06	1821009-06	E	6 pin-4 pin	Nickel	24/30	1.83	7.22	6.85	6.50
562-1821011-06	1821011-06	F	4 pin-4 pin	Nickel	24/30	1.83	7.22	6.85	6.50
562-1821013-10	1821013-10	D	6 pin-6 pin	Nickel	24/30	3.05	10.56	10.04	9.53
562-1821017-10	1821017-10	F	4 pin-4 pin	Nickel	24/30	3.05	9.89	9.40	8.93

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Conn. Plating	Wire (AWG)	Length (m)	Price Each		
							1	10	25
562-1721001-03	1721001-03	I	Type A-Type A	Nickel	28	.914	17.25	16.39	15.57
562-1721003-03	1721003-03	J	Type A-DVI (18+1)	Nickel	28	.914	17.25	16.39	15.57
562-1721005-06	1721005-06	I	Type A-Type A	Nickel	28	1.83	21.32	19.38	18.41
562-1721007-06	1721007-06	J	Type A-DVI (18+1)	Nickel	28	1.83	21.94	20.84	19.79
562-1721009-10	1721009-10	I	Type A-Type A	Nickel	28	3.05	24.24	23.27	22.30
562-1721011-10	1721011-10	J	Type A-DVI (18+1)	Nickel	28	3.05	27.85	26.45	25.13
562-1721013-16	1721013-16	I	Type A-Type A	Nickel	26	4.88	38.25	36.33	34.52
562-1721015-16	1721015-16	J	Type A-DVI (18+1)	Nickel	26	4.88	36.50	34.95	33.00