


QUALTEK AC Receptacles

Qualtek ELECTRONICS CORPORATION

Primary Power Components Div.
Power Line Filter

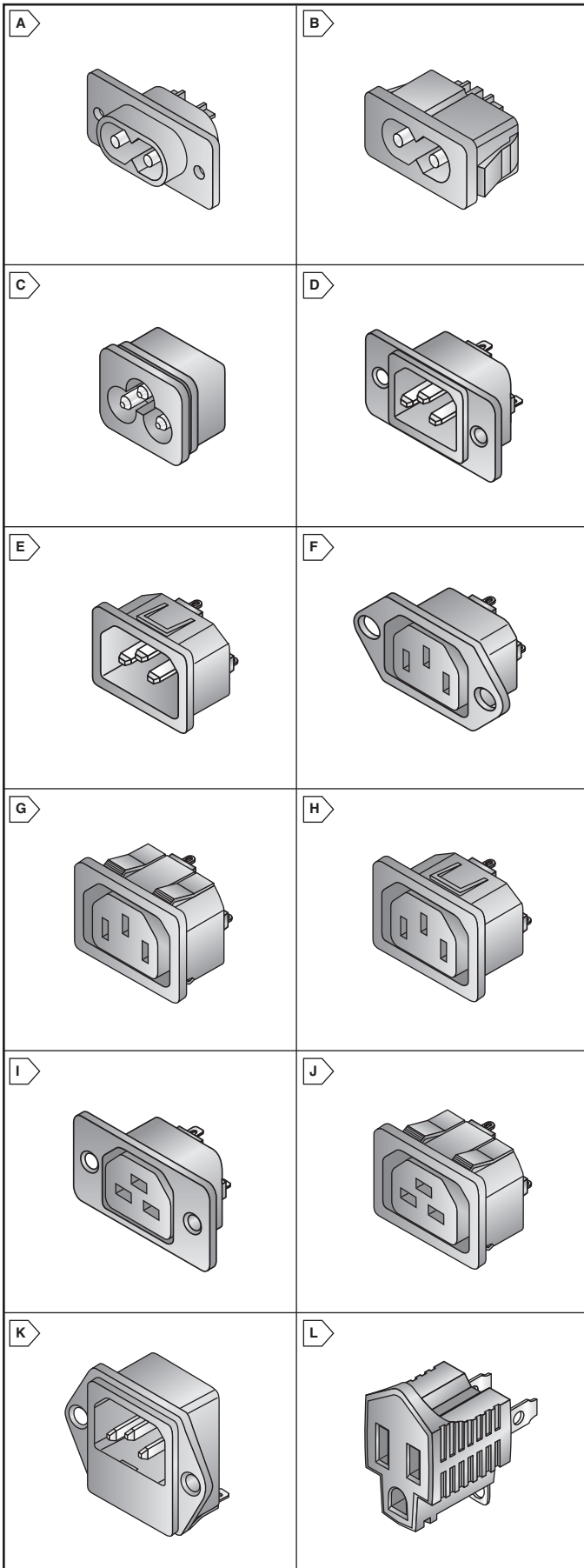

LOW CURRENT INLET IEC 320-C6/C8

Male low current inlet with snap-in and screw mount version.

Features:

- Max Rating: 2.5A/250VAC
- * Max Rating: UL & CSA 20A/250VAC - VDE 16A/250VAC
- * Universal snap-in feature to fit 0.6mm; 1.5mm panel thickness



RoHS Compliant

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Terminals	Price Each			
					1	10	25	50
562-77001	770W-00/01	A	Screw Mount	Solder Tab	.84	.731	.671	.62
562-77101	771W-X2/01	B	* Snap-in Mount	Solder Tab	.65	.58	.51	.45
562-77102	771W-X2/02	B	* Snap-in Mount	PCB Mount	.95	.82	.75	.70
562-771W-CX2/01	771W-CX2/01	C	* Snap-in Mount	Solder Tab	1.00	.91	.84	.78

AC POWER INLETS IEC 320-C20

Male power outlets include snap-in and screw mount types.

Features:

- Max Rating: UL & CSA 20A/250VAC - VDE 16A/250VAC
- * Panel thickness: 1.5mm (1.0, 2.0, 2.5, & 3.0 are also available)



RoHS Compliant

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Terminals	Price Each			
					1	10	25	50
562-744W-001	744W-00/01	D	Screw Mount	Solder Tab	.77	.70	.64	.61
562-744W-003	744W-00/03	D	Screw Mount	.187 QD/Solder	.77	.70	.64	.61
562-744W-00/04	744W-00/04	D	Screw Mount	.250 Q.D.	.86	.80	.74	.71
562-745W-1505	745W-15/05	E	* Snap-In	Solder Tab	.75	.71	.67	.64
562-745W-1507	745W-15/07	E	* Snap-In	.187 QD/Solder	.74	.709	.639	.579
562-745W-1508	745W-15/08	E	* Snap-In	.250 QD/Solder	.80	.74	.70	.62

AC POWER OUTLETS IEC 320-C13

Female power outlets available in screw or snap-in mounting.

Features:

- Max Rating: UL & CSA 15A/250VAC - VDE 10A/250VAC
- * Universal snap-in feature to fit 0.8mm; 2.0mm panel thickness
- ** Panel thickness: 1.5mm (1.0, 2.0, 2.5, & 3.0 are also available)



RoHS Compliant

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Terminals	Price Each			
					1	10	25	50
562-710W-00/01	710W-00/01	F	Screw Mount	Solder Tab	1.00	.85	.80	.69
562-710W-00/02	710W-00/02	F	Screw Mount	.187 QD/Solder	1.00	.85	.80	.72
562-710W-00/03	710W-00/03	F	Screw Mount	.250 Q.D.	.82	.77	.73	.68
562-716W-X2/02	716W-X2/02	G	* Snap-in Mount	.187 QD/Solder	.82	.769	.709	.639
562-716W-X2/03	716W-X2/03	G	* Snap-in Mount	.250 Q.D.	.92	.83	.74	.67
562-716W-1505	716W-15/05	H	**Snap-in Mnt	Solder Tab	.87	.78	.72	.68
562-716W-1510	716W-15/10	H	**Snap-in Mnt	.187 QD/Solder	.91	.87	.85	.80
562-716W-15/15	716W-15/15	H	**Snap-in Mnt	.250 Q.D.	.91	.82	.76	.71

LOW CURRENT OUTLET IEC 320-C19

Female power outlets available in screw or snap-in mounting.

Features:

- Max Rating: UL & CSA 20A/250VAC - VDE 16A/250VAC
- * Panel thickness: 1.5mm (1.0, 2.0, 2.5, & 3.0 are also available)



RoHS Compliant

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Terminals	Price Each			
					1	10	25	50
562-743W-00/02	743W-00/02	I	Screw Mount	.187 QD/Solder	1.13	1.03	.95	.89
562-743W-00/03	743W-00/03	I	*Screw Mount	.250 Q.D.	1.20	1.08	1.00	.92
562-746W-1508	746W-15/08	J	* Snap-in Mount	.250 Q.D.	1.26	1.15	.97	.91

INLET W/VOLTAGE SELECTOR & FUSEHOLDER IEC 320-C14

Male power inlet with fuseholder and voltage selector switch. (Accepts 5 x 20mm fuse)

Features:

- Voltage selector switch adapts to 110V or 240V.



RoHS Compliant

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Terminals	Price Each			
					1	10	25	50
562-755-00/28	755-00/28	K	Screw Mount	Solder Tab	3.89	3.48	3.20	2.92

AC ADAPTER

Features:

- NEMA 5-15R



RoHS Compliant

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Price Each			
				1	10	25	50
562-738W-E-01	738W-E-01	L	3 Prong / 2 Prong - Wall Plug	.79	.719	.589	.519