


BOMAR Compression and Broadcast Connectors



RoHS Compliant This product is RoHS compliant.

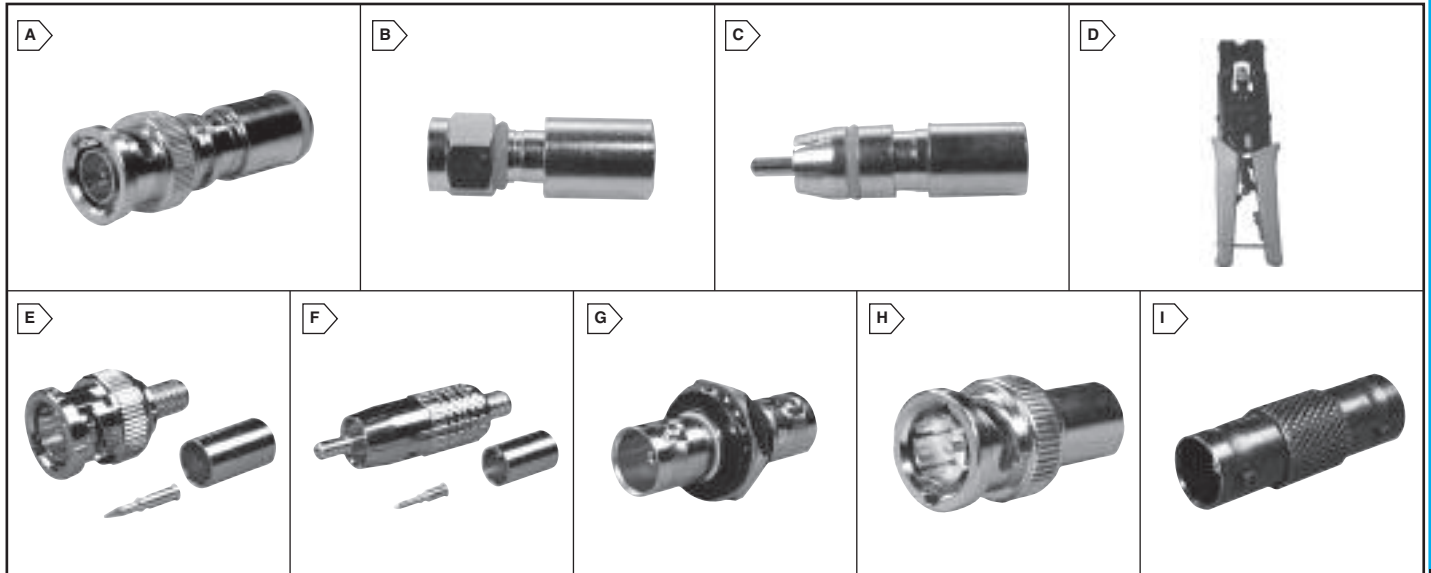

COMPRESSION CONNECTORS

Manufactured of precision-machined brass, with heavy nickel plating, these corrosion-resistant parts feature gold-plated, semi-captive contact for long-lasting connections. Their advanced shielding technology provides maximum isolation from EMI and RFI interference. Each BNC and RCA connector is shipped with six color coded O-rings to allow easy identification when systems require multiple cables.

Features:

- RoHS Compliant per Bomar documentation



RoHS Compliant

BNC Connectors

For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Belden Cable Type	RG Cable Type	Price Each			
					1	10	25	100
678-KCC1505B	KCC1505B	A	1505A	RG 59	3.57	3.29	2.99	2.81
678-KCC1694B	KCC1694B	A	1649A	RG 6	3.57	3.29	2.99	2.81
678-KCC1855B	KCC1855B	A	1855A	RG 59 mini	3.57	3.29	2.99	2.81

F Connectors

For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Belden Cable Type	RG Cable Type	Price Each			
					1	10	25	100
678-KCC1505F	KCC1505F	B	1505A	RG 59	1.08	.98	.91	.87
678-KCC1694F	KCC1694F	B	1649A	RG 6	1.02	.93	.89	.82
678-KCC1855F	KCC1855F	B	1855A	RG 59 mini	1.08	.98	.91	.87

RCA Connectors

For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Belden Cable Type	RG Cable Type	Price Each			
					1	10	25	100
678-KCC1505R	KCC1505R	C	1505A	RG 59	2.57	2.42	2.15	2.08
678-KCC1694R	KCC1694R	C	1649A	RG 6	2.47	2.33	2.17	2.02
678-KCC1855R	KCC1855R	C	1855A	RG 59 mini	2.57	2.42	2.15	2.02

Tool

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Price Each	
				1	5
678-BDKC6000	BDKC6000	D	3 in 1 tool, KCC Series RG6, RG59, F, BNC and RCA connector adapters stored in handle	89.74	81.01

BNC AND RCA BROADCAST CONNECTORS FOR BELDEN CABLE

Features:

- HDTV Broadcast grade connectors matched for Belden cable
- True 75Ω connectors made from precision machined brass
- RCA Plugs are shielded with gold plated contacts
- RoHS Compliant per Bomar documentation



RoHS Compliant

For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Impedance (Ω)	Description	Belden Cable Type	Price Each			
						1	10	25	100
678-SBC1505A	SBC1505A	E	75	Plug, 3 pc., dual crimp	1505A	2.38	2.24	2.11	1.98
678-SBC1694A	SBC1694A	E	75	Plug, 3 pc., dual crimp	1694A	2.30	2.25	2.18	2.00
678-SBC8281	SBC8281	E	75	Plug, 3 pc., dual crimp	8281	2.10	2.07	1.76	1.65
678-SBC8218	SBC8218	E	75	Plug, 3 pc., dual crimp	8218	2.46	2.24	2.07	1.94
678-SBC8241	SBC8241	E	75	Plug, 3 pc., dual crimp	8241	2.45	2.24	1.97	1.85
678-HBC1505A	HBC1505A	E	75	Plug, 3 pc., dual crimp	1505A (HD)	2.24	2.03	1.87	1.76
678-HBC1694A	HBC1694A	E	75	Plug, 3 pc., dual crimp	1694A (HD)	2.24	2.03	1.87	1.76
678-HBC179DT	HBC179DT	E	75	Plug, 3 pc., dual crimp	179DT (HD)	2.84	2.58	2.49	2.29
678-RBC1505A	RBC1505A	F	75	RCA Crimp Plug	1505A (HD)	3.92	3.56	3.44	3.16
678-RBC1694A	RBC1694A	F	75	RCA Crimp Plug	1694A (HD)	3.92	3.56	3.44	3.16
678-RBC1855A	RBC1855A	F	75	RCA Crimp Plug	1855A (HD)	3.92	3.56	3.44	3.16
678-HBC335R744	HBC335R744	G	75	Jack/Jack iso. panel	-----	9.98	9.07	8.75	8.46
678-HBC310X075	HBC310X075	H	75	Precision 0.1% term.	-----	5.36	4.87	4.70	4.40
678-HBC332A705	HBC332A705	I	---	BNC F/F HD Adapter, Black	-----	3.40	3.09	2.98	2.74

NEW FROM BOMAR NEW FROM BOMAR Audio/Video Connectors Bomar NEW FROM BOMAR NEW FROM BOMAR