


BOMAR Between Series Adapters

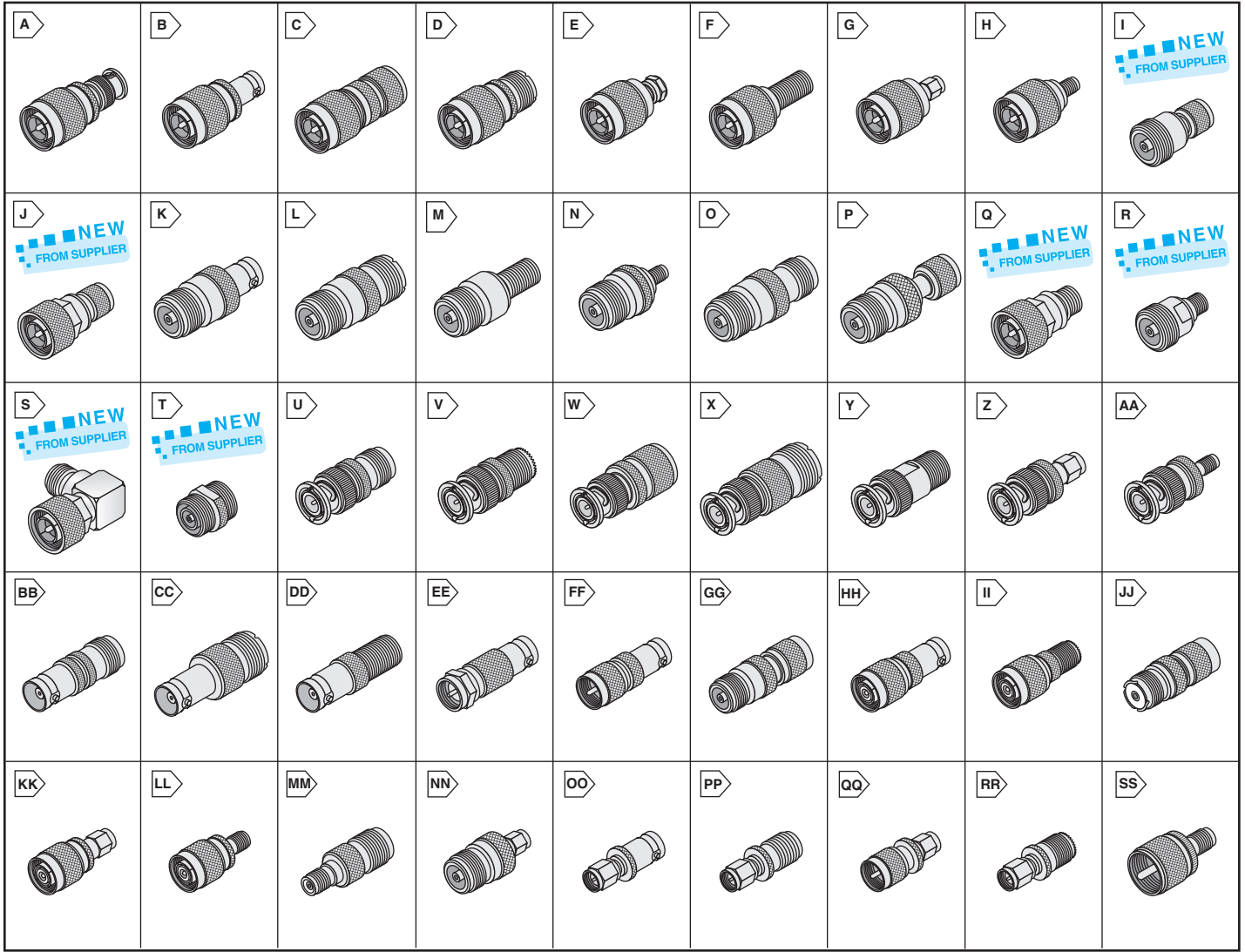

Bomar RF Connectors

Between series adapters solve a variety of connection problems where connectors of different types could ordinarily not be mated together. Each adapter has a different type coupling at each end allowing for a wide variety of interconnections to fit almost all interconnection situations. All adapters are constructed of machined brass and are nickel plated.

• RoHS Compliant per Bomar documentation



RoHS Compliant

*Plating: Tri-plate, a copper alloy composed of three components: 55% copper, 25% tin, and 20% zinc

For quantities of 100 and up, call for quote.



RoHS Compliant

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Price Each			
				1	10	25	50
Type N Adapters							
678-1303505	1303505	A	N Plug to BNC Plug	27.04	24.58	23.72	21.81
678-1313505	1313505	B	N Plug to BNC Jack	10.04	9.13	8.81	8.10
678-1307505	1307505	C	N Plug to UHF Plug	14.42	13.11	12.65	11.63
678-1317505	1317505	D	N Plug to UHF Jack	15.02	13.65	13.18	12.11
678-1308505	1308505	E	N Plug to F Plug	6.92	6.29	6.07	5.58
678-1318505	1318505	F	N Plug to F Jack	15.06	13.69	13.21	12.15
678-1309505	1309505	G	N Plug to SMA Plug	28.50	25.91	25.00	22.98
678-1319505	1319505	H	N Plug to SMA Jack	12.38	11.25	10.86	9.98
*678-131150011	131150011	I	N Plug to 7/16 Jack	33.56	30.51	29.44	27.06
*678-153115011	153115011	J	N Plug to 7/16 Plug	34.42	31.29	30.19	27.76
678-1323505	1323505	K	N Jack to BNC Jack	8.90	8.09	7.81	7.18
678-1327505	1327505	L	N Jack to UHF Jack	12.64	11.49	11.09	10.19
678-1328505	1328505	M	N Jack to F Jack	68.00	61.82	59.65	54.84
678-1329505	1329505	N	N Jack to SMA Jack	35.50	32.27	30.85	28.63
678-1325505	1325505	O	N Jack to TNC Jack	18.16	16.51	15.85	14.65
678-6311505	6311505	P	N Jack to Mini-UHF Plug	13.62	12.38	11.95	10.98
*678-153150011	153150011	Q	N Jack to 7/16 Plug	31.56	28.69	27.68	25.45
*678-153215011	153215011	R	N Jack to 7/16 Jack	30.78	27.98	27.00	24.82
Type 7/16 Adapters							
*678-1513A5011	1513A5011	S	7/16 Plug to 7/16 Jack R/A	60.92	55.38	53.44	49.13
*678-1532A5011	1532A5011	T	7/16 Jack to 7/16 Jack	35.72	32.47	31.33	28.81
Type BNC Adapters							
678-3315505	3315505	U	BNC Plug to TNC Jack	4.92	4.47	4.32	3.97
678-3316505	3316505	V	BNC Plug to Mini-UHF Jack	8.20	7.45	7.19	6.61
678-3307505	3307505	W	BNC Plug to UHF Plug	14.90	13.55	13.07	12.02

MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Price Each			
				1	10	25	50
Type BNC Adapters Cont.							
678-3317505	3317505	X	BNC Plug to UHF Jack	7.70	7.00	6.75	6.21
678-3318505	3318505	Y	BNC Plug to F Jack	4.62	4.20	4.05	3.73
678-3309505	3309505	Z	BNC Plug to SMA Plug	24.24	22.04	21.26	19.55
678-3319505	3319505	AA	BNC Plug to SMA Jack	7.98	7.25	7.00	6.44
678-3325505	3325505	BB	BNC Jack to TNC Jack	14.60	13.27	12.68	11.77
678-3327505	3327505	CC	BNC Jack to UHF Jack	14.62	13.29	12.70	11.79
678-3328505	3328505	DD	BNC Jack to F Jack	5.28	4.80	4.63	4.26
678-8313505	8313505	EE	BNC Jack to F Plug	4.08	3.71	3.58	3.29
678-6313505	6313505	FF	BNC Jack to Mini-UHF Plug	8.64	7.85	7.58	6.97
Type TNC Adapters							
678-5311505	5311505	GG	TNC Plug to N Jack	6.96	6.33	6.11	5.61
678-5313505	5313505	HH	TNC Plug to BNC Jack	5.26	4.78	4.61	4.24
678-5316505	5316505	II	TNC Plug to Mini-UHF Jack	8.30	7.55	7.28	6.69
678-5317505	5317505	JJ	TNC Plug to UHF Jack	14.28	12.98	12.53	11.52
678-5309505	5309505	KK	TNC Plug to SMA Plug	12.48	11.35	10.95	10.06
678-5319505	5319505	LL	TNC Plug to SMA Jack	27.26	24.78	23.91	21.98
678-5329505	5329505	MM	TNC Jack to SMA Jack	26.82	24.38	23.53	21.63
Type SMA Adapters							
678-9311505	9311505	NN	SMA Plug to N Jack	24.96	22.69	21.89	20.13
678-9313505	9313505	OO	SMA Plug to BNC Jack	10.58	9.62	9.28	8.53
678-9315505	9315505	PP	SMA Plug to TNC Jack	25.26	22.96	22.16	20.37
678-9306505	9306505	QQ	SMA Plug to Mini-UHF Plug	6.48	5.89	5.68	5.23
678-9316505	9316505	RR	SMA Plug to Mini-UHF Jack	30.12	27.38	26.42	24.29
678-9317505	9317505	SS	SMA Jack to UHF Plug	32.00	29.09	28.07	25.81

