


CONEC D-Subminiature Connectors

RoHS Compliant This product is RoHS compliant.

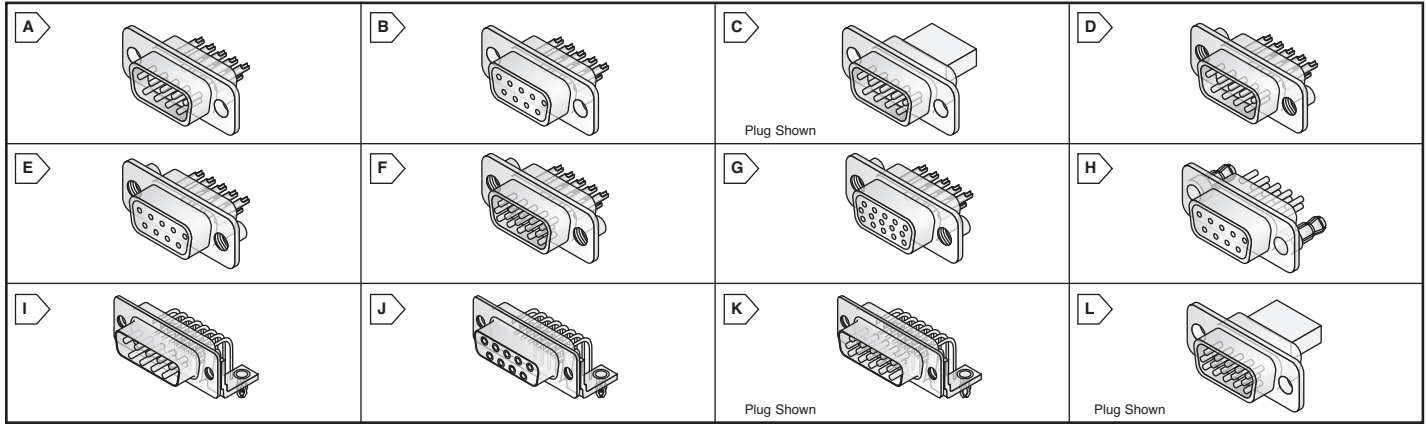

NON-FILTERED D-SUBS

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	No. of Positions	Type	Description	Price Each		
						1	10	100
Through Hole								
706-163A11069X	163A11069X	A	9	Plug	Solder Cup	2.69	1.97	1.53
706-163A11079X	163A11079X	A	15	Plug	Solder Cup	3.25	2.24	1.85
706-163A11089X	163A11089X	A	25	Plug	Solder Cup	4.03	2.82	2.32
706-163A11099X	163A11099X	A	37	Plug	Solder Cup	5.29	3.98	3.26
706-163A11109X	163A11109X	A	50	Plug	Solder Cup	6.08	4.57	3.85
706-164A10019X	164A10019X	B	9	Socket	Solder Cup	2.99	2.11	1.74
706-164A10029X	164A10029X	B	15	Socket	Solder Cup	4.02	2.85	2.37
706-164A10039X	164A10039X	B	25	Socket	Solder Cup	5.11	3.82	3.14
706-164A10049X	164A10049X	B	37	Socket	Solder Cup	7.12	5.38	4.45
706-164A10059X	164A10059X	B	50	Socket	Solder Cup	9.13	6.85	5.76
706-163X10019X	163X10019X	C	9	Plug	Crimp	1.44	.97	.74
706-163X10029X	163X10029X	C	15	Plug	Crimp	1.69	1.11	.90
706-163X10039X	163X10039X	C	25	Plug	Crimp	1.49	1.01	.78
706-163X10049X	163X10049X	C	37	Plug	Crimp	2.29	1.62	1.28
706-163X10059X	163X10059X	C	50	Plug	Crimp	3.05	2.10	1.74
706-164X11769X	164X11769X	C	9	Socket	Crimp	1.72	1.13	.86
706-164X11779X	164X11779X	C	15	Socket	Crimp	1.69	1.22	.98
706-164X11789X	164X11789X	C	25	Socket	Crimp	1.89	1.28	1.02
706-164X11799X	164X11799X	C	37	Socket	Crimp	2.47	1.66	1.37
706-164X11809X	164X11809X	C	50	Socket	Crimp	3.12	2.09	1.76
4-40 UNC Threaded								
706-163A11269X	163A11269X	D	9	Plug	Solder Cup	2.95	2.01	1.70
706-163A11279X	163A11279X	D	15	Plug	Solder Cup	3.65	2.58	2.16
706-163A11289X	163A11289X	D	25	Plug	Solder Cup	3.89	2.81	2.30
706-163A11299X	163A11299X	D	37	Plug	Solder Cup	5.77	4.29	3.55
706-163A11309X	163A11309X	D	50	Plug	Solder Cup	6.65	4.98	4.16
706-164A10219X	164A10219X	E	9	Socket	Solder Cup	3.48	2.43	2.04
706-164A10229X	164A10229X	E	15	Socket	Solder Cup	4.41	3.16	2.62
706-164A10239X	164A10239X	E	25	Socket	Solder Cup	5.65	4.19	3.42
706-164A10249X	164A10249X	E	37	Socket	Solder Cup	7.49	5.51	4.62
706-164A10259X	164A10259X	E	50	Socket	Solder Cup	9.54	6.99	6.04
706-163A16649X	163A16649X	F	15	Plug	Solder Cup High Density	4.49	3.33	2.75
706-163A16659X	163A16659X	F	26	Plug	Solder Cup High Density	6.59	4.98	4.15
706-163A16669X	163A16669X	F	44	Plug	Solder Cup High Density	9.39	7.04	5.89
706-164A17059X	164A17059X	G	15	Socket	Solder Cup High Density	5.74	4.25	3.52
706-164A17069X	164A17069X	G	26	Socket	Solder Cup High Density	8.36	7.26	6.91
706-164A17079X	164A17079X	G	44	Socket	Solder Cup High Density	11.80	10.77	10.26
With Threaded Spacer Clip								
706-164A16569X	164A16569X	H	9	Socket	PC Mount-Vertical	4.75	3.31	2.77
706-164A16579X	164A16579X	H	15	Socket	PC Mount-Vertical	5.16	3.88	3.45
706-164A16589X	164A16589X	H	25	Socket	PC Mount-Vertical	6.09	4.57	4.28
With Metal Bracket Threaded Insert and Clip								
706-163A17529X	163A17529X	I	9	Plug	PC Mount-Right Angle	6.38	4.85	4.04
706-163A17539X	163A17539X	I	15	Plug	PC Mount-Right Angle	7.90	5.99	5.04
706-163A17549X	163A17549X	I	25	Plug	PC Mount-Right Angle	9.89	7.58	6.58
706-164A17939X	164A17939X	J	9	Socket	PC Mount-Right Angle	6.76	5.09	4.30
706-164A17949X	164A17949X	J	15	Socket	PC Mount-Right Angle	8.41	6.35	5.33
706-164A17959X	164A17959X	J	25	Socket	PC Mount-Right Angle	10.65	8.12	7.00
High Density With Metal Bracket Threaded Insert and Clip								
706-163A17769X	163A17769X	K	15	Plug	PC Mount-Right Angle	11.02	8.45	7.28
706-164A18179X	164A18179X	K	15	Socket	PC Mount-Right Angle	12.69	9.81	8.89
High Density Shell for Screw Machine Contacts with Through Hole								
706-163X10169X	163X10169X	L	15	Plug	Crimp	2.94	2.05	1.71
706-163X10179X	163X10179X	L	26	Plug	Crimp	3.75	2.64	2.15
706-163X10189X	163X10189X	L	44	Plug	Crimp	2.43	1.74	1.44
706-164X11949X	164X11949X	L	15	Socket	Crimp	3.71	2.65	2.16
706-164X11959X	164X11959X	L	26	Socket	Crimp	4.04	2.91	2.40
706-164X11969X	164X11969X	L	44	Socket	Crimp	3.59	2.51	2.08

CONTACTS

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Type	Description	Price Each		
				1	10	100
Crimp						
706-161A18299X	161A18299X	Male	20-24 AWG	.45	.30	.21
706-161A18309X	161A18309X	Male	24-28 AWG	.46	.28	.20
706-162A18709X	162A18709X	Female	20-24 AWG	.89	.60	.44
706-162A18719X	162A18719X	Female	24-28 AWG	.98	.65	.49
Screw Machine High Density Crimp Contacts						
706-161A18009X	161A18009X	Male	22 AWG	.28	.17	.11
706-162A18419X	162A18419X	Female	22 AWG	.39	.25	.17