


# CONEC D-Subminiature Connectors



This product is RoHS compliant.

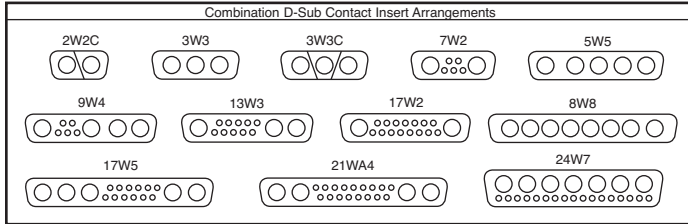

## COMBINATION D-SUBS


- Shell: Tin Plated Steel
- Mating Cycles: 500
- RoHS Compliant per CONEC documentation

- Insulator: UL94V-0

\*4-40 Threaded insert

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Contact Arrangement	Price Each		
			1	10	100
<b>Crimp Style - Female - Contacts Sold Separately</b>					
706-302W2CSXX99A10X	302W2CSXX99A10X	2W2C	2.54	1.97	1.57
*706-302W2CSXX99A30X	302W2CSXX99A30X	2W2C	2.95	2.14	1.78
706-303W3CSXX99A10X	303W3CSXX99A10X	3W3C	1.83	1.37	1.18
*706-303W3CSXX99A30X	303W3CSXX99A30X	3W3C	2.48	1.89	1.66
706-3003W3SXX99A10X	3003W3SXX99A10X	3W3	1.86	1.45	1.24
*706-3003W3SXX99A30X	3003W3SXX99A30X	3W3	2.43	1.81	1.68
706-3005W5SXX99A10X	3005W5SXX99A10X	5W5	2.79	1.90	1.41
*706-3005W5SXX99A30X	3005W5SXX99A30X	5W5	2.64	1.92	1.78
706-3008W8SXX99A10X	3008W8SXX99A10X	8W8	2.39	1.79	1.60
*706-3008W8SXX99A30X	3008W8SXX99A30X	8W8	3.25	2.19	1.80
<b>Crimp Style - Male - Contacts Sold Separately</b>					
706-302W2CPXX99A10X	302W2CPXX99A10X	2W2C	1.76	1.27	1.18
*706-303W3CPXX99A10X	303W3CPXX99A10X	3W3C	1.89	1.38	1.24
706-3003W3PXX99A10X	3003W3PXX99A10X	3W3	1.89	1.38	1.14
*706-3005W5PXX99A10X	3005W5PXX99A10X	5W5	2.32	1.50	1.21
706-3008W8PXX99A10X	3008W8PXX99A10X	8W8	2.34	1.82	1.49
<b>Solder Cup - Female - Power Contacts Sold Separately</b>					
706-3007W2SCM99A10X	3007W2SCM99A10X	7W2	4.25	3.24	2.62
*706-3007W2SCM99A30X	3007W2SCM99A30X	7W2	5.78	4.84	3.94
706-3009W4SCM99A10X	3009W4SCM99A10X	9W4	3.85	2.81	2.58
*706-3009W4SCM99A30X	3009W4SCM99A30X	9W4	4.64	3.38	2.97
706-3017W2SCM99A10X	3017W2SCM99A10X	17W2	7.89	5.95	4.88
*706-3017W2SCM99A30X	3017W2SCM99A30X	17W2	8.16	5.83	5.30
706-3013W3SCM99A10X	3013W3SCM99A10X	13W3	5.32	4.11	3.81
*706-3013W3SCM99A30X	3013W3SCM99A30X	13W3	6.53	4.77	4.18
706-3017W5SCM99A10X	3017W5SCM99A10X	17W5	7.25	5.54	4.47
*706-321WA4SCM99A10X	321WA4SCM99A10X	21WA4	6.64	5.39	5.07
*706-321WA4SCM99A30X	321WA4SCM99A30X	21WA4	8.75	6.26	5.71
706-3024W7SCM99A10X	3024W7SCM99A10X	24W7	7.39	6.09	5.64
*706-3024W7SCM99A30X	3024W7SCM99A30X	24W7	9.29	6.74	6.06
<b>Solder Cup - Male - Power Contacts Sold Separately</b>					
706-3007W2PCM99A10X	3007W2PCM99A10X	7W2	3.12	2.22	1.98
*706-3009W4PCM99A10X	3009W4PCM99A10X	9W4	2.85	2.04	1.86
706-3017W2PCM99A10X	3017W2PCM99A10X	17W2	4.87	3.68	3.29
*706-3013W3PCM99A10X	3013W3PCM99A10X	13W3	4.09	2.98	2.79
706-321WA4PCM99A10X	321WA4PCM99A10X	21WA4	5.75	4.48	4.15
*706-3024W7PCM99A10X	3024W7PCM99A10X	24W7	5.71	4.39	4.14
<b>PC Mount - Female - Right Angle</b>					
706-302W2CSXX56N40X	302W2CSXX56N40X	2W2C	8.29	6.18	5.21
706-303W3CSXX56N40X	303W3CSXX56N40X	3W3C	10.11	7.74	6.45
706-3008W8SXX56N40X	3008W8SXX56N40X	8W8	16.95	14.79	13.71
706-3007W2SCT56N40X	3007W2SCT56N40X	7W2	9.83	7.24	6.49
706-3017W2SCT56N40X	3017W2SCT56N40X	17W2	15.75	11.38	10.12
706-3013W3SCT56N40X	3013W3SCT56N40X	13W3	12.12	10.93	10.12

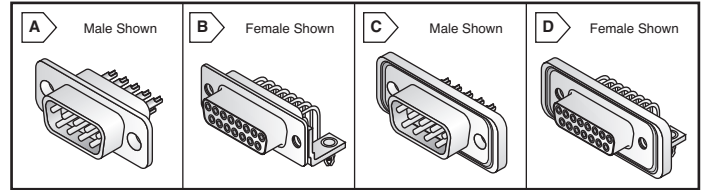

## COAX CONTACTS

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Cable Type	Price Each		
			1	10	100
<b>Female</b>					
706-132J20019X	132J20019X	178, 196, 404	5.84	4.29	3.53
706-132J20029X	132J20029X	174, 188, 316	6.57	4.81	3.94
706-132J20049X	132J20049X	58	5.98	4.39	3.84
706-132J30019X	132J30019X	179, 187	6.15	4.51	3.72
<b>Male</b>					
706-131J20019X	131J20019X	178, 196, 404	5.83	4.09	3.41
706-131J20029X	131J20029X	174, 188, 316	5.94	4.36	3.59
706-131J20049X	131J20049X	58	5.39	3.96	3.49
706-131J30019X	131J30019X	179, 187	6.37	4.71	3.89

## FILTERED D-SUBS

- Shell: Tin plated Brass/Steel
- Contacts: Copper Alloy with Gold over Nickel
- RoHS Compliant per CONEC documentation

\* High Density Version

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	Number of Positions	Price Each		
				1	10	100
<b>C-Filter Adapter - Male/Female with Jack Screws</b>						
706-243A10050X	243A10050X	---	9	11.82	9.42	8.79
*706-243A10060X	243A10060X	---	15	13.77	11.18	11.03
706-243A10070X	243A10070X	---	25	16.97	14.08	13.28
706-243A11680X	243A11680X	---	15	16.79	14.43	13.74
<b>Solder Cup - Female - Through Hole</b>						
706-242A26860X	242A26860X	A	9	8.33	6.97	6.33
706-242A26870X	242A26870X	A	15	11.95	9.33	8.79
<b>Solder Cup - Female - Threaded Insert</b>						
706-242A27020X	242A27020X	A	9	10.74	8.51	7.99
706-242A27030X	242A27030X	A	15	13.33	11.29	10.48
<b>Solder Cup - Male - Through Hole</b>						
706-241A26960X	241A26960X	A	9	8.45	6.76	6.22
706-241A26970X	241A26970X	A	15	11.34	8.89	8.43
706-241A26980X	241A26980X	A	25	14.16	11.37	10.93
<b>Solder Cup - Male - Threaded Insert</b>						
706-241A27120X	241A27120X	A	9	10.67	8.20	7.73
<b>PCB Mount - Female - Threaded Insert - Right Angle</b>						
706-242A17660X	242A17660X	B	9	13.29	10.74	10.07
706-242A17670X	242A17670X	B	15	20.69	18.58	17.69
706-242A17680X	242A17680X	B	25	20.11	15.95	15.61
<b>PCB Mount - Male - Threaded Insert - Right Angle</b>						
706-241A16060X	241A16060X	B	9	11.63	8.92	8.57
706-241A16070X	241A16070X	B	15	13.85	11.04	10.47
706-241A16080X	241A16080X	B	25	17.59	14.49	14.27
<b>PCB Mount - Female - Threaded Spacer Clip - Vertical</b>						
706-242A15030X	242A15030X	A	9	11.29	8.83	8.25
706-242A15040X	242A15040X	A	15	13.74	11.07	10.31
706-242A15050X	242A15050X	A	25	21.33	18.22	17.35

## HIGH POWER CONTACTS

- Contacts: Copper Alloy with Gold over Nickel

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Current	Wire Range	Price Each		
				1	10	100
<b>Female - Crimp</b>						
706-132C11019X	132C11019X	10A	16-20AWG	2.32	1.55	1.31
706-132C11029X	132C11029X	20A	12-14AWG	2.28	1.59	1.26
706-132C11039X	132C11039X	30A	10-12AWG	2.31	1.54	1.32
706-132C11049X	132C11049X	40A	8-10AWG	2.49	1.75	1.45
<b>Male - Crimp</b>						
706-131C11019X	131C11019X	10A	16-20AWG	1.98	1.33	1.08
706-131C11029X	131C11029X	20A	12-14AWG	1.95	1.36	1.11
706-131C11039X	131C11039X	30A	10-12AWG	1.95	1.36	1.11
706-131C11049X	131C11049X	40A	8-10AWG	2.00	1.41	1.12
<b>Female - Solder Cup</b>						
706-132C10019X	132C10019X	10A	16-20AWG	2.29	1.57	1.30
706-132C10029X	132C10029X	20A	12-14AWG	2.59	1.84	1.46
706-132C10039X	132C10039X	30A	10-12AWG	2.36	1.55	1.32
706-132C10049X	132C10049X	40A	8-10AWG	2.67	1.81	1.42
<b>Male - Solder Cup</b>						
706-131C10019X	131C10019X	10A	16-20AWG	2.06	1.42	1.12
706-131C10029X	131C10029X	20A	12-14AWG	1.95	1.49	1.15
706-131C10039X	131C10039X	30A	10-12AWG	1.91	1.37	1.08
706-131C10049X	131C10049X	40A	8-10AWG	1.98	1.41	1.13

## WATER RESISTANT D-SUBS

- Shell: Tin plated Brass/Steel
- Contacts: Copper Alloy with Gold over Nickel
- Operating Temperature: -40°C to +105°C
- Voltage: 125V
- RoHS Compliant per CONEC documentation
- Current: 5A
- IP67

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	Number of Positions	Price Each		
				1	10	100
<b>Solder Cup - Female</b>						
706-6STD09SCM99B30X	6STD09SCM99B30X	C	9	11.04	8.73	8.37
706-6STD15SCM99B30X	6STD15SCM99B30X	C	15	12.79	10.83	9.98
706-6STD25SCM99B30X	6STD25SCM99B30X	C	25	16.13	13.47	12.83
<b>Solder Cup - Male - PCB Mount - Die Cast</b>						
706-6STD09PCM99B30X	6STD09PCM99B30X	C	9	12.33	10.09	9.61
706-6STD25PCM99B30X	6STD25PCM99B30X	C	25	16.34	13.69	12.96
<b>Solder Cup - Male - Sealed - No Frame</b>						
706-4STD09PCM99A10X	4STD09PCM99A10X	A	9	8.49	8.04	7.44
706-4STD25PCM99A10X	4STD25PCM99A10X	A	25	12.11	11.02	9.99
<b>Solder Pin - Female - Right Angle</b>						
706-6STD09SCT99S40X	6STD09SCT99S40X	D	9	15.60	11.49	10.56
706-6STD15SCT99S40X	6STD15SCT99S40X	D	15	15.52	13.06	12.09
<b>Hoods</b>						
706-165X14819XE	165X14819XE	---	9	15.64	11.49	10.73
706-165X14829XE	165X14829XE	---	15	14.79	11.64	10.17
706-165X14839XE	165X14839XE	---	25	15.59	11.98	10.47

CONEC "D" Connectors