

CONEC D-Sub Hardware and Accessories



RoHS Compliant This product is RoHS compliant.

D-SUB HOODS

Plastic Hoods

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	Number of Positions	Price Each		
				1	10	100
Shielded - Side Entry						
706-165X00789XE	165X00789XE	A	15	9.10	6.99	5.90
Straight Entry - Black						
706-165X10139XE	165X10139XE	B	9	5.19	3.71	3.12
706-165X10149XE	165X10149XE	B	15	5.19	3.82	3.16
706-165X10159XE	165X10159XE	B	25	5.57	4.09	3.41
706-165X10169XE	165X10169XE	B	37	6.15	4.54	3.81
706-165X10179XE	165X10179XE	B	50	10.25	7.98	6.86
706-165X10389XE	165X10389XE	B	9	3.94	2.82	2.33
706-165X10419XE	165X10419XE	B	37	4.51	3.22	2.65
706-165X10429XE	165X10429XE	B	50	5.11	3.89	3.23
Straight Entry - Metalized						
706-165X10909XE	165X10909XE	B	9	7.78	5.64	4.75
706-165X10919XE	165X10919XE	B	15	7.85	5.91	4.94
706-165X10929XE	165X10929XE	B	25	8.31	6.18	5.17
Top Entry - Gray						
706-165X11869XE	165X11869XE	B	9	3.49	2.51	2.06
Side Entry - Black						
706-165X10439XE	165X10439XE	C	9	3.76	2.51	2.14
706-165X10449XE	165X10449XE	C	15	3.96	2.91	2.42
706-165X10459XE	165X10459XE	C	25	3.94	2.88	2.37
706-165X10479XE	165X10479XE	C	50	4.24	3.01	2.96
Dual Entry Gray						
706-165X11879XE	165X11879XE	D	15	3.35	2.37	1.97
706-165X11889XE	165X11889XE	D	25	4.14	2.97	2.45
706-165X11899XE	165X11899XE	D	37	4.21	2.98	2.49
Dual Entry - Black						
706-165X11239XE	165X11239XE	D	9	4.21	3.05	2.52
706-165X11249XE	165X11249XE	D	15	3.95	2.89	2.36
706-165X11259XE	165X11259XE	D	25	4.97	3.45	2.88
706-165X11269XE	165X11269XE	D	37	5.03	3.67	3.11
Dual Entry with Slidlock						
706-165X11279XE	165X11279XE	D	9	6.06	4.32	3.69
706-165X11289XE	165X11289XE	D	15	6.19	4.52	3.74
706-165X11299XE	165X11299XE	D	25	6.63	4.85	3.95
706-165X11309XE	165X11309XE	D	37	8.41	6.29	5.34
Dual Entry with Slidlock - Metalized						
706-165X11319XE	165X11319XE	D	9	6.75	5.73	5.16
706-165X11329XE	165X11329XE	D	15	7.06	5.27	4.42
706-165X11339XE	165X11339XE	D	25	7.35	6.24	5.05
706-165X11349XE	165X11349XE	D	37	8.91	6.28	5.96
Dual Entry - No Hardware						
706-165X13219XE	165X13219XE	E	9	2.36	1.64	1.34
706-165X13239XE	165X13239XE	E	25	2.39	1.54	1.31
For IDC Flat Cable						
706-165X14029XE	165X14029XE	F	25	4.57	3.88	3.49
Straight Entry - For Combination D-Subs						
706-165X13369XE	165X13369XE	G	9	4.61	3.33	2.74
706-165X13379XE	165X13379XE	G	15	4.94	3.53	2.95
706-165X13389XE	165X13389XE	G	25	4.97	3.65	2.98
706-165X13399XE	165X13399XE	G	37	5.88	4.24	3.51
706-165X13409XE	165X13409XE	G	50	5.88	4.24	3.51
Side Entry - For Combination D-Subs						
706-165X13419XE	165X13419XE	H	9	4.68	3.37	2.75
706-165X13429XE	165X13429XE	H	15	4.49	3.42	2.85
706-165X13439XE	165X13439XE	H	25	4.97	3.65	3.03
706-165X13449XE	165X13449XE	H	37	4.98	3.67	3.09
706-165X13459XE	165X13459XE	H	50	5.66	4.08	3.49

Metal Hoods


For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	Number of Positions	Price Each		
				1	10	100
Straight Entry						
706-165X02609XE	165X02609XE	I	9	5.58	3.97	3.36
706-165X02619XE	165X02619XE	I	15	6.61	4.89	4.06
706-165X02629XE	165X02629XE	I	25	6.69	4.92	4.14
706-165X02639XE	165X02639XE	I	37	8.54	6.29	5.36
Side Entry						
706-165X02689XE	165X02689XE	J	9	5.59	4.06	3.34
706-165X02699XE	165X02699XE	J	15	5.61	4.08	3.36
706-165X02709XE	165X02709XE	J	25	5.69	4.18	3.41
706-165X02719XE	165X02719XE	J	37	8.56	6.29	5.36

GENDER CHANGERS

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	Number of Positions	Price Each		
				1	10	100
Male/Male						
706-320X12509X	320X12509X	K	9	2.72	1.89	1.52
706-320X12529X	320X12529X	K	15	2.59	1.95	1.59
706-320X10549X	320X10549X	K	25	3.57	2.58	2.08
706-320X12549X	320X12549X	K	37	4.90	3.45	2.99
Female/Female						
706-320X12519X	320X12519X	L	9	2.65	1.84	1.52
706-320X12539X	320X12539X	L	15	2.53	1.82	1.74
706-320X10559X	320X10559X	L	25	3.69	2.55	2.11
706-320X12559X	320X12559X	L	37	5.09	3.68	3.02

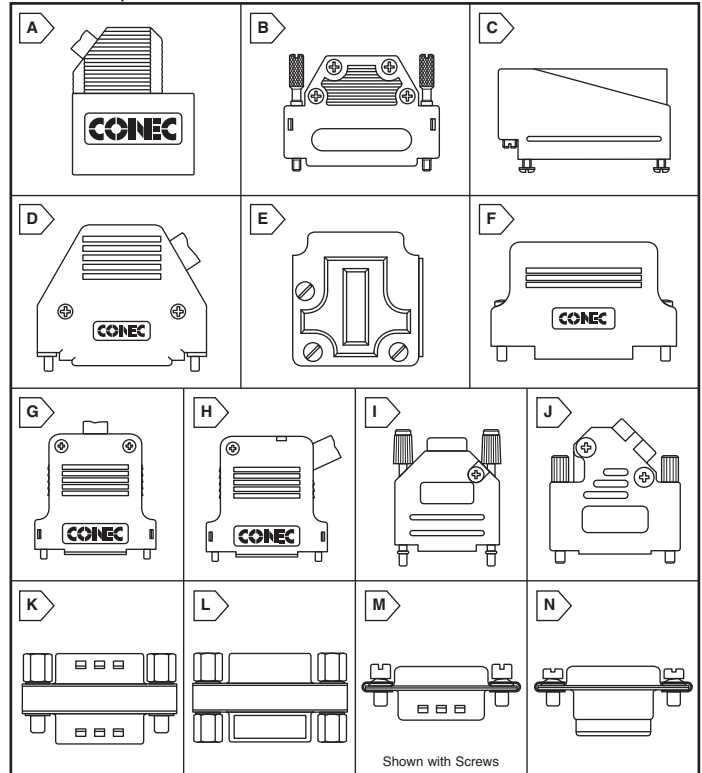

METAL DUST CAPS

Metal Caps

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	Number of Positions	Price Each		
				1	10	100
Female						
706-165X12969X	165X12969X	M	9	1.25	.87	.68
706-165X12979X	165X12979X	M	15	1.28	.89	.69
Female with Screws						
706-165X16719X	165X16719X	M	9	1.92	1.35	1.10
706-165X16729X	165X16729X	M	15	2.11	1.49	1.24
Male						
706-165X13129X	165X13129X	M	9	1.18	.86	.68
706-165X13149X	165X13149X	M	25	1.39	.98	.81
Male with Screws						
706-165X16769X	165X16769X	M	9	1.97	1.33	1.08
706-165X16789X	165X16789X	M	25	2.11	1.49	1.19

Water Resistant Metal Caps

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	Number of Positions	Price Each		
				1	10	100
Female with Screws						
706-165X14719X	165X14719X	M	9	6.13	4.45	3.84
706-165X14729X	165X14729X	M	15	6.21	4.52	3.80
Male with Screws						
706-165X14769X	165X14769X	N	9	5.71	4.25	3.85
706-165X14779X	165X14779X	N	15	5.42	4.06	3.72

HARDWARE

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	Number of Positions	Price Each		
				1	10	100
Slidlock with Self Tapping Screws						
706-160X10159X	160X10159X	---	9	1.89	1.26	1.03
706-160X10169X	160X10169X	---	15	1.98	1.40	1.16
706-160X10179X	160X10179X	---	25	1.86	1.34	1.19
Slidlock with 4-40 Screws						
706-160X10689X	160X10689X	---	9	2.05	1.39	1.17
706-160X10709X	160X10709X	---	25	2.05	1.38	1.14
Lock for Slidlock - Use with Dual Entry Slidlock Hoods						
706-165X10119X	165X10119X	---	---	.52	.36	.27
Locking Bolt Set - Use with Slidlocks						
706-160X10209X	160X10209X	---	---	.75	.53	.38
Hex Locking Screws and Hardware						
706-160X10359X	160X10359X	---	---	.74	.52	.38
706-160X10329X	160X10329X	---	---	2.14	1.46	1.20
Screw Locking Clamp						
706-160X10259X	160X10259X	---	---	.79	.51	.49

"D" Connectors

CONEC