



HARTING Filtered D-Sub Adapters and Connectors

FILTERED D-SUB ADAPTERS

Features:

- Provides electronic noise reduction in various applications from high speed industrial digital broadcast to industrial test equipment.
- Internal shielding through utilization of copper foil soldered to male and female connectors.
- Efficient shielding of internal signal lines from EMI and RFI.
- Design uses the same patented design of multiple layer PCB with chip capacitors as HARTING'S range of filter D connectors.
- Plating performance level 2 as per CECC 75 301-802, guarantees > 250 mating cycles.
- Ideal solution for diagnostic purposes in R&D departments

NEW
FROM SUPPLIER



RoHS Compliant

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	HARTING Part No.	Fig.	No. of Positions	Capacitance	Price Each		
					1	5	10
617-09-64-100-7210	09 64 100 7210	A	9	47 pF	30.20	28.90	27.93
617-09-64-100-7220	09 64 100 7220	A	9	470 pF	30.20	28.90	27.93
617-09-64-100-7230	09 64 100 7230	A	9	1000 pF	30.20	28.90	27.93
617-09-64-100-7240	09 64 100 7240	A	9	3900 pF	30.20	28.90	27.93
617-09-64-200-7210	09 64 200 7210	A	15	47 pF	40.27	38.53	37.25
617-09-64-200-7220	09 64 200 7220	A	15	470 pF	40.27	38.53	37.25
617-09-64-200-7230	09 64 200 7230	A	15	1000 pF	40.27	38.53	37.25
617-09-64-200-7240	09 64 200 7240	A	15	3900 pF	40.27	38.53	37.25
617-09-64-300-7210	09 64 300 7210	A	25	47 pF	54.86	52.50	50.75
617-09-64-300-7220	09 64 300 7220	A	25	470 pF	54.86	52.50	50.75
617-09-64-300-7230	09 64 300 7230	A	25	1000 pF	54.86	52.50	50.75
617-09-64-300-7240	09 64 300 7240	A	25	3900 pF	54.86	52.50	50.75
617-09-64-400-7210	09 64 400 7210	A	37	47 pF	69.53	66.53	64.32
617-09-64-400-7220	09 64 400 7220	A	37	470 pF	69.53	66.53	64.32
617-09-64-400-7230	09 64 400 7230	A	37	1000 pF	69.53	66.53	64.32
617-09-64-400-7240	09 64 400 7240	A	37	3900 pF	69.53	66.53	64.32

3900 PF CAPACITANCE FILTERED D-SUB CONNECTORS



RoHS Compliant

Solder Cup

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	HARTING Part No.	Fig.	No. of Positions	Type	Price Each			
					1	10	25	50
617-09-64-121-7240	09 64 121 7240	B	9	Male	8.79	8.31	7.97	7.77
617-09-64-221-7240	09 64 221 7240	B	15	Male	12.51	11.82	11.35	11.05
617-09-64-321-7240	09 64 321 7240	B	25	Male	17.72	16.74	16.07	15.65
617-09-64-421-7240	09 64 421 7240	B	37	Male	21.81	20.60	19.77	19.26
617-09-64-111-7240	09 64 111 7240	C	9	Female	9.19	8.68	8.33	8.12
617-09-64-211-7240	09 64 211 7240	C	15	Female	13.04	12.32	11.83	11.52
617-09-64-311-7240	09 64 311 7240	C	25	Female	18.91	17.86	17.15	16.70
617-09-64-411-7240	09 64 411 7240	C	37	Female	24.38	23.03	22.11	21.53



RoHS Compliant

Straight

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	HARTING Part No.	Fig.	No. of Positions	Type	Price Each			
					1	10	25	50
617-09-64-122-7240	09 64 122 7240	D	9	Male	7.86	7.34	6.98	6.74
617-09-64-222-7240	09 64 222 7240	D	15	Male	12.54	11.85	11.37	11.08
617-09-64-322-7240	09 64 322 7240	D	25	Male	17.74	16.75	16.08	15.66
617-09-64-422-7240	09 64 422 7240	D	37	Male	22.71	21.44	20.59	20.05
617-09-64-112-7240	09 64 112 7240	E	9	Female	9.26	8.75	8.40	8.18
617-09-64-212-7240	09 64 212 7240	E	15	Female	13.19	12.46	11.96	11.65
617-09-64-312-7240	09 64 312 7240	E	25	Female	19.13	18.07	17.35	16.90
617-09-64-412-7240	09 64 412 7240	E	37	Female	24.72	23.35	22.41	21.83




RoHS Compliant

Right Angle Boardlock and Clinch Nut

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	HARTING Part No.	Fig.	No. of Positions	Type	Price Each			
					1	10	25	50
617-09-64-124-7242	09 64 124 7242	F	9	Male	11.49	10.85	10.41	10.14
617-09-64-224-7242	09 64 224 7242	F	15	Male	15.71	14.83	14.24	13.87
617-09-64-324-7242	09 64 324 7242	F	25	Male	21.78	20.57	19.75	19.23
617-09-64-424-7242	09 64 424 7242	F	37	Male	27.79	26.25	25.20	24.55
617-09-64-114-7242	09 64 114 7242	G	9	Female	11.69	11.04	10.60	10.32
617-09-64-214-7242	09 64 214 7242	G	15	Female	15.94	15.06	14.45	14.08
617-09-64-314-7242	09 64 314 7242	G	25	Female	22.44	21.19	20.35	19.82
617-09-64-414-7242	09 64 414 7242	G	37	Female	28.68	27.08	26.00	25.32

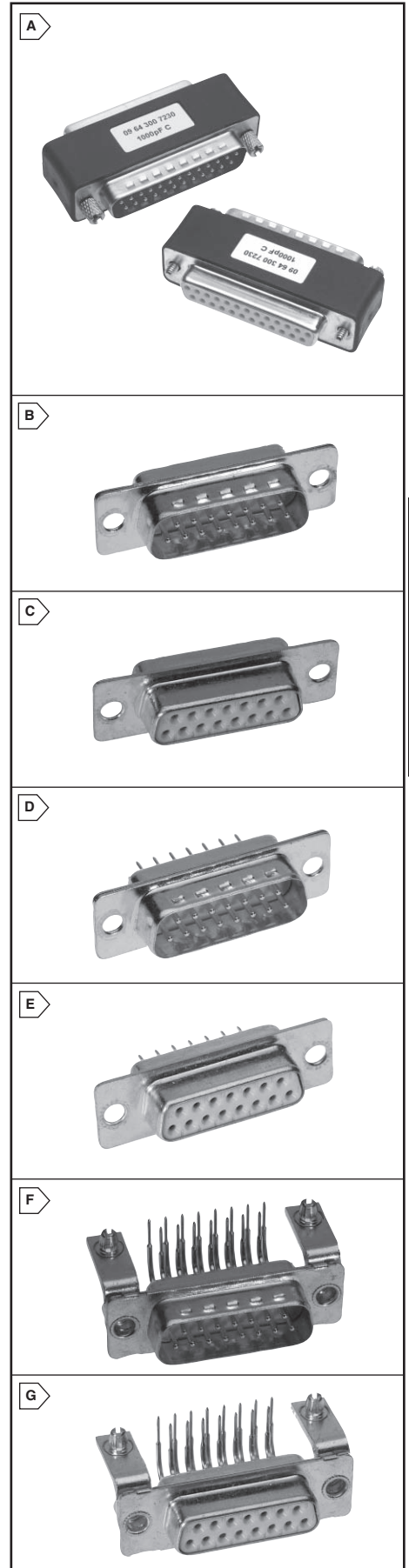

"D" Connectors

HARTING