

OSRAM SMD LEDs




This product is RoHS compliant.

OSRAM

Opto Semiconductors

For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Fig.	Size	Emitting Color	Wavelength	Intensity (Typ.)	Forward Voltage	Forward Current	Viewing Angle	Price Each					
									1	10	50	100		
Top LED (Cont.)														
720-LPT676L1M225Z	A	PLCC-2	Pure Green	560nm	28mcd	2V	20mA	120°	.22	.209	.19	.168		
720-LTT673N2S125Z	A	PLCC-2	True Green	532nm	224mcd	3V	10mA	120°	.73	.698	.64	.562		
720-LTT67CS2V135Z	A	PLCC-2	True Green	528nm	900mcd	3.5V	20mA	120°	.71	.682	.62	.548		
720-LVT67CS1U235Z	A	PLCC-2	Verde Green	505nm	710mcd	3.5V	20mA	120°	.84	.798	.73	.642		
720-LBT673L2N135Z	A	PLCC-2	Blue	471nm	75mcd	3.1V	10mA	120°	.64	.611	.56	.492		
720-LBT67CP2R135Z	A	PLCC-2	Blue	470nm	140mcd	3.6V	10mA	120°	.66	.628	.58	.506		
720-LWT673P1A5K8LZ	A	PLCC-2	White	5600K	1055mcd	3.2V	20mA	120°	.66	.632	.58	.508		
720-LWT673P1S15K8LZ	A	PLCC-2	White	5600K	224mcd	3.1V	10mA	120°	.63	.599	.55	.482		
720-LWT673P1S15K8LZ	A	PLCC-2	White	5600K	560mcd	3.6V	20mA	120°	.66	.628	.58	.506		
720-LWT673P1S15K8LZ	A	PLCC-2	White	5600K	900mcd	3.6V	20mA	120°	.61	.582	.53	.468		
Power Top LED														
720-LSE67BS2V111Z	B	PLCC-4	Super Red	633nm	1700mcd	2.2V	50mA	120°	.20	.196	.18	.158		
720-LSE67BV2BA11Z	B	PLCC-4	Super Red	633nm	2240mcd	2.15V	50mA	120°	.33	.316	.29	.254		
720-LREG6SFV2AB11Z	B	PLCC-4	Red	625nm	1800mcd	2.15V	50mA	120°	.29	.282	.28	.277		
720-LAE67BU2AA241Z	B	PLCC-4	Amber	617nm	1400mcd	2.2V	50mA	120°	.21	.208	.19	.167		
720-LAE67FAABA243B5A	B	PLCC-4	Amber	617nm	1680mcd	2.3V	50mA	120°	.26	.249	.23	.20		
720-LAE67SFBACA241Z	B	PLCC-4	Amber	617nm	3550mcd	2.15V	50mA	120°	.33	.316	.29	.254		
720-LOE67BU2AA241Z	B	PLCC-4	Orange	606nm	1400mcd	2.2V	50mA	120°	.20	.196	.18	.158		
720-LOE67SFBACB241Z	B	PLCC-4	Orange	606nm	4500mcd	2.15V	50mA	120°	.33	.316	.29	.254		
720-LYE67SFV2AB351Z	B	PLCC-4	Yellow	590nm	1800mcd	2.15V	50mA	120°	.35	.331	.30	.267		
720-LYE67BU2AA261Z	B	PLCC-4	Yellow	587nm	2950mcd	2.2V	50mA	120°	.22	.212	.19	.17		
720-LTE67CT1V235Z	B	PLCC-4	True Green	525nm	1120mcd	3.8V	30mA	120°	.82	.68	.61	.54		
720-LTE67SGV2AB361Z	B	PLCC-4	True Green	525nm	1350mcd	3.4V	30mA	120°	.73	.698	.64	.562		
720-LBE67C-R2T1-35Z	B	PLCC-4	Blue	469nm	196mcd	3.9V	30mA	120°	.74	.701	.64	.564		
720-LBE67CQ1S235Z	B	PLCC-4	Blue	469nm	280mcd	3.9V	30mA	120°	.66	.632	.58	.508		
720-LBE67SGS2U135Z	B	PLCC-4	Blue	469nm	392mcd	3.4V	30mA	120°	.70	.665	.61	.535		
720-LCWE67SV1AB4U9XS	B	PLCC-4	Warm White	3200K	1800mcd	3.4V	30mA	120°	.73	.698	.64	.562		
720-LCWE67SV1AB4R9TZ	B	PLCC-4	Warm White	3500K	1800mcd	3.4V	30mA	120°	.73	.698	.64	.562		
720-LCWE67SV2BA4O9QZ	B	PLCC-4	Warm White	3800K	2240mcd	3.4V	30mA	120°	.73	.698	.64	.562		
720-LCWE67SV2BA4L8NZ	B	PLCC-4	Warm White	4100K	2240mcd	3.4V	30mA	120°	.73	.698	.64	.562		
720-LCWE67SV2BA4J8KZ	B	PLCC-4	Warm White	4200K	2240mcd	3.4V	30mA	120°	.73	.698	.64	.562		
720-LWE67CU2V25K8L1Z	B	PLCC-4	White	5600K	1120mcd	3.9V	30mA	120°	.70	.664	.61	.535		
720-LWE67SV2AB5K8LZ	B	PLCC-4	White	5600K	1350mcd	3.4V	30mA	120°	.66	.632	.58	.508		
720-LWE67CU2AA5K8L1Z	B	PLCC-4	White	5600K	1400mcd	3.9V	30mA	120°	.63	.599	.55	.482		
720-LUWE67SGAABA4N7QZ	B	PLCC-4	Ultra White	6500K	2240mcd	3.4V	30mA	120°	.73	.698	.64	.562		
Power Top Lens														
720-LSE63BBBCB11Z	C	PLCC-4	Super Red	633nm	1700mlm	2.2V	50mA	30°	.27	.259	.24	.208		
720-LSE63BV1BB11Z	C	PLCC-4	Super Red	633nm	2400mlm	2.2V	50mA	60°	.27	.259	.24	.208		
720-LSE65F-BBDA-1-Z	C	PLCC-4	Super Red	633nm	4480mlm	2.15V	50mA	60°	.36	.349	.32	.281		
720-LSE63F-DBFA-1-Z	C	PLCC-4	Super Red	633nm	4650mlm	2.15V	50mA	60°	.36	.349	.32	.281		
720-LAE65BBACA241Z	C	PLCC-4	Amber	617nm	3000mlm	2.2V	50mA	60°	.29	.28	.26	.225		
720-LAE63BCBEA241Z	C	PLCC-4	Amber	617nm	3050mlm	2.2V	50mA	30°	.27	.259	.24	.208		
720-LAE63FEAFA243B5A	C	PLCC-4	Amber	617nm	5000mlm	2.15V	50mA	30°	.36	.349	.32	.281		
720-LAE65FCBEA243A4B	C	PLCC-4	Amber	617nm	7170mlm	2.15V	50mA	60°	.36	.349	.32	.281		
720-LOE63BDAEB241Z	C	PLCC-4	Orange	606nm	3850mlm	2.2V	50mA	30°	.27	.259	.24	.208		
720-LYE65FCADA461Z	C	PLCC-4	Yellow	590nm	4800mlm	2.15V	50mA	60°	.36	.349	.32	.281		
720-LYE63FEAFA461Z	C	PLCC-4	Yellow	590nm	5000mlm	2.15V	50mA	30°	.38	.366	.34	.294		
720-LYE65BAACA261Z	C	PLCC-4	Yellow	587nm	2775mlm	2.2V	50mA	60°	.27	.259	.24	.208		
720-LYE63BCBEA261Z	C	PLCC-4	Yellow	587nm	3050mlm	2.2V	50mA	30°	.27	.259	.24	.208		
720-LTE63CBADB351Z	C	PLCC-4	True Green	525nm	2610mlm	3.8V	30mA	20°	.77	.732	.67	.589		
720-LVE63C-ABDA-35LZ	C	PLCC-4	Verde Green	503nm	1450mlm	3.8V	30mA	20°	.98	.81	.73	.65		
720-LBE63CU2V235LZ	C	PLCC-4	Blue	469nm	490mlm	3.9V	30mA	20°	.89	.844	.77	.679		
Multi-Top LED														
720-LSYT67BS1T2T1U21	D	PLCC-4	Red/Yellow	633/587nm	355/710mcd	2.1V, 2.1V	30mA	120°	.40	.385	.35	.31		
720-LSYT676P2R110Q2	D	PLCC-4	Red/Yellow	633/587nm	98/157mcd	2V, 2V	20mA	120°	.29	.276	.25	.222		
720-LSGT676P7Q71N7P	D	PLCC-4	Red/Green	633/570nm	140/90mcd	2V, 2V	20mA	120°	.38	.32	.27	.24		
720-LATB7686QR1RS78	D	PLCC-4	Am/Gr/Blu	617/528/465nm	180/280/18mcd	2.4V, 3.9V, 4.1V	20mA	120°	1.29	1.07	.97	.86		
Advanced Power Top LED														
720-LRG65PCADB11Z	E	PLCC-6	Red	625nm	7100mcd	2.1V	140mA	120°	.87	.832	.76	.669		
720-LAG65PCBEA241Z	E	PLCC-6	Amber	617nm	9000mcd	2.1V	140mA	120°	1.02	.765	.76	.724		
720-LYG65PBBDB361Z	E	PLCC-6	Yellow	590nm	7100mcd	2.2V	140mA	120°	.80	.765	.70	.615		
720-LTG65PCBEB251Z	E	PLCC-6	True Green	528nm	11200mcd	3.6V	140mA	120°	1.93	1.83	1.68	1.47		
720-LBG65PV2BB351Z	E	PLCC-6	Blue	470nm	2800mcd	3.6V	140mA	120°	1.93	1.83	1.68	1.47		
720-LCWG65PCAEA4U9XZ	E	PLCC-6	Warm White	2700K	9000mcd	3.6V	140mA	120°	2.10	1.99	1.83	1.60		
720-LCWG65PCAEA4R9TZ	E	PLCC-6	Warm White	3000K	9000mcd	3.6V	140mA	120°	2.10	1.99	1.83	1.60		
720-LCWG65PCBEB4O9QZ	E	PLCC-6	Warm White	3500K	11200mcd	3.6V	140mA	120°	2.10	1.99	1.83	1.60		
720-LCWG65PCBEB4L8NZ	E	PLCC-6	Warm White	4000K	11200mcd	3.6V	140mA	120°	2.10	1.99	1.83	1.60		
720-LCWG65PCBEB4J8KZ	E	PLCC-6	Warm White	4500K	11200mcd	3.6V	140mA	120°	2.10	1.99	1.83	1.60		
720-LWVG65PCBEA5K8L1Z	E	PLCC-6	White	5600K	9000mcd	3.6V	140mA	120°	2.00	1.90	1.74	1.53		
Multi LED														
720-LATB766BST1TU735	F	PLCC-4	Amb/Gr/Blu	617/528/465nm	450/900/280mcd	2V, 3.5V, 3.6V	20mA	120°	1.42	1.19	1.07	.95		
720-LATB766CRS1ST735	F	PLCC-4	Amb/Gr/Blu	617/528/470nm	196/540/168mcd	2V, 3.5V, 3.6V	20mA	120°	.87	.832	.76	.669		
720-LRTB66GTGVVV736	F	PLCC-6	Red/Gr/Blu	625/528/465nm	700/1055/370mcd	2.1V, 3.2V, 3.2V	20mA	120°	1.97	1.64	1.48	1.31		
720-LRTB66SGT1V11-35Z	F	PLCC-6	Red/Gr/Blu	625/528/458nm	900/1400/560mcd	2.1V, 3.2V, 3.2V	20mA	120°	1.97	1.64	1.48	1.31		
720-LRTB66GTGV1VV736	F	PLCC-6	Red/Gr/Blu	625/528/458nm	900/1400/560mcd	2.1V, 3.2V, 3.2V	20mA	120°	1.97	1.64	1.48	1.31		
720-LRTB66SGT1V11UA	F	PLCC-6	Red/Gr/Blu	625/528/458nm	590/925/336mcd	2.1V, 3.2V, 3.2V	20mA	120°	1.97	1.64	1.48	1.31		
720-LRTB66SGT1V15R1U	F	PLCC-6	Red/Gr/Blu	625/528/458nm	590/925/336mcd	2.1V, 3.2V, 3.2V	20mA	120°	1.97	1.64	1.48	1.31		
720-LATB666BST1TV735	F	PLCC-6	Amb/Gr/Blu	617/528/470nm	450/1120/280mcd	2.1V, 3.2V, 3.2V	20mA	120°	1.59	1.33	1.19	1.06		
720-LRTB7686QR7T51S7U	G	PLCC-6	Red/Gr/Blu	625/528/470nm	140/224/56mcd	2V, 3.3V, 3.4V	20mA	120°	.90	.76	.68	.60		

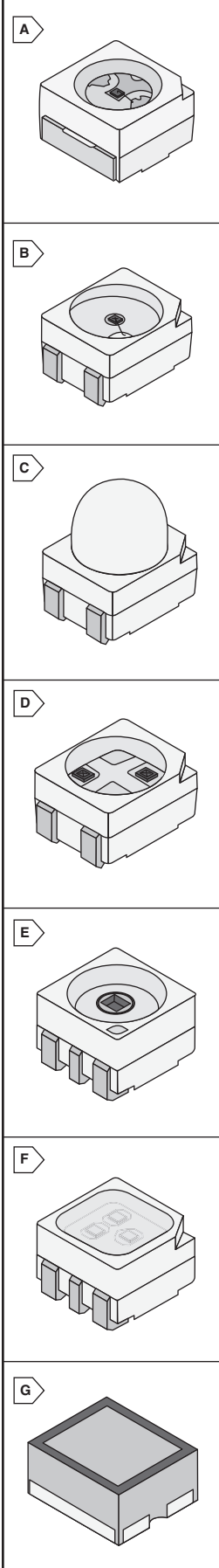

ILLUMINATION

OSRAM

NEW SUPPLIER

NEW SUPPLIER

NEW SUPPLIER

NEW SUPPLIER

