


ALPS Tactile Switches

ALPS

RoHS Compliant This product is RoHS compliant.

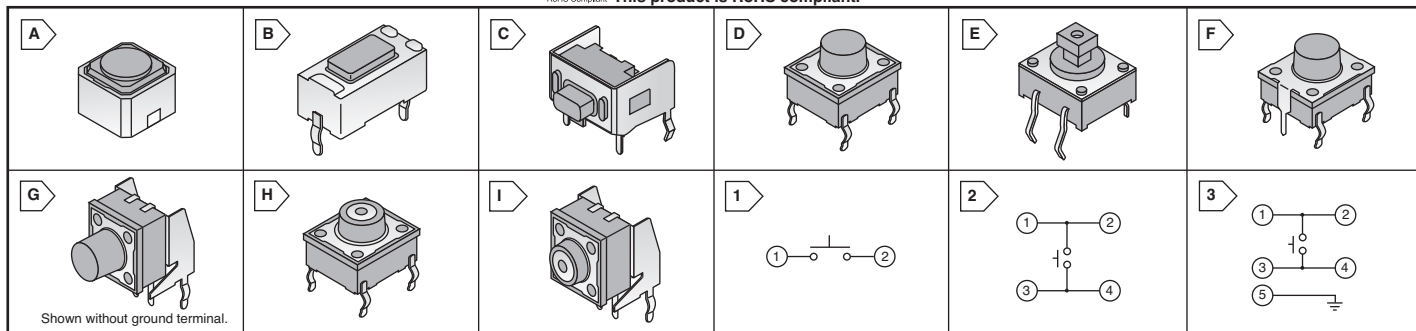

ALPS SMD SOFT FEELING TACTILE SWITCHES

• Contact rating: 50mA @ 16VDC max. • Tape and reel packaging • Reflow solderable

RoHS Compliant

For quantities greater than listed, call for a quote.

MOUSER STOCK NO.	Alps Part Number	Fig.	Dim.: mm			Operating Force	Travel (mm)	Operating Life	Features	Price Each				Reel Quantity	Reel Qty. Price Each
			L	W	H					1	50	100	500		
688-SKPMAM	SKPMAM	A1	5.9	6.0	4.3	160 g	1.3	100,000	Strong OF prevents mis-operations	.76	.59	.53	.44	2,500	.32
688-SKPMAN	SKPMAN	A1	5.9	6.0	5.0	200 g	1.3	100,000	Strong OF prevents mis-operations	.76	.59	.53	.44	2,000	.32
688-SKPMAP	SKPMAP	A1	5.9	6.0	5.0	250 g	1.3	100,000	Strong OF prevents mis-operations	.76	.59	.53	.44	2,000	.32

ALPS SNAP-IN SHARP FEELING TYPE TACTILE SWITCHES

• Contact rating: 50mA @ 12VDC max.

RoHS Compliant

For quantities of 4000 and up, call for a quote.

MOUSER STOCK NO.	Alps Part Number	Fig.	Dim.: mm			Operating Force	Travel (mm)	Operating Life	Features	Price Each					
			L	W	H					1	50	100	500	1000	2000
688-SKHLAA	SKHLAA	B1	6.0	3.5	4.3	100 g	0.25	50,000	High density mounting, Black stem	.48	.37	.34	.28	.22	.20
688-SKHLAC	SKHLAC	B1	6.0	3.5	4.3	160 g	0.25	50,000	High density mounting, Dark gray stem	.48	.37	.34	.28	.22	.20
688-SKHLAJ	SKHLAJ	B1	6.0	3.5	4.3	260 g	0.25	30,000	High density mounting, Red stem	.48	.37	.34	.28	.22	.20
688-SKHLAB	SKHLAB	B1	6.0	3.5	5.0	100 g	0.25	50,000	High density mounting, Black stem	.48	.37	.34	.28	.22	.20
688-SKHLAD	SKHLAD	B1	6.0	3.5	5.0	160 g	0.25	50,000	High density mounting, Dark gray stem	.48	.37	.34	.28	.22	.20
688-SKHLAK	SKHLAK	B1	6.0	3.5	5.0	260 g	0.25	30,000	High density mounting, Red stem	.48	.37	.34	.28	.22	.20
688-SKHLLA	SKHLLA	C1	6.0	3.72	3.5	100 g	0.25	50,000	Terminal length = 3.5mm, Black stem	.60	.47	.42	.35	.27	.25
688-SKHLLB	SKHLLB	C1	6.0	3.72	3.5	160 g	0.25	50,000	Terminal length = 3.5mm, Dark gray stem	.60	.47	.42	.35	.27	.25
688-SKHL LF	SKHL LF	C1	6.0	3.72	3.5	260 g	0.25	30,000	Terminal length = 3.5mm, Red stem	.48	.37	.34	.28	.22	.20
688-SKHL LC	SKHL LC	C1	6.0	3.72	3.5	100 g	0.25	50,000	Terminal length = 2.5mm, Black stem	.60	.47	.42	.35	.27	.25
688-SKHL LD	SKHL LD	C1	6.0	3.72	3.5	160 g	0.25	50,000	Terminal length = 2.5mm, Dark gray stem	.60	.47	.42	.35	.27	.25
688-SKHRAA	SKHRAA	D2	4.5	4.5	3.8	100 g	0.25	50,000	High density mounting, Black stem	.54	.43	.40	.34	.28	.26
688-SKHRAB	SKHRAB	D2	4.5	4.5	3.8	160 g	0.25	30,000	High density mounting, Dark gray stem	.54	.43	.40	.34	.28	.26
688-SKHRAH	SKHRAH	D2	4.5	4.5	3.8	260 g	0.25	50,000	High density mounting, Red stem	.54	.43	.40	.34	.28	.26
688-SKHHAJ	SKHHAJ	D2	6.0	6.0	4.3	100 g	0.25	1,000,000	High density mounting, Black stem	.26	.20	.18	.15	.12	.11
688-SKHHAL	SKHHAL	D2	6.0	6.0	4.3	160 g	0.25	500,000	High density mounting, Dark gray stem	.26	.20	.18	.15	.12	.11
688-SKHHAQ	SKHHAQ	D2	6.0	6.0	4.3	260 g	0.25	200,000	High density mounting, Red stem	.26	.20	.18	.15	.12	.11
688-SKHHAH	SKHHAH	D2	6.0	6.0	5.0	100 g	0.25	1,000,000	High density mounting, Black stem	.26	.20	.18	.15	.12	.11
688-SKHHAM	SKHHAM	D2	6.0	6.0	5.0	160 g	0.25	500,000	High density mounting, Dark gray stem	.26	.20	.18	.15	.12	.11
688-SKH HAR	SKH HAR	D2	6.0	6.0	5.0	260 g	0.25	200,000	High density mounting, Red stem	.26	.20	.18	.15	.12	.11
688-SKH HBV	SKH HBV	D2	6.0	6.0	7.0	100 g	0.25	1,000,000	High density mounting, Black stem	.26	.20	.18	.15	.12	.11
688-SKH HBW	SKH HBW	D2	6.0	6.0	7.0	160 g	0.25	500,000	High density mounting, Dark gray stem	.26	.20	.18	.15	.12	.11
688-SKH HBY	SKH HBY	D2	6.0	6.0	7.0	260 g	0.25	200,000	High density mounting, Red stem	.26	.20	.18	.15	.12	.11
688-SKH HAN	SKH HAN	D2	6.0	6.0	9.5	100 g	0.25	1,000,000	High density mounting, Black stem	.26	.20	.18	.15	.12	.11
688-SKH HAP	SKH HAP	D2	6.0	6.0	9.5	160 g	0.25	500,000	High density mounting, Dark gray stem	.26	.20	.18	.15	.12	.11
688-SKH HBS	SKH HBS	D2	6.0	6.0	9.5	260 g	0.25	200,000	High density mounting, Red stem	.26	.20	.18	.15	.12	.11
688-SKH HDT	SKH HDT	D2	6.0	6.0	13.0	100 g	0.25	1,000,000	High density mounting, Black stem	.56	.44	.39	.32	.25	.23
688-SKH HDU	SKH HDU	D2	6.0	6.0	13.0	160 g	0.25	500,000	High density mounting, Dark gray stem	.56	.44	.39	.32	.25	.23
688-SKH HCW	SKH HCW	E2	6.0	6.0	7.3	100 g	0.25	1,000,000	High density mounting, Black joint stem	.36	.27	.25	.21	.18	.17
688-SKH HPJ	SKH HPJ	F3	6.0	6.0	4.3	100 g	0.25	1,000,000	With ground terminal, Black stem	.26	.20	.18	.15	.12	.11
688-SKH HPL	SKH HPL	F3	6.0	6.0	4.3	160 g	0.25	500,000	With ground terminal, Dark gray stem	.26	.20	.18	.15	.12	.11
688-SKH HPQ	SKH HPQ	F3	6.0	6.0	4.3	260 g	0.25	200,000	With ground terminal, Red stem	.26	.20	.18	.15	.12	.11
688-SKH HPK	SKH HPK	F3	6.0	6.0	5.0	100g	0.25	1,000,000	With ground terminal, Black stem	.26	.20	.18	.15	.12	.11
688-SKH HPM	SKH HPM	F3	6.0	6.0	5.0	160 g	0.25	500,000	With ground terminal, Dark gray stem	.26	.20	.18	.15	.12	.11
688-SKH HPR	SKH HPR	F3	6.0	6.0	5.0	260 g	0.25	200,000	With ground terminal, Red stem	.26	.20	.18	.15	.12	.11
688-SKH HQV	SKH HQV	F3	6.0	6.0	7.0	100 g	0.25	1,000,000	With ground terminal, Black stem	.26	.20	.18	.15	.12	.11
688-SKH HQW	SKH HQW	F3	6.0	6.0	7.0	160 g	0.25	500,000	With ground terminal, Dark gray stem	.26	.20	.18	.15	.12	.11
688-SKH HQY	SKH HQY	F3	6.0	6.0	7.0	260g	0.25	200,000	With ground terminal, Red stem	.26	.20	.18	.15	.12	.11
688-SKH HPN	SKH HPN	F3	6.0	6.0	9.5	100 g	0.25	1,000,000	With ground terminal, Black stem	.26	.20	.18	.15	.12	.11
688-SKH HPP	SKH HPP	F3	6.0	6.0	9.5	160 g	0.25	500,000	With ground terminal, Dark gray stem	.26	.20	.18	.15	.12	.11
688-SKH HQN	SKH HQN	F3	6.0	6.0	9.5	260 g	0.25	200,000	With ground terminal, Red stem	.26	.20	.18	.15	.12	.11
688-SKH HLM	SKH HLM	G1	6.0	3.85	6.0	100 g	0.25	1,000,000	High density mounting, Black stem	.30	.24	.21	.17	.14	.13
688-SKH HLN	SKH HLN	G1	6.0	3.85	6.0	160 g	0.25	500,000	High density mounting, Dark gray stem	.30	.24	.21	.17	.14	.13
688-SKH HLP	SKH HLP	G1	6.0	3.85	6.0	260 g	0.25	200,000	High density mounting, Red stem	.30	.24	.21	.17	.14	.13
688-SKH HLU	SKH HLU	G1	6.0	5.85	6.0	100 g	0.25	1,000,000	High density mounting, Black stem	.30	.24	.21	.17	.14	.13
688-SKH HLV	SKH HLV	G1	6.0	5.85	6.0	160 g	0.25	500,000	High density mounting, Dark gray stem	.30	.24	.21	.17	.14	.13
688-SKH HLW	SKH HLW	G1	6.0	5.85	6.0	260 g	0.25	200,000	High density mounting, Red stem	.30	.24	.21	.17	.14	.13
688-SKH HLQ	SKH HLQ	G1	6.0	8.35	6.0	100 g	0.25	1,000,000	High density mounting, Black stem	.30	.24	.21	.17	.14	.13
688-SKH HLR	SKH HLR	G1	6.0	8.35	6.0	160 g	0.25	500,000	High density mounting, Dark gray stem	.30	.24	.21	.17	.14	.13
688-SKH HLS	SKH HLS	G1	6.0	8.35	6.0	260 g	0.25	200,000	High density mounting, Red stem	.30	.24	.21	.17	.14	.13
688-SKH HNH	SKH HNH	G1	6.0	15.85	6.0	100 g	0.25	500,000	High density mounting, Black stem	.60	.47	.42	.35	.27	.25
688-SKH HNJ	SKH HNJ	G1	6.0	15.85	6.0	160 g	0.25	300,000	High density mounting, Dark gray stem	.60	.47	.42	.35	.27	.25
688-SKH HNK	SKH HNK	G1	6.0	15.85	6.0	260 g	0.25	200,000	High density mounting, Red stem	.60	.47	.42	.35	.27	.25
688-SKQJAA	SKQJAA	H2	6.6	6.6	5.0	100 g	0.25	1,000,000	Dust proof, Black stem	.57	.44	.40	.33	.26	.24
688-SKQJAB	SKQJAB	H2	6.6	6.6	5.0	160 g	0.25	500,000	Dust proof, Gray stem	.57	.44	.40	.33	.26	.24
688-SKQJAD	SKQJAD	H2	6.6	6.6	7.0	100 g	0.25	1,000,000	Dust proof, Black stem	.57	.44	.40	.33	.26	.24
688-SKQJAE	SKQJAE	H2	6.6	6.6	7.0	160 g	0.25	500,000	Dust proof, Gray stem	.57	.44	.40	.33	.26	.24
688-SKQJAJ	SKQJAJ	H2	6.6	6.6	9.5	100 g	0.25	200,000	Dust proof, Black stem	.57	.44	.40	.33	.26	.24
688-SKQJAK	SKQJAK	H2	6.6	6.6	9.5	160 g	0.25	200,000	Dust proof, Gray stem	.57	.44	.40	.33	.26	.24
688-SKQJLA	SKQJLA	I3	6.6	3.85	6.6	100 g	0.25	1,000,000	Dust proof, Black stem	1.06	.82	.74	.61	.48	.44
688-SKQJLB	SKQJLB	I3	6.6	3.85	6.6	160 g	0.25	500,000	Dust proof, Gray stem	1.06	.82	.74	.61	.48	.44

ALPS Tactile Switches