


SONG CHUAN General Purpose Relays



U.S.A

DIMENSIONS: mm

This product is RoHS compliant.

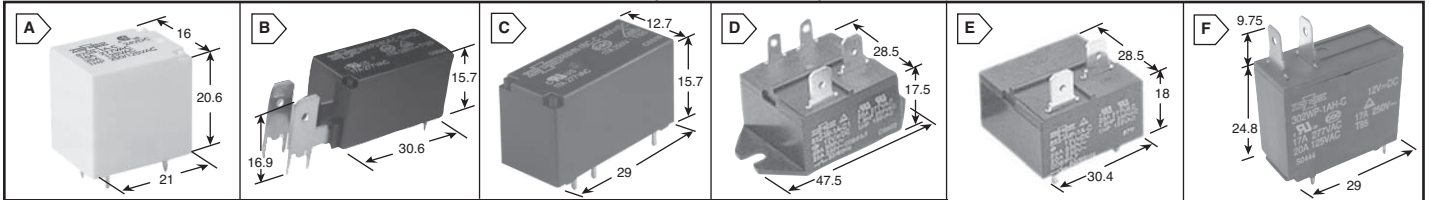


GENERAL PURPOSE RELAYS



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Song Chuan Part No.	Fig.	Contact Form	Contact Rating	Coil Voltage	Price Each			
						1	25	50	100
Miniature PCB Surge Relays									
893-875B1CCFS12VDC	875B-1CC-F-S-12VDC	A	SPDT	16A	12VDC	2.72	2.04	1.84	1.56
893-875B1CCFS24VDC	875B-1CC-F-S-24VDC	A	SPDT	16A	24VDC	2.72	2.04	1.84	1.56
Low Profile Relays w/Fasten Terminals									
893-881WP11ACFS12VDC	881WP1-1AC-F-S-12VDC	B	SPNO	18A	12VDC	3.56	2.67	2.40	1.78
893-881WP11ACFS24VDC	881WP1-1AC-F-S-24VDC	B	SPNO	18A	24VDC	3.56	2.67	2.40	1.78
High Inrush Miniature PCB Relays									
893-888H1AHFSIR12	888H-1AH-F-S-IR-12VDC	C	SPNO	17A	12VDC	2.92	2.19	1.97	1.74
893-888H1AHFSIR24V	888H-1AH-F-S-IR-24VDC	C	SPNO	17A	24VDC	2.92	2.19	1.97	1.74
Miniature Power Relays									
893-852W1AFC112VDC	852W-1A-F-C-1-12VDC	D	SPNO	25A	12VDC	3.16	2.37	2.13	1.99
893-852W1AFC124VDC	852W-1A-F-C-1-24VDC	D	SPNO	25A	24VDC	3.16	2.37	2.13	1.99
893-852WP1AFC12VDC	852WP-1A-F-C-1-12VDC	E	SPNO	25A	12VDC	3.16	2.37	2.13	1.91
893-852WP1AFC24VDC	852WP-1A-F-C-2-24VDC	E	SPNO	25A	24VDC	3.16	2.37	2.13	1.91
893-302WP1AHFC12VDC	302WP1-1AH-F-C-1-12VDC	F	SPNO	20A	12VDC	2.68	2.01	1.81	1.63
893-302WP1AHFC24VDC	302WP1-1AH-F-C-2-24VDC	F	SPNO	20A	24VDC	2.68	2.01	1.81	1.63
893-4012AHS12VDC	401-2AH-S-12VDC	G	DPNO	5A	12VDC	1.92	1.44	1.30	1.06
893-4012AHS24VDC	401-2AH-S-24VDC	G	DPNO	5A	24VDC	1.92	1.44	1.30	1.06
893-812H1CS12VDC	812H-1C-S-12VDC	H	SPDT	10A	12VDC	1.28	.96	.86	.71
893-812H1CS24VDC	812H-1C-S-24VDC	H	SPDT	10A	24VDC	1.28	.96	.86	.71
Flat Pack Miniature Relays									
893-8341AFS12VDC	834-1A-F-S-12VDC	I	SPNO	12A	12VDC	1.88	1.41	1.27	1.10
893-8341AFS24VDC	834-1A-F-S-24VDC	I	SPNO	24A	24VDC	1.88	1.41	1.27	1.10
Automotive Relays									
893-301CCS12VDC	301-1C-C-12VDC	J	SPDT	35A	12VDC	3.36	2.52	2.27	1.77
893-3031AHC12VDC	303-1AH-C-12VDC	K	SPNO	35A	12VDC	3.56	2.67	2.40	1.93
893-896H1CHC12VDC	896H-1CH-C-12VDC	L	SPDT	30A	12VDC	2.88	2.16	1.94	1.61
893-896HP1CHC12VDC	896HP-1CH-C-12VDC	L	SPDT	50A	12VDC	2.88	2.16	1.94	1.61
893-8971AHC12VDC	897-1AH-C-12VDC	M	SPNO	70A	12VDC	4.28	3.21	2.89	2.39
893-897P1AHC12VDC	897P-1AH-C-12VDC	M	SPNO	70A	12VDC	4.28	3.21	2.89	2.39
893-898H1CHC12V	898H-1CH-C-12VDC	N	SPDT	50A	12VDC	3.24	2.43	2.19	1.81
Miniature PCB Sugar Cube Relays									
893-833H1CS12VDC	833H-1C-S-12VDC	O	SPDT	10A	12VDC	1.00	.75	.68	.57
893-833H1CS24VDC	833H-1C-S-24VDC	O	SPDT	10A	24VDC	1.00	.75	.68	.57
Heavy Duty General Purpose Relays									
893-832A1CFS12VDC	832A-1C-F-S-12VDC	P	SPDT	30A	12VDC	2.88	2.16	1.94	1.84
893-832A1CFS24VDC	832A-1C-F-S-24VDC	P	SPDT	30A	24VDC	2.88	2.16	1.94	1.84
893-832AW1CFC112VDC	832AW-1C-F-C-1-12VDC	P	SPDT	30A	12VDC	3.00	2.25	2.03	1.70
893-832AW1CFC124VDC	832AW-1C-F-C-1-24VDC	P	SPDT	30A	24VDC	3.00	2.25	2.03	1.70
893-832AWP1CS12VDC	832AWP-1C-S-12VDC	P	SPDT	30A	12VDC	3.24	2.43	2.19	1.84
893-832AWP1CS24VDC	832AWP-1C-S-24VDC	P	SPDT	30A	24VDC	3.24	2.43	2.19	1.84
High Rating Miniature PCB Relays									
893-8811CCFS12VDC	881-1CC-F-S-12VDC	Q	SPDT	12A	12VDC	2.84	2.13	1.92	1.67
893-8811CCFS24VDC	881-1CC-F-S-24VDC	Q	SPDT	12A	24VDC	2.84	2.13	1.92	1.67
893-881H1CCFS12VDC	881H-1CC-F-S-12VDC	Q	SPDT	16A	12VDC	2.84	2.13	1.92	1.67
893-881H1CCFS24VDC	881H-1CC-F-S-24VDC	Q	SPDT	16A	24VDC	2.84	2.13	1.92	1.67
General Purpose Power Relays									
893-703XB12VDC	703XB-12VDC	R	DPDT	10A	12VDC	10.72	8.04	7.24	6.31
893-703XB24VDC	703XB-24VDC	R	DPDT	10A	24VDC	10.72	8.04	7.24	6.31
893-703XB120VAC	703XB-120VAC	R	DPDT	10A	120VAC	10.72	8.04	7.24	6.31
893-703XB240VAC	703XB-240VAC	R	DPDT	10A	240VAC	11.56	8.67	7.80	6.31
893-703XC12VDC	703XC-12VDC	R	3PDT	10A	12VDC	12.40	9.30	8.37	7.45
893-703XC24VDC	703XC-24VDC	R	3PDT	10A	24VDC	12.40	9.30	8.37	7.45
893-703XC120VAC	703XC-120VAC	R	3PDT	10A	120VAC	12.40	9.30	8.37	7.45
893-703XC240VAC	703XC-240VAC	R	3PDT	10A	240VAC	13.20	9.90	8.91	7.45
893-731DPDTC12VDC	731-DPDT-C-12VDC	S	DPDT	10A	12VDC	11.32	8.49	7.64	6.31
893-731DPDTC24VDC	731-DPDT-C-24VDC	S	DPDT	10A	24VDC	11.32	8.49	7.64	6.31
893-731DPDTC120VAC	731-DPDT-C-120VAC	S	DPDT	10A	120VAC	11.32	8.49	7.64	6.31
893-731DPDTC240VAC	731-DPDT-C-240VAC	S	DPDT	10A	240VAC	12.12	9.09	8.18	6.31
893-731TPDTC12VDC	731-TPDT-C-12VDC	S	3PDT	10A	12VDC	12.76	9.57	8.61	7.55
893-731TPDTC24VDC	731-TPDT-C-24VDC	S	3PDT	10A	24VDC	12.76	9.57	8.61	7.55
893-731TPDTC120VAC	731-TPDT-C-120VAC	S	3PDT	10A	120VAC	12.76	9.57	8.61	7.55
893-731TPDTC240VAC	731-TPDT-C-240VAC	S	3PDT	10A	240VAC	13.56	10.17	9.15	7.55
893-83CLDPDT12VDC	SCL-DPDT-12VDC	T	DPDT	12A	12VDC	6.32	4.74	4.27	3.55
893-83CLDPDT24VDC	SCL-DPDT-24VDC	T	DPDT	12A	24VDC	6.32	4.74	4.27	3.55
893-83CLDPDT120VAC	SCL-DPDT-120VAC	T	DPDT	12A	120VAC	6.60	4.95	4.46	3.55
893-83CLBWDPTC12VDC	SCLB-W-DPDT-C-12VDC	T	DPDT	5A	12VDC	5.16	3.87	3.48	3.01
893-83CLBWDPTC24VDC	SCLB-W-DPDT-C-24VDC	T	DPDT	5A	24VDC	5.16	3.87	3.48	3.01
893-83CLBWDPTC120VAC	SCLB-W-DPDT-C-120VAC	T	DPDT	5A	120VAC	5.20	3.90	3.51	3.01
893-83CLDW4PDT12VDC	SCLD-WB-4PDT-C-12VDC	T	4PDT	5A	12VDC	6.64	4.98	4.48	3.72
893-83CLDW4PDT24VDC	SCLD-WB-4PDT-C-24VDC	T	4PDT	5A	24VDC	6.64	4.98	4.48	3.72
893-83CLDW4PDT120VAC	SCLD-WB-4PDT-C-120VAC	T	4PDT	5A	120VAC	6.88	5.16	4.64	3.72

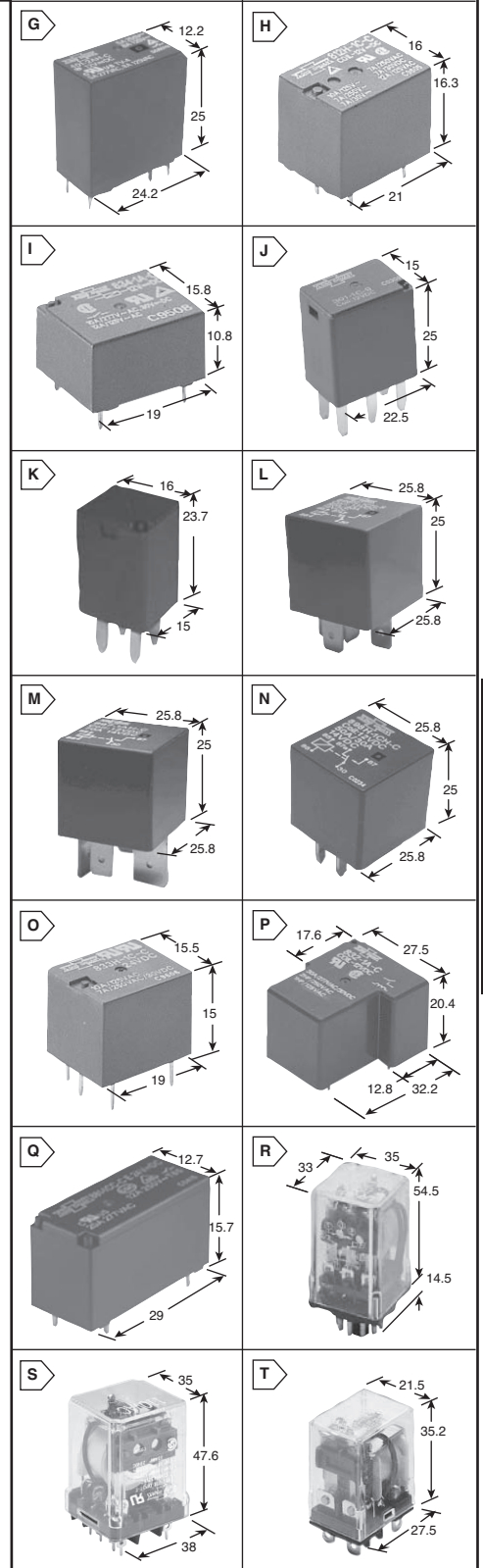

Song Chuan General Purpose Relays