

POTTER & BRUMFIELD General Purpose Relays



Authorized Distributor

KUHP SERIES: 20 & 30 AMP ENCLOSED GENERAL PURPOSE RELAYS


Specifications:

- Enclosure: Clear polycarbonate cover
- Contact material: AgCdO
- Expected mechanical life: 10 million operations min.
- Terminals: .250" QC/Solder



For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	P&B Part No.	Fig.	Coil Voltage	Contact Form	Contact Rating	Price Each			
						1	25	50	100
Bracket Mount Case									
655-KUHP-5A51-24	KUHP-5A51-24	A1	24VAC	SPDT	30A	11.49	10.64	10.30	9.86
655-KUHP-5A51-120	KUHP-5A51-120	A1	120VAC	SPDT	30A	11.50	10.92	10.47	10.00
655-KUHP-5D51-12	KUHP-5D51-12	A1	12VDC	SPDT	30A	19.36	17.15	16.03	14.91
655-KUHP-5D51-24	KUHP-5D51-24	A1	24VDC	SPDT	30A	10.33	9.77	9.38	8.92
655-KUHP-11A51-24	KUHP-11A51-24	A2	24VAC	DPDT	20A	11.52	10.91	10.31	10.00
655-KUHP-11A51-120	KUHP-11A51-120	A2	120VAC	DPDT	20A	12.71	11.51	10.52	9.13
655-KUHP-11D51-12	KUHP-11D51-12	A2	12VDC	DPDT	20A	11.14	10.59	10.15	8.91
655-KUHP-11D51-24	KUHP-11D51-24	A2	24VDC	DPDT	20A	11.14	10.23	9.40	8.70
Top Flange Case									
655-KUHP-5AT1-120	KUHP-5AT1-120	B1	120VAC	SPDT	30A	17.10	16.05	14.44	14.12
655-KUHP-5DT1-12	KUHP-5DT1-12	B1	12VDC	SPDT	30A	10.71	10.00	9.62	9.06
655-KUHP-5DT1-24	KUHP-5DT1-24	B1	24VDC	SPDT	30A	12.15	11.00	10.16	9.42
655-KUHP-11AT1-120	KUHP-11AT1-120	B2	120VAC	DPDT	20A	12.51	11.50	10.68	9.51
655-KUHP-11DT1-12	KUHP-11DT1-12	B2	12VDC	DPDT	20A	12.75	11.65	10.77	8.86
655-KUHP-11DT1-24	KUHP-11DT1-24	B2	24VDC	DPDT	20A	13.22	12.48	11.28	8.90

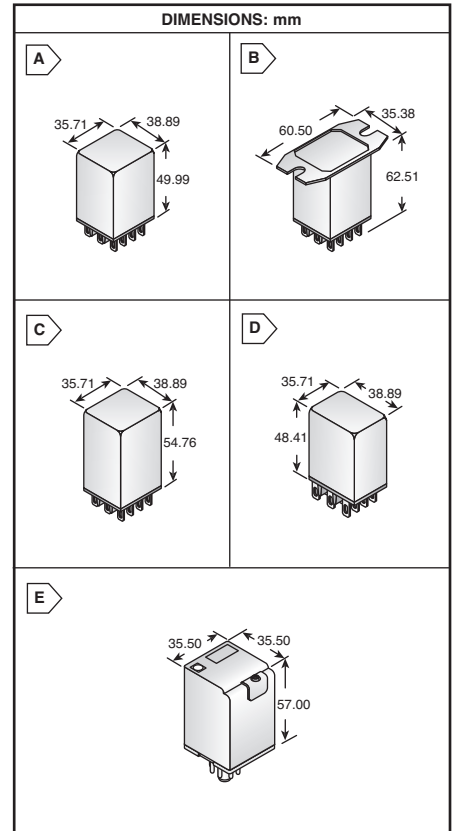

KUL SERIES: 10 AMP MAGNETIC LATCHING RELAY

Specifications:

- Enclosure: Clear polycarbonate cover
- Contact material: AgCdO
- Expected mechanical life: 100,000 operations min.
- Terminals: .187" QC/Solder; silver-cadmium oxide, 10Amps



For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	P&B Part No.	Fig.	Coil Voltage	Contact Form	Number of Coils	Price Each			
						1	25	50	100
655-KUL-11A15S-120	KUL-11A15S-120	C3	120VAC	DPDT	1	35.05	31.64	29.75	26.30
655-KUL-11D15D-12	KUL-11D15D-12	C4	12VDC	DPDT	2	45.55	41.90	38.88	34.05
655-KUL-11D15D-24	KUL-11D15D-24	C4	24VDC	DPDT	2	45.55	41.90	38.88	34.05
Sockets and Accessories for KUL Series									
655-27E043	27E043			Solder eyelet socket, rated 15A, for 1-3 pole relays		2.01	1.88	1.68	1.33
655-27E067	27E067			PCB terminal socket, rated 15A, for 1-3 pole relays		3.19	2.98	2.81	2.43
655-27E121	27E121			Screw terminal socket, rated 15A, for 1-3 pole relays		6.66	6.10	5.70	5.11
655-27E396	27E396			.187" quick connect socket, rated 15A, for 1-3 pole relays		2.80	2.61	2.50	2.15
655-27E893	27E893			Screw term., DIN rail snap-mnt socket, for 1-3 pole relays		7.76	7.11	6.56	6.10
655-20C247	20C247			Hold down spring for 27E043 and 27E067		1.35	1.18	1.13	.885
655-20C314	20C314			Hold down spring for 27E121		.41	.35	.33	.27
655-20C318	20C318			Hold down spring for 27E893		.28	.24	.21	.18
655-24A110	24A110			Aluminum DIN rail track, 36"		10.28	9.42	8.68	8.01

KUMP SERIES: 15 AMP ENCLOSED GENERAL PURPOSE RELAYS

Specifications:

- Enclosure: Clear polycarbonate cover
- Contact material: AgCdO
- Expected mechanical life: 100,000 operations min.
- Terminals: .187" QC/solder; silver-cadmium-oxide
- Mounting: #6-32 stud, .218" locating tab



For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	P&B Part No.	Fig.	Coil Voltage	Contact Form	Contact Rating	Price Each			
						1	25	50	100
655-KUMP-11A18-24	KUMP-11A18-24	D5	24VAC	DPDT	15A	17.15	14.02	13.85	12.39
655-KUMP-11A18-120	KUMP-11A18-120	D5	120VAC	DPDT	15A	11.35	10.57	10.11	8.85
655-KUMP-11A18-240	KUMP-11A18-240	D5	240VAC	DPDT	15A	14.89	13.44	12.13	11.35
655-KUMP-11D18-12	KUMP-11D18-12	D5	12VDC	DPDT	15A	10.27	9.75	9.34	8.92
655-KUMP-11D18-24	KUMP-11D18-24	D5	24VDC	DPDT	15A	10.27	9.75	9.34	8.19
655-KUMP-11D18-110	KUMP-11D18-110	D5	110VDC	DPDT	15A	13.81	12.13	11.25	10.51
655-KUMP-14A18-24	KUMP-14A18-24	D6	24VAC	3PDT	15A	16.58	15.06	13.52	12.15
655-KUMP-14A18-120	KUMP-14A18-120	D6	120VAC	3PDT	15A	10.83	10.65	10.25	9.89
655-KUMP-14D18-12	KUMP-14D18-12	D6	12VDC	3PDT	15A	12.95	11.70	10.71	9.89
655-KUMP-14D18-24	KUMP-14D18-24	D6	24VDC	3PDT	15A	11.86	11.29	10.80	9.50
Sockets and Accessories for KUMP Series									
655-27E043	27E043			Solder eyelet socket, rated 15A, for 1-3 pole relays		2.01	1.88	1.68	1.33
655-27E067	27E067			.187" quick connect, rated 15A, for 1-3 pole relays		3.19	2.98	2.81	2.43
655-27E121	27E121			Screw terminal socket, rated 15A, for 1-3 pole relays		6.66	6.10	5.70	5.11
655-27E396	27E396			.187" quick connect socket, rated 15A, for 1-3 pole relays		2.80	2.61	2.50	2.15
655-27E867	27E867			Screw terminal socket, rated 15A, for 4 pole relays		17.05	15.65	14.43	11.99
655-27E893	27E893			Screw term., DIN rail snap-mnt socket, for 1-3 pole relays		7.76	7.11	6.56	6.10
655-20C228	20C228			Hold down spring with screw for 27E043 and 27E067		.63	.59	.52	.45
655-20C254	20C254			Snap-on hold down spring for 27E043 and 27E067		.28	.24	.21	.18
655-20C318	20C318			Hold down spring for 27E893		.28	.24	.21	.18
655-24A110	24A110			Aluminum DIN rail track, 36"		10.28	9.42	8.68	8.01

MT SERIES: GENERAL PURPOSE MULTIMODE RELAY

Specifications:

- Enclosure: clear polycarbonate cover
- Contact rating/material: 10A / AgNi (90/10)
- Expected mechanical life: 20 million operations min.
- Mechanical indicator (test-button)
- 10Amp



For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	P&B Part No.	Fig.	Coil Voltage	Contact Form	Number of Pins	Price Each			
						1	25	50	100
655-MT226024	MT226024	E7	24VAC	DPDT	8 pin	11.65	10.19	9.24	7.31
655-MT226115	MT226115	E7	115VAC	DPDT	8 pin	12.84	11.31	10.72	8.13
655-MT221012	MT221012	E7	12VDC	DPDT	8 pin	9.73	9.25	8.00	7.02
655-MT221024	MT221024	E7	24VDC	DPDT	8 pin	12.95	11.31	10.25	7.30
655-MT326115	MT326115	E8	115VAC	3PDT	11 pin	13.64	11.90	9.38	7.61
655-MT321012	MT321012	E8	12VDC	3PDT	11 pin	13.64	13.15	12.15	11.45
655-MT321024	MT321024	E8	24VDC	3PDT	11 pin	13.64	11.90	10.77	7.61

