


ALCOSWITCH Knobs

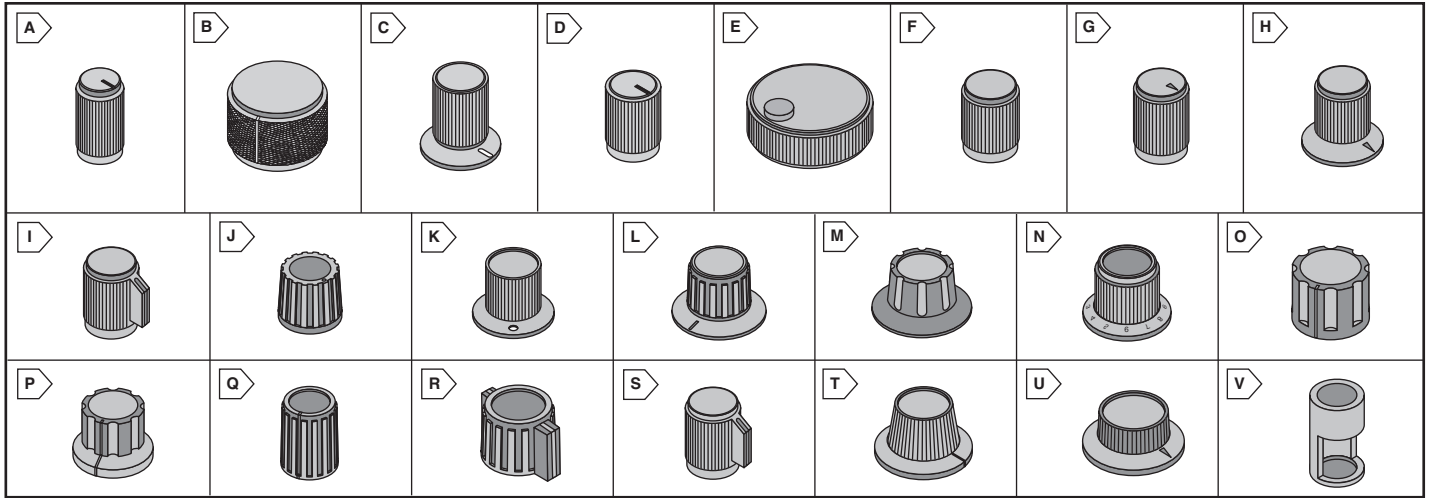

K SERIES MACHINED ALUMINUM CONTROL KNOBS

Specifications:

- Made of machined aluminum alloy stock
- Finish is gloss anodize
- Set screws: steel, type 303, hex head, cup point

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Alcoswitch Part Number	Fig.	Description	Diameter Inches (mm)	Height Inches (mm)	Price Each			
						1	25	50	100
506-KB500B1/4	KB500B1/4	A	Black with straight knurl and top line indicator, 1/4" shaft	.500 (12.7)	.787 (20.0)	6.96	6.10	5.70	5.15
506-KB500B1/8	KB500B1/8	A	Black with straight knurl and top line indicator, 1/8" shaft	.500 (12.7)	.787 (20.0)	8.45	7.73	6.96	6.48
506-KD1250A-1/4	KD1250A1/4	B	Natural with diamond knurl with side indicator line, 1/4" shaft	1.25 (31.8)	.750 (19.1)	19.35	18.38	17.41	16.44
506-KFS400B1/8	KFS400B1/8	C	Black matte with straight knurl with indicator dot on skirt, 1/8" shaft	.380 (9.65)	.500 (12.7)	8.43	7.12	6.84	6.62
506-KLN1250B1/4	KLN1250B1/4	D	Black with straight knurl with top and side indicator, 1/4" shaft	1.25 (31.8)	.591 (15.0)	12.83	11.41	10.28	9.58
506-KLN500A1/8	KLN500A1/8	D	Natural with straight knurl with top and side indicator, 1/8" shaft	.500 (12.7)	.625 (15.9)	6.86	5.94	5.54	5.00
506-KLN500B1/8	KLN500B1/8	D	Black with straight knurl with top and side indicator, 1/8" shaft	.500 (12.7)	.625 (15.9)	7.77	7.32	6.66	6.21
506-KLN700A-1/4	KLN700A1/4	D	Natural with straight knurl with top and side indicator, 1/4" shaft	.740 (18.8)	.625 (15.9)	8.05	7.49	6.88	6.42
506-KLN700B1/4	KLN700B1/4	D	Black with straight knurl with top and side indicator, 1/4" shaft	.740 (18.8)	.625 (15.9)	7.28	5.95	5.46	5.04
506-KLN900B1/4	KLN900B1/4	D	Black with straight knurl with top and side indicator, 1/4" shaft	.937 (23.8)	.625 (15.9)	9.93	8.98	7.94	7.06
506-KN1751AS1/4	KN1751AS1/4	E	Natural with straight knurl with fingertip spinner, 1/4" shaft	1.75 (44.5)	.620 (15.8)	27.19	23.37	21.46	20.03
506-KN1751BS1/4	KN1751BS1/4	E	Black with straight knurl with fingertip spinner, 1/4" shaft	1.75 (44.5)	.620 (15.8)	23.60	21.99	20.43	19.06
506-KN500B-1/4	KN500B1/4	F	Black with straight knurl with side indicator line, 1/4" shaft	.500 (12.7)	.625 (15.9)	6.57	6.19	5.69	5.31
506-KN500B1/8	KN500B1/8	F	Black with straight knurl with side indicator line, 1/8" shaft	.500 (12.7)	.625 (15.9)	5.75	5.00	4.59	4.22
506-KN501B1/8	KN501B1/8	G	Black with straight knurl with arrowhead indicator on top, 1/8" shaft	.500 (12.7)	.625 (15.9)	5.30	4.26	3.75	3.47
506-KNS501BA1/8	KNS501BA1/8	H	Blk. body, nat. skirt & top w/ straight knurl w/ arrowhead indicator on skirt, 1/8" shaft	.500 (12.7)	.625 (15.9)	10.94	10.14	9.35	8.40
506-KNS701BA1/4	KNS701BA1/4	H	Blk. body, nat. skirt & top w/ straight knurl w/ arrowhead indicator on skirt, 1/4" shaft	.750 (19.1)	.625 (15.9)	12.35	11.30	10.43	9.69
506-KPN500B1/8	KPN500B1/8	I	Black with straight knurl with pointer and indicator line, 1/8" shaft	.500 (12.7)	.625 (15.9)	14.71	13.62	12.57	11.68

P SERIES MOLDED PHENOLIC KNOBS

Specifications:

- Made of general purpose phenolic (thermoset)
- Finish is gloss
- Insert is made of Cu alloy
- Set screws: steel, hex head, cup point
- Inlays and skirts are aluminum alloy, spun finish

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Alcoswitch Part Number	Fig.	Description	Diameter Inches (mm)	Height Inches (mm)	Price Each			
						1	25	50	100
506-PK1100B1/4	PK1100B1/4	J	Serrated with white indicator on top and spun alum. inlay, 1/4" shaft	.700 (17.8)	.530 (13.5)	2.28	2.06	1.90	1.75
506-PK50B1/4	PK50B1/4	K	Straight knurl with white dot indicator on skirt and spun alum. inlay, 1/4" shaft	.748 (19.0)	.550 (14.0)	1.84	1.63	1.47	1.34
506-PK50B1/8	PK50B1/8	K	Straight knurl with white dot indicator on skirt and spun alum. inlay, 1/8" shaft	.748 (19.0)	.550 (14.0)	1.74	1.58	1.47	1.35
506-PK70B1/4	PK70B1/4	K	Straight knurl with white dot indicator on skirt and spun alum. inlay, 1/4" shaft	.984 (25.0)	.590 (15.0)	2.88	2.57	2.47	2.21
506-PK90B-1/4	PK90B1/4	K	Straight knurl with white dot indicator on skirt and spun alum. inlay, 1/4" shaft	1.25 (31.8)	.595 (15.1)	2.83	2.57	2.47	2.21
506-PKA50B1/4	PKA50B1/4	L	Ribbed with white line indicator on skirt and spun alum. inlay, 1/4" shaft	.795 (20.2)	.590 (15.0)	1.62	1.41	1.34	1.26
506-PKA50B1/8	PKA50B1/8	L	Ribbed with white line indicator on skirt and spun alum. inlay, 1/8" shaft	.795 (20.2)	.590 (15.0)	1.68	1.51	1.35	1.27
506-PKA70B1/4	PKA70B1/4	L	Ribbed with white line indicator on skirt and spun alum. inlay, 1/4" shaft	.980 (24.9)	.750 (19.1)	2.83	2.52	2.26	2.06
506-PKB90B1/4	PKB90B1/4	M	Fluted with white line indicator on skirt and spun alum. inlay, 1/4" shaft	1.50 (38.1)	.820 (20.8)	5.06	4.57	4.23	3.85
506-PKD70B101/4	PKD70B101/4	N	Straight knurl with 0-10 numerals on skirt and spun alum. inlay, 1/4" shaft	1.02 (25.9)	.610 (15.5)	2.60	2.38	2.18	2.00
506-PKE90-B	PKE90B1/4	O	Fluted with white line indicator on side and spun alum. inlay, 1/4" shaft	.890 (22.6)	.512 (13.0)	3.08	2.80	2.68	2.40
506-PKES120B1/4	PKES120B1/4	P	Fluted with skirt and white indicator line and spun alum. inlay, 1/4" shaft	1.30 (32.9)	.628 (16.0)	3.21	2.65	2.39	2.17
506-PKES60B1/4	PKES60B1/4	P	Fluted with skirt and white indicator line and spun alum. inlay, 1/4" shaft	.748 (19.0)	.470 (11.9)	2.09	1.91	1.75	1.62
506-PKES60B1/8	PKES60B1/8	P	Fluted with skirt and white indicator line and spun alum. inlay, 1/8" shaft	.748 (19.0)	.470 (11.9)	2.09	1.91	1.75	1.62
506-PKES90B1/4	PKES90B1/4	P	Fluted with skirt and white indicator line and spun alum. inlay, 1/4" shaft	1.01 (25.7)	.570 (14.5)	2.96	2.63	2.37	2.15
506-PKG40B1/8	PKG40B1/8	Q	Ribbed with white indicator line and spun alum. inlay, 1/8" shaft	.437 (11.1)	.472 (12.0)	1.51	1.39	1.30	1.24
506-PKG50B1/4	PKG50B1/4	Q	Ribbed with white indicator line and spun alum. inlay, 1/4" shaft	.551 (14.0)	.512 (13.0)	2.50	2.17	2.07	1.87
506-PKG50B1/8	PKG50B1/8	Q	Ribbed with white indicator line and spun alum. inlay, 1/8" shaft	.551 (14.0)	.512 (13.0)	2.25	1.86	1.69	1.55
506-PKG70B1/8	PKG70B1/8	Q	Ribbed with white indicator line and spun alum. inlay, 1/8" shaft	.740 (18.8)	.559 (14.2)	4.48	4.11	3.95	3.61
506-PKGP-70B-1/4	PKGP70B1/4	R	Ribbed with bar pointer, white indicator line, and spun alum. inlay, 1/4" shaft	.740 (18.8)	.460 (11.7)	3.72	3.40	3.11	2.88
506-PKJT50B1/8	PKJT50B1/8	S	Straight knurl with bar pointer, white indicator line, and alum. spin plate, 1/8" shaft	.515 (13.1)	.585 (14.9)	4.17	3.80	3.45	3.14
506-PKS1106B1/4	PKS1106B1/4	T	Straight knurl, black line indicator on alum. skirt, spun alum. inlay, 1/4" shaft	1.17 (29.6)	.670 (17.0)	5.14	4.67	4.48	4.02
506-PKS90B1/4	PKS90B1/4	U	Straight knurl, black arrow indicator on alum. skirt, spun alum. inlay, 1/4" shaft	1.42 (36.1)	.596 (15.1)	3.87	3.52	3.38	3.03
506-PKS90B101/4	PKS90B101/4	U	Straight knurl, black numbers 1-10 on alum. skirt, spun alum. inlay, 1/4" shaft	1.42 (36.1)	.596 (15.1)	4.99	4.25	4.05	3.90

ADAPTER

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Alcoswitch Part Number	Fig.	Description	Diameter Inches (mm)	Height Inches (mm)	Price Each			
						1	25	50	100
506-KR104	KR104	V	Shaft hole adapter, 1/4" to 1/8"	- - -	- - -	.85	.79	.73	.66