

# HEYCO Strain Reliefs

RoHS Compliant This product is RoHS compliant.



## SNAP-IN RATCHETING STRAIN RELIEF

Independent of insertion into the panel, the Ratcheting Strain relief self-locks onto the cable.

- Installs easily with fingertip pressure
- Black
- For Round and Double D Holes



For quantities of 2000 and up, call for quote.

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Panel Dimensions: In.		Description	Price Each			
				Hole Size	Max. Thickness		1	100	500	1000
836-1280	1280	A	--	0.875	.125	RSR-875	.66	.62	.59	.56

## SELF-LOCKING STRAIN RELIEFS

For Flat Cables • Black • 6/6 Nylon • 94V-2

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Panel Dimensions: In.		Description	Price Each			
				Hole Size	Max. Thickness		1	100	500	1000
836-1829	1829	B	SPT-1, SPT-2, HPN	.453 x .512	0.099	ST-100N	.23	.18	.15	.12
836-1834	1834	B	SPT-2, SPT-3	.689 x .689	0.157	ST-200N	.26	.13	.11	.10

For Round Cables • Black • 6/6 Nylon • 94V-2

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Panel Dimensions: In.		Description	Price Each			
				Hole Size	Max. Thickness		1	100	500	1000
836-1832	1832	C	SV, SVT, HPD	.453 x .512	0.099	ST-101N	.23	.18	.15	.12
836-1836	1836	C	SJ, SJO, SJD	.689 x .689	0.157	ST-201N	.26	.16	.14	.12
836-1848	1848	C	SJT, STO, SEOW-A	.689 x .689	0.157	ST-301N	.26	.13	.11	.10

For Round and Flat Cables • Black • 6/6 Nylon • 94V-2

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Panel Dimensions: In.		Description	Price Each			
				Hole Size	Max. Thickness		1	100	500	1000
836-1843	1843	D	Round, Flat SPT-3	1.142 x 1.142	0.032	LSR1939-300	.52	.48	.43	.39

For Round Cables (U-Shape Chassis Slot) • Black • 6/6 Nylon

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Panel Dimensions: In.		Description	Price Each			
				Hole Size	Max. Thickness		1	100	500	1000
836-1839	1839	E	SV, SVT, HPD	.453 x .512	0.062	ST-101A	.23	.18	.15	.12

## LAY-IN STRAIN RELIEF FOR ROUND, FLAT, OR MULTIPLE CABLES UP TO .600"

• Black

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Panel Dimensions: In.		Description	Price Each			
				Hole Size	Max. Thickness		1	100	500	1000
836-1266	1266	F	--	.875 x .875	0.100	SR 8R-200	.75	.68	.62	.55

## STRAIGHT-THRU STRAIN RELIEFS

For Round Cables • Black • 6/6 Nylon

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Panel Dimensions: In.			Description	Price Each			
				Mounting Hole Dia. (A)	To Prevent Rotation (B)	Max. Thickness		Price Each			
								1	100	500	1000
836-1157	1157	G	SV, SVT	0.500	0.450	0.062	SR 5MN-3	.14	.10	.08	.07
836-1150	1150	G	SV, SVT, HPD	.500 x .515	0.450	0.062	SR 5N-4	.13	.09	.07	.06
836-1147	1147	G	SV, SVT, HPD	.500 x .515	0.450	0.100	SR 5P-4	.13	.09	.07	.06
836-1184	1184	G	SJ, SJO, SJT	0.500	0.465	0.090	SR 6W-1	.13	.09	.07	.06
836-1217	1217	G	SJ, SJO, SJT	0.625	0.550	0.062	SR 6N-4	.16	.12	.10	.08
836-1210	1210	G	SJ, SJO, SJT	0.625	0.550	0.125	SR 6P-4	.16	.12	.10	.08
836-1200	1200	G	SJ, SJO, SJT	0.625	0.550	0.062	SR 6N3-4	.16	.12	.10	.08
836-1207	1207	G	SJ, SJO, SJT	0.625	0.550	0.125	SR 6P3-4	.16	.12	.10	.08
836-1214	1214	G	SJ, SJO, SJT	0.625	0.550	0.156	SR 6L-1	.16	.12	.10	.08
836-1240	1240	G	SJ, SJO, SJT	0.875	0.770	0.125	SR 7K-2	.23	.18	.15	.12
836-1244	1244	G	SJT, S, ST	0.750	0.660	0.062	SR 7N-2	.23	.18	.15	.12
836-1237	1237	G	SJT, S, ST	0.750	0.660	0.125	SR 7P-2	.23	.18	.15	.12
836-1247	1247	G	SJT, S, ST	0.875	0.770	0.125	SR 2W-2	.23	.18	.15	.12
836-1250	1250	G	SJT, S, ST	0.875	0.770	0.200	SR 7L-2	.23	.18	.15	.12
836-1497	1497	G	SJT	0.875	0.840	0.125	SR 31-2	.23	.18	.15	.12
836-1254	1254	G	S, ST	0.875	0.840	0.062	SR 8N-2	.23	.18	.15	.12
836-1260	1260	G	S, ST	0.875	0.840	0.125	SR 8P-2	.23	.18	.15	.12
836-1287	1287	G	S, ST, SO	1.093	1.000	0.281	SR 9P-2	.24	.22	.19	.17

For Flat Cables \* Uses Elongated Hole • Black † For flat or round cable

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Hole Size	Max. Thickness	Description	Price Each			
							1	100	500	1000
836-1174	1174	H	HPN, SPT-2	0.562	0.530	SR 5W-1	.18	.13	.11	.09
836-1484 *	1484	H	SPT-2, SPT-3	0.560	0.730	SR 30-1	.17	.12	.10	.08
836-1517	1517	H	SPT-3	0.875	0.840	SR 34-2	.23	.18	.15	.12
836-1497 †	1497	H	SPT-3	0.875	0.840	SR 31-2	.23	.18	.15	.12

For Flat Cables With Flex-Protecting Internal Radii • Black

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Hole Size	Max. Thickness	Description	Price Each			
							1	100	500	1000
836-1120	1120	H	SPT-1, HSN	0.500	0.465	SR 4N-4	.11	.07	.06	.05
836-1117	1117	H	SPT-1, HSN	0.500	0.465	SR 4K-4	.10	.069	.059	.049
836-1127	1127	H	SPT-1, SPT-2, HSN	0.500	0.465	SR 4L-4	.13	.09	.07	.06
836-1114	1114	H	SPT-1, SPT-2, HSN	0.500	0.460	SR 4K-1	.10	.069	.059	.049
836-1170	1170	H	SPT-2, SPT-3	0.562	0.530	SR 5KN-4	.18	.13	.11	.09
836-1167	1167	H	SPT-2, SPT-3	0.562	0.530	SR 5K-4	.18	.13	.11	.09
836-1160	1160	H	SPT-2	0.625	0.550	SR 6N4-4	.17	.12	.10	.08
836-1163	1163	H	SPT-2	0.625	0.550	SR 6P4-4	.17	.12	.10	.08


## RIGHT ANGLE STRAIN RELIEFS

For Flat Cables • Black • 6/6 Nylon • 94V-2

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Panel Dimensions: In.			Description	Price Each			
				Mounting Hole Dia. (A)	To Prevent Rotation (B)	Max. Thickness		1	100	500	1000
836-1361	1361	I	SPT-2, HSN	0.500	0.450	0.040	SR 14A-1	.22	.15	.12	.10
836-1364	1364	I	SPT-2, HSN	0.500	0.450	0.100	SR 14-1	.22	.15	.12	.10
836-1384	1384	I	SPT-2, SPT-3, HSN	0.562	0.525	0.125	SR 16-1	.23	.15	.14	.13
836-1424	1424	I	SPT-2, SPT-3	0.560	0.730	0.080	SR 20-1	.24	.23	.21	.18
836-1464	1464	I	SPT-3	0.875	0.840	0.125	SR 24-1	.30	.27	.25	.23

For Round Cables

MOUSER STOCK NO.	Heyco Part No.	Fig.	UL Type Designation	Hole Size	Max. Thickness	Description	Price Each			
							1	100	500	1000
836-1374	1374	J	SV, SVT, HPD	0.500	0.450	SR 15-1	.22	.15	.12	.10
836-1320	1320	J	SJ, SJO, SJT	0.625	0.550	SR 10-2	.23	.15	.14	.13
836-1327	1327	J	SJ, SJO, SJT	0.625	0.550	SR 11-2	.23	.15	.14	.13
836-1397	1397	J	SJ, S, ST	0.750	0.660	SR 17-2	.43	.39	.35	.31

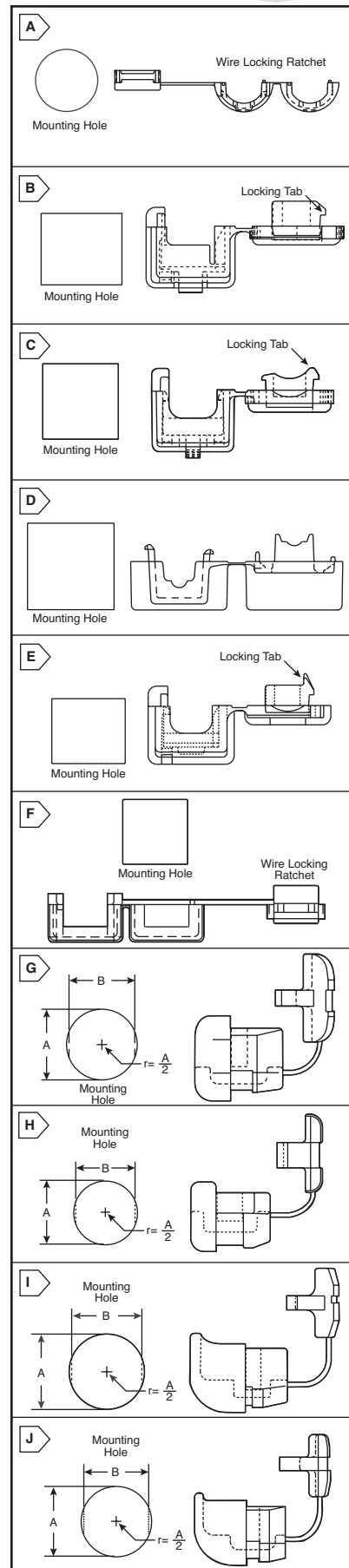

Heyco

Hardware