


SERPAC Enclosures and Cases

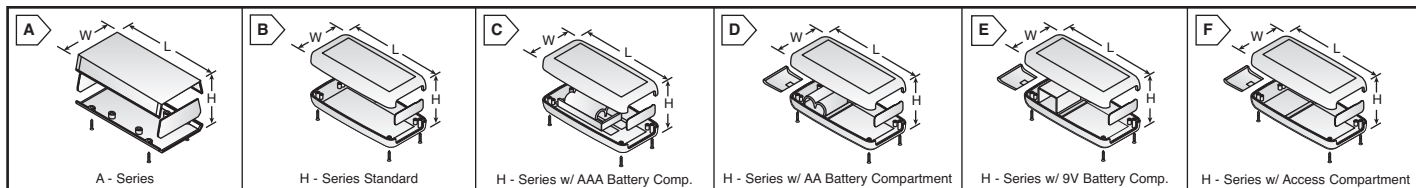

SERPAC A - SERIES

- Features:**
- Hi-Impact ABS plastic
 - UL 94 HB flammability rating
 - Custom colors, machining, molding, and pad printing available
 - Four-piece design
 - Circuit board mounting bosses

There are 3 colors available, replace the () in the part number with:

A for Almond or **B** for Black or **G** for Gray

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each		
			L	W	H	1	10	25
Standard								
635-A-20-__	A-20-__	A	4.25	2.60	0.87	5.63	4.42	4.02
635-A-21-__	A-21-__	A	4.25	2.60	1.12	5.78	4.54	4.13
635-A-27-__	A-27-__	A	5.31	3.35	1.51	8.51	6.68	6.08
635-A-31-__	A-31-__	A	5.30	5.10	1.71	10.96	8.61	7.83
635-A-41-__	A-41-__	A	7.10	5.00	1.30	14.01	11.36	9.60
635-A-42-__	A-42-__	A	7.10	5.00	1.57	13.38	10.51	9.56
With 9V Battery Compartment								
635-A-21-9V-__	A-21-9V-__	A	4.25	2.60	1.12	7.31	5.74	5.22
635-A-27-9V-__	A-27-9V-__	A	5.31	3.14	1.51	10.52	8.27	7.52
635-A-31-9V-__	A-31-9V-__	A	5.30	5.10	1.71	12.89	10.13	9.21
635-A-41-9V-__	A-41-9V-__	A	7.10	5.00	1.30	14.28	11.22	10.20
635-A-42-9V-__	A-42-9V-__	A	7.10	5.00	1.62	14.97	11.76	10.70

Optional End Panels for A Series Enclosures

Available in Clear (CL), Infrared (IR), DB9 Cutout, DB25 Cutout, and 9V Battery Cutout

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	For Enclosure	Price Each		
			1	10	25
635-2003-CL	2003-CL	A-20	1.92	1.12	1.08
635-2003-IR	2003-IR	A-20	2.05	1.17	1.13
635-2003-DB9	2003-DB9	A-20	1.65	.95	.92
635-2003-DB25	2003-DB25	A-20	1.65	.95	.92
635-2005-CL	2005-CL	A-21	1.92	1.12	1.08
635-2005-IR	2005-IR	A-21	2.05	1.66	1.61
635-2005-DB9	2005-DB9	A-21	2.05	1.85	1.77
635-2005-DB25	2005-DB25	A-21	1.65	.95	.92
635-2006-9V	2006-9V	A-21	1.52	.87	.83
635-2010-CL	2010-CL	A-27	2.10	1.17	1.13
635-2010IR	2010-IR	A-27	2.24	1.26	1.21
635-2010DB9	2010-DB9	A-27	1.96	1.63	1.57
635-2010DB25	2010-DB25	A-27	1.77	1.02	.98
635-2011-9V	2011-9V	A-27	1.62	.92	.89
635-2015-CL	2015-CL	A-31	3.74	3.38	3.07
635-2015-IR	2015-IR	A-31	3.40	1.89	1.82
635-2015-DB9	2015-DB9	A-31	2.76	1.59	1.54
635-2015-DB25	2015-DB25	A-31	2.76	1.59	1.54
635-2016-9V	2016-9V	A-31	2.54	1.43	1.37
635-2020-CL	2020-CL	A-41	2.90	1.62	1.56
635-2020-IR	2020-IR	A-41	3.11	1.73	1.67
635-2020-DB9	2020-DB9	A-41	2.39	1.37	1.32
635-2020-DB25	2020-DB25	A-41	2.39	1.37	1.32
635-2021-9V	2021-9V	A-42	2.24	1.26	1.21
635-2024-CL	2024-CL	A-42	3.17	1.75	1.68
635-2024IR	2024-IR	A-42	3.40	1.89	1.82
635-2024-DB9	2024-DB9	A-42	2.76	1.59	1.54
635-2024-DB25	2024-DB25	A-42	2.76	1.59	1.54
635-2025-9V	2025-9V	A-42	2.54	1.43	1.37

SERPAC H - SERIES SOLID COLORS

- Features:**
- Hi-Impact ABS plastic
 - UL 94 HB flammability rating
 - Custom colors, machining, molding, and pad printing available
 - Multiple battery compartment configurations with contactors
 - Three-piece design with ergonomic handheld shape
 - Circuit board mounting bosses
 - Pocket clip available

There are 3 colors available, replace the () in the part number with:

A for Almond or **B** for Black or **G** for Gray

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each		
			L	W	H	1	10	25
Standard								
635-H-45-__	H-45-__	B	3.90	2.20	.94	10.14	9.21	8.39
635-H-65-__	H-65-__	B	4.94	2.75	.94	7.50	5.89	5.36
635-H-75-__	H-75-__	B	7.20	3.65	1.26	9.30	7.31	6.65
With AAA Battery Compartment								
635-H-45-AAA-__	H-45-AAA-__	C	3.90	2.20	.94	11.22	10.21	9.27
With AA Battery Compartment								
635-H-65AA-__	H-65-AA-__	D	4.94	2.75	.94	8.21	6.45	5.87
635-H-67AA-__	H-67-AA-__	D	4.94	2.75	1.28	9.58	7.78	6.58
635-H-75-4AA-__	H-75-4AA-__	D	7.20	3.65	1.26	13.64	11.05	9.35
With 9V Battery Compartment								
635-H-659V-__	H-65-9V-__	E	4.94	2.75	.94	8.09	6.35	5.78
635-H-679V-__	H-67-9V-__	E	4.94	2.75	1.28	8.25	6.48	5.90
635-H-75-9V-__	H-75-9V-__	E	7.20	3.65	1.26	10.29	8.09	7.35
With Access Compartment								
635-H-65AC-__	H-65-AC-__	F	4.94	2.75	.94	7.50	5.89	5.36
635-H-67AC-__	H-67-AC-__	F	4.94	2.75	1.28	7.50	5.89	5.36

SERPAC H - SERIES TRANSLUCENT COLORS

- Features:**
- Hi-Impact ABS plastic
 - UL 94 HB flammability rating
 - Custom colors, machining, molding, and pad printing available
 - Pocket clip available

There are 4 colors available, replace the () in the part number with:

BL for Blue or **GR** for Green or **RD** for Red or **GY** for Gray

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each		
			L	W	H	1	10	25
635-H-65AATR-__	H-65-AA-TR-__	D	4.94	2.75	.94	14.49	11.39	10.35
635-H-659VTR-__	H-65-9V-TR-__	E	4.94	2.75	.94	14.26	11.20	10.19

Optional End Panels for H Series Enclosures

Available in Clear (CL), Infrared (IR), and Red (R)

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Price Each			
		1	10	25	50
635-2104-CL	2104-CL	2.39	1.44	1.39	1.35
635-2104-IR	2104-IR	3.03	1.92	1.85	1.78
635-2104-R	2104-R	3.25	2.00	1.93	1.86
635-2105-CL	2105-CL	2.54	1.50	1.44	1.39
635-2105IR	2105-IR	3.18	1.97	1.90	1.83
635-2105-R	2105-R	3.39	2.08	2.01	1.93
635-2106-CL	2106-CL	2.65	1.58	1.52	1.47
635-2106IR	2106-IR	3.37	2.07	2.00	1.92
635-2106R	2106-R	3.60	2.20	2.12	2.04
635-2107-CL	2107-CL	2.87	1.73	1.67	1.61
635-2107-IR	2107-IR	3.82	2.22	2.14	2.06
635-2107-R	2107-R	4.10	2.39	2.31	2.22

SERPAC R - SERIES EQUIPMENT CASES

There are 4 colors available, replace the () in the part number with:

GM for Gunmetal (Dark Gray) or **B** for Black or

CY for Caution Yellow or **IQ** for International Orange

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each
			L	W	H	
635-R-120-__	R-120-__	A	8.70	7.45	3.89	26.26
635-R-300-__	R-300-__	A	10.80	9.85	4.50	48.10
635-R-520-__	R-520-__	A	14.85	12.15	6.85	75.83
635-R-710-__	R-710-__	A	19.75	15.53	5.41	114.95
635-R-720-__	R-720-__	A	19.75	15.53	7.48	119.03
635-R-920-__	R-920-__	B	24.00	16.00	10.10	234.78
635-R-1220-__	R-1220F-__	B	28.17	22.27	15.10	337.60
Extreme RX Series						
* Flame retardant protection * Available in Black only						
635-RX-120F	RX-120F	A	7.59	8.88	3.97	43.87
635-RX-300F	RX-300F	A	10.9	9.9	4.92	71.93
635-RX-520F	RX-520F	A	15.11	12.4	6.94	144.95
635-RX-710F	RX-710F	A	20.1	15.8	5.51	253.90
635-RX-720F	RX-720F	A	20.1	15.8	7.6	253.90
R-Series Computer Case						
635-R-710CC-__	R-710CC-__	C	19.75	15.53	5.41	125.59
635-R-720CC-__	R-720CC-__	C	19.75	15.53	7.48	154.95
R-Series Enclosure With Divider Set						
635-R-720D-__	R-720D-__	D	19.75	15.53	7.48	217.28

Features:

- O-ring watertight/airtight seal
- Ergonomic handle
- Pressure purge valve
- Corrosion proof
- Foam inserts included
- Lifetime guarantee
- UV protected

