


SERPAC Enclosures and Accessories

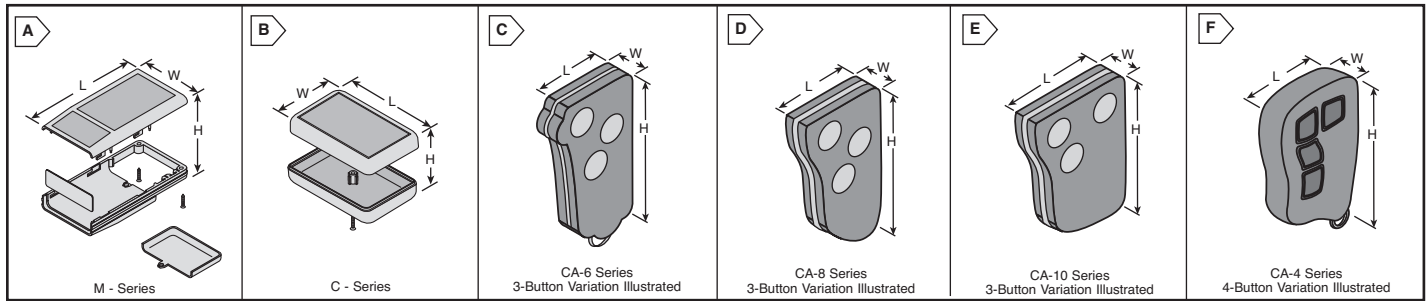

SERPAC M - SERIES SOLID COLORS

- Features:**
- Hi-Impact ABS plastic
 - UL 94 HB flammability rating
 - Custom colors, machining, molding, and pad printing available
 - Four-piece handheld design
 - Battery compartment with contactors

There are 3 colors available, replace the () in the part number with:
A for Almond or **B** for Black or **G** for Gray

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Battery Compartment	Dimensions: in.			Price Each		
				L	W	H	1	10	25
Standard									
635-M-4-__	M-4-__	A	1 x AA	2.80	2.20	0.71	6.28	4.93	4.49
635-M-6-__	M-6-__	A	2 x AA/ 1 x 9V	4.15	2.40	0.85	7.83	6.15	5.60
635-M-8-__	M-8-__	A	2 x AA/ 1 x 9V	6.97	2.40	0.85	9.32	7.33	6.66
With Pocket Clip									
635-M-4PC-__	M-4-PC-__	A	1 x AA	2.80	2.20	0.70	7.43	5.84	5.31
635-M-6PC-__	M-6-PC-__	A	2 x AA/ 9V	4.15	2.40	0.85	9.87	7.75	7.06
635-M-8PC-__	M-8-PC-__	A	2 x AA/ 9V	6.97	2.40	0.85	10.75	8.45	7.68

SERPAC M - SERIES TRANSLUCENT COLORS

- Features:**
- Hi-Impact ABS plastic
 - UL 94 HB flammability rating
 - Custom colors, machining, molding, and pad printing available

There are 4 colors available, replace the () in the part number with:
BL for Blue or **GR** for Green or **RD** for Red or **GY** for Gray

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each		
			L	W	H	1	10	25
635-M-4TR-__	M-4-TR-__	A	2.80	2.20	0.70	11.00	8.65	7.86
635-M-6TR-__	M-6-TR-__	A	4.15	2.40	0.85	13.82	10.86	9.87

Optional End Panels for M Series Enclosures

Available in Clear (CL), Infrared (IR), and Transparent Red (R)

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	For Enclosures	Price Each			
			1	10	25	50
635-4004-CL	4004-CL	M-4	2.39	1.44	1.39	1.35
635-4004IR	4004-IR	M-4	3.03	1.92	1.85	1.78
635-4004-R	4004-R	M-4	3.25	2.00	1.93	1.86
635-4008CL	4008-CL	M-6, M-8	2.54	1.50	1.44	1.39
635-4008IR	4008-IR	M-6, M-8	3.18	1.97	1.90	1.83
635-4008-R	4008-R	M-6, M-8	3.39	2.08	2.01	1.93

SERPAC C - SERIES SOLID COLORS

- Features:**
- Hi-Impact ABS plastic
 - UL 94 HB flammability rating
 - Custom colors, machining, molding, and pad printing available
 - Two Insert Areas
 - Two-piece design
 - Accepts .031" circuit board trapped on outer perimeter and central boss

There are 3 colors available, replace the () in the part number with:
A for Almond or **B** for Black or **G** for Gray

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each		
			L	W	H	1	10	25
Standard								
635-C-4-__	C-4-__	B	2.13	1.38	.58	2.65	2.08	1.89
635-C-6-__	C-6-__	B	2.26	1.61	.75	2.65	2.08	1.89
635-C-8-__	C-8-__	B	2.40	1.85	.93	2.98	2.34	2.13
635-C-10-__	C-10-__	B	2.30	3.25	.80	2.98	2.34	2.13
635-C-12-__	C-12-__	B	2.40	3.75	1.00	4.08	3.73	3.39
635-C-28-__	C-28-__	B	1.85	5.00	1.00	4.20	3.81	3.46
With Pocket Clip								
635-C-4PC-__	C-4-PC-__	B	2.13	1.32	.58	4.68	3.68	3.35
635-C-6PC-__	C-6-PC-__	B	2.26	1.61	.75	5.35	4.35	3.68
635-C-8PC-__	C-8-PC-__	B	2.40	1.85	.93	4.68	3.68	3.35
635-C-10PC-__	C-10-PC-__	B	3.25	2.30	.80	5.02	3.94	3.59

SERPAC C - SERIES TRANSLUCENT COLORS

- Features:**
- Hi-Impact ABS plastic
 - UL 94 HB flammability rating
 - Custom colors, machining, molding, and pad printing available

There are 4 colors available, replace the () in the part number with:
BL for Blue or **GR** for Green or **RD** for Red or **GY** for Gray

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each		
			L	W	H	1	10	25
635-C-4TR-__	C-4-TR-__	B	2.13	1.38	.58	4.47	3.51	3.20
635-C-6TR-__	C-6-TR-__	B	2.26	1.61	.75	4.47	3.51	3.20
635-C-8TR-__	C-8-TR-__	B	2.40	1.85	.93	4.47	3.51	3.20
635-C-10TR-__	C-10-TR-__	B	3.25	2.30	.80	5.08	3.99	3.63

SERPAC CH - SERIES

- Features:**
- Hi-Impact ABS plastic
 - UL 94 HB flammability rating
 - Custom colors, machining, molding, and pad printing available
 - One Insert Area
 - Two-piece design with rounded edges
 - Accepts .031" circuit board trapped on outer perimeter and central boss

There are 3 colors available, replace the () in the part number with:
A for Almond or **B** for Black or **G** for Gray

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each		
			L	W	H	1	10	25
635-CH-4-__	CH-4-__	B	2.27	1.52	.59	3.26	2.96	2.70
635-CH-6-__	CH-6-__	B	2.39	1.74	.76	3.26	2.96	2.70
635-CH-8-__	CH-8-__	B	2.40	1.85	.93	3.26	2.96	2.70

SERPAC CA - SERIES

- Features:**
- Ergonomic design
 - 0 to 6 button configurations available (configurations vary by model)
 - All models are designed to hold 20mm coin cell battery (CA-10 is also designed to hold 2 x AAA batteries)
 - CA-6 and CA-8 models have watertight button(s) and a perimeter ring
 - Assembles with two or three screws
 - High impact ABS plastic
 - UL 94HB flammability rating

There are 3 colors available, replace the () in the part number with:
A for Almond or **B** for Black or **G** for Gray

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	No. of Buttons	Dimensions: in.			Price Each		
				L	W	H	1	10	25
635-CA-6-0-__	CA-6-0-__	C	0	3.01	1.45	1.07	8.12	7.20	6.65
635-CA-8-0-__	CA-8-0-__	D	0	3.27	1.81	1.02	8.64	7.59	7.01
635-CA-10-0-__	CA-10-0-__	E	0	3.32	2.47	1.08	10.26	8.92	8.23
635-CA-6-1-__	CA-6-1-__	C	1	3.01	1.45	1.07	8.12	7.20	6.65
635-CA-8-1-__	CA-8-1-__	D	1	3.27	1.81	1.02	8.64	7.59	7.01
635-CA-10-1-__	CA-10-1-__	E	1	3.32	2.47	1.08	10.26	8.92	8.23
635-CA-4-2-__	CA-4-2-__	F	2	1.73	0.6	2.48	5.56	5.06	4.59
635-CA-6-2-__	CA-6-2-__	C	2	3.01	1.45	1.07	8.12	7.20	6.65
635-CA-8-2-__	CA-8-2-__	D	2	3.27	1.81	1.02	8.64	7.59	7.01
635-CA-10-2-__	CA-10-2-__	E	2	3.32	2.47	1.08	10.26	8.92	8.23
635-CA-4-3-__	CA-4-3-__	F	3	1.73	0.6	2.48	5.56	5.06	4.59
635-CA-6-3-__	CA-6-3-__	C	3	3.01	1.45	1.07	8.12	7.20	6.65
635-CA-8-3-__	CA-8-3-__	D	3	3.27	1.81	1.02	8.64	7.59	7.01
635-CA-10-3-__	CA-10-3-__	E	3	3.32	2.47	1.08	10.26	8.92	8.23
635-CA-4-4-__	CA-4-4-__	F	4	1.73	0.6	2.48	5.56	5.06	4.59
635-CA-6-4-__	CA-6-4-__	C	4	3.01	1.45	1.07	8.12	7.20	6.65
635-CA-8-4-__	CA-8-4-__	D	4	3.27	1.81	1.02	8.64	7.59	7.01
635-CA-10-4-__	CA-10-4-__	E	4	3.32	2.47	1.08	10.26	8.92	8.23
635-CA-8-5-__	CA-8-5-__	D	5	3.27	1.81	1.02	8.64	7.59	7.01
635-CA-10-5-__	CA-10-5-__	E	5	3.32	2.47	1.08	10.26	8.92	8.23
635-CA-10-6-__	CA-10-6-__	E	6	3.32	2.47	1.08	10.26	8.92	8.23