


Power, Plug-In and Variable Transformers

XICON POWER TRANSFORMERS

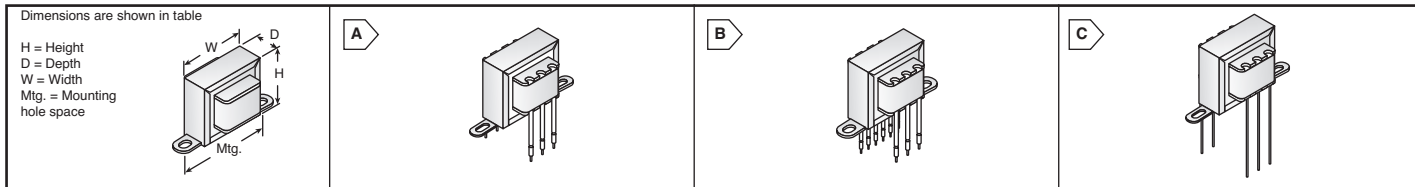

These power transformers feature 115VAC/60Hz primaries, in six popular outputs. They have 6" color coded leads for positive identification.

- Lead color coding: primary = black, secondary = red/white
- Full load voltage tolerance: ±2%
- Voltage regulation: <15%
- Hi-pot test voltage: 1500VAC 60Hz for 1 minute
- Coil-to-coil insulation: 200MQ @ 500VDC

Multi-Tapped Power Transformer

Secondary voltages are as shown. 6" leads are color coded for easy identification. The secondary common is black.

- Current rating: .3A
- Primary rating: 115/220, 50/60Hz

MOUSER STOCK NO.	Fig.	Secondary Volts	Dimensions: in.				Price Each		
			H	W	D	Mtg.	1	10	100
41FW300	B	12.0, 9.0, 6.0, 4.5, 3.0	1.375	1.75	1.5	2.05	6.10	5.08	4.62

Heavy Duty Power Transformers

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Fig.	Secondary		Dimensions: in.				Price Each		
		Volts	Amps	H	W	D	Mtg.	1	10	100
41FD200	A	6.3CT	.2	1.3	1.5	1.1	1.9	5.13	3.42	3.11
41FD010	A	6.3CT	1.0	1.65	2.0	1.9	2.4	6.81	5.67	5.16
41FD030	A	6.3CT	3.0	1.95	2.5	1.95	2.8	6.98	5.82	5.29
41FG100	A	12.6CT	.1	1.25	1.5	1.1	1.71	2.74	2.28	2.07
41FG200	A	12.6CT	.2	1.25	1.5	1.25	1.9	4.45	3.71	3.38
41FG300	A	12.6CT	.3	1.65	1.75	1.55	2.1	3.84	3.20	2.91
41FG010	A	12.6CT	1.0	1.75	2.1	1.6	2.3	5.85	4.88	4.43
41FJ300	A	18.0CT	.3	1.5	1.7	1.4	2.1	5.45	4.54	4.13
41FJ600	A	18.0CT	.6	1.75	2.0	1.6	2.4	6.49	5.39	4.91
41FJ010	A	18.0CT	1.0	1.95	2.4	1.65	2.9	8.28	6.89	6.27
41FJ020	A	18.0CT	2.0	2.25	2.63	2.25	3.2	9.36	7.79	7.08
41FK200	A	24.0CT	.2	1.5	1.75	1.4	2.1	5.70	4.75	4.32
41FK300	A	24.0CT	.3	1.69	1.97	1.5	2.48	6.27	5.70	5.18
41FK600	A	24.0CT	.6	1.7	2.0	1.7	2.3	7.44	6.19	5.64
41FK010	A	24.0CT	1.0	1.95	2.35	1.9	2.8	8.28	6.89	6.27


PC Mount Power Transformers

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Fig.	Secondary		Dimensions: in.				Price Each		
		Volts	Amps	H	W	D	Mtg.	1	10	100
41PG006	C	12.6CT	.06	1.05	1.18	1.0	1.65	2.76	2.29	2.09
41PG120	C	12.0CT	.12	1.25	1.5	1.18	1.75	3.34	2.78	2.53
41PG300	C	12.6CT	.3	1.38	1.75	1.4	2.05	5.67	3.78	3.44
41PK100	C	24.0CT	.1	1.5	1.75	1.25	2.05	4.55	3.79	3.43
41PK200	C	24.0CT	.2	1.4	1.75	1.33	2.05	5.89	4.91	4.46
41PK600	C	24.0CT	.6	1.75	2.0	1.58	2.4	6.35	5.29	4.81

amprobe PLUG-IN TRANSFORMERS

- Specifications:**
- Input voltage: 120VAC
 - Protected by thermal/current fuse

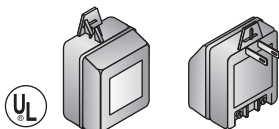


For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Color	Output Voltage (VAC)	Output Power (VA)	Output Current (A)	Price Each			
					1	10	20	50
507-XT1220	White	12	20	1.666	7.61	6.89	6.46	6.25
507-XT1620	White	16.5	20	1.212	7.61	6.89	6.46	6.25
507-XT1820	White	18	20	1.11	7.61	6.89	6.46	6.25
507-XT2420	White	24	20	0.833	7.61	6.89	6.46	6.25
507-XT1240	White	12	40	3.33	9.50	8.57	8.03	7.77
507-XT1640	White	16.5	40	2.424	9.50	8.57	8.03	7.77
507-XT1840	White	18	40	2.222	9.50	8.57	8.03	7.77
507-XT2440	White	24	40	1.666	9.50	8.57	8.03	7.77

STACO ENERGY VARIABLE TRANSFORMERS AC VOLTAGE CONTROLS

DIMENSIONS: in.

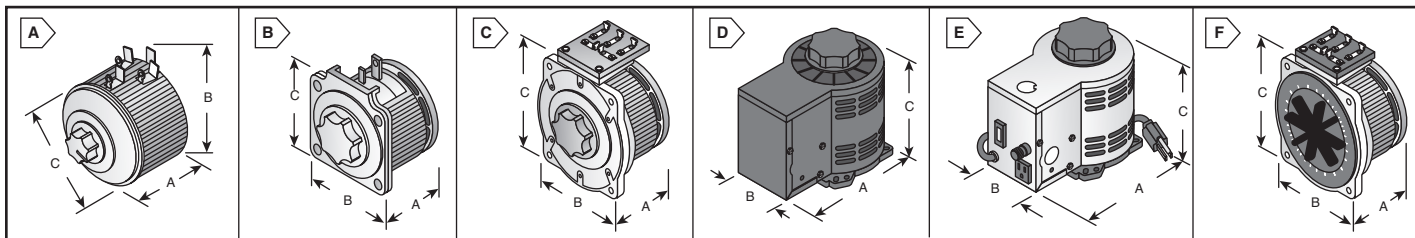

Open models have an adjustable shaft design on most manually operated models that permits back-of-panel or bench mounting. Cased models are available in "C" styles enclose only the coil, while "CT" models provide protective housing for both coil and terminal board. Portable cord and plug models are cased plug-in models that have a ventilated steel case, line cord, receptacle, illuminated on/off switch and fuse.

MOUSER STOCK NO.	Staco Part No.	Fig.	Input		Output		Net Wt. Lbs.	Dimensions: in.			Price Each			
			Volts	Hertz	KVA	Amps		A	B	C	1	2	5	10
5874-171	171	A	120	50/60	0.21	1.75	2.00	1.88	3.28	2.93	98.11	88.75	84.68	80.62
5874-201	201	A	120	50/60	0.24	2.00	2.00	1.88	3.28	2.93	91.01	86.65	82.67	80.97
5874-221B	221-B	A	120	50/60	0.26	2.00	2.50	2.12	3.28	2.93	102.41	95.19	89.61	83.69
5874-252	252	A	240	50/60	0.30	2.50	2.50	2.12	3.28	2.93	162.47	154.99	146.93	141.69
5874-291	291	A	120	50/60	0.19	0.80	2.50	2.31	3.28	2.93	134.73	126.49	122.11	117.77
5874-501C	501C	B	120	50/60	0.36	3.00	5.25	3.00	3.75	4.38	165.01	153.13	147.84	142.56
5874-1010B	1010B	C	120	50/60	0.40	3.00	10.25	4.16	4.62	5.57	203.05	196.05	189.29	182.54
5874-1010BCT	1010BCT	D	120	50/60	0.60	5.00	10.25	4.44	4.62	6.31	314.64	304.14	293.66	283.16
5874-3PN1010B	3PN1010B	E	120	50/60	0.70	5.00	10.25	6.96	4.62	5.50	321.88	312.25	294.71	287.31
5874-1210B	1210B	C	120	60	1.40	10.00	10.25	4.16	4.62	5.57	227.67	220.08	212.49	204.90
5874-2510	2510	F	120	50/60	3.00	25.00	21.00	4.38	7.66	8.31	607.66	587.41	567.15	546.90
5874-2520	2520	F	240	50/60	3.50	25.00	21.00	4.38	7.66	8.31	607.58	587.33	567.09	546.82
			120	50/60	2.40	10.00	21.00	4.38	7.66	8.31	607.58	587.33	567.09	546.82
			120	50/60	2.80	10.00	21.00	4.38	7.66	8.31	607.58	587.33	567.09	546.82
			120	50/60	1.20	10.00	21.00	4.38	7.66	8.31	607.58	587.33	567.09	546.82



LR18948



a tti company