


RoHS Compliant This product is RoHS compliant.

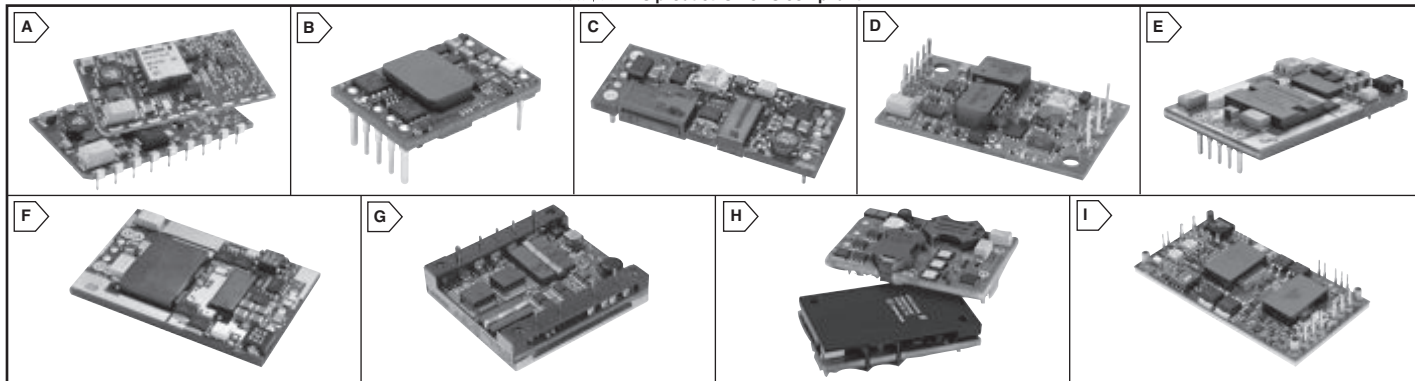

## PKR SERIES, 5-15W MACRODENS FOOTPRINT, ISOLATED, SMD

- High efficiency: typ. 86% @ 3.3V full load
- Output voltage: 1.8 to 12V; Single and Dual Volts
- Dimensions (LxWxH): 1.88x1.11x0.32in. (47.8x28.1x8.0mm)



RoHS Compliant

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Ericsson Part No.	Fig.	Input (V)	Output (V)	Amps (A)	Power (W)	Price Each			
							1	5	10	20
764-PKR2111ASI	PKR2111ASI	A	18-36	5.0	2.00	10.0	39.42	28.98	25.59	22.73
764-PKR5611SI	PKR5611SI	A	18-75	5.0	1.20	6.0	42.21	31.03	27.40	24.34
764-PKR5113SI	PKR5113SI	A	18-75	12.0	0.92	11.0	42.21	31.03	27.40	24.34
764-PKR4928ASI	PKR4928ASI	A	36-75	3.3, 5.0	2.1, 0.5	9.4	45.89	33.73	29.79	26.45
764-PKR4221ASI	PKR4221ASI	A	36-75	±12	0.6, 0.6	15.0	45.89	33.73	29.79	26.45

## PKM-D SERIES, 108W QUARTER-BRICK, ISOLATED, THRU HOLE

- High efficiency: typ. 91% at 3.3V
- Input voltage range: 36-75V
- Output voltage: 7.2V
- Dimensions (LxWxH): 2.28x1.45x0.35in. (57.8x36.8x9.1mm)



RoHS Compliant

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Ericsson Part No.	Fig.	Input (V)	Output (V)	Amps (A)	Power (W)	Price Each			
							1	5	10	20
764-PKM4116DPINB	PKM4116DPINB	E	36-75	7.2	15	108	53.26	47.67	45.58	43.67

## PKM-C SERIES, 165-204W QUARTER-BRICK, "DOUBLE-P", ISOLATED, THRU HOLE

- High efficiency: typ. 92% at 3.3V
- Input voltage range: 36-75V
- Output voltage: 1.2 to 12V
- Dimensions (LxWxH): 2.28x1.45x0.35in. (57.8x36.8x9.1mm)



RoHS Compliant

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Ericsson Part No.	Fig.	Input (V)	Output (V)	Amps (A)	Power (W)	Price Each			
							1	5	10	20
764-PKM4211CPINB	PKM4211CPINB	F	36-75	5.0	40	200	75.00	66.20	63.10	60.40
764-PKM4213CPINBSP	PKM4213CPINBSP	F	36-75	12.0	17	204	75.00	66.20	63.10	60.40

## PKU SERIES, 30-50W SIXTEENTH BRICK, ISOLATED, THRU HOLE

- High efficiency: typ. 90%
- Output voltage: 1.2 to 15V
- Dimensions (LxWxH): 1.3x0.9x0.39in. (33x22.9x9.9mm)



RoHS Compliant

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Ericsson Part No.	Fig.	Input (V)	Output (V)	Amps (A)	Power (W)	Price Each			
							1	5	10	20
764-PKU4418GPI	PKU4418GPI	B	36-75	1.8	25.0	45	51.24	42.81	39.75	37.00
764-PKU4319PI	PKU4319PI	B	36-75	2.5	15.0	38	51.24	42.81	39.75	37.00
764-PKU4511PI	PKU4511PI	B	36-75	5.0	10.0	50	51.24	42.81	39.75	37.00
764-PKU4513PI	PKU4513PI	B	36-75	12.0	4.2	50	51.24	42.81	39.75	37.00
764-PKU4515PI	PKU4515PI	B	36-75	15.0	3.3	50	51.24	42.81	39.75	37.00
• Dimensions: (LxWxH): 1.3 x 0.9 x 0.295 in (33.02 x 22.86 x 7.50 mm)										
764-PKU5310EPI	PKU5310EPI	C	18-72	3.30	10.0	33	54.39	40.16	35.55	31.65
764-PKU5311EPI	PKU5311EPI	C	18-72	5.0	7.0	35	54.39	40.16	35.55	31.65

## BMR453, 300W QUARTER BRICK, ISOLATED THRU HOLE

- High efficiency: typ. 96% at 12V
- Input voltage range: 36-75V
- ISO 9001/14001 certified supplier
- Dimensions (LxWxH): 2.28x1.45x0.46in. (57.9x36.8x11.6mm)
- PMBUS Revision 1.1 Compliant



RoHS Compliant

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Ericsson Part No.	Fig.	Input (V)	Output (V)	Amps (A)	Power (W)	Price Each			
							1	5	10	20
764-BMR4530000/001	BMR4530000/001	G	36-75	12	33	400	148.40	123.44	114.40	106.25

## PKB SERIES, 60-150W EIGHTH BRICK, ISOLATED, THRU HOLE

- High efficiency: typ. 92% at 3.3
- Input voltage range: 36-75V
- Output voltage: 1.2 to 15V
- Dimensions (LxWxH): 2.3x0.896x0.319in. (58.42x22.76x8.10mm)



RoHS Compliant

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Ericsson Part No.	Fig.	Input (V)	Output (V)	Amps (A)	Power (W)	Price Each			
							1	5	10	20
764-PKB4711PINB	PKB4711PINB	C	36-75	5.0	15.0	75	52.83	44.13	40.98	38.14
764-PKB4717PINB	PKB4717PINB	C	36-75	7.2	10.5	75	52.83	44.13	40.98	38.14
764-PKB4913PINB	PKB4913PINB	C	36-75	12.0	7.5	90	52.83	44.13	40.98	38.14
764-PKB4715PINB	PKB4715PINB	C	36-75	15.0	5.0	75	52.83	44.13	40.98	38.14
764-PKB4113CPI	PKB4113CPI	C	36-75	12.0	12.5	150	74.26	60.60	57.75	53.79

## PKJ SERIES, 250-350W HALF-BRICK, ISOLATED, THRU HOLE

- Baseplated
- High efficiency: typ. 93% at 3.3V
- Input voltage range: 36-75V
- Output voltage: 1.8 to 12V
- Dimensions (LxWxH): 2.4x2.28x0.5in. (61.0x57.9x12.7mm)



RoHS Compliant

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Ericsson Part No.	Fig.	Input (V)	Output (V)	Amps (A)	Power (W)	Price Each			
							1	5	10	20
764-PKJ4316API	PKJ4316API	H	36-75	28	12.4	350	101.81	85.42	82.00	77.24

## PKM-E SERIES, 50-82.5W QUARTER-BRICK, ISOLATED, THRU HOLE

- High efficiency: typ. 91% at 3.3V full load
- Input voltage range: 18-36V, 36-75V
- Output voltage: 1.5 to 24V
- Dimensions (LxWxH): 2.28x1.45x0.5in. (57.9x36.8x12.7mm)



RoHS Compliant

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Ericsson Part No.	Fig.	Input (V)	Output (V)	Amps (A)	Power (W)	Price Each			
							1	5	10	20
764-PKM2511EPI	PKM2511EPI	D	18-36	5.0	10.0	50.0	53.51	44.63	41.42	38.52
764-PKM2513EPI	PKM2513EPI	D	18-36	12.0	4.2	50.0	53.51	44.63	41.42	38.52
764-PKM2515EPI	PKM2515EPI	D	18-36	15.0	3.3	50.0	53.51	44.63	41.42	38.52
764-PKM4515EPI	PKM4515EPI	D	36-75	15.0	3.3	50.0	53.51	44.63	41.42	38.52
764-PKM4516ZEPI	PKM4516ZEPI	D	36-75	24.0	2.1	50.0	53.51	44.63	41.42	38.52

## PKY SERIES, 600-700W, FULL-BRICK, ISOLATED, THRU HOLE

- High efficiency: typ. 95% at 28V
- Input voltage range: 18-36V, 36-75V
- Output voltage: 28V
- Dimensions (LxWxH): 4.6x2.4x0.5in. (16.8x61.0x12.7mm)



RoHS Compliant

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Ericsson Part No.	Fig.	Input (V)	Output (V)	Amps (A)	Power (W)	Price Each			
							1	5	10	20
764-PKY2616PIM	PKY2616PIM	I	18-36	28	21.5	600	139.67	121.62	115.09	109.20
764-PKY4716PIM	PKY4716PIM	I	36-75	28	25.0	700	155.19	135.14	127.88	121.33