


# XICON AC/DC Switching Adapters



RoHS Compliant This page of product is compliant.

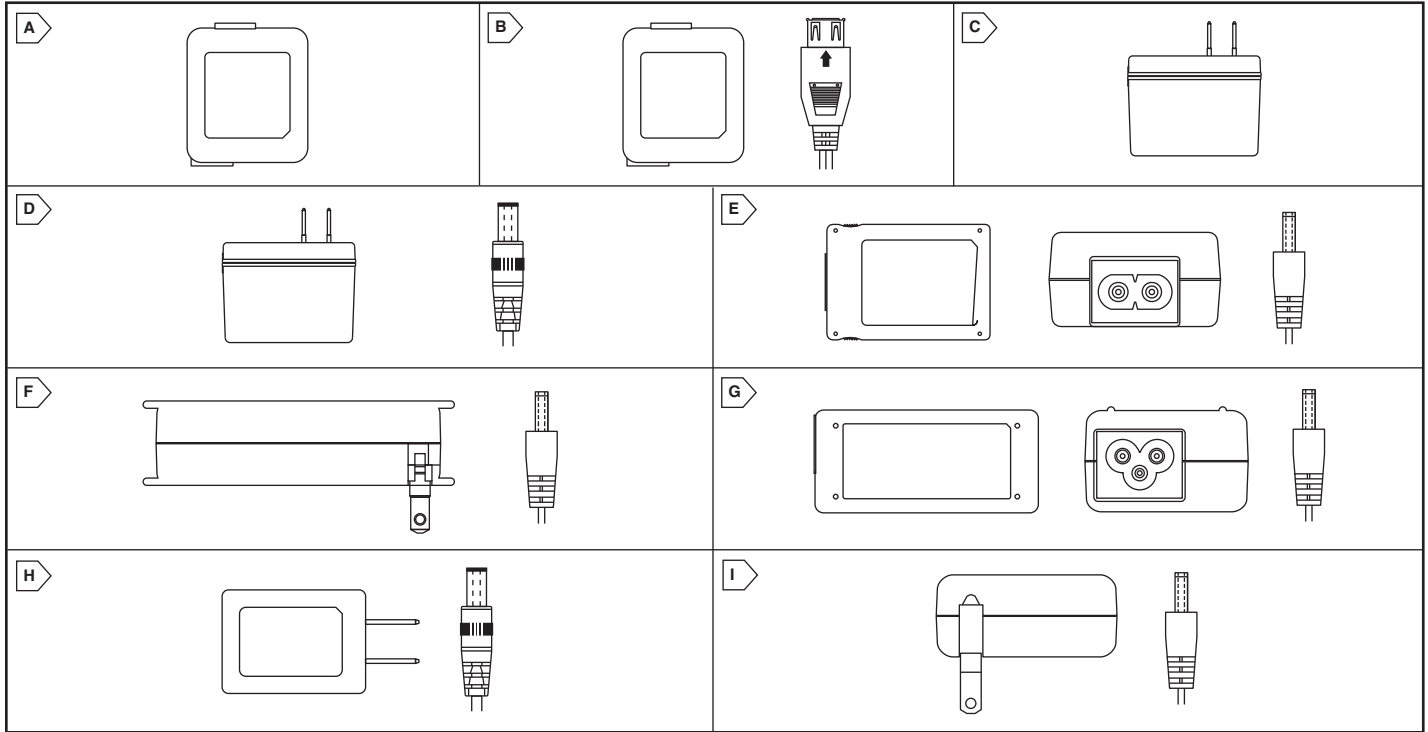

## AC/DC SWITCHING ADAPTERS

**Features:**

- Input voltage: 100-240VAC, 50-60/Hz
- Constant voltage mode
- Light and convenient plug-ins

**Applications:**

- MP3 players
- Digital cameras
- Notebook PCs

For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Fig.	Output Watts	Output Voltage	Output Current	Output Connector	Price Each			
						1	5	25	100
419-10505-USB-RCX	A	2.5	5.0V	0.5A	USB	25.55	23.22	21.12	19.20
419-10510-USB-RCX	A	5	5.0V	1.0A	USB	25.55	23.22	21.12	19.20
419-10505-UCB-RCX	B	2.5	5.0V	0.5A	USB	28.27	25.71	23.38	21.25
419-10510-UCB-RCX	B	5	5.0V	1.0A	USB	28.27	25.71	23.38	21.25
419-10520-4UV-RCX	C	10	5.0V	2.0A	2.1x5.5mm	29.51	26.83	24.40	22.18
419-10523-4UV-RCX	C	11.5	5.0V	2.3A	2.1x5.5mm	29.51	26.83	24.40	22.18
419-10913-4UV-RCX	C	11.7	9.0V	1.3A	2.1x5.5mm	29.51	26.83	24.39	22.18
419-11210-4UV-RCX	C	12	12.0V	1.0A	2.1x5.5mm	29.51	26.83	24.39	22.18
419-10530-4-RCX	D	15	5.0V	3.0A	2.1x5.5mm	32.21	29.28	26.62	24.20
419-11215-4-RCX	D	18	12.0V	1.5A	2.1x5.5mm	32.21	29.28	26.62	24.20
419-11512-4-RCX	D	18	15V	1.2A	2.1x5.5mm	32.21	29.28	26.62	24.20
419-10505USB240V-RCX	A	2.5	5.0V	0.5A	USB	22.19	20.18	18.34	16.68
419-10510USB240V-RCX	A	5	5.0V	1.0A	USB	22.19	20.18	18.34	16.68
419-10320-4DT-RCX	E	6.6	3.3V	2.0A	2.1x5.5mm	26.09	23.72	21.56	19.60
419-10520-4DT-RCX	E	10	5.0V	2.0A	2.1x5.5mm	26.09	23.72	21.56	19.60
419-10523-4DT-RCX	E	11.5	5.0V	2.3A	2.1x5.5mm	26.09	23.72	21.56	19.60
419-11210-4DT-RCX	E	12	12.0V	1.0A	2.1x5.5mm	26.09	23.72	21.56	19.60
419-11238-4-RCX	F	45.6	12.0V	3.8A	2.1x5.5mm	39.13	35.58	32.34	29.40
419-11924-4-RCX	F	45.6	19.0V	2.4A	2.1x5.5mm	39.13	35.58	32.34	29.40
419-12419-4-RCX	F	45.6	24.0V	1.9A	2.1x5.5mm	39.13	35.58	32.34	29.40
419-11238-4-UIT-RCX	G	45.6	12.0V	3.8A	2.1x5.5mm	37.83	34.39	31.27	28.43
419-10505-4WM-RCX	H	2.5	5.0V	0.5A	2.1x5.5mm	24.54	22.32	20.89	18.45
419-10510-4WM-RCX	H	5	5.0V	1.0A	2.1x5.5mm	24.54	22.32	20.29	18.45
419-11205-4WM-RCX	H	6	12.0V	0.5A	2.1x5.5mm	24.54	22.32	20.29	18.45
419-10505-3WM-RCX	I	2.5	5.0V	0.5A	2.5x5.5mm	24.95	22.68	20.62	18.75
419-10510-3WM-RCX	I	5	5.0V	1.0A	2.5x5.5mm	24.95	22.68	20.62	18.75
419-11205-3WM-RCX	I	6	12.0V	0.5A	2.5x5.5mm	24.95	22.68	20.62	18.75

Xicon

## POWER SUPPLY CORDS

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Size	Type	Length	Color	Price Each			
						1	10	100	500
173-21101-E	A	.75mm 2 Conductor	VFF	6'	Black	3.69	3.17	2.88	2.65
173-21112-E	A	.75mm 2 Conductor	VFF	10'	Black	4.03	3.58	3.32	3.05
173-21103-E	B	3 conductor 18 AWG	SVT	6'	Black	4.21	3.82	3.47	3.15
173-21113-E	B	3 conductor 18 AWG	SVT	10'	Black	5.80	5.27	4.79	4.35
173-21102-E	A	2 conductor 18 AWG	SPT-2	6'	Black	2.71	2.46	2.24	2.04
173-21114-E	A	2 conductor 18 AWG	SPT-2	10'	Black	3.96	3.60	3.27	2.97

