


TRIPP LITE Power Protection and Mobile Power Solutions



PROTECT IT!™ SURGE SUPPRESSORS

- Features:**
- Protect all computers & home/office electronics
 - Economical, reliable protection against damaging surges, spikes, and line noise
 - Select models offer tel/modem, coaxial and/or ethernet surge protection
 - Up to \$250,000 Ultimate Lifetime Insurance

RoHS Compliant

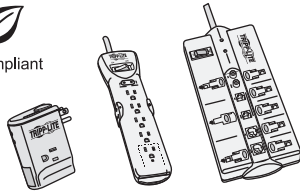


For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Joules	Cord Length	Price Each
545-TLP404	TLP404	4	390	4'	9.34
545-TLP602	TLP602	6	250	2'	7.84
545-TLP604TEL	TLP604TEL	6 + tel/DSL	870	4'	11.57
545-TLP606	TLP606	6	750	6'	11.94
545-STRIKER	STRIKER	7	750	6'	13.98
545-SUPER7	SUPER7	7	2350	7'	21.64
545-TLP808	TLP808	8	1900	8'	25.75
545-TLP808TELTV	TLP808TELTV	8 + tel/DSL + coax	3500	8'	41.79
545-TLP810SAT	TLP810SAT	8 + tel/DSL + 2 coax	3570	10'	50.74

WABER BY TRIPP & POWER STRIPS

- Features:**
- Ideal for industrial, office, school, and lab applications
 - A seamless steel case with baked-on finish on select models
 - Available in keyhole(K) or flange(F) mount

 RoHS Compliant



Outlet Strips

For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Mounting Options	Body Length	Cord Length	Price Each
545-3SP	3SP	3	K/F	7.38"	6'	22.00
545-4SPDX	4SPDX	4	K	7.5"	6'	18.85
545-602	602	5	K/F	7.38"	6'	20.00
545-602-15	602-15	5	K/F	7.38"	15'	29.00
545-6SP	6SP	6	K/F	12.5"	6'	28.50
545-6NX6	6NX6	6	K	12.5"	6'	18.31
545-6SPDX	6SPDX	6	K	12.5"	6'	22.69
545-6SPDX-15	6SPDX-15	6	K	12.5"	15'	29.23
545-UL24CB-15	UL24CB-15	6	K/F	12.5"	15'	37.00
545-UL24RA-15	UL24RA-15	6 (90°)	K/F	12.5"	15'	38.00
545-UL620-15	UL620-15	6 (20A)	K/F	12.5"	15'	87.00
545-UL800CB-15	UL800CB-15	10	K/F	17.5"	15'	59.00

POWER STRIPS AND POWER DISTRIBUTION UNITS

- Features:**
- Mount in rack enclosures, along walls, or on desks or workbenches
 - Rugged, all-metal cases stand up to the most demanding environments
 - 1U rackmount models mount horizontally in a standard 19 inch rack

RoHS Compliant




For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Length	Cord Length	Price Each
545-PS2408	PS2408	8	24"	15'	49.50
545-PS3612	PS3612	12	36"	15'	53.14
545-PS4816	PS4816	16	48"	15'	55.20
545-PS6020	PS6020	20	60"	15'	65.52
545-PS7224	PS7224	24	72"	15'	67.67
545-PS7224-20	PS7224-20	24 (20A)	72"	15'	89.20
545-PS3612-20HW	PS3612-20HW	12 (20A)	36"	hardwire	43.68
1U Rackmount Models					
545-RS-1215	RS-1215	6 front / 6 rear	19"	15'	60.42
545-RS1215-20	RS-1215-20	6 front / 6 rear (20A)	19"	15'	71.95
545-RS1215-RA	RS-1215-RA	6 front / 6 rear (right angle)	19"	15'	61.88
545-RS0615-R	RS-0615-R	6 rear	19"	15'	60.42
545-RS0615-F	RS-0615-F	6 front	19"	15'	60.42
Power Distribution Units					
545-PDU1220	PDU1220	1 front / 12 rear (20A)	19"	15'	142.67


UTILITY SURGE SUPPRESSORS W/HOSPITAL GRADE OUTLETS

- Features:**
- Stop damaging surges, spikes, and line noise
 - Hospital-grade (HG) plug and receptacles

 RoHS Compliant



MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Joules	Cord Length	Price Each
545-ISOBAR6ULTRAHG	ISOBAR6ULTRAHG	6	600	15'	95.73

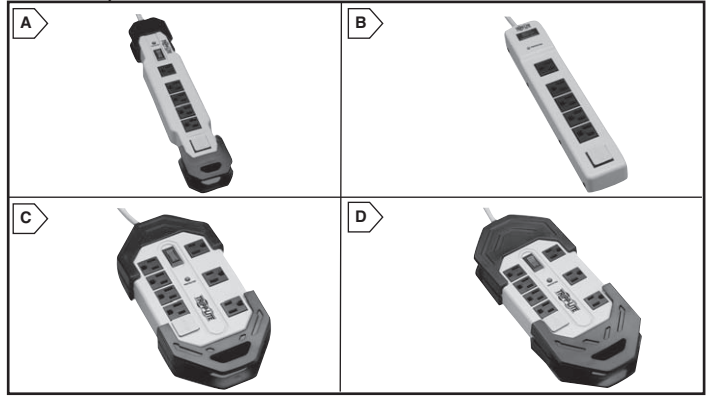

PROTECT IT!™ SAFETY SURGE SUPPRESSORS

Protect IT!™ Safety Series Surge Suppressors and Power IT Safety Power Strips, provide industrial-strength surge and line-noise protection for a variety of tools and appliances.

- Features:**
- LED
 - Transformer
 - Input 120V (15A)
 - Metal housings with safety OSHA yellow color
 - Up to 3600 joules of surge protection
 - Cord wrap with hang holes on select models
 - Include outlet safety covers
 - Up to \$100,000 Ultimate Lifetime Insurance

RoHS Compliant

For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Fig.	Outlets	Cord Length	Price Each
545-TLM609SA	TLM609SA	A	6	9'	36.90
545-TLM615SA	TLM615SA	A	6	15'	43.73
545-TLM626SA	TLM626SA	B	6	6'	23.92
545-TLM812SA	TLM812SA	C	8	12'	43.73
545-TLM825SA	TLM825SA	D	8	25'	60.82

POWER IT!™ SAFETY POWER STRIPS

(with out LED light)

For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Fig.	Outlets	Cord Length	Price Each
545-TLM609NS	TLM609NS	A	6	9'	28.70
545-TLM626NS	TLM626NS	B	6	6'	17.08
545-TLM815NS	TLM815NS	C	8	15'	40.32
545-TLM609GF	TLM609GF	A	6	9'	53.30
545-TLM812GF	TLM812GF	C	8	12'	60.82
545-TLM825GF	TLM825GF	D	8	25'	66.97

UTILITY POWER STRIPS WITH HOSPITAL GRADE RECEPTACLES

- Features:**
- Hospital-grade (HG) plug and receptacles
 - Rackmount (1U) and strip formats
 - PS-615-HGULTRA features GFCI protection

RoHS Compliant

For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Cord Length	Price Each
545-PS415HG	PS-415-HG	4	15'	71.67
545-PS-415-HGULTRA	PS-415-HGULTRA *	4	15'	104.83

ISOBAR® PREMIUM SURGE SUPPRESSORS

- Features:**
- The world's most trusted premium surge suppressor - more than 15 million in use worldwide
 - Isolated filter banks eliminate interference between connected equipment
 - All-metal housings won't burn, melt or crack
 - ULTRA models include diagnostic LED's
 - Rackmount models fit standard 19" (1U) rack space
 - Up to \$50,000 Ultimate Lifetime Insurance

RoHS Compliant

For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Joules	Cord Length	Price Each
545-ISOBAR8ULTRA	ISOBAR8ULTRA	8	2350	12'	83.12
545-ISOBAR4ULTRA	ISOBAR4ULTRA	4	2200	6'	59.60
545-ISOBAR6	ISOBAR6	6	2350	6'	69.33
545-ISOTEL-6ULTRA	ISOTEL6ULTRA	6+(2) tel/DSL	2850	6'	80.16
Rackmount Models					
545-ISOBAR12ULTRA	ISOBAR12ULTRA	12	1280	15'	165.66
545-DRS1215	DRS-1215	14	1050	15'	69.89
Direct Plug-In Models					
545-ISOBLOK2-0	ISOBLOK2-0	2	600	direct plug-in	31.24
545-ULTRABLOK428	ULTRABLOK428	2	600	direct plug-in	41.00

Tripp Lite

Power Protection