

WIREMOLD Surge Suppressors, Strips and Outlet Centers **WIREMOLD**

legrand

WIREMOLD 19" RACK MOUNTED COMPUTER GRADE SURGE SUPPRESSORS- 20 AMP

 
legrand

Specifications:

- Max surge current: 13,000 amps
- Clamping voltage: UL 300 volts
- Electrical rating: 20A, 120V
- EMI/RFI noise reduction: 40db

Features:

- Designed to fit all standard 19" cabinets, carts, and racks
- Matte black steel housing
- Black 12/3 SJT cord with NEMA 5-20P plug
- UL1449 Approved, CSA Approved
- 120 Volt resettable circuit breaker
- Five year warranty
- Surge protection, led indicator
- Dimensions: 19" W x 1.75" H x 2.75" D



For quantities of 10 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Outlets	On/Off Switch	Cord Length	Price Each	
					1	5
681-R5BZ20	R5BZ20	6 Rear	Yes	6'	97.20	91.10
681-R5BZ20-15	R5BZ20-15	6 Rear	Yes	15'	103.83	97.98
681-R5BZ20X-15	R5BZ20X-15	6 Rear	No	15'	103.83	97.98

WIREMOLD SPECIAL APPLICATION 19" RACK MOUNTED POWER STRIPS

 
legrand

Specifications:

- Electrical rating: 15A, 120V

Features:

- Designed to fit all standard 19" cabinets, carts, and racks
- Matte black steel housing
- Black 14/3 SJT cord
- UL recognized CSA approved
- 120 Volt, 15 amp resettable circuit breaker
- Dimensions: 19" W x 1.75" H x 2.75" D
- 90° Rotated outlet units are rotated for applications using plug in power supplies
- Two year warranty



For quantities of 10 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Outlets	On/Off Switch	Description	Cord Length	Price Each	
						1	5
681-J60B0B-90	J60B0B-90	6 Front	Yes	90° Outlets	6'	53.45	50.90
681-J06B0BX	J06B0BX	6 Rear	No	Regular Outlets	6'	53.05	50.89
681-J06B2BX	J06B2BX	6 Rear	No	Regular Outlets	15'	58.35	55.57

WIREMOLD 19" RACK MOUNTED PLUG-IN OUTLET CENTERS-20 AMP

 
 
legrand

Specifications:

- Electrical rating: 20A,120V

Features:

- Designed to fit all standard 19" cabinets, carts, and racks
- Matte black steel housing
- 12/3 SJT cord with NEMA 5-20P plug
- Resettable circuit breaker
- Two year warranty
- Dimensions: 19" W x 1.75" H x 2.75" D
- UL recognized



For quantities of 10 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Fig.	Outlets	On/Off Switch	Cord Length	Price Each	
						1	5
681-J06B0B20	J06B0B20	A	6 Rear	Yes	6'	78.43	72.60
681-J06B2B20	J06B2B20	A	6 Rear	Yes	15'	67.18	64.59
681-J06B0B20X	J06B0B20X	A	6 Rear	No	6'	60.80	57.90
681-J60B0B20	J60B0B20	B	6 Front	Yes	6'	78.43	72.23
681-J60B2B20	J60B2B20	B	6 Front	Yes	15'	67.10	63.90
681-J60B0B20X	J60B0B20X	B	6 Front	No	6'	70.70	65.26
681-J60B2B20X	J60B2B20X	B	6 Front	No	15'	67.10	63.90

WIREMOLD STANDARD 19" RACK MOUNTED POWER STRIPS

 
legrand

Specifications:

- Electrical rating: 15A, 120V

Features:

- Designed to fit all standard 19" cabinets, carts, racks
- Matte black steel housing
- Black 14/3 SJT cord
- Resettable circuit breaker
- Two year warranty
- Dimensions: 19" W x 1.75" x 2.75" D
- UL listed, CSA approved



For quantities of 10 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Fig.	Outlets	On/Off Switch	Cord Length	Price Each	
						1	5
681-J60B0B	J60B0B	A	6 Front	Yes	6'	51.47	49.48
681-J60B2B	J60B2B	A	6 Front	Yes	15'	58.43	56.17
681-J08B0B	J08B0B	B	8 Rear	Yes	6'	53.05	50.27
681-J08B2B	J08B2B	B	8 Rear	Yes	15'	58.42	57.08

* Outlets rotated 90°, 4 outlets spaced to accommodate transformers.

WIREMOLD CENTEREX POWERCENTERS




legrand

Specifications:

- Electrical rating: 15A, 120V

Features:

- UL listed, CSA approved
- Resettable circuit breaker

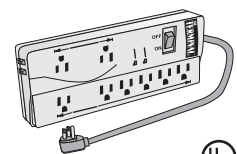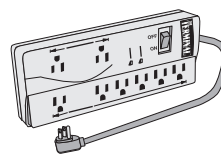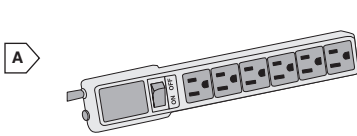

For quantities of 10 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Fig.	Outlets	On/Off Switch	Surge	Joules	Cord Length	Max Surge Current (Amps)	Clamping Voltage	EMI/RFI Reduction	Price Each	
											1	5
681-63100	63100	A	6	Yes	No	N/A	33"	N/A	N/A	N/A	4.15	3.95
681-77000N	77000N	B	8	Yes	Yes	1200	6'	10,000	300	15db	15.13	13.96
681-77001N *	77001	C	8	Yes	Yes	1200	6'	10,000	300	15db	18.99	17.85

* Has 2 Phone Jacks

WIREMOLD METERREADER™ RETROFIT CURRENT MONITORING DEVICE


legrand

The first UL approved product of its kind, the MeterReader™ measures current and displays the reading on the remote unit installed at the front of the IT rack or cabinet.

Features:

- Retrofit current monitoring capability
- Remote display
- 20A or 30A current monitoring
- User configurable
- cULus listed
- All models include remote display, patch cable, and rack mountable faceplate

MOUSER STOCK NO.	Wiremold Part No.	Current Rating	Input/Output	Input/Output Connector	Price Each	
					1	5
681-METL530	METL530	30A max.	100-127VAC	L5-30P/L5-30R	244.15	241.90
681-METL520	METL520	20A max.	100-127VAC	L5-20P/L5-20R	244.15	241.90
681-METL630	METL630	30A max.	208-250VAC	L6-30P/L6-30R	244.15	241.90
681-METL620	METL620	20A max.	208-250VAC	L6-20P/L6-20R	244.15	241.90

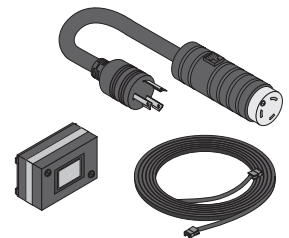

© Copyright 2009 Mouser Electronics

© Copyright 2009 Mouser Electronics