

# WIREMOLD Power Strips and Surge Suppression **WIREMOLD**

## WIREMOLD COMPUTER GRADE SURGE SUPPRESSORS

 
 


### Specifications:

- Max surge current: 13,000A
- 681-PR610 6500A
- Clamping voltage: UL 300V
- 681-PR610 390V
- Electrical rating: 15A, 120V
- EMI/RFI noise reduction: 40db

### Features:

- Surge indicator light
- Resettable circuit breaker
- White housing
- Five year warranty
- UL1449 Approved, CSA certified



For quantities of 10 and up, call for quote.

MOUSER STOCK NO.		Fig.	Outlets	Length	Case	Cord Length	Phone Fax Protected	On/Off Switch	Price Each	
Mfr.	Mfr. Stock No.								1	5
681—M6BZ		A	6	13"	Aluminum	6'	-----	Lighted	40.67	39.38
681—M6BZ-15		A	6	13"	Aluminum	15'	-----	Lighted	44.28	42.47
681—SRD10		B	6	13"	Plastic	6'	1(RJ11)	Lighted	43.74	41.23
681—M6BZM		A	6	16"	Aluminum	6'	1(RJ45)	Lighted	76.65	74.62

## WIREMOLD COMPACT PLUG-IN OUTLET CENTERS

 
 
 


### Specifications:

- Electrical rating: 15A, 120V

### Features:

- Resettable circuit breaker
- 14/3 SJT cord
- Gray aluminum housing except where noted
- UL listed, CSA approved
- Two year warranty



\*White Plastic Housing For quantities of 10 and up, call for quote.


MOUSER STOCK NO.		Fig.	Outlets	Length	Mounting Type	Cord Length	Switch/Pilot Light	Price Each	
Mfr.	Mfr. Stock No.							1	5
681—UL101BC		A	4	9.187"	Snap/Slide	6'	No	21.33	20.91
681—UL101BD		A	4	9.187"	Snap/Slide	15'	No	26.75	26.23
681—UL104BC		B	4	9.75"	Snap/Slide	6'	Yes	26.05	25.55
681—UL104BD		B	4	9.75"	Snap/Slide	15'	Yes	31.51	30.16
681—UL207BC		B	6	12.25"	Snap/Slide	6'	Yes	31.77	30.46
681—UL207BD		B	6	12.25"	Snap/Slide	15'	Yes	37.21	36.44
681—P6 *		C	6	12"	Keyhole	6'	Yes	11.67	11.11
681—P6-15 *		C	6	12"	Keyhole	15'	Yes	17.20	16.98

## WIREMOLD INTERNATIONAL PLUG-IN OUTLET CENTER


 
### Features:

- Five 250V, IEC 320 outlets
- 10A single pole circuit breaker
- Gray finish
- Power cord not included (use 173-63101)
- Length: 11"



For quantities of 10 and up, call for quote.

MOUSER STOCK NO.		Description	Price Each	
Mfr.	Mfr. Stock No.		1	5
681—IEC5		5 250V, IEC320 Outlets	45.13	43.05

## WIREMOLD SPECIAL USE PLUG-IN OUTLET CENTERS

 


### Features:

- Green dot outlets
- 14/3 SJT white cord
- Resettable circuit breaker
- UL Listed, CSA approved
- White aluminum housing
- Two year warranty

### Specifications:

- Electrical rating: 15A, 120V



For quantities of 10 and up, call for quote.

MOUSER STOCK NO.		Outlets	Length	Cord Length	Price Each	
Mfr.	Mfr. Stock No.				1	5
681—ULBH4-6		4	10 3/4"	6'	48.13	47.65
681—ULBH4-15		4	10 3/4"	15'	53.22	52.09
681—ULBH6-6		6	13 1/4"	6'	64.56	64.18
681—ULBH6-15		6	13 1/4"	15'	73.76	69.67


## WIREMOLD MEDICAL/DENTAL GRADE OUTLET CENTERS


 
### Features:

- Electrical Rating 12A, 125V
- Green dot outlets
- 14/3 SJT white cord
- Receptacle center-to-center

- White aluminum housing
- Two year warranty
- Suitable for use where Article 517 of the NEC requires hospital grade outlets



For quantities of 10 and up, call for quote.

MOUSER STOCK NO.		Outlets	Length	Cord Length	Price Each	
Mfr.	Mfr. Stock No.				1	5
681—ULM4-6		4	10 3/4"	6'	97.18	91.78
681—ULM4-15		4	10 3/4"	15'	107.42	101.46
681—ULM6-6		6	13 1/4"	6'	119.36	112.73
681—ULM6-15		6	13 1/4"	15'	129.55	122.35

## WIREMOLD INDUSTRIAL PLUG-IN OUTLET CENTERS

 


### Features:

- 14/3 SJT cord
- Gray aluminum housing
- UL listed, CSA approved
- Two year warranty

### Specifications:

- Electrical rating: 15A, 120V



For quantities of 10 and up, call for quote.

MOUSER STOCK NO.		Outlets	Length	Mounting Type	Cord Length	Switch/Pilot Light	Price Each	
Mfr.	Mfr. Stock No.						1	5
681—UL300BC		8	24"	Snap/Slide	6'	Yes	48.32	47.65
681—UL300BD		8	24"	Snap/Slide	15'	Yes	52.66	51.64
681—UL401BC		8	48"	Snap/Slide	6'	Yes	53.98	52.94
681—UL402BC		16	48"	Snap/Slide	6'	Yes	65.18	64.92
681—UL402BD		16	48"	Snap/Slide	15'	Yes	80.85	77.00
681—UL2065BD		24	72"	Snap/Slide	15'	Yes	82.87	81.21

## WIREMOLD HEAVY DUTY PLUG-IN OUTLET CENTERS-20 AMP

 


### Specifications:

- Electrical rating: 20A, 120V, 60Hz, 2500 watts continuous

### Features:

- White aluminum housing
- UL listed
- Resettable circuit breaker
- 12/3 SJT black cord with NEMA 5-20P plug
- Two year warranty



For quantities of 10 and up, call for quote.

MOUSER STOCK NO.		Outlets	Length	Cord Length	Switch/Pilot Light	Price Each	
Mfr.	Mfr. Stock No.					1	5
681—ULB420-6		4	10 3/8"	6'	Yes	80.08	76.99
681—ULB420-15		4	10 3/8"	15'	Yes	86.60	83.20
681—ULB620-6		6	13 3/8"	6'	Yes	82.60	79.41
681—ULB620-15		6	13 3/8"	15'	Yes	89.13	85.76

## WIREMOLD CABINETMATE POWER STRIPS




### Specifications:

- Electrical rating: 120V

### Features:

- Designed to fit in all types of cabinets
- Gray aluminum housing
- UL listed, CSA approved (15A models only)
- Resettable circuit breaker

- Two year warranty
- 15A units: 14/3 SJT cord with NEMA 5-15P plug
- 20A units: 12/3 SJT cord with NEMA 5-20P plug

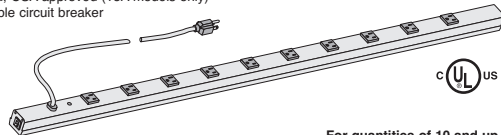

For quantities of 10 and up, call for quote.

MOUSER STOCK NO.		Outlets	Amps	Length	Cord Length	Price Each	
Mfr.	Mfr. Stock No.					1	5
681—4810ULBC		10	15	48"	6'	57.99	54.99
681—4810ULBD		10	15	48"	15'	63.89	60.68
681—7011ULBC		11	15	70"	6'	66.71	64.14
681—7011ULBD		11	15	70"	15'	71.00	67.52
681—7712ULBC		12	15	77"	6'	70.51	70.22
681—7712ULBD		12	15	77"	15'	84.72	80.41
681—4810ULBC20R		10	20	48"	6'	74.52	70.58
681—4810ULBD20R		10	20	48"	15'	84.81	80.33
681—7011ULBC20R		11	20	70"	6'	86.00	81.46
681—7011ULBD20R		11	20	70"	15'	96.29	91.21
681—7712ULBC20R		12	20	77"	6'	94.75	89.76
681—7712ULBD20R		12	20	77"	15'	103.38	98.46


## WIREMOLD POWER COMMANDER 30A AND 40A POWER DISTRIBUTION UNITS



Among the first in the industry to meet the new UL60950-1 1st Edition and ITE standards, these PDUs feature UL489 Listed breakers to increase the safety and reliability of distributed power.

### Features:

- Meets UL60950-1 1st Edition and ITE standards
- AC Voltage input:
  - 30A units: 100-127V, L5-30P plug
  - 40A units: 200-230V, L14-20P plug
- Narrow aluminum profile: (1 1/2"W x 2 7/8"H)
- Easy access breakers provide overload protection
- Built in mounting rail

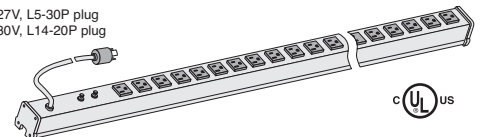

For quantities of 10 and up, call for quote.

MOUSER STOCK NO.		Total Current Rating	Outlets	Amps	Length	Cord Length	Price Each	
Mfr.	Mfr. Stock No.						1	5
681—3A44B2-1		30A	24	20	48"	12'	181.66	173.01
681—3A86B2-1		30A	36	20	70"	12'	178.52	169.25
681—4B44B2-2		40A	24	20	48"	12'	183.71	176.33
681—4B86B2-2		40A	36	20	70"	12'	232.94	221.85