

Rechargeable Batteries and Chargers

SANYO CADNICA NICKEL-CADMIUM BATTERIES

Nickel-Cadmium batteries may be used in cyclic, trickle or float charge use.

- Operating Temperature Range: Charge: 0 - 45°C (Standard) 10° - 45°C (Quick); Discharge: -20° - 60°C; Storage: -30° - 50°C

Standard/General

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Size	Volts	Capacity mAh	Dimensions: in. Diameter x Height	Price Each		
					1	10	50
Consumer Batteries							
639-N250AAA	AAA	1.2	250	0.41 x 1.75	3.42	3.22	3.13
639-N700AAC	AA	1.2	700	0.56 x 1.99	2.94	2.51	2.29
639-KR2000C	C	1.2	2000	1.02 x 1.97	7.68	6.94	6.79
639-KR4400D	D	1.2	4400	1.34 x 2.42	13.09	11.57	10.35
Specialty Batteries							
639-N110AA	1/3AA	1.2	110	0.55 x 0.66	1.99	1.78	1.73
639-N270AA	2/3AA	1.2	270	0.57 x 1.18	2.25	1.99	1.82
639-KR1300SC	SC	1.2	1300	0.91 x 1.69	3.35	3.15	3.06
639-KR1500SC	SC	1.2	1500	0.91 x 1.69	3.35	3.02	2.82
639-KR7000F	F	1.2	7000	1.69 x 3.58	27.90	25.11	22.32
639-N150N	N	1.2	150	0.47 x 1.18	2.35	2.10	2.00
Solder Tabs							
639-N110AA-T	1/3AA	1.2	110	0.55 x 0.66	2.28	2.03	1.97
639-N270AA-ST	2/3AA	1.2	270	0.57 x 1.18	2.54	2.09	1.67
639-N700AAC-ST	AA	1.2	700	0.56 x 1.99	2.58	2.45	2.32
639-KR1300SC-ST	SC	1.2	1300	0.91 x 1.69	3.61	3.24	3.04
639-KR1500SC-ST	SC	1.2	1500	0.91 x 1.69	4.39	4.16	3.93
639-KR4400D-ST	D	1.2	4400	1.34 x 2.42	13.72	11.39	10.86

High Capacity/Extra Series

- Operating Temperature Range: Charge: 0 - 45°C (Standard) 10° - 45°C (Quick); Discharge: -20° - 60°C; Storage: -30° - 50°C

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Size	Volts	Capacity mAh	Dimensions: in. Diameter x Height	Price Each		
					1	10	50
639-KR1100AAU	AA	1.2	1100	0.56 x 1.99	3.61	3.35	2.73
639-KR600AE	2/3AA	1.2	600	0.67 x 1.10	2.36	2.13	2.03
639-KR1100AEL	4/5A	1.2	1100	0.67 x 1.69	4.48	4.16	3.84
639-KR1400AE	A	1.2	1400	0.67 x 1.97	4.51	4.06	3.88
639-KR1800SCE	SC	1.2	1800	0.91 x 1.69	5.56	5.02	4.58
639-KR5000DEL	D	1.2	5000	1.34 x 2.36	11.77	11.05	10.73

POWER SONIC NICKEL-CADMIUM BATTERIES

- Nominal Voltage: 1.2V

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Size	Description	Capacity 5 Hr. Rate (mAh)	Std. Charge		Price Each			
				(mA)	(Hrs)	1	10	20	50
547-PS-AAA	AAA	Std. button top	250	22	15	2.06	1.88	1.73	1.66
547-PSAAA-T	AAA	With solder tabs	250	22	15	2.28	2.09	1.94	1.88
547-PS-AA	AA	Std. button top	600	60	15	2.08	1.87	1.70	1.65
547-PS-AA/FT	AA	Flat top	600	60	15	2.47	2.22	2.03	1.96
547-PSAA-T	AA	With solder tabs	600	60	15	2.89	2.63	2.42	2.33
547-PS-SC	SC	Flat top	1500	150	15	4.94	4.37	3.99	3.86
547-PS-SC-T	SC	With solder tabs	1500	150	15	5.73	4.95	4.54	4.41
547-PS-C	C	Flat top	2000	200	15	9.46	8.51	7.68	7.42
547-PS-C-T	C	With solder tabs	2000	200	15	10.30	9.30	8.42	8.16
547-PS-D	D	Flat top	4000	400	15	8.09	7.61	6.79	6.37
547-PS-DL	D	Std. button top	4000	400	15	11.58	10.36	9.38	9.06

GP NICKEL-CADMIUM BATTERIES


- Long Life
- Sealed, Strong, Leakproof Construction
- Excellent Discharge Characteristics

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Size	Volts	Capacity (mAh)	Price Each			
				1	10	25	100
573-60AAK	AA	1.2	600	2.40	2.23	2.04	1.80
573-100AAK	AA	1.2	1000	4.72	4.22	3.92	3.02

GP 3.6V BATTERY PACKS

 - Termination: Solder Tab
- For Cordless Devices



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Size	Type	Capacity (mAh)	Price Each			
				1	10	25	100
573-30AAK3B1P	3 x 2/3 AA	Ni-Cad	300	6.96	6.27	5.57	5.31
573-60AAK3B1P	3 x AA	Ni-Cad	600	4.99	4.50	4.99	3.81

SANYO NICKEL METAL HYDRIDE BATTERIES

- Operating Temperature Range:
 - Charge: 0°-40°C
 - Discharge: 0°-50°C
 - Storage: -20°C - 50°C


For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Size	Volts	Capacity mAh	Dimensions: in. Diameter x Height	Price Each		
					1	10	50
Consumer Top							
* 639-HR-4U	AAA	1.2	750	0.41 x 1.75	2.70	2.40	2.30
* 639-HR-3U	AA	1.2	1650	0.56 x 1.99	4.33	3.86	3.64
Flat Top							
639-HR-AAU	AA	1.2	720	0.41 x 1.75	3.64	3.42	3.30
639-HR-AAC	AA	1.2	1100	0.56 x 1.99	4.99	4.60	4.28
639-HR-AAU	AA	1.2	1500	0.56 x 1.99	5.88	5.40	4.66
639-HR-AUX	A	1.2	2700	0.67 x 1.97	6.98	6.34	5.81
Solder Tabs							
639-HRAAUU-ST	AAA	1.2	720	0.41 x 1.75	3.51	3.30	3.10
639-HRAAC-ST	AA	1.2	1100	0.56 x 1.99	3.80	3.40	3.05
639-HRAAUU-ST	AA	1.2	1500	0.56 x 1.99	6.57	6.03	5.20

* OEM Label Packaging


ENERGIZER ACCU RECHARGEABLE NICKEL METAL-HYDRIDE BATTERIES

 - Designed for high-drain devices
- Batteries charge up to 1,000 times
- Provides up to 70% more power than standard NiCd



MOUSER STOCK NO.	Size	Nominal Voltage	Capacity (mAh)	Batteries Per Pkg.	Price Per Pkg.		
					1	12	48
525-NH12BP-4	AAA	1.2	850	4	15.77	14.02	13.14
525-NH15BP-4	AA	1.2	2500	4	15.77	14.02	13.14
525-NH35BP-2	C	1.2	2500	2	11.51	10.22	9.60
525-NH22NBP	9V	7.2	150	1	11.51	10.22	9.60

ACCU RECHARGEABLE NIMH AND NICD BATTERY CHARGERS

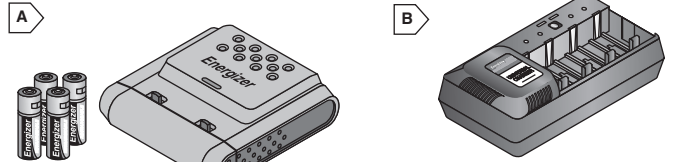


- Charges NiMH batteries only
- LED indicator shows when charging is complete
- Comes with 2 AA and 2 AAA batteries
- LED indicator shows when charging is complete
- CHFCV charges NiMH battery only
- CHG-6P charges NiMH and NiCd batteries only



- Charges NiMH batteries only
- LED indicator shows when charging is complete
- Comes with 4 AA batteries
- Charges in 15 minutes

MOUSER STOCK NO.	Fig.	Description	Price Each	
			1	6
525-CHDCWB-4	A	Charges 2-4 AAA or AA batteries	27.00	24.75
525-CHFCV	B	Charges 2-4 AAA, AA, C, or D, or 1-2 9V batteries	38.98	29.99
639-CHG-6P	B	Charges 2-4 AAA, AA, C, or D, or 1-2 9V batteries	21.47	19.80
525-CH15MNCB4	C	Charges 1-4 AAA or AA batteries	51.73	47.27

 GP NICKEL METAL HYDRIDE BATTERIES



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Size	Volts	Cap. (mAh)	Price Each			
				1	10	25	100
573-GP130AA	AA	1.2	1300	4.13	3.78	3.28	2.94
573-GP160AA	AA	1.2	1600	3.81	3.51	3.25	2.83
573-GP180AAHC	AA	1.2	1800	4.84	4.02	3.52	3.19
573-GP17R8H	9V	8.4	170	9.38	8.21	7.36	7.03