


# EAGLE PLASTIC DEVICES 9V Battery Snaps



Largest selection of battery snaps available. All leads are stripped and pre-tinned. Leads are polarity color coded. All except "molded" type, feature PVC plastic insulation over a base of vulcanized fiber board.

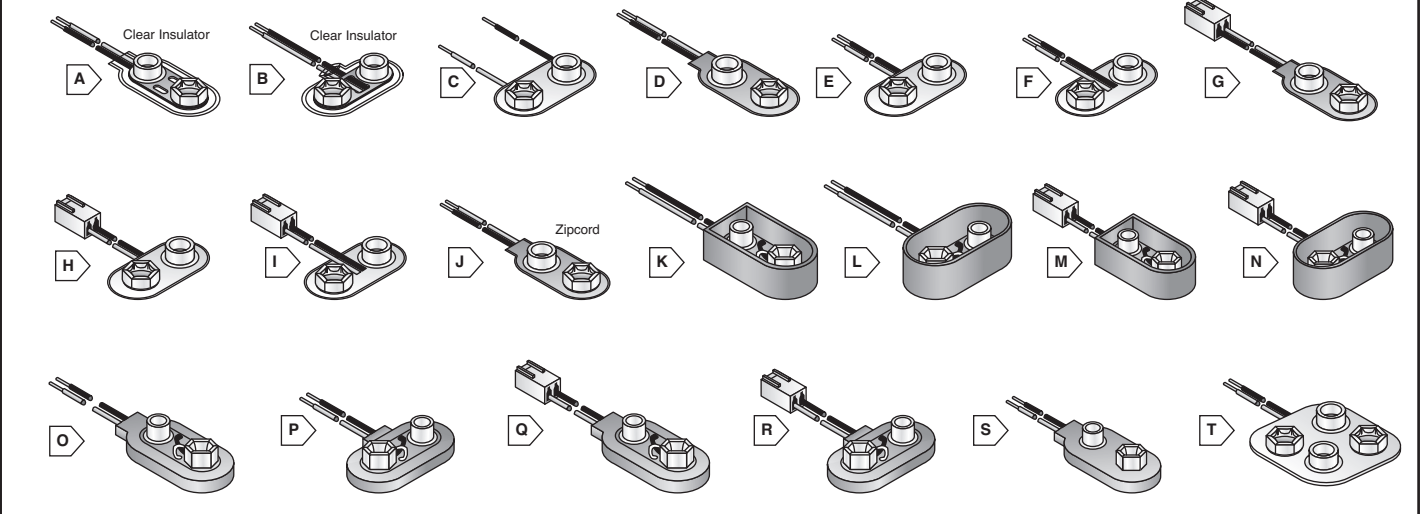

## STANDARD BATTERY SNAPS

Snaps • 6 prong contacts

RoHS Compliant

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
12BC310-GR	A	26AWG	4	.39	.28	.25	.23
12BC309-GR	A	26AWG	6	.39	.28	.25	.23
12BC311-GR	B	26AWG	4	.39	.28	.25	.23
123-BS-M-A-GR	C	26AWG	6	.53	.39	.31	.27
121-0426/I-GR	D	26AWG	4	.34	.25	.20	.17
121-0526/I-GR	D	26AWG	5	.34	.25	.20	.17
121-0626/I-GR	D	26AWG	6	.34	.25	.20	.17
121-0826/I-GR	D	26AWG	8	.38	.28	.22	.19
121-1026/I-GR	D	26AWG	10	.38	.28	.22	.19
121-1226/I-GR	D	26AWG	12	.38	.28	.22	.19
121-0424/I-GR	D	24AWG	4	.38	.28	.22	.19
121-0624/I-GR	D	24AWG	6	.38	.28	.22	.19
121-0422/I-GR	D	22AWG	4	.38	.28	.22	.19
121-0622/I-GR	D	22AWG	6	.38	.28	.22	.19
121-1022/I-GR	D	22AWG	10	.41	.30	.24	.21
121-0426/T-GR	E	26AWG	4	.41	.30	.24	.21
121-0526/T-GR	E	26AWG	5	.41	.30	.24	.21
121-0626/T-GR	E	26AWG	6	.41	.30	.24	.21
121-0826/T-GR	E	26AWG	8	.41	.30	.24	.21
121-1026/T-GR	E	26AWG	10	.41	.30	.24	.21
121-0426/O-GR	F	26AWG	4	.41	.30	.24	.21
121-0626/O-GR	F	26AWG	6	.41	.30	.24	.21
121-0424/O-GR	F	24AWG	4	.41	.30	.24	.21
121-0624/O-GR	F	24AWG	6	.41	.30	.24	.21
121-0422/O-GR	F	22AWG	4	.41	.30	.24	.21
121-0622/O-GR	F	22AWG	6	.41	.30	.24	.21

## Snaps With 2 Pole Socket Wire Termination

• Mates with Molex P/N 22-11-2022  
• 6 prong contacts

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
121-0426/IM-GR	G	26AWG	4	.44	.37	.34	.31
121-0626/IM-GR	G	26AWG	6	.44	.37	.34	.31
121-0426/TM-GR	H	26AWG	4	.44	.37	.34	.31
121-0626/TM-GR	H	26AWG	6	.44	.37	.34	.31
121-0426/OM-GR	I	26AWG	4	.44	.37	.34	.31
121-0626/OM-GR	I	26AWG	6	.44	.37	.34	.31

## Snaps With Zipcord Leads

• Zipcord lead colors: black & white • 4 prong contacts

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
12BC015-GR	J	24AWG	4	.42	.30	.28	.25
12BC010-GR	J	24AWG	6	.42	.30	.28	.25
12BC016-GR	J	24AWG	10	.42	.30	.28	.25

## MOLDED BATTERY SNAPS

• Molded 2 piece construction  
• Covers battery terminals completely  
• UL1007 26AWG wire stripped and tinned 5mm

• Material ABS resin, black  
• 6 prong brass nickel plated snap  
• UL listed wire

### 4000 Series

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
123-4006-GR	K	26AWG	6	.41	.29	.26	.24
123-4016-GR	L	26AWG	6	.41	.29	.26	.24

## MOLDED BATTERY SNAPS (CONT.)

### 4000 Series With 2 Pole Socket Wire Termination

• Mates with Molex P/N 22-11-2022

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
123-4006/M-GR	M	26AWG	6	.54	.45	.41	.37
123-4016/M-GR	N	26AWG	6	.54	.45	.41	.37

### 5000 Series

A unique 2 piece molded design. Leads are attached to the snaps with copper solderless ring terminals for extra strength and reliability. 7-strand copper conductor (tin overcoated).

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
123-5004-GR	O	26AWG	4	.43	.30	.24	.22
123-5006-GR	O	26AWG	6	.43	.30	.24	.22
123-5008-GR	O	26AWG	8	.43	.30	.24	.22
123-5114-GR	P	26AWG	4	.43	.30	.24	.22
123-5116-GR	P	26AWG	6	.43	.30	.24	.22
123-5118-GR	P	26AWG	8	.43	.30	.24	.22

### 5000 Series With 2 Pole Socket Wire Termination

• Mates with Molex P/N 22-11-2022

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
123-5004/M-GR	Q	26AWG	4	.53	.44	.40	.36
123-5006/M-GR	Q	26AWG	6	.53	.44	.40	.36
123-5114/M-GR	R	26AWG	4	.53	.44	.40	.36
123-5116/M-GR	R	26AWG	6	.53	.44	.40	.36

### PREMIUM 7000 Series

A unique 2 piece molded design. Leads are attached to the snaps with copper solderless ring terminals for extra strength and reliability.

- High reliability
- 6 prong nickel plated brass snaps
- Attractive white housing with light blue cover
- UL/CSA 1007 24AWG stripped and tinned wire
- Solderless ring terminals eliminate cold solder joints

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
123-7014	S	24AWG	4	.83	.42	.38	.35
123-7016	S	24AWG	6	.83	.42	.38	.35
123-7020	S	24AWG	10	.98	.49	.46	.42

### Dual 9V Battery Snaps

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Description	Price Each			
					1	25	50	100
123-BS-M-4A-GR	T	26AWG	6	Wire Leads	.83	.76	.72	.63
123-BS-M-4B-GR	T	--	--	Rivets	.83	.76	.72	.63
123-BS-M-4D-GR	T	--	--	Solder Tabs	.83	.76	.72	.63