


# KEYSTONE Battery Holders, Clips & Spring Contacts



RoHS Compliant This product is RoHS compliant.

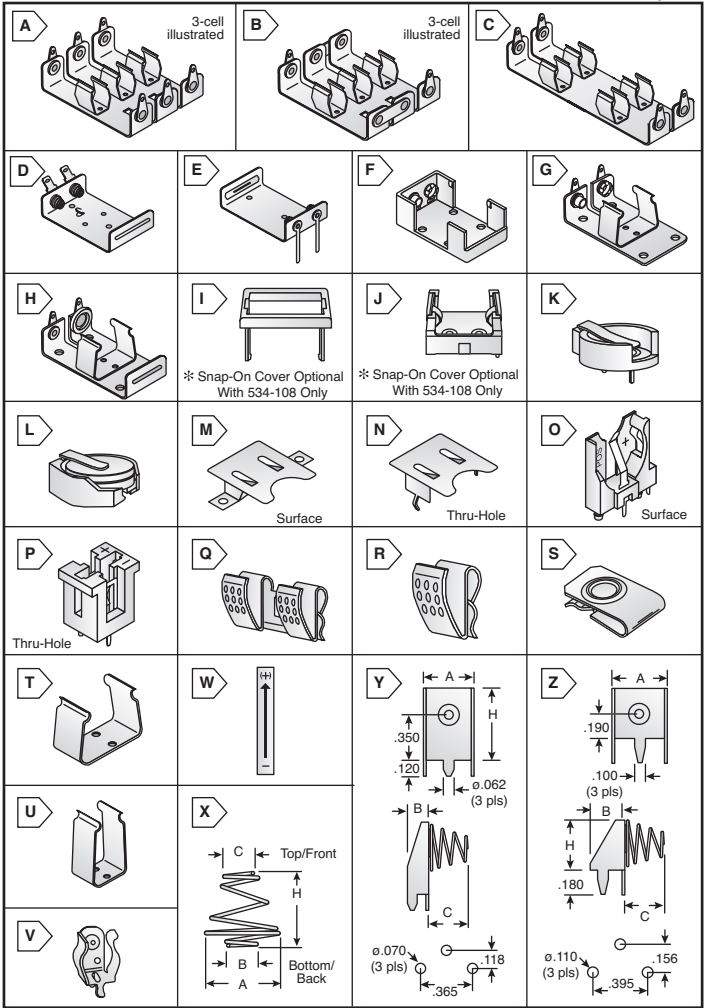

## KEYSTONE PC BATTERY HOLDERS

MOUSER STOCK NO.	Fig.	Description	Price Each		
			1	10	100
*534-108A	I	1 cell; Cover only	.60	.48	.30
*534-108	J	1 cell; 1/2 AA size	1.30	.94	.84
534-1028	J	1 cell; AA size	1.45	.91	.81

## KEYSTONE PC MOUNT COIN CELL BATTERY HOLDERS

\* Contact material: nickel over copper plated spring steel \* Housing material: glass-filled nylon, UL 94V-0

534-501	K	2-ø12mm cells; BR1216, CR1216, BR1220, CL1220, CR1220, BR1225	Price Each		
			1.54	1.41	1.29
534-502	K	1-ø16mm cell; BR1616, CR1616, CR1620, CR1632	1.26	1.06	.87
534-103	K	1-ø20mm cell; BR2016, BR2020, BR2025, BR2032	1.40	1.25	.94
534-104	K	1-ø23mm cell; BR2320, BR2325, BR2330, BR2335	1.20	.99	.86
534-301	K	1-ø30mm cell; BR3032	1.26	1.06	.86

## KEYSTONE PC MOUNT COIN CELL BATTERY HOLDERS

\* Made of UL approved glass-filled nylon 94V-0 For quantities of 500 and up, call for quote.

534-500	K	Holds 3-volt cell, .47" dia. x .1"	1.32	1.15	.94
---------	---	------------------------------------	------	------	-----

MOUSER STOCK NO.	Fig.	No. of Cells	Duracell	Ray-O-Vac Panasonic	Eveready GP	Price Each		
						1	10	100
534-105	K	1	-----	-----	-----	1.49	1.33	1.15
534-1025	K	2	DL2430	-----	-----	1.34	1.12	.95
			DL2450	-----	-----	-----	-----	-----
534-106	K	1	DL2016	BR2016	CR2016	1.20	1.00	.86
534-1026	K	2	DL2025	CR2016	CR2025	1.33	1.04	.94
			DL2032	CR2025	CR2032	-----	-----	-----
			-----	BR2032	CR2032	-----	-----	-----
			-----	-----	-----	-----	-----	-----
534-107	K	1	CR2316	BR2320	-----	1.20	1.00	.86
534-1027	K	2	-----	CR2325	-----	1.67	1.52	1.26
			-----	BR2330	-----	-----	-----	-----

## KEYSTONE COIN CELL BATTERY HOLDERS

\* Contact: tin over nickel plated steel \* Housing: Nylon, Stanyl-46 \* Temp. rating: -15°C to 282°C

MOUSER STOCK NO.	Fig.	No. of Cells	Cell Dia.	Fits Battery Types	Price Each		
					1	10	100
534-1061	L	1	20mm	2016, 2025, 2032	1.56	1.30	1.11
534-1062	L	2	20mm	2016, 2025, 2032	1.50	1.28	1.14

## KEYSTONE COIN CELL HOLDERS

\* Spring: nickel plated steel For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Fig.	Cell Dia.	Description	Price Each		
				1	10	100
<b>Horizontal</b>						
534-3000	M	12mm	BR1216, BR1220, BR1225	.34	.29	.26
534-3002	M	20mm	BR2016, BR2020, BR2025, BR2032	.35	.30	.27
534-3004	M	23mm	BR2320, BR2325, BR2330	.46	.32	.24
534-3006	M	24mm	CR2430, DL2430	.40	.32	.29
534-3001	N	12mm	BR1216, BR1220, BR1225	.39	.33	.26
534-3003	N	20mm	BR2016, BR2020, BR2025, BR2032	.38	.32	.24
534-3005	N	23mm	BR2320, BR2325, BR2330	.46	.32	.24
<b>Vertical</b>						
534-1065	O	20mm	Fits all major mfg. 20mm batteries	1.55	1.55	1.09
534-1067	P	20mm	Fits all major mfg. 20mm batteries	1.60	1.60	1.35

## KEYSTONE SNAP-ON BATTERY CLIPS

\* Self-anchoring \* Clips over panels from .060" to .070" thick

MOUSER STOCK NO.	Fig.	No. of Cells	Description	Price Each		
				1	100	500
534-210	Q	2	A and AA snap-on double clip	.42	.21	.18
534-202	Q	2	AAA, AAAA and N snap-on double clip	.31	.22	.19
534-288	Q	2	A and AA snap-on double clip	.42	.21	.18
534-204	R	1	AAA, AAAA and N snap-on clip	.28	.14	.12
534-209	R	1	AA snap-on clip	.29	.15	.13
534-228	S	1	AA positive snap-on clip	.23	.12	.10
534-238	S	1	AAA, AAAA and N snap-on clip	.21	.11	.09

## KEYSTONE BATTERY CLIPS

\* Aluminum clips: plain finish \* Steel clips: nickel plated

MOUSER STOCK NO.	Fig.	Fits 9V Size	Dimensions H x W (In.)	Cell Mounts	Material	Price Each		
						1	10	100
534-071	T	.593 x 1.031	.687 x 1.031	flat / horiz.	.015 steel	.30	.25	.24
534-079	T	.650 x 1.031	.765 x 1.050	flat / horiz.	.015 steel	.35	.31	.28
534-080	U	.650 x 1.031	1.187 x .625	side / vert.	.015 steel	.39	.33	.28
534-095	U	.625 x 1.000	1.125 x .656	side / vert.	.025 alum.	.70	.65	.49

## KEYSTONE PC BATTERY CLIP

\* For A and AA type batteries with diameters from .531" to .665" \* Spring: .015", nickel plated steel

MOUSER STOCK NO.	Fig.	Description	Price Each		
			1	100	500
534-082	V	1 cell; AAA and N snap-on clip	.20	.17	.13
534-092	V	1 cell; A, AA type battery clip, snap-in design	.25	.19	.15

## KEYSTONE POLARITY INDICATOR LABELS

\* Pressure sensitive adhesive back \* Adheres to all surfaces

534-058	W	Labels measure .25" x 1.375"	.06	.04	.03
---------	---	------------------------------	-----	-----	-----

## KEYSTONE BATTERY SPRING CONTACTS

\* Easy to assemble with eyelets or rivets \* Spring: nickel plated steel

MOUSER STOCK NO.	Fig.	Battery Type	Dimension (In.)			Price Each				
			H	A	B	C	1	100	500	1000
534-211	X	AA, A	.290	.335	.100	.140	.13	.07	.05	.04
534-211D	X	C, D	.850	.650	.162	.300	.26	.14	.12	.10

## KEYSTONE PC SPRING CONTACTS

\* Space saving design installs directly onto the PC board \* Spring: .015", tin plated steel

534-628	Y	A	Dimension (In.)			Price Each				
			.55	.38	.156	.29	.46	.41	.35	.34
534-629	Z	AA, AAA	.38	.41	.265	.29	.46	.41	.36	.32

## KEYSTONE ALUMINUM BATTERY HOLDERS

In series type holders feature pre-connected jumper strap insulated from the aluminum base. Batteries held in series circuit without additional wiring. For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Fig.	No. of Cells	Type	Price Each		
				1	10	100
<b>"AA" Size</b>						
534-139	A	1	One cell individually connected	1.08	.90	.80
534-140	A	2	Two cells individually connected	2.09	1.78	1.61
534-146	B	2	Two cells connected in series	2.30	1.95	1.73
534-171	A	3	Three cells individually connected	3.51	3.02	2.55
534-147	B	3	Three cells connected in series	3.99	3.34	2.96
534-192	C	4	Four cells individually connected, 2 x 2	3.22	2.69	2.36
534-148	C	4	Four cells connected in series	3.51	2.94	2.63
<b>"C" Size</b>						
534-173	A	1	One cell individually connected	1.28	1.08	1.00
534-174	A	2	Two cells individually connected	2.30	2.03	1.75
534-149	B	2	Two cells connected in series	2.46	2.05	1.95
534-151	C	4	Four cells connected in series	4.09	3.51	2.95
<b>"D" Size</b>						
534-175	A	1	One cell individually connected	1.47	1.21	1.10
534-176	A	2	Two cells individually connected	2.62	2.19	1.97

## KEYSTONE "6V" LITHIUM BATTERY HOLDERS

\* For Eveready EL223A or equivalent For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Fig.	No. of Cells	Terminal Type	Price Each		
				1	10	100
534-223	D	1	Quick disconnect/solder lug	2.53	2.11	1.92
534-224	E	1	PC	2.67	2.24	1.98

## KEYSTONE "9V" BATTERY HOLDERS

Glass Filled Nylon

\* Terminals: tin plated brass \* Contacts: nickel plated steel For quantities of 500 and up, call for quote.

534-1294	F	1	PC	Price Each		
				1.10	.98	.92
534-1295	F	1	Solder	1.15	.96	.88

Aluminum

\* Solder & PC lugs: tin plated brass \* Contacts & clips: nickel plated steel \* Insulation: resin impregnated fiber

534-1290	G	1	Solder	Price Each		
				1.85	1.60	1.32
534-1291	G <td>1 <td>PC</td> <td>1.95</td> <td>1.70</td> <td>1.50</td> </td>	1 <td>PC</td> <td>1.95</td> <td>1.70</td> <td>1.50</td>	PC	1.95	1.70	1.50
534-203	H <td>1 <td>Solder</td> <td>2.15</td> <td>1.92</td> <td>1.80</td> </td>	1 <td>Solder</td> <td>2.15</td> <td>1.92</td> <td>1.80</td>	Solder	2.15	1.92	1.80

Keystone Battery Holders