


B&K PRECISION Multimeters

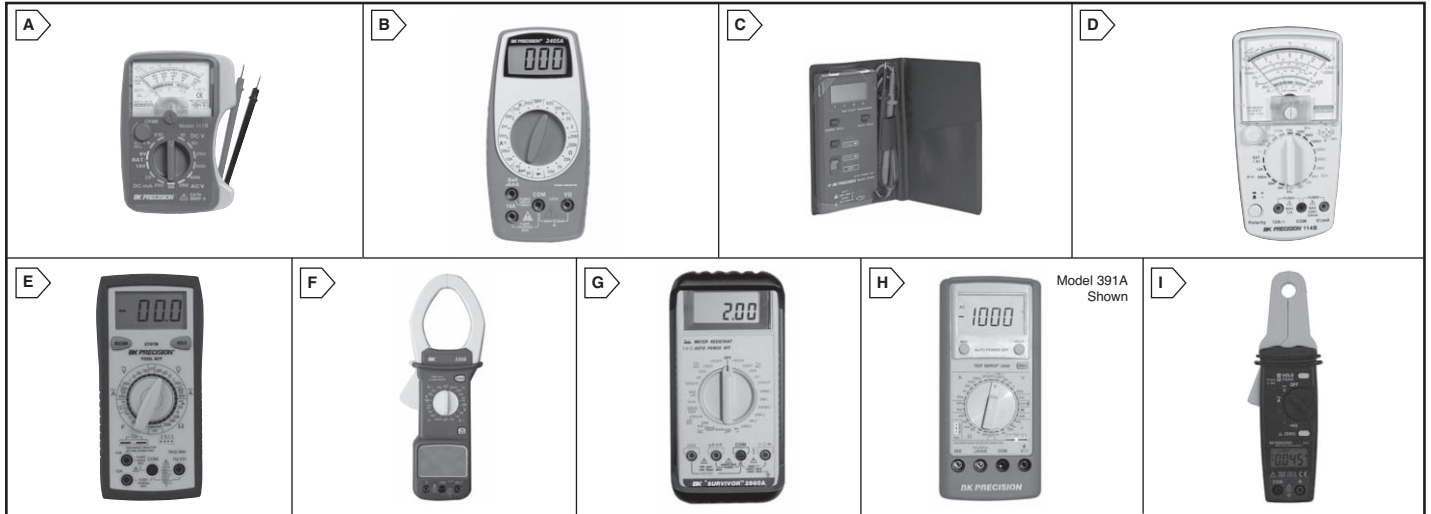

BK PRECISION DIGITAL MULTIMETERS

MOUSER STOCK NO.	BK Precision Part No.	Fig.	DCV Accuracy	Ranging	Display LCD	Analog Bar Graph	Data Hold	Memory	Cap	Frequency	Logic	Tran Gain	Temp.	Auto Off	Warranty	Price Each
615-117B	117B	A	5	Manual	Analog	No	No	No	No	No	No	No	No	No	1 Year	21.88
615-2405A	2405A	B	2	Manual	2000	No	No	No	No	No	Yes	No	No	No	1 Year	29.00
615-2700	2700	C	1.3	Auto	3200	Yes	Yes	No	No	No	No	No	No	Yes	1 Year	38.00
615-114B	114B	D	3	Manual	Analog	No	No	No	No	No	No	Yes	No	No	1 Year	42.00
615-2703C	2703C	E	0.5	Manual	3 1/2	No	No	No	No	No	No	No	No	No	1 Year	43.00
615-2408	2408	B	1.2	Manual	2000	No	Yes	No	No	No	Yes	No	No	No	1 Year	49.00
615-2407A	2407A	B	1.2	Auto	3200	Yes	Yes	No	No	No	Yes	No	No	Yes	1 Year	57.68
615-2704C	2704C	E	0.5	Manual	3 1/2	No	No	No	Yes	No	No	Yes	No	No	1 Year	61.66
615-2706B	2706B	E	0.5	Manual	3 1/2	No	No	No	Yes	No	No	Yes	Yes	No	1 Year	81.55
615-2707B	2707B	E	0.5	Manual	3 1/2	No	No	No	Yes	Yes	Yes	Yes	No	No	1 Year	91.00
615-2703C	2703C	E	1.2	Manual	3 1/2	No	No	No	No	No	No	No	No	No	1 Year	43.00
615-2705B	2705B	E	2	Auto	3 3/4	No	No	No	No	No	No	No	No	Yes	1 Year	65.00
615-2708B	2708B	E	2	Auto	3 3/4	Yes	No	No	No	No	No	No	No	Yes	1 Year	95.00
615-2709B	2709B	E	2	Auto	3 3/4	No	No	No	Yes	Yes	No	No	No	Yes	1 Year	99.00
615-330B	330B	F	1	Manual	3 1/2	No	No	No	No	No	No	No	No	Yes	1 Year	98.46
615-350B	350B	F	1	Manual	3 1/2	Yes	Yes	No	No	Yes	No	No	No	Yes	1 Year	163.11
615-369B	369B	F	1	Auto	3 1/2	Yes	Yes	Yes	Yes	Yes	Yes	Yes	No	Yes	1 Year	200.00
615-2860A	2860A	G	0.5	Manual	3 1/2	No	No	No	No	No	No	No	No	Yes	5 Years	105.00
615-388B	388B	H	0.5	Manual	4000	No	No	No	Yes	Yes	Yes	Yes	No	Yes	3 Years	134.27
615-389A	389A	H	0.25	Auto	4000	Yes	Yes	Yes	Yes	Yes	No	No	No	Yes	3 Years	154.16
615-390A	390A	H	0.1	Auto	4000	Yes	Yes	Yes	Yes	Yes	No	No	Yes	Yes	3 Years	174.05
615-391A	391A	H	0.05	Manual	4 1/2	No	Yes	No	No	Yes	Yes	No	No	Yes	3 Years	193.95
615-316	316	I	1	Auto	3 1/2	No	Yes	No	No	No	No	No	No	Yes	1 Year	169.00

BK PRECISION DMM ACCESSORIES

MOUSER STOCK NO.	BK Precision Part No.	Description	Price Each
615-TL-130A	TL-130A	General Purpose DMM Kit Includes soft, flexible silicone lead wire easy movement and Tri-Fold Velcro Pouch for convenient storage.	41.77
615-TL-50	TL-50	Maxi-Pro DMM Kit is voltage and current rated for either electronic or electrical applications. All components compliant to IEC61010-031	68.00
615-1943991	194-039-9-001	Fuse for DMM 2703-2707 - Package of 4	5.92
615-1944191	194-041-9-001	Fuse for DMM 2860 - Package of 4	35.52
615-1944391	194-043-9-001	Fuse for DMM 388-391 - Package of 4	14.80
615-1944491	194-044-9-001	Fuse 2A for DMM's - Package of 4	7.40
615-1944591	194-045-9-001	Fuse 0.5A for DMM 389-391 - Package of 4	5.92
615-2001	TL-1	Standard test leads, economical replacement test leads, TL-1 has safety shrouded banana plugs	8.50
615-2002	TL-2A	Deluxe test lead set, IEC61010 1000V CATIII rating silicone lead wire length 60" black alligator clip included. Threaded tips fits TL-3	20.80
615-2003	TL-3	Probe Accessory kit black and red pairs alligator clip, red only spring hook clips 4" sharp extension tips No. 10 spade lugs	17.00
615-2103	CP-3	DC/AC current clamp adapter Converts any DMM to a current clamp, measures current without disconnecting circuit under test to 400A DC/AC	89.44
615-2129B	LG-29B	DMM case, light weight, durable Cordura nylon, protects your instruments, room to hold your test leads	17.65
615-2144	HV-44A	High-voltage probe/meter 0-40,000V	119.00

BK PRECISION BENCH MULTIMETERS

4 1/2 Digit True RMS Bench Digital Multimeter

The model 2831D provides versatility and reliability for a broad spectrum of laboratory and service applications.

Features:

- True RMS for accurate interpretation of any waveform signal
- 4 1/2 Digit LED display for clear reading in darkest environment
- Great overload protection on all ranges
- Voltage measurements up to 1200VDC and 1000VAC
- Current measurements up to 20A AC/DC
- Basic accuracy for DCV is 0.05%



B&K Part Number 2831D

615-2831D	True RMS Bench Digital Multimeter	317.28
-----------	-----------------------------------	--------

5 1/2 Digit Dual Display Bench DMM with 0.012% Basic Accuracy

Applications:

The Dual Display Multimeter model 5492 is a 5 1/2 digit multimeters with selectable count resolutions up to 120,000 count. It is designed for bench-top, field service, and system applications with a high performance to price ratio. One set of TL 36 Test Leads and AC 01 caps for TL 36 are included with each 5492.

Features:

- Selectable count resolutions of 120,000, 40,000 and 4,000 count
- Selectable 2 wire and 4 wire resistance measurements
- Measure frequency to 1MHz with 0.01Hz best resolution
- RS-232 interface
- GPIB option available



B&K Part Number 5492

615-5492		721.10
----------	--	--------

50,000 Count Digit Dual Display Bench Multimeter

The model 5491A is a very accurate 50,000 count, dual display, true RMS bench multimeter.

Features:

- Low cost and high performance
- True RMS(AC, AC + DC)
- Resistance measurements up to 50M ohms
- Measures frequency to 500KHZ
- dBm measurement
- RS 232 interface



B&K Part Number 5491A

615-5491A		419.00
-----------	--	--------

Test Equipment