


FLUKE Test Equipment

FLUKE®

FLUKE MULTIMETERS

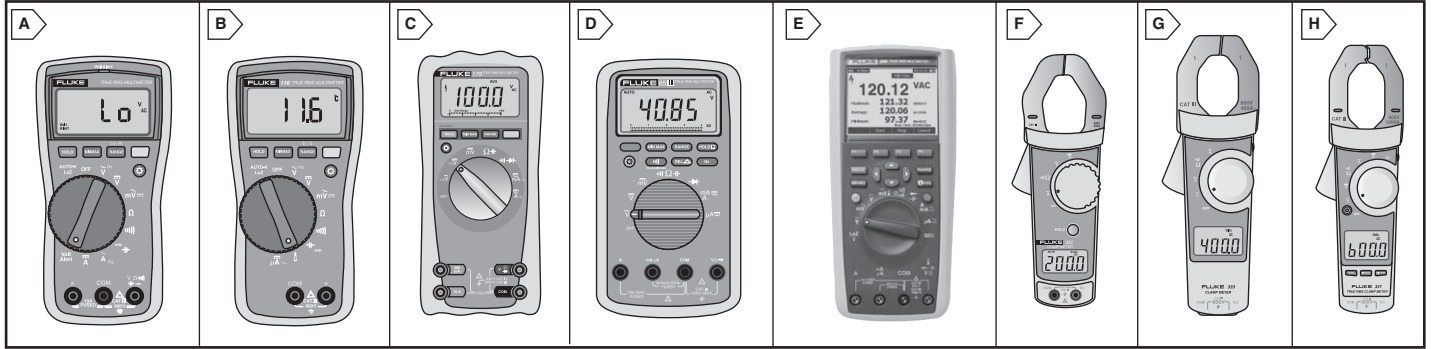

Fluke Digital Multimeters

MOUSER STOCK NO.	Fig.	DCV Accuracy	Ranging	Display LCD	Analog Bar Graph	PC Interface	Memory	Logging	Cap	Frequency	Safety Rating CAT III	Safety Rating CAT IV	Temp.	Warranty	Price Each
Mfr. Mfr. Part Number															
676—115	A	0.5	Manual or Auto	6000	Yes	No	No	No	Yes	Yes	600V	No	No	3 years	156.95
676—117	A	0.5	Manual or Auto	6000	Yes	No	No	No	Yes	Yes	600V	No	No	3 years	186.95
676—114	B	0.5	Manual or Auto	6000	Yes	No	No	No	No	No	600V	No	No	3 years	129.95
676—116	B	0.5	Manual or Auto	6000	Yes	No	No	No	Yes	Yes	600V	No	Yes	3 years	176.95
676—77-4	C	0.3	Manual or Auto	3200	Yes	No	No	No	Yes	Yes	1000V	600V	No	Lifetime	249.95
676—175	C	0.15	Manual or Auto	6000	Yes	No	No	No	Yes	Yes	1000V	600V	No	Lifetime	237.95
676—177	C	0.09	Manual or Auto	6000	Yes	No	No	No	Yes	Yes	1000V	600V	No	Lifetime	247.95
676—179	C	0.09	Manual or Auto	6000	Yes	No	No	No	Yes	Yes	1000V	600V	Yes	Lifetime	257.95
676—83-5	D	0.1	Manual or Auto	20000	Yes	No	No	No	Yes	Yes	1000V	600V	No	Lifetime	369.95
676—87-5	D	0.05	Manual or Auto	20000	Yes	No	No	No	Yes	Yes	1000V	600V	Yes	Lifetime	379.95
676—287	E	0.025	Manual or Auto	50000	Yes	Yes	Yes	Yes	Yes	Yes	1000V	600V	Yes	Lifetime	464.95
676—289	E	0.025	Manual or Auto	50000	Yes	Yes	Yes	Yes	Yes	Yes	1000V	600V	Yes	Lifetime	544.95

Fluke Clamp Meters

MOUSER STOCK NO.	Fig.	DCV Accuracy	Ranging	Display LCD	Res.	Data Hold	Back Light	In Rush	Min./Max.	Frequency	Safety Rating CAT III	Auto Off	Cont.	Warranty	Price Each
Mfr. Mfr. Part Number															
676—322	F	1% ± 5 counts	Auto	4000	Yes	Yes	No	No	No	No	600V	Yes	Yes	2 Years	111.95
676—334A	G	1% ± 5 counts	Auto	6000	Yes	Yes	Yes	Yes	No	No	600V	Yes	Yes	3 Years	171.95
676—335A	G	1% ± 5 counts	Auto	6000	Yes	Yes	Yes	Yes	No	No	600V	Yes	Yes	3 Years	231.95
676—337A	H	1% ± 5 counts	Auto	6000	Yes	Yes	Yes	Yes	Yes	Yes	600V	Yes	Yes	3 Years	368.95

Fluke Accessories

* SureGrip clips and probes require SureGrip test leads

MOUSER STOCK NO.	Description	Recommended For Fluke Model	Price Each
Mfr. Mfr. Part Number			
Clips, Probes, and Leads			
*676—AC220	SureGrip Alligator Clips	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 287, 289, 333, 334, 335, 336, 337	30.10
*676—AC280	SureGrip™ Hook Clips use with TL222 Test Leads	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 287, 289	26.45
*676—AC283	SureGrip™ Pincer Clips use with TL222 Test Leads	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 287, 289	30.10
*676—AC285	SureGrip Alligator Clips	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 287, 289, 333, 334, 335, 336, 337	18.05
*676—TP220	SureGrip Industrial Test Probes	73-3, 83-5, 87-5, 114, 115, 117, 175, 177, 179, 287, 289	14.45
*676—TL221	SureGrip Test Lead Extension Set	73-3, 114, 115, 116, 117, 175, 177, 179, 287, 289	22.85
676—TL220	SureGrip Industrial Test Lead Set	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 287, 289	59.10
676—TL910	Electronic Test Probe	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 287, 289	50.60
676—TP920	Test Probe Adapter	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 287, 289	31.30
676—TL222	SureGrip™ Silicone Test Leads (right angle)	73-3, 83-5, 87-5, 114, 115, 117, 175, 179, 322, 334, 335, 336, 337	22.85
676—TL223	SureGrip Electrical Test Lead Set	73-3, 114, 115, 117, 175, 177, 179, 287, 289, 322, 333, 334, 335, 336, 337	59.10
676—TL224	SureGrip™ Silicone Test Leads	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 287, 289, 333, 334, 335, 336, 337	22.85
676—TL40	Retractable Tip Test Lead Set Recommended Y8140A Replacement	73-3, 83-5, 87-5, 114	34.85
676—TL71	Precision Probe Assembly; Recommended for μV Measurements	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 333, 334, 335, 336, 337	21.65
676—TL75	Hardpoint Test Leads Set; Extremely Hard Alloy Tips	73-3, 83-5, 87-5, 114, 115, 117, 175, 177, 179, 333, 334, 335, 336, 337	18.05
676—TL80A	Basic Electronic Test Lead Set	73-3, 83-5, 87-5, 114	56.60
676—TL238	Suregrip Test Lead Set For High Energy	73-3, 83-5, 87-5, 114, 115, 117, 175, 177, 179, 333, 334, 335, 336, 337	58.45
Current Clamps			
676—I200	200 Amp Clamp; Compatible with any Fluke Multimeter	73-3, 83-5, 87-5, 114, 116, 175, 177, 179	121.65
676—I400	Current Probe; Compatible with any Fluke Multimeter	83-5, 87-5, 175, 177, 179, 287, 289	121.65
676—I410-KIT	AC/DC Current Clamp with Carry Case	73-3, 83-5, 87-5, 114, 116, 175, 177, 179	240.95
676—I1010-KIT	AC/DC Current Clamp with Meter Carry Case	73-3, 83-5, 87-5, 114, 116, 175, 177, 179	337.40
Cases and Holsters			
676—C12A	Soft Carrying Case	114, 115, 116, 117, 73-3, 83-5, 87-5, 175, 177, 179	23.85
676—C25	Soft Case; Zippered Softcase	114, 115, 116, 117, 175, 177, 179, 83-5, 87-5, 73-3	31.00
676—C50	Vinyl Case with Belt Loop	73-3, 114, 115, 116, 117	29.85
676—C90	Soft Case for DMM's	73-3, 114, 115, 117, 175, 177, 179	29.65
676—C125	Compact Soft Case for 120 Series ScopeMeter Test Tools	123, 124	32.00
676—C781	Soft Case	287, 289	47.65
676—C550	Heavy Duty Tool Bag	289	77.50
Meter Accessories			
676—87RETRO	Retrofit Kit for FLUKE 83, 85, 87-3, 787 Meters	83-5, 87-5	108.40
676—C1600	Meter Gear Box	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 333, 334, 335, 336, 337	47.20
676—TPAK	Meter Hanging Kit; Universal Hanger	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 287, 289	33.15
676—TLK287	Electronics Master Test Lead Set	73-3, 83-5, 87-5, 114, 115, 116, 117, 175, 177, 179, 289	119.55
676—TLK289	Industrial Master Test Lead Set	73-3, 83-5, 87-5, 114, 115, 116, 117, 179, 289	119.55
676—TLK-220	SureGrip Accessory Set	289, 87-5, 116, 179, 287	117.00
676—TLK-225	SureGrip Master Accessory Set	73-3, 83-5, 87-5, 114, 115, 117, 175, 177, 179	117.00
Probes, Adapters, Plugs, and Kits			
676—80PK-1	Probe, Thermocouple, Beaded K-type	175, 177, 179	24.25
676—80TK	Thermocouple Module, Converts any Fluke DMM to a Thermometer	73-3, 83-5, 87-5, 114, 115, 117, 175, 177, 179	109.45