

POMONA Test Clips and Enclosures



Pomona TEST LEAD HOLDERS AND PATCH CORDS KITS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Max Cable Dia. (in.)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
565—1508		A	Test lead holder, orange	0.210	11.50	10.93	10.38
565—2708		A	Test lead holder, blue	0.450	11.51	10.93	10.39
565—4408		A	Test lead holder, black	0.320	9.40	8.94	8.54
565—5523		B	Patch cord Kit: 10pcs, 1 ea. Standard color.	-	39.87	37.88	35.98

Pomona GRABBERS AND TEST CLIPS

Replace blank with 0 for Black, 2 for Red. For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Max Wire Dia. (in.)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
565—3925		C	Do-it-yourself Minigrabber test clip .09Ga	0.09	1.70	1.62	1.54
565—4555		C	Do-it-yourself Minigrabber test clip .144Ga	0.14	1.83	1.74	1.65
565—4233		D	Do-it-yourself Micrograbber test clip	0.10	2.09	1.99	1.89
565—5243		E	Do-it-yourself SMD Grabber test clip	0.05	2.30	2.19	2.08
565—4723		F	Minigrabber test clip with banana Jack	0.15	5.04	4.79	4.55

Pomona TEST CLIPS

Replace blank with 0 for Black, 2 for Red. For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Max Wire Dia. (in.)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
565—5788		G	Miniature alligator to 2mm banana jack	0.24	2.08	2.02	1.92
565—6041B		G	XL pair (red/black) alligator clip to 4mm banana jack	0.80	11.34	10.77	10.23
565—2240		H	Alligator test clip to banana jack, with insulator	0.30	.78	.74	.71

Pomona MICRO SMD GRABBER TEST CLIPS

Replace blank with 0 for Black, 2 for Red. For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Length (in.)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
565—6490		I	Micro SMD Grabber Test Clip for 0.05 to 0.02in.	-	29.22	27.83	26.44
565—4771-36		J	Order to attach SMD Grabber Test Clip to DMM.	-	6.74	6.42	6.10

Pomona TELECOM PRODUCTS (BANTAM PLUGS)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Length (in.)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
565—4279-12		K	Bantam plug patch cable	12	28.86	27.49	26.12
565—4279-24		K	Bantam plug patch cable	24	28.86	27.49	26.12
565—4279-36		K	Bantam plug patch cable	36	28.86	27.49	26.12
565—4279-48		K	Bantam plug patch cable	48	30.94	29.47	28.00
565—4279-60		K	Bantam plug patch cable	60	30.94	29.47	28.00
565—5026-36		L	Bantam plug to 2 alligator clips patch cable	36	34.80	33.14	31.48
565—5026-60		L	Bantam plug to 2 alligator clips patch cable	60	36.61	34.87	33.13
565—4281-60		M	Bantam plug to double banana plug, balanced line	60	48.14	45.85	43.56

Pomona BOXES AND ENCLOSURES

Miniature Size Die Cast Aluminum Boxes (1.5" x 1.13" x .88")

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Price Each		
Mfr.	Mfr. Part No.			1	25	50
565—3752		N	Blue Bake Enamel Finish BNC (FML) to BNC(Male)	29.12	27.73	26.34
565—3753		N	Blue Bake Enamel Finish	8.35	7.95	7.55
565—3754		N	Unfinished	5.77	5.48	5.21
565—4742		-	Replacement Cover	3.63	3.46	3.29
565—4864		-	Cover Screws, 100/Package	17.87	17.02	16.17

'A' Size Die Cast Aluminum Boxes (2.25" x 1.13" x .88")

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Price Each		
Mfr.	Mfr. Part No.			1	25	50
565—2400		O	Unfinished	7.28	6.93	6.58
565—2397		O	Blue Bake Enamel Finish	8.66	8.25	7.84
565—2390		O	Blue Bake Enamel Finish BNC (FML) to BNC(FML)	27.02	25.73	24.44
565—2391		O	Blue Bake Enamel Finish BNC (Male) to BNC(FML)	28.04	26.64	25.31
565—4245		-	Replacement Cover	3.63	3.46	3.29
565—3728		-	Flange Mounting Cover	9.43	8.56	8.29
565—4864		-	Cover Screws, 100/Package	17.87	17.02	16.17

'B' Size Die Cast Aluminum Boxes (2.25" x 1.38" x 1.13")

For quantities greater than listed, call for quote.


MOUSER STOCK NO.		Fig.	Description	Price Each		
Mfr.	Mfr. Part No.			1	25	50
565—2417		O	Blue Bake Enamel Finish	8.60	8.19	7.78
565—2428		O	Unfinished	7.81	7.44	7.07
565—3230		O	Blue Bake Enamel Finish BNC (FML) to BNC(FML)	25.05	23.86	22.67
565—4246		-	Replacement Cover	3.63	3.46	3.29
565—3719		-	Flange Mounting Cover	5.13	4.89	4.65
565—4864		-	Cover Screws, 100/Package	17.87	17.02	16.17

'C' Size Die Cast Aluminum Boxes With Cover (4.25" x 2.64" x 1.71")

MOUSER STOCK NO.		Fig.	Description	Price Each		
Mfr.	Mfr. Part No.			1	25	50
565—2901		P	Blue Bake Enamel Finish	19.89	18.92	18.07
565—2906		P	Unfinished	16.68	15.87	15.05
565—2902		P	Blue Bake Enamel Finish BNC (FML) to BNC(FML)	40.15	38.24	36.33
565—4248		-	Replacement Cover	5.99	5.70	5.42
565—2352		-	Connector Screws with Solder Turret for all Boxes	64.21	61.15	58.09

'D' Size Die Cast Aluminum Boxes With Cover (3.00" x 2.63" x 1.65")

MOUSER STOCK NO.		Fig.	Description	Price Each		
Mfr.	Mfr. Part No.			1	25	50
565—3606		O	Shielded Box, Unfinished with Cover	14.34	13.66	12.98

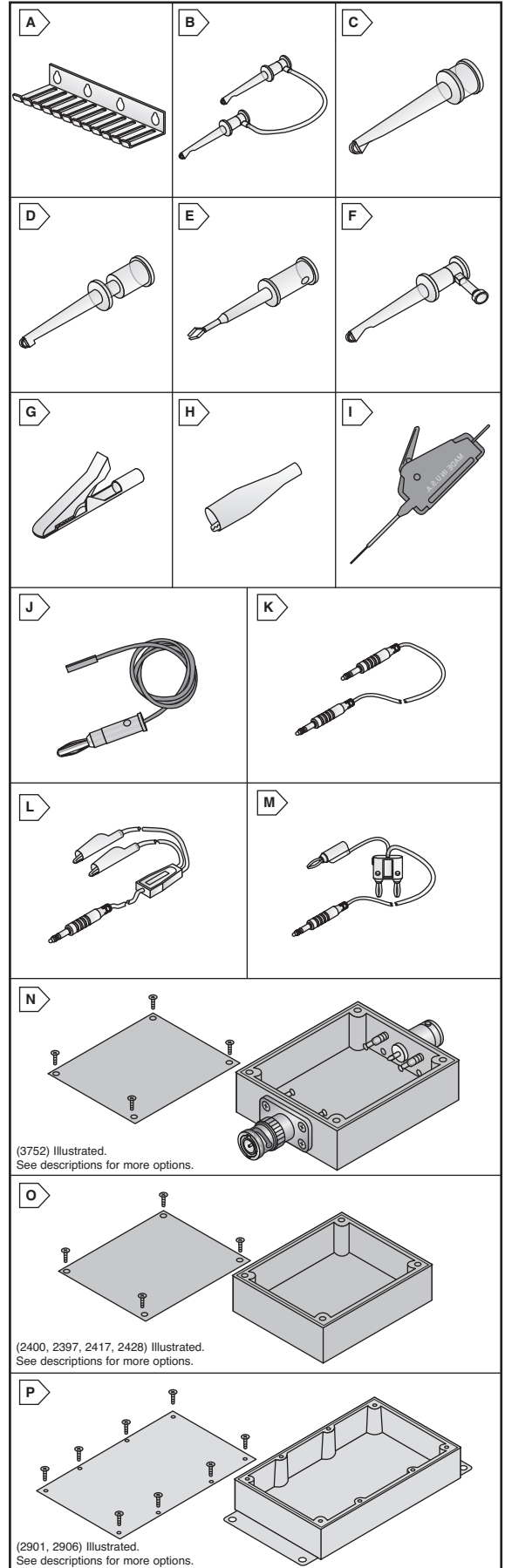

(3752) Illustrated. See descriptions for more options.

(2400, 2397, 2417, 2428) Illustrated. See descriptions for more options.

(2901, 2906) Illustrated. See descriptions for more options.